
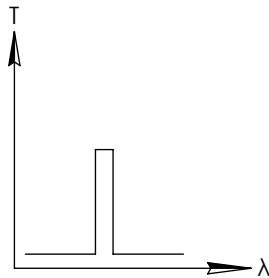
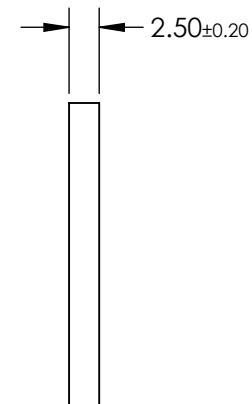
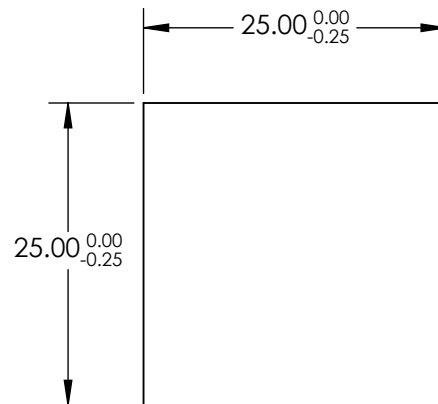


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

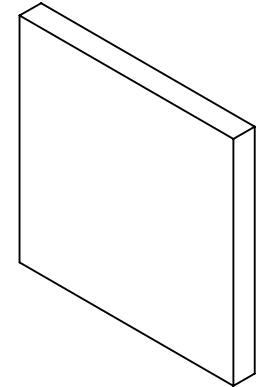

BANDPASS FILTER

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

| | VALUE |
|---------------------------------|----------------------|
| SHAPE | PLANO |
| CENTER WAVELENGTH (nm) | 460 |
| FULL WIDTH HALF MAX (FWHM) (nm) | 200 |
| SURFACE QUALITY | 80-50 |
| CAOTING TYPE | Uncoated |
| BEVEL | PROTECTIVE AS NEEDED |



| | | | |
|--------|--|--------------|--|
| TITLE | HOYA B-460 (UV-VIS) 25mm Square, Colored Glass Bandpass Filter | | |
| DWG NO | 34444 | SHEET 1 OF 1 | |

ALL DIMS IN

mm

DWG NO

34444

SHEET 1 OF 1