
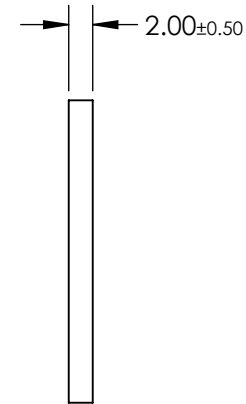
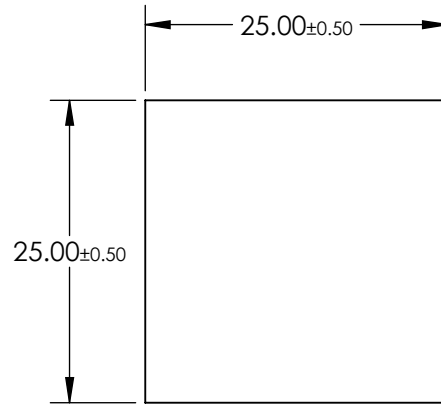


**FOR INFORMATION ONLY:
DO NOT MANUFACTURE
PARTS TO THIS DRAWING**

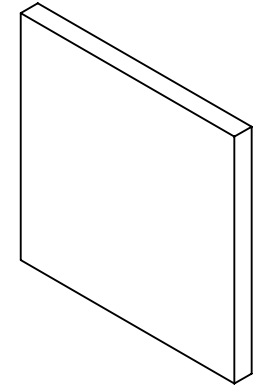

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	300
WAVELENGTH RANGE (nm)	250 - 500
BLAZE ANGLE	8.6°
RoHS	COMPLIANT

EO[®] Edmund Optics[®]



ALL DIMS IN mm

TITLE

300 Grooves/mm, 25mm Sq, UV Transmission
Grating Beamsplitter

DWG NO

85291

SHEET
1 OF 1