
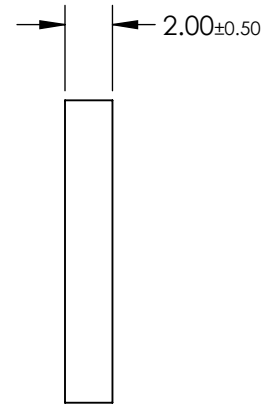
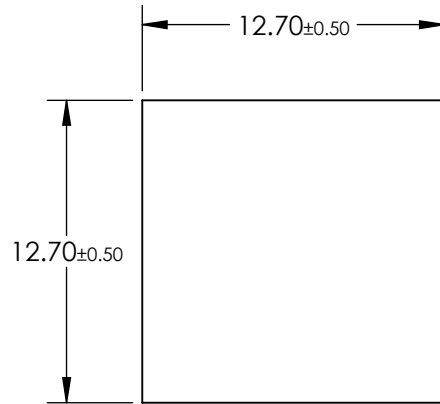
 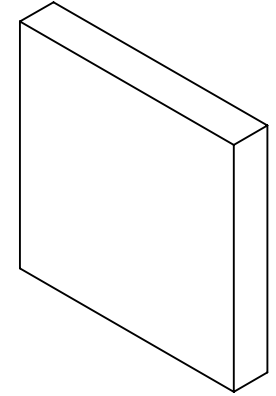


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**



SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

SUBSTRATE	Fused Silica
GROOVE DENSITY (grooves/mm)	1200
WAVELENGTH RANGE (nm)	250 - 450
BLAZE ANGLE	26.7°
RoHS	COMPLIANT

THIRD ANGLE PROJECTION 

ALL DIMS IN mm

**EO**® **Edmund Optics**®

TITLE	1200 Grooves/mm, 12.7mm Sq, UV Transmission Grating Beamsplitter	
DWG NO	85290	SHEET 1 OF 1