


NOTES:

- 1. RoHS: EXEMPT


**FOR INFORMATION ONLY:  
DO NOT MANUFACTURE  
PARTS TO THIS DRAWING**

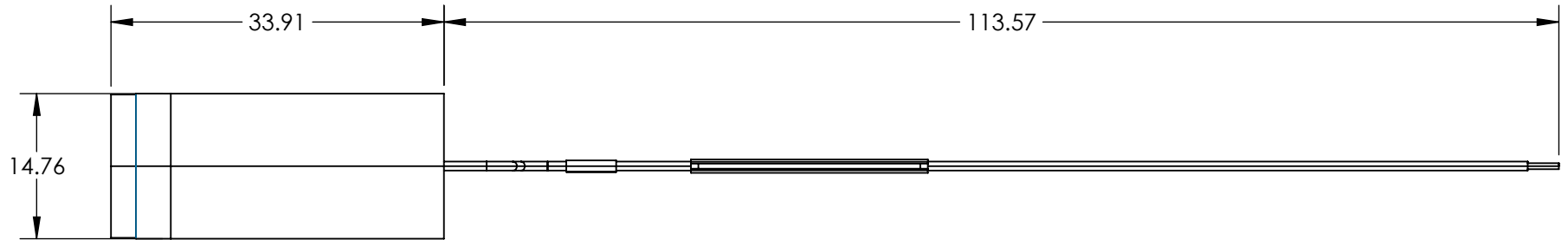

	VALUE
DESIGN WAVELENGTH (nm)	670.0
OUTPUT POWER (mW)	0.95
BEAM DIAMETER (mm)	1.1 @ MODULE FACE
COLOR	RED
LASER CLASS - CDRH	II
POINTING ACCURACY (mrad)	<4
POWER REQUIREMENT	5-10V DC
TYPE	DIODE

SPECIFICATIONS SUBJECT TO CHANGE WITHOUT NOTICE  
DIMENSIONS ARE FOR REFERENCE ONLY

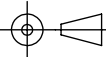

THIRD ANGLE PROJECTION 	TITLE	COHERENT® VHK™ CIRCULAR BEAM VISIBLE LASER DIODE 0222-152-01   0.95mW 670nm	
	ALL DIMS IN	mm	DWG NO 54019