

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Longpass Filters](#)

Hoya Colored Glass Longpass Filters

See More by [Hoya](#)



- UV, VIS and IR Pass Ranges
- VIS Can Be Used for Color Bandpass
- Also Available [Mounted](#)

Common Specifications


Physical & Mechanical Properties

Bevel:	Protective as needed
--------	----------------------


Optical Properties

Substrate:	Colored Glass
Coating:	Uncoated

Technical Information

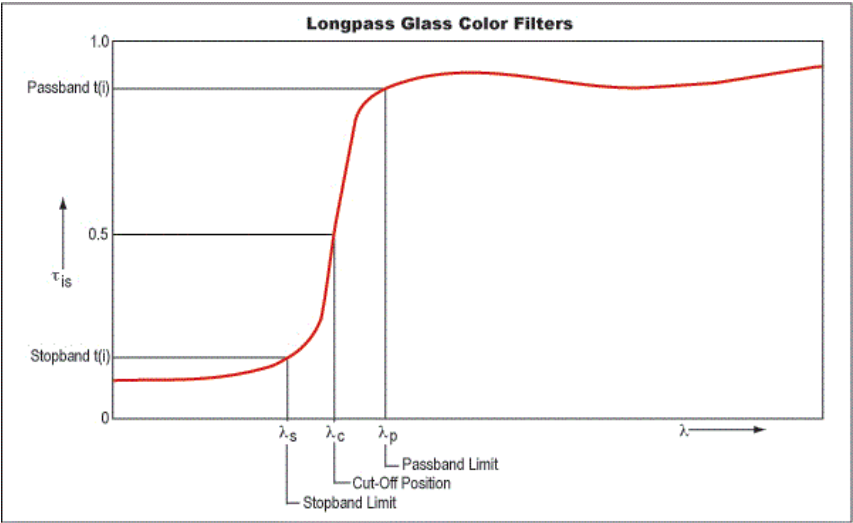

Hoya Colored Glass Longpass Filters

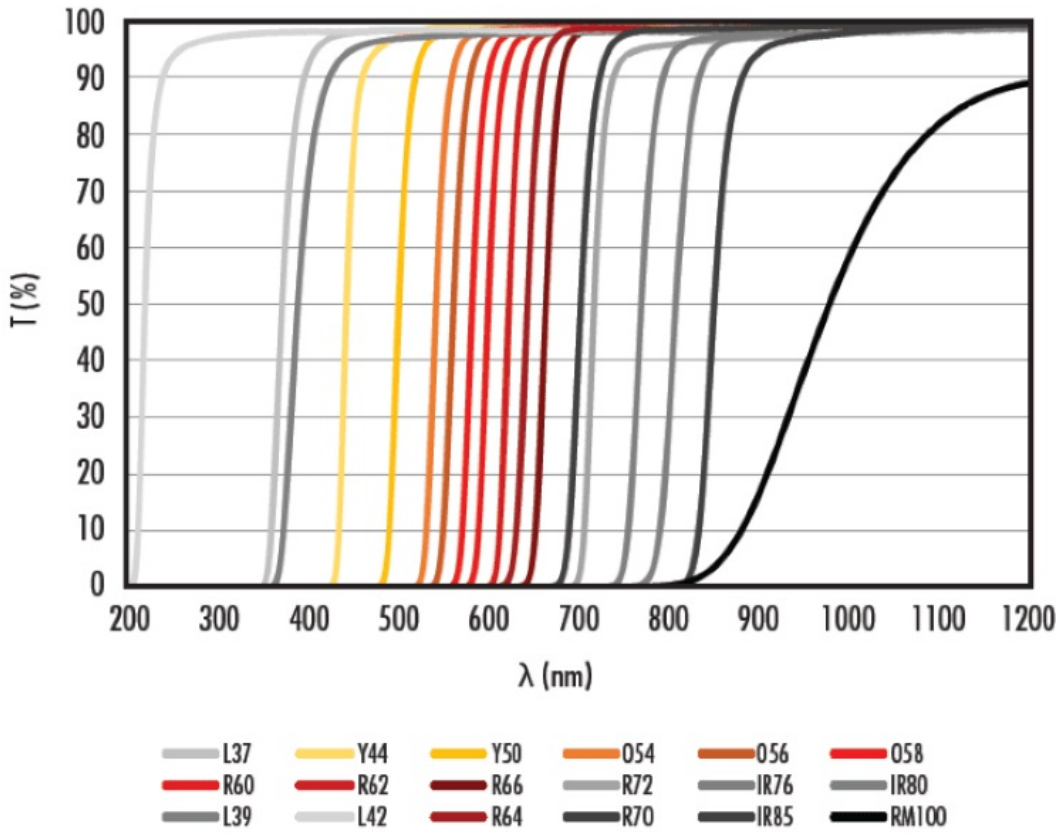

Products

Dimensions (mm)	Dia. (mm)	Glass/Filter Number	Cut-On Wavelength (nm)	Thickness (mm)	Stock Number	Price	Buy
-	12.50	Hoya UV28N	280.00	1.00	#18-791	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya UV28N	280.00	2.50	#18-792	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya UV28N	280.00	1.00	#18-793	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya UV28N	280.00	2.50	#18-794	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya UV28N	280.00	1.00	#18-795	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya UV28N	280.00	2.50	#18-796	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV28N	280.00	1.00	#18-797	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV28N	280.00	2.50	#18-798	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya UV30N	300.00	1.00	#18-799	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya UV30N	300.00	2.50	#18-800	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya UV30N	300.00	1.00	#18-801	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya UV30N	300.00	2.50	#18-802	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya UV30N	300.00	1.00	#18-803	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya UV30N	300.00	2.50	#18-804	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV30N	300.00	1.00	#18-805	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV30N	300.00	2.50	#18-806	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya UV32N	320.00	1.00	#18-807	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya UV32N	320.00	2.50	#18-808	€33,00 Qty 11+ €29,00	3-4 days

-	25.40	Hoya UV32N	320.00	1.00	#18-809	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya UV32N	320.00	2.50	#18-810	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya UV32N	320.00	1.00	#18-811	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya UV32N	320.00	2.50	#18-812	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV32N	320.00	1.00	#18-813	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV32N	320.00	2.50	#18-814	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya UV34N	340.00	1.00	#18-815	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya UV34N	340.00	2.50	#18-816	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya UV34N	340.00	1.00	#18-817	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya UV34N	340.00	2.50	#18-818	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya UV34N	340.00	1.00	#18-819	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya UV34N	340.00	2.50	#18-820	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV34N	340.00	1.00	#18-821	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV34N	340.00	2.50	#18-822	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya UV36N	360.00	1.00	#18-823	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya UV36N	360.00	2.50	#18-824	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya UV36N	360.00	1.00	#18-825	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya UV36N	360.00	2.50	#18-826	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya UV36N	360.00	1.00	#18-827	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya UV36N	360.00	2.50	#18-828	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya UV36N	360.00	1.00	#18-829	€92,00 Qty 11+ €81,00	Contact Us

50.8 x 50.8	-	Hoya UV36N	360.00	2.50	#18-830	€92,00 Qty 11+ €81,00	Contact Us
-	12.50	Hoya L37	370.00	2.50	#66-038	€33,00 Qty 11+ €29,00	In Stock
-	25.40	Hoya L37	370.00	2.50	#66-049	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya L37	370.00	2.50	#66-060	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya L37	370.00	2.50	#66-075	€92,00 Qty 11+ €81,00	3-4 days
#66-076 Clearance							
× Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
-	50.00	Hoya L38	380.00	2.50		€29,95	3-4 days
-	12.50	Hoya L38	380.00	1.00	#18-831	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya L38	380.00	2.50	#18-832	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya L38	380.00	1.00	#18-833	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya L38	380.00	2.50	#18-834	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya L38	380.00	1.00	#18-835	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya L38	380.00	2.50	#18-836	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L38	380.00	1.00	#18-837	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L38	380.00	2.50	#18-838	€92,00 Qty 11+ €81,00	Contact Us

-	12.50	Hoya L39	390.00	1.00	#18-839	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya L39	390.00	2.50	#18-840	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya L39	390.00	1.00	#18-841	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya L39	390.00	2.50	#18-842	€46,00 Qty 26+ €41,00	Contact Us
-	50.00	Hoya L39	390.00	1.00	#18-843	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya L39	390.00	2.50	#18-844	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L39	390.00	1.00	#18-845	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L39	390.00	2.50	#18-846	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya L42	420.00	1.00	#18-847	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya L42	420.00	2.50	#18-848	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya L42	420.00	1.00	#18-849	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya L42	420.00	2.50	#18-850	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya L42	420.00	1.00	#18-851	€92,00 Qty 11+ €81,00	Contact Us
-	50.00	Hoya L42	420.00	2.50	#18-852	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L42	420.00	1.00	#18-853	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya L42	420.00	2.50	#18-854	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya Y44	440.00	1.00	#18-855	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya Y44	440.00	2.50	#18-856	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya Y44	440.00	1.00	#18-857	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya Y44	440.00	2.50	#18-858	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya Y44	440.00	1.00	#18-859	€92,00 Qty 11+ €81,00	3-4 days

-	50.00	Hoya Y44	440.00	2.50	#18-860	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya Y44	440.00	1.00	#18-861	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya Y44	440.00	2.50	#18-862	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya Y48	480.00	1.00	#18-863	€33,00 Qty 11+ €29,00	Contact Us
-	12.50	Hoya Y48	480.00	2.50	#18-864	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya Y48	480.00	1.00	#18-865	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya Y48	480.00	2.50	#18-866	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya Y48	480.00	1.00	#18-867	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya Y48	480.00	2.50	#18-868	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya Y48	480.00	1.00	#18-869	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya Y48	480.00	2.50	#18-870	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya Y50	500.00	2.50	#66-039	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya Y50	500.00	2.50	#66-050	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya Y50	500.00	2.50	#66-061	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya Y50	500.00	2.50	#66-084	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya Y52	520.00	1.00	#18-871	€33,00 Qty 11+ €29,00	Contact Us
-	12.50	Hoya Y52	520.00	2.50	#18-872	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya Y52	520.00	1.00	#18-873	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya Y52	520.00	2.50	#18-874	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya Y52	520.00	1.00	#18-875	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya Y52	520.00	2.50	#18-876	€92,00 Qty 11+ €81,00	3-4 days

50.8 x 50.8	-	Hoya Y52	520.00	1.00	#18-877	€92,00 Qty 11+ €81,00	Contact Us
50.8 x 50.8	-	Hoya Y52	520.00	2.50	#18-878	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya O54	540.00	2.50	#66-040	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya O54	540.00	2.50	#66-051	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya O54	540.00	2.50	#66-062	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya O54	540.00	2.50	#66-087	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya O56	560.00	2.50	#66-041	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya O56	560.00	2.50	#66-052	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya O56	560.00	2.50	#66-063	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya O56	560.00	2.50	#66-089	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya O58	580.00	2.50	#66-042	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya O58	580.00	2.50	#66-053	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya O58	580.00	2.50	#66-091	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya R60	600.00	2.50	#66-043	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya R60	600.00	2.50	#66-054	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya R60	600.00	2.50	#66-065	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya R60	600.00	2.50	#66-093	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya R62	620.00	2.50	#66-044	€33,00 Qty 11+ €29,00	In Stock
-	25.40	Hoya R62	620.00	2.50	#66-055	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya R62	620.00	2.50	#66-066	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya R62	620.00	2.50	#66-095	€92,00 Qty 11+ €81,00	3-4 days

-	12.50	Hoya R64	640.00	1.00	#18-879	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya R64	640.00	2.50	#18-880	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya R64	640.00	1.00	#18-881	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya R64	640.00	2.50	#18-882	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya R64	640.00	1.00	#18-883	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya R64	640.00	2.50	#18-884	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya R64	640.00	1.00	#18-885	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya R64	640.00	2.50	#18-886	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya R66	660.00	2.50	#66-045	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya R66	660.00	2.50	#66-056	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya R66	660.00	2.50	#66-067	€92,00 Qty 11+ €81,00	In Stock
-	50.00	Hoya R66	660.00	2.50	#66-098	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya R70	700.00	1.00	#18-887	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya R70	700.00	2.50	#18-888	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya R70	700.00	1.00	#18-889	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya R70	700.00	2.50	#18-890	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya R70	700.00	1.00	#18-891	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya R70	700.00	2.50	#18-892	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya R70	700.00	1.00	#18-893	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya R70	700.00	2.50	#18-894	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya R72	720.00	2.50	#66-046	€33,00 Qty 11+ €29,00	3-4 days

-	25.40	Hoya R72	720.00	2.50	#66-057	€46,00 Qty 11+ €41,00	In Stock
50.8 x 50.8	-	Hoya R72	720.00	2.50	#66-068	€92,00 Qty 11+ €81,00	In Stock
-	50.00	Hoya R72	720.00	2.50	#66-102	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya IR76N	760.00	2.50	#66-047	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya IR76N	760.00	2.50	#66-058	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya IR76N	760.00	2.50	#66-069	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya IR76N	760.00	2.50	#66-103	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya IR80N	800.00	2.50	#66-048	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya IR80N	800.00	2.50	#66-059	€46,00 Qty 11+ €41,00	3-4 days
50.8 x 50.8	-	Hoya IR80N	800.00	2.50	#66-070	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya IR80N	800.00	2.50	#66-105	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya IR83N	830.00	1.00	#18-895	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya IR83N	830.00	2.50	#18-896	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya IR83N	830.00	1.00	#18-897	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya IR83N	830.00	2.50	#18-898	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya IR83N	830.00	1.00	#18-899	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya IR83N	830.00	2.50	#18-900	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya IR83N	830.00	1.00	#18-901	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya IR83N	830.00	2.50	#18-902	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya IR85N	850.00	1.00	#18-903	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya IR85N	850.00	2.50	#18-904	€33,00 Qty 11+ €29,00	3-4 days

-	25.40	Hoya IR85N	850.00	1.00	#18-905	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya IR85N	850.00	2.50	#18-906	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya IR85N	850.00	1.00	#18-907	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya IR85N	850.00	2.50	#18-908	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya IR85N	850.00	1.00	#18-909	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya IR85N	850.00	2.50	#18-910	€92,00 Qty 11+ €81,00	3-4 days
-	12.50	Hoya RM100	1,000.00	1.00	#18-911	€33,00 Qty 11+ €29,00	3-4 days
-	12.50	Hoya RM100	1,000.00	2.50	#18-912	€33,00 Qty 11+ €29,00	3-4 days
-	25.40	Hoya RM100	1,000.00	1.00	#18-913	€46,00 Qty 11+ €41,00	3-4 days
-	25.40	Hoya RM100	1,000.00	2.50	#18-914	€46,00 Qty 11+ €41,00	3-4 days
-	50.00	Hoya RM100	1,000.00	1.00	#18-915	€92,00 Qty 11+ €81,00	3-4 days
-	50.00	Hoya RM100	1,000.00	2.50	#18-916	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya RM100	1,000.00	1.00	#18-917	€92,00 Qty 11+ €81,00	3-4 days
50.8 x 50.8	-	Hoya RM100	1,000.00	2.50	#18-918	€92,00 Qty 11+ €81,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com