


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)

TECHSPEC®

Precision Optical Flat Mirrors

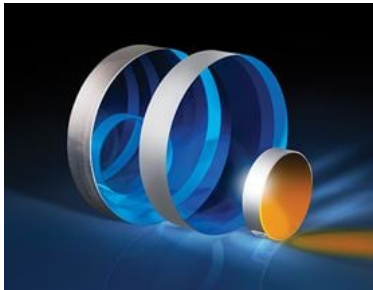

- Fused Silica and ZERODUR® Substrates
- $\lambda/10$ and $\lambda/20$ Surface Flatness
- Variety of Coating Options Offered

Common Specifications

General	
Note: Flatness is specified as Peak to Valley	
Physical & Mechanical Properties	
Back Surface: Commercial Polish	
Optical Properties	
Surface Quality: 60-40	Coating Type: Metal

Technical Information

Products

Surface Flatness (P-V)	Dia. (mm)	Substrate	Coating Specification	Coating	Thickness (mm)	Stock Number	Price	Buy
λ/10	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-319-522	€99,91 Volume Pricing	1 In Stock
λ/20	12.70	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-400-522	€135,96 Volume Pricing	4 In Stock
λ/10	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-327-522	€109,18 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400-2000nm)	3.20	#43-404-522	€155,53 Volume Pricing	4 In Stock
λ/10	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-319-533	€105,06 Volume Pricing	5 In Stock
λ/20	12.70	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-400-533	€141,11 Volume Pricing	20+ In Stock
λ/10	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-327-533	€114,33 Volume Pricing	1 In Stock
λ/20	12.70	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450-650nm)	3.20	#43-404-533	€160,68 Volume Pricing	2 In Stock
λ/10	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-319-566	€120,51 Volume Pricing	20+ In Stock
λ/20	12.70	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-400-566	€156,56 Volume Pricing	Contact Us
λ/10	12.70	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700-10000nm)	3.20	#43-327-566	€129,78 Volume Pricing	Contact Us

$\lambda/20$	12.70	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	3.20	#43-404-566	€176,13 Volume Pricing	7 In Stock
$\lambda/10$	12.70	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-319-577	€115,36 Volume Pricing	20+ In Stock
$\lambda/20$	12.70	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-400-577	€151,41 Volume Pricing	Contact Us
$\lambda/10$	12.70	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-327-577	€124,63 Volume Pricing	Contact Us
$\lambda/20$	12.70	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	3.20	#43-404-577	€170,98 Volume Pricing	2 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#01-913-522	€147,29 Volume Pricing	5 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-408-522	€213,21 Volume Pricing	11 In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#32-195-522	€165,83 Volume Pricing	3 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-412-522	€221,45 Volume Pricing	1 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#01-913-533	€152,44 Volume Pricing	3 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-408-533	€218,36 Volume Pricing	20+ In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#32-195-533	€170,98 Volume Pricing	2 In Stock

$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-412-533	€226,60 Volume Pricing	1 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#01-913-566	€173,04 Volume Pricing	Contact Us
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-408-566	€238,96 Volume Pricing	1 In Stock
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#32-195-566	€191,58 Volume Pricing	6 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-412-566	€247,20 Volume Pricing	6 In Stock
$\lambda/10$	25.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#01-913-577	€193,64 Volume Pricing	4 In Stock
$\lambda/20$	25.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-408-577	€259,56 Volume Pricing	Contact Us
$\lambda/10$	25.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#32-195-577	€212,18 Volume Pricing	6 In Stock
$\lambda/20$	25.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-412-577	€267,80 Volume Pricing	4 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#01-914-522	€246,17 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-416-522	€321,36 Volume Pricing	9 In Stock

$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#32-199-522	€271,92 Volume Pricing	Contact Us
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	12.70	#43-420-522	€370,80 Volume Pricing	5 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#01-914-533	€271,92 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-416-533	€347,11 Volume Pricing	Contact Us
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#32-199-533	€297,67 Volume Pricing	1 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	12.70	#43-420-533	€396,55 Volume Pricing	6 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#01-914-566	€333,72 Volume Pricing	4 In Stock
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-416-566	€408,91 Volume Pricing	10 In Stock
$\lambda/10$	50.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#32-199-566	€359,47 Volume Pricing	1 In Stock
$\lambda/20$	50.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	12.70	#43-420-566	€458,35 Volume Pricing	4 In Stock
$\lambda/10$	50.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#01-914-577	€323,42 Volume Pricing	Contact Us
$\lambda/20$	50.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	12.70	#43-416-577	€398,61 Volume Pricing	3 In Stock

λ/10	50.80	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#32-199-577	€349,17 Volume Pricing	2 In Stock
λ/20	50.80	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	12.70	#43-420-577	€448,05 Volume Pricing	9 In Stock
λ/10	76.20	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#01-915-522	€525,30 Volume Pricing	Contact Us
λ/20	76.20	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#47-573-522	€592,25 Volume Pricing	7 In Stock
λ/10	76.20	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#31-391-522	€654,05 Volume Pricing	1 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#48-117-522	€901,25 Volume Pricing	1 In Stock
λ/10	76.20	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#01-915-533	€576,80 Volume Pricing	2 In Stock
λ/20	76.20	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#47-573-533	€643,75 Volume Pricing	3 In Stock
λ/10	76.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#31-391-533	€705,55 Volume Pricing	3 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#48-117-533	€952,75 Volume Pricing	1 In Stock
λ/10	76.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#01-915-566	€607,70 Volume Pricing	Contact Us
λ/20	76.20	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#47-573-566	€674,65 Volume Pricing	Contact Us

λ/10	76.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#31-391-566	€736,45 Volume Pricing	4 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	19.10	#48-117-566	€983,65 Volume Pricing	Contact Us
λ/10	76.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#01-915-577	€597,40 Volume Pricing	Contact Us
λ/20	76.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#47-573-577	€664,35 Volume Pricing	5 In Stock
λ/10	76.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#31-391-577	€726,15 Volume Pricing	1 In Stock
λ/20	76.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	19.10	#48-117-577	€973,35 Volume Pricing	12 In Stock
λ/10	101.60	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#01-611-522	€942,45 Volume Pricing	1 In Stock
λ/20	101.60	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#47-574-522	€1.019,70 Volume Pricing	9 In Stock
λ/10	101.60	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#31-392-522	€968,20 Volume Pricing	Contact Us
λ/20	101.60	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	19.10	#48-118-522	€1.076,35 Volume Pricing	5 In Stock
λ/10	101.60	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#01-611-533	€993,95 Volume Pricing	5 In Stock
λ/20	101.60	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	19.10	#47-574-533	€1.071,20 Volume Pricing	2 In Stock

$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#31-392-533	€1.019,70 Volume Pricing	1 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	19.10	#48-118-533	€1.127,85 Volume Pricing	1 In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#01-611-566	€1.035,15 Volume Pricing	5 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#47-574-566	€1.112,40 Volume Pricing	3 In Stock
$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#31-392-566	€1.060,90 Volume Pricing	4 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	19.10	#48-118-566	€1.169,05 Volume Pricing	20+ In Stock
$\lambda/10$	101.60	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#01-611-577	€1.019,70 Volume Pricing	4 In Stock
$\lambda/20$	101.60	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#47-574-577	€1.096,95 Volume Pricing	4 In Stock
$\lambda/10$	101.60	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#31-392-577	€1.045,45 Volume Pricing	2 In Stock
$\lambda/20$	101.60	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	19.10	#48-118-577	€1.153,60 Volume Pricing	3 In Stock

[#71-130-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	€1.581,05 Volume Pricing	1 In Stock
--------------	--------	--------------------------------	---	------------------------------------	-------	---	------------

[#71-247-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	88.90	€14.574,50	Contact Us
--------------	--------	----------	---	------------------------------------	-------	------------	------------

[#71-130-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	25.40	€1.668,60 Volume Pricing	1 In Stock
--------------	--------	--------------------------------	-----------------------------------	----------------------------------	-------	---	------------

[#71-130-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700-10000nm)	25.40	€1.725,25 Volume Pricing	1 In Stock
--------------	--------	--------------------------------	---	---------------------------------	-------	---	------------

[#71-130-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	25.40
--------------	--------	--------------------------------	---	-----------------------------------	-------

€1.699,50
[Volume Pricing](#)

1 In Stock

[#71-131-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40
--------------	--------	--------------------------------	---	------------------------------------	-------

€2.096,05
[Volume Pricing](#)

1 In Stock

[#71-131-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	25.40
--------------	--------	--------------------------------	-----------------------------------	----------------------------------	-------

€2.183,60
[Volume Pricing](#)

1 In Stock

[#71-247-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	88.90	€14.626,00	Contact Us
--------------	--------	----------	--------------------------------	-------------------------------	-------	------------	------------

[#71-131-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	€2.240,25 Volume Pricing	1 In Stock
--------------	--------	-----------------------------	---	------------------------------	-------	---	------------

[#71-247-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	88.90	€15.450,00	Contact Us
--------------	--------	----------	---	------------------------------	-------	------------	------------

[#71-131-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	127.00	Fused Silica (Corning 7980)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	25.40		€2.214,50 Volume Pricing	Contact Us
--------------	--------	-----------------------------	---	--------------------------------	-------	--	---	------------

[#71-247-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	355.60	ZERODUR®	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	Protected Silver (450-10000nm)	88.90		€15.141,00	Contact Us
--------------	--------	----------	---	--------------------------------	-------	--	------------	------------

$\lambda/10$	152.40	Fused Silica	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#01-612-522	€2.054,85 Volume Pricing	2 In Stock
--------------	--------	------------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	152.40	Fused Silica	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#47-575-522	€2.909,75 Volume Pricing	4 In Stock
--------------	--------	------------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#31-393-522	€2.199,05 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	25.40	#48-119-522	€3.265,10 Volume Pricing	2 In Stock
--------------	--------	--------------------------	---	---------------------------------	-------	-----------------------------	---	------------

$\lambda/10$	152.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#01-612-533	€2.106,35 Volume Pricing	6 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#47-575-533	€2.961,25 Volume Pricing	5 In Stock
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#31-393-533	€2.250,55 Volume Pricing	Contact Us
$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	25.40	#48-119-533	€3.316,60 Volume Pricing	2 In Stock
$\lambda/10$	152.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#01-612-566	€2.235,10 Volume Pricing	5 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#47-575-566	€3.090,00 Volume Pricing	3 In Stock
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#31-393-566	€2.379,30 Volume Pricing	1 In Stock
$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	25.40	#48-119-566	€3.445,35 Volume Pricing	2 In Stock
$\lambda/10$	152.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#01-612-577	€2.209,35 Volume Pricing	1 In Stock
$\lambda/20$	152.40	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#47-575-577	€3.064,25 Volume Pricing	Contact Us
$\lambda/10$	152.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#31-393-577	€2.353,55 Volume Pricing	4 In Stock

$\lambda/20$	152.40	ZERODUR®	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	25.40	#48-119-577	€3.419,60 Volume Pricing	Contact Us
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#31-390-522	€4.197,25 Volume Pricing	2 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#49-048-522	€5.165,45 Volume Pricing	Contact Us
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#31-394-522	€4.444,45 Volume Pricing	1 In Stock
$\lambda/20$	203.20	ZERODUR®	$R_{avg} > 85\% @ 400 - 700nm$ $R_{avg} > 90\% @ 400 - 2000nm$	Protected Aluminum (400-2000nm)	38.10	#49-049-522	€5.314,80 Volume Pricing	Contact Us
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#31-390-533	€4.274,50 Volume Pricing	4 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#49-048-533	€5.242,70 Volume Pricing	1 In Stock
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#31-394-533	€4.521,70 Volume Pricing	1 In Stock
$\lambda/20$	203.20	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#49-049-533	€5.392,05 Volume Pricing	5 In Stock
$\lambda/10$	203.20	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#31-390-566	€4.403,25 Volume Pricing	1 In Stock
$\lambda/20$	203.20	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#49-048-566	€5.371,45 Volume Pricing	4 In Stock
$\lambda/10$	203.20	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#31-394-566	€4.650,45 Volume Pricing	2 In Stock

λ/20	203.20	ZERODUR®	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#49-049-566	€5.520,80 Volume Pricing	Contact Us
λ/10	203.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#31-390-577	€4.377,50 Volume Pricing	2 In Stock
λ/20	203.20	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#49-048-577	€5.345,70 Volume Pricing	Contact Us
λ/10	203.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#31-394-577	€4.624,70 Volume Pricing	1 In Stock
λ/20	203.20	ZERODUR®	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#49-049-577	€5.495,05 Volume Pricing	1 In Stock
λ/10	254.00	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#46-715-522	€6.386,00 Volume Pricing	Contact Us
λ/20	254.00	Fused Silica	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	#65-879-522	€9.403,90 Volume Pricing	Contact Us
λ/10	254.00	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#46-715-533	€6.489,00 Volume Pricing	4 In Stock
λ/20	254.00	Fused Silica	R _{avg} >95% @ 450 - 650nm	Enhanced Aluminum (450- 650nm)	38.10	#65-879-533	€9.506,90 Volume Pricing	Contact Us
λ/10	254.00	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#46-715-566	€6.617,75 Volume Pricing	1 In Stock
λ/20	254.00	Fused Silica	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	#65-879-566	€9.635,65 Volume Pricing	2 In Stock

$\lambda/10$	254.00	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#46-715-577	€6.592,00 Volume Pricing	3 In Stock
$\lambda/20$	254.00	Fused Silica	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	Protected Silver (450- 10000nm)	38.10	#65-879-577	€9.609,90 Volume Pricing	4 In Stock
#71-108-522 New								
								
						New		
$\lambda/10$	254.00	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€6.437,50 Volume Pricing	Contact Us
#71-110-522 New								
								
						New		
$\lambda/20$	254.00	ZERODUR®	R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm	Protected Aluminum (400- 2000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€9.321,50 Volume Pricing	Contact Us

[#71-108-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	€6.540,50 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	---	------------

[#71-110-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	€9.424,50 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	---	------------

[#71-108-566 New](#)



New

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€6.669,25 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	----------------------------

[#71-110-566 New](#)



New

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	Protected Gold (700- 10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€9.553,25 Volume Pricing	Contact Us
--------------	--------	--------------------------	--	--	-------	--	---	----------------------------

[#71-108-577 New](#)



New

$\lambda/10$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€6.643,50 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	-----------------------------------	-------	--	---	------------

[#71-110-577 New](#)



New

$\lambda/20$	254.00	ZERODUR®	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	Protected Silver (450-10000nm)	38.10	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€9.527,50 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	-----------------------------------	-------	--	---	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#69-921-522	€8.327,55 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 85\% @$ 400 - 700nm $R_{avg} > 90\% @$ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	#65-880-522	€12.725,65 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------------	-------	-----------------------------	--	------------

[#71-109-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	€8.368,75 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	---------------------------------	-------	---	------------

[#71-111-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 85\%$ @ 400 - 700nm $R_{avg} > 90\%$ @ 400 - 2000nm	Protected Aluminum (400-2000nm)	38.10	€12.746,25 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	---------------------------------	-------	--	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 95\%$ @ 450 - 650nm	Enhanced Aluminum (450-650nm)	38.10	#69-921-533 €8.404,80 Volume Pricing	1 In Stock
--------------	--------	------------------------------	--------------------------------	-------------------------------	-------	--	------------

[#71-109-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10		€8.446,00 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	--	---	------------

[#71-111-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10		€12.823,50 Volume Pricing	Contact Us
--------------	--------	--------------------------	--------------------------------	-------------------------------	-------	--	--	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 95\% @ 450 - 650nm$	Enhanced Aluminum (450-650nm)	38.10	#65-880-533	€12.802,90 Volume Pricing	Contact Us
--------------	--------	------------------------------	--------------------------------	-------------------------------	-------	-----------------------------	--	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#69-921-566	€8.533,55 Volume Pricing	1 In Stock
--------------	--------	------------------------------	---	------------------------------	-------	-----------------------------	---	------------

[#71-109-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$	304.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10		€8.574,75 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	------------------------------	-------	--	---	------------

[#71-111-566 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$	304.80	ZERODUR®	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10		€12.952,25 Volume Pricing	Contact Us
--------------	--------	--------------------------	---	------------------------------	-------	--	--	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	Protected Gold (700-10000nm)	38.10	#65-880-566	€12.931,65 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	------------------------------	-------	-----------------------------	--	------------

$\lambda/10$	304.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	38.10	#69-921-577	€8.507,80 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	--------------------------------	-------	-----------------------------	---	------------

$\lambda/20$	304.80	Fused Silica	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	Protected Silver (450-10000nm)	38.10	#65-880-577	€12.905,90 Volume Pricing	Contact Us
--------------	--------	------------------------------	---	--------------------------------	-------	-----------------------------	--	------------

[#71-109-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/10$ 304.80 [ZERODUR®](#) $R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm Protected Silver (450-10000nm) 38.10

€8.549,00
[Volume Pricing](#)

[Contact Us](#)

[#71-111-577 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/20$ 304.80 [ZERODUR®](#) $R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm Protected Silver (450-10000nm) 38.10

€12.926,50
[Volume Pricing](#)

[Contact Us](#)



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com