

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® Uncoated Plano-Convex (PCX) Lenses



- Wavelength Range of 350-2200nm
- Precision Diameter and Centration Tolerances Allow for Easy OEM Integration
- Wide Variety of Diameters, Focal Lengths, and Coatings
- Anti-Reflection PCX Coating Options: [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [NIR II](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel:



Protective bevel as needed

Optical Properties

Coating:

Uncoated

Technical Information

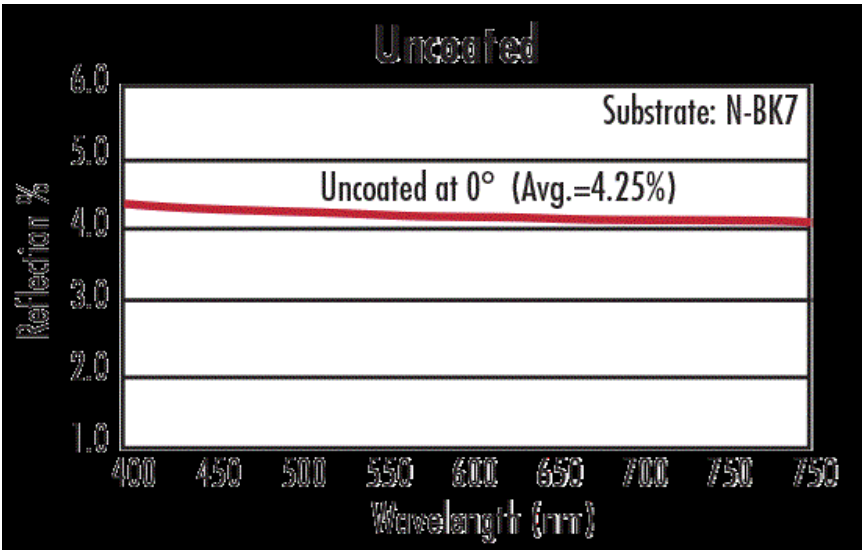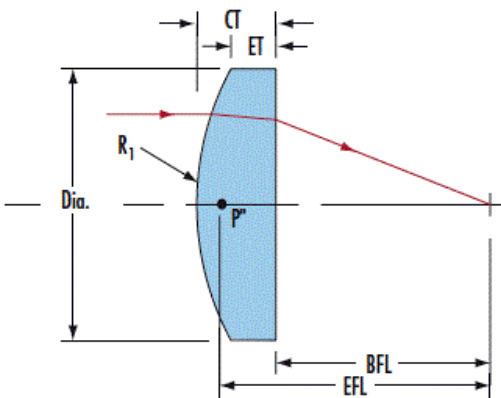

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	Uncoated	N-LASF9	#45-588	€66,50 Qty 10+ €60,00	3-4 days
1.00	1.00	0.57	Uncoated	N-LASF9	#45-589	€66,50 Qty 10+ €60,00	3-4 days
1.00	1.50	1.07	Uncoated	N-LASF9	#65-252	€66,50 Qty 10+ €60,00	3-4 days
1.00	2.00	1.57	Uncoated	N-LASF9	#65-253	€66,50 Qty 10+ €60,00	3-4 days
1.50	1.00	0.57	Uncoated	N-LASF9	#43-394	€66,50 Qty 10+ €60,00	Contact Us
1.50	1.50	1.07	Uncoated	N-LASF9	#43-395	€66,50 Qty 10+ €60,00	3-4 days
1.50	2.00	1.57	Uncoated	N-LASF9	#65-254	€66,50 Qty 10+ €60,00	3-4 days
2.00	1.50	1.07	Uncoated	N-LASF9	#43-396	€65,50 Qty 10+ €59,00	3-4 days
2.00	2.00	1.57	Uncoated	N-LASF9	#43-397	€65,50 Qty 10+ €59,00	3-4 days
2.00	3.00	2.57	Uncoated	N-LASF9	#65-255	€65,50 Qty 10+ €59,00	3-4 days
2.00	4.00	3.57	Uncoated	N-LASF9	#65-256	€65,50 Qty 10+ €59,00	3-4 days
2.50	2.00	1.57	Uncoated	N-LASF9	#43-398	€65,50 Qty 10+ €59,00	3-4 days
2.50	2.50	2.07	Uncoated	N-LASF9	#43-399	€65,50 Qty 10+ €59,00	3-4 days
2.50	3.00	2.57	Uncoated	N-LASF9	#45-590	€65,50 Qty 10+ €59,00	3-4 days
2.50	4.00	3.57	Uncoated	N-LASF9	#48-643	€65,50 Qty 10+ €59,00	3-4 days
2.50	5.00	4.57	Uncoated	N-LASF9	#48-644	€65,50 Qty 10+ €59,00	3-4 days

3.00	3.00	1.88	Uncoated	N-SF11	#45-117	€53,00 Qty 10+ €47,75	3-4 days
3.00	4.50	3.50	Uncoated	N-LASF44	#45-141	€53,00 Qty 10+ €47,75	In Stock
3.00	6.00	4.81	Uncoated	N-BK7	#32-952	€48,00 Qty 10+ €43,25	In Stock
3.00	7.50	6.51	Uncoated	N-BK7	#48-645	€48,00 Qty 10+ €43,25	3-4 days
3.00	9.00	8.01	Uncoated	N-BK7	#32-954	€48,00 Qty 10+ €43,25	In Stock
3.00	12.00	11.29	Uncoated	N-BK7	#45-272	€48,00 Qty 10+ €43,25	3-4 days
3.00	15.00	14.22	Uncoated	N-BK7	#45-425	€48,00 Qty 10+ €43,25	3-4 days
4.00	4.00	3.06	Uncoated	N-LASF44	#45-223	€48,00 Qty 10+ €43,25	3-4 days
4.00	6.00	4.51	Uncoated	N-BK7	#45-427	€48,00 Qty 10+ €43,25	In Stock
4.00	8.00	7.17	Uncoated	N-BAF10	#45-225	€43,75 Qty 10+ €39,50	3-4 days
4.00	10.00	8.92	Uncoated	N-BK7	#45-429	€43,75 Qty 10+ €39,50	In Stock
4.00	12.00	11.00	Uncoated	N-BK7	#45-431	€43,75 Qty 10+ €39,50	3-4 days
4.50	4.50	3.05	Uncoated	N-LASF44	#45-143	€48,00 Qty 10+ €43,25	3-4 days
4.50	9.00	7.41	Uncoated	N-BK7	#45-147	€43,75 Qty 10+ €39,50	3-4 days
5.00	5.00	3.96	Uncoated	N-LASF44	#45-227	€36,25 Qty 10+ €32,75	3-4 days
5.00	7.50	6.43	Uncoated	N-SF11	#48-652	€35,75 Qty 10+ €32,25	In Stock
5.00	10.00	8.91	Uncoated	N-BK7	#45-229	€35,75 Qty 10+ €32,25	In Stock
5.00	12.00	10.83	Uncoated	N-BK7	#45-433	€35,75 Qty 10+ €32,25	3-4 days
5.00	15.00	13.94	Uncoated	N-BK7	#45-356	€35,75 Qty 10+ €32,25	In Stock

5.00	20.00	19.02	Uncoated	N-BK7	#49-873	€35,75 Qty 10+ €32,25	3-4 days
5.00	25.00	23.95	Uncoated	N-BK7	#87-911	€35,75 Qty 10+ €32,25	3-4 days
5.00	30.00	28.95	Uncoated	N-BK7	#87-912	€35,75 Qty 10+ €32,25	3-4 days
6.00	6.00	4.60	Uncoated	N-SF11	#45-077	€28,00 Qty 10+ €25,25	In Stock
6.00	7.50	6.10	Uncoated	N-SF11	#49-874	€27,50 Qty 10+ €24,75	3-4 days
6.00	9.00	7.95	Uncoated	N-SF5	#32-469	€27,50 Qty 10+ €24,75	3-4 days
6.00	10.00	8.82	Uncoated	N-BK7	#37-775	€27,50 Qty 10+ €24,75	In Stock
6.00	12.00	10.94	Uncoated	N-BK7	#32-471	€26,50 Qty 10+ €23,75	3-4 days
6.00	15.00	13.68	Uncoated	N-BK7	#45-079	€26,50 Qty 10+ €23,75	3-4 days
6.00	18.00	17.07	Uncoated	N-BK7	#32-473	€26,50 Qty 10+ €23,75	3-4 days
6.00	20.00	19.04	Uncoated	N-BK7	#37-776	€26,50 Qty 10+ €23,75	3-4 days
6.00	21.00	20.06	Uncoated	N-BK7	#45-231	€26,50 Qty 10+ €23,75	3-4 days
6.00	24.00	23.01	Uncoated	N-BK7	#32-956	€26,50 Qty 10+ €23,75	In Stock
6.00	25.00	24.04	Uncoated	N-BK7	#37-777	€26,50 Qty 10+ €23,75	3-4 days
6.00	30.00	29.14	Uncoated	N-BK7	#45-119	€26,50 Qty 10+ €23,75	3-4 days
6.00	36.00	34.95	Uncoated	N-BK7	#32-848	€26,50 Qty 10+ €23,75	In Stock
6.00	48.00	46.95	Uncoated	N-BK7	#45-233	€26,50 Qty 10+ €23,75	3-4 days
6.00	60.00	58.95	Uncoated	N-BK7	#67-146	€26,50 Qty 10+ €23,75	In Stock
6.00	72.00	70.97	Uncoated	N-BK7	#32-850	€26,50 Qty 10+ €23,75	In Stock

7.00	7.00	5.50	Uncoated	N-SF11	#28-946	€28,00	Contact Us
7.00	10.00	8.10	Uncoated	N-BK7	#28-947	€27,50 Qty 10+ €24,75	3-4 days
7.00	12.00	10.30	Uncoated	N-BK7	#28-948	€27,50 Qty 10+ €24,75	3-4 days
8.00	8.00	6.40	Uncoated	N-SF11	#28-952	€28,00 Qty 10+ €25,25	3-4 days
8.00	10.00	7.60	Uncoated	N-BK7	#28-953	€27,50 Qty 10+ €24,75	3-4 days
8.00	12.00	10.00	Uncoated	N-BK7	#28-954	€27,50 Qty 10+ €24,75	3-4 days
9.00	9.00	7.32	Uncoated	N-SF11	#45-081	€28,50 Qty 10+ €25,75	3-4 days
9.00	10.00	8.49	Uncoated	N-SF11	#37-778	€28,50 Qty 10+ €25,75	3-4 days
9.00	12.00	10.60	Uncoated	N-SF11	#49-875	€28,50 Qty 10+ €25,75	In Stock
9.00	13.50	11.94	Uncoated	N-SF5	#32-009	€28,50 Qty 10+ €25,75	3-4 days
9.00	15.00	13.02	Uncoated	N-BK7	#49-876	€28,50 Qty 10+ €25,75	In Stock
9.00	18.00	16.41	Uncoated	N-BK7	#32-008	€27,50 Qty 10+ €24,75	In Stock
9.00	20.00	18.55	Uncoated	N-BK7	#37-779	€27,50 Qty 10+ €24,75	3-4 days
9.00	22.00	20.73	Uncoated	N-BK7	#45-235	€27,50 Qty 10+ €24,75	3-4 days
9.00	25.00	23.68	Uncoated	N-BK7	#37-780	€27,50 Qty 10+ €24,75	3-4 days
9.00	27.00	25.34	Uncoated	N-BK7	#32-958	€27,50 Qty 10+ €24,75	3-4 days
9.00	36.00	34.48	Uncoated	N-BK7	#45-121	€27,50 Qty 10+ €24,75	In Stock
9.00	45.00	43.98	Uncoated	N-BK7	#45-358	€27,50 Qty 10+ €24,75	3-4 days
9.00	54.00	52.69	Uncoated	N-BK7	#67-147	€27,50 Qty 10+ €24,75	3-4 days

9.00	72.00	70.68	Uncoated	N-BK7	#67-148	€27,50 Qty 10+ €24,75	3-4 days
9.00	90.00	88.68	Uncoated	N-BK7	#67-149	€27,50 Qty 10+ €24,75	3-4 days
10.00	10.00	8.18	Uncoated	N-SF11	#63-471	€28,50 Qty 10+ €25,75	In Stock
10.00	12.50	10.99	Uncoated	N-SF11	#37-781	€28,50 Qty 10+ €25,75	3-4 days
10.00	15.00	13.32	Uncoated	N-SF11	#63-472	€28,50 Qty 10+ €25,75	3-4 days
10.00	17.50	15.66	Uncoated	N-BK7	#37-782	€27,50 Qty 10+ €24,75	3-4 days
10.00	20.00	18.03	Uncoated	N-BK7	#63-473	€27,50 Qty 10+ €24,75	3-4 days
10.00	25.00	23.02	Uncoated	N-BK7	#63-474	€27,50 Qty 10+ €24,75	3-4 days
10.00	30.00	28.01	Uncoated	N-BK7	#63-475	€27,50 Qty 10+ €24,75	3-4 days
10.00	40.00	38.02	Uncoated	N-BK7	#63-476	€27,50 Qty 10+ €24,75	3-4 days
10.00	50.00	48.02	Uncoated	N-BK7	#63-477	€27,50 Qty 10+ €24,75	3-4 days
10.00	75.00	73.02	Uncoated	N-BK7	#63-478	€27,50 Qty 10+ €24,75	3-4 days
10.00	100.00	98.02	Uncoated	N-BK7	#63-479	€27,50 Qty 10+ €24,75	In Stock
12.00	12.00	9.76	Uncoated	N-SF11	#45-083	€30,50 Qty 10+ €27,50	In Stock
12.00	15.00	12.03	Uncoated	N-BK7	#45-302	€30,50 Qty 10+ €27,50	In Stock
12.00	18.00	16.22	Uncoated	N-SF5	#32-006	€30,50 Qty 10+ €27,50	In Stock
12.00	20.00	17.69	Uncoated	N-BK7	#49-877	€30,50 Qty 10+ €27,50	In Stock
12.00	24.00	22.15	Uncoated	N-BK7	#32-011	€29,50 Qty 10+ €26,50	In Stock
12.00	25.00	23.22	Uncoated	N-BK7	#37-783	€29,50 Qty 10+ €26,50	Contact Us

12.00	30.00	28.02	Uncoated	N-BK7	#45-085	€29,50 Qty 10+ €26,50	Contact Us
12.00	36.00	34.02	Uncoated	N-BK7	#33-352	€29,50 Qty 10+ €26,50	3-4 days
12.00	42.00	40.22	Uncoated	N-BK7	#45-123	€29,50 Qty 10+ €26,50	In Stock
12.00	48.00	46.36	Uncoated	N-BK7	#32-852	€29,50 Qty 10+ €26,50	3-4 days
12.00	50.00	48.75	Uncoated	N-BK7	#37-784	€29,50 Qty 10+ €26,50	3-4 days
12.00	54.00	52.02	Uncoated	N-BK7	#45-304	€29,50 Qty 10+ €26,50	3-4 days
12.00	60.00	58.37	Uncoated	N-BK7	#32-854	€29,50 Qty 10+ €26,50	3-4 days
12.00	72.00	70.42	Uncoated	N-BK7	#45-125	€29,50 Qty 10+ €26,50	3-4 days
12.00	84.00	82.39	Uncoated	N-BK7	#32-856	€29,50 Qty 10+ €26,50	3-4 days
12.00	100.00	98.35	Uncoated	N-BK7	#45-274	€29,50 Qty 10+ €26,50	In Stock
12.50	12.50	10.40	Uncoated	N-SF11	#37-785	€29,50 Qty 10+ €26,50	3-4 days
12.50	15.00	13.26	Uncoated	N-SF11	#37-786	€29,50 Qty 10+ €26,50	3-4 days
12.50	17.50	15.00	Uncoated	N-BK7	#37-787	€29,50 Qty 10+ €26,50	3-4 days
12.50	20.00	17.69	Uncoated	N-BK7	#37-788	€29,50 Qty 10+ €26,50	Contact Us
12.50	25.00	22.96	Uncoated	N-BK7	#37-789	€28,50 Qty 10+ €25,75	3-4 days
12.50	30.00	28.22	Uncoated	N-BK7	#37-790	€28,50 Qty 10+ €25,75	3-4 days
12.50	35.00	33.42	Uncoated	N-BK7	#37-791	€28,50 Qty 10+ €25,75	3-4 days
12.50	40.00	38.55	Uncoated	N-BK7	#37-792	€28,50 Qty 10+ €25,75	3-4 days
12.50	45.00	43.68	Uncoated	N-BK7	#37-793	€28,50 Qty 10+ €25,75	3-4 days

12.50	50.00	48.68	Uncoated	N-BK7	#37-796	€28,50 Qty 10+ €25,75	3-4 days
12.50	75.00	73.88	Uncoated	N-BK7	#37-798	€28,50 Qty 10+ €25,75	Contact Us
12.50	100.00	98.95	Uncoated	N-BK7	#37-800	€28,50 Qty 10+ €25,75	3-4 days
12.70	12.70	10.46	Uncoated	N-SF11	#49-839	€29,50 Qty 10+ €26,50	In Stock
12.70	15.00	11.53	Uncoated	N-BK7	#49-840	€29,50 Qty 10+ €26,50	In Stock
12.70	19.10	16.46	Uncoated	N-BK7	#49-841	€29,50 Qty 10+ €26,50	3-4 days
12.70	20.00	17.49	Uncoated	N-BK7	#37-801	€29,50 Qty 10+ €26,50	3-4 days
12.70	25.40	23.43	Uncoated	N-BK7	#49-842	€28,50 Qty 10+ €25,75	Contact Us
12.70	30.00	28.22	Uncoated	N-BK7	#37-802	€28,50 Qty 10+ €25,75	3-4 days
12.70	31.80	29.81	Uncoated	N-BK7	#49-843	€28,50 Qty 10+ €25,75	3-4 days
12.70	38.10	36.12	Uncoated	N-BK7	#49-844	€28,50 Qty 10+ €25,75	3-4 days
12.70	40.00	38.48	Uncoated	N-BK7	#37-803	€28,50 Qty 10+ €25,75	3-4 days
12.70	44.50	42.69	Uncoated	N-BK7	#49-845	€28,50 Qty 10+ €25,75	3-4 days
12.70	50.80	49.15	Uncoated	N-BK7	#49-846	€28,50 Qty 10+ €25,75	3-4 days
12.70	100.00	98.88	Uncoated	N-BK7	#37-804	€28,50 Qty 10+ €25,75	3-4 days
15.00	15.00	11.71	Uncoated	N-SF5	#45-093	€30,50 Qty 10+ €27,50	In Stock
15.00	18.00	15.61	Uncoated	N-SF5	#49-878	€30,50 Qty 10+ €27,50	3-4 days
15.00	20.00	17.74	Uncoated	N-SF5	#63-480	€30,50 Qty 10+ €27,50	In Stock
15.00	22.50	20.50	Uncoated	N-SF5	#32-004	€30,50 Qty 10+ €27,50	In Stock

15.00	25.00	22.50	Uncoated	N-BK7	#37-806	€29,50 Qty 10+ €26,50	3-4 days
15.00	30.00	27.90	Uncoated	N-BK7	#32-003	€29,50 Qty 10+ €26,50	Contact Us
15.00	40.00	38.02	Uncoated	N-BK7	#45-095	€29,50 Qty 10+ €26,50	In Stock
15.00	45.00	43.35	Uncoated	N-BK7	#49-879	€29,50 Qty 10+ €26,50	3-4 days
15.00	50.00	48.35	Uncoated	N-BK7	#37-808	€29,50 Qty 10+ €26,50	In Stock
15.00	60.00	58.65	Uncoated	N-BK7	#45-435	€29,50 Qty 10+ €26,50	3-4 days
15.00	75.00	73.79	Uncoated	N-BK7	#45-360	€29,50 Qty 10+ €26,50	Contact Us
15.00	100.00	98.02	Uncoated	N-BK7	#45-259	€29,50 Qty 10+ €26,50	In Stock
15.00	250.00	248.02	Uncoated	N-BK7	#14-382	€29,50 Qty 10+ €26,50	3-4 days
18.00	18.00	15.20	Uncoated	N-SF11	#48-423	€31,00 Qty 10+ €28,00	3-4 days
18.00	22.50	20.26	Uncoated	N-SF11	#49-880	€30,50 Qty 10+ €27,50	In Stock
18.00	27.00	24.73	Uncoated	N-SF5	#32-001	€30,50 Qty 10+ €27,50	3-4 days
18.00	36.00	33.65	Uncoated	N-BK7	#32-000	€29,00 Qty 10+ €26,00	3-4 days
18.00	54.00	52.02	Uncoated	N-BK7	#45-306	€29,00 Qty 10+ €26,00	In Stock
18.00	72.00	70.05	Uncoated	N-BK7	#32-859	€29,00 Qty 10+ €26,00	3-4 days
18.00	20.00	17.59	Uncoated	N-SF11	#37-810	€30,50 Qty 10+ €27,50	3-4 days
18.00	25.00	21.51	Uncoated	N-BK7	#37-811	€30,50 Qty 10+ €27,50	3-4 days
18.00	30.00	27.10	Uncoated	N-BK7	#37-812	€29,00 Qty 10+ €26,00	In Stock
18.00	50.00	48.09	Uncoated	N-BK7	#37-813	€29,00 Qty 10+ €26,00	3-4 days

20.00	20.00	17.42	Uncoated	N-SF11	#45-237	€31,50 Qty 10+ €28,25	In Stock
20.00	25.00	22.76	Uncoated	N-SF11	#49-881	€31,00 Qty 10+ €28,00	3-4 days
20.00	30.00	27.30	Uncoated	N-BAF10	#45-239	€31,00 Qty 10+ €28,00	In Stock
20.00	35.00	32.04	Uncoated	N-BK7	#49-882	€31,00 Qty 10+ €28,00	In Stock
20.00	40.00	36.77	Uncoated	N-BK7	#32-960	€29,50 Qty 10+ €26,50	In Stock
20.00	50.00	47.87	Uncoated	N-BK7	#45-362	€29,50 Qty 10+ €26,50	3-4 days
20.00	60.00	57.03	Uncoated	N-BK7	#32-962	€29,50 Qty 10+ €26,50	In Stock
20.00	70.00	68.03	Uncoated	N-BK7	#32-936	€29,50 Qty 10+ €26,50	3-4 days
20.00	80.00	78.45	Uncoated	N-BK7	#45-439	€29,50 Qty 10+ €26,50	In Stock
20.00	100.00	97.13	Uncoated	N-BK7	#32-475	€29,50 Qty 10+ €26,50	In Stock
20.00	150.00	148.02	Uncoated	N-BK7	#45-276	€29,50 Qty 10+ €26,50	3-4 days
25.00	25.00	20.22	Uncoated	N-SF5	#45-097	€31,50 Qty 10+ €28,25	In Stock
25.00	30.00	24.69	Uncoated	N-BK7	#45-364	€31,50 Qty 10+ €28,25	3-4 days
25.00	35.00	30.42	Uncoated	N-BK7	#45-145	€31,50 Qty 10+ €28,25	In Stock
25.00	40.00	36.31	Uncoated	N-BK7	#45-278	€31,50 Qty 10+ €28,25	3-4 days
25.00	50.00	46.75	Uncoated	N-BK7	#32-477	€29,50 Qty 10+ €26,50	Contact Us
25.00	60.00	56.90	Uncoated	N-BK7	#45-127	€29,50 Qty 10+ €26,50	In Stock
25.00	75.00	72.00	Uncoated	N-BK7	#32-479	€29,50 Qty 10+ €26,50	3-4 days
25.00	85.00	82.17	Uncoated	N-BK7	#45-366	€29,50 Qty 10+ €26,50	3-4 days

25.00	100.00	97.17	Uncoated	N-BK7	#32-481	€29,50 Qty 10+ €26,50	3-4 days
25.00	125.00	122.70	Uncoated	N-BK7	#32-861	€29,50 Qty 10+ €26,50	In Stock
25.00	150.00	147.81	Uncoated	N-BK7	#32-863	€29,50 Qty 10+ €26,50	In Stock
25.00	175.00	172.85	Uncoated	N-BK7	#32-865	€29,50 Qty 10+ €26,50	3-4 days
25.00	200.00	197.89	Uncoated	N-BK7	#33-358	€29,50 Qty 10+ €26,50	In Stock
25.00	250.00	248.02	Uncoated	N-BK7	#67-150	€29,50 Qty 10+ €26,50	3-4 days
25.00	300.00	298.02	Uncoated	N-BK7	#67-151	€29,50 Qty 10+ €26,50	In Stock
25.00	400.00	397.89	Uncoated	N-BK7	#33-364	€29,50 Qty 10+ €26,50	3-4 days
25.00	500.00	497.89	Uncoated	N-BK7	#45-280	€29,50 Qty 10+ €26,50	3-4 days
25.00	750.00	747.89	Uncoated	N-BK7	#45-282	€29,50 Qty 10+ €26,50	3-4 days
25.40	25.40	21.48	Uncoated	N-SF11	#49-847	€31,50 Qty 10+ €28,25	3-4 days
25.40	38.10	33.48	Uncoated	N-BK7	#49-848	€31,50 Qty 10+ €28,25	3-4 days
25.40	50.80	47.50	Uncoated	N-BK7	#49-849	€29,50 Qty 10+ €26,50	Contact Us
25.40	63.50	60.37	Uncoated	N-BK7	#49-850	€29,50 Qty 10+ €26,50	3-4 days
25.40	76.20	73.56	Uncoated	N-BK7	#49-851	€29,50 Qty 10+ €26,50	In Stock
25.40	88.90	86.26	Uncoated	N-BK7	#49-852	€29,50 Qty 10+ €26,50	3-4 days
25.40	101.60	98.97	Uncoated	N-BK7	#49-853	€29,50 Qty 10+ €26,50	3-4 days
25.40	35.00	30.46	Uncoated	N-BK7	#37-814	€31,50 Qty 10+ €28,25	3-4 days
25.40	40.00	36.11	Uncoated	N-BK7	#37-815	€31,50 Qty 10+ €28,25	3-4 days

25.40	75.00	72.69	Uncoated	N-BK7	#37-816	€29,50 Qty 10+ €26,50	3-4 days
25.40	100.00	98.02	Uncoated	N-BK7	#37-817	€29,50 Qty 10+ €26,50	3-4 days
25.40	125.00	123.02	Uncoated	N-BK7	#37-818	€29,50 Qty 10+ €26,50	In Stock
25.40	150.00	148.02	Uncoated	N-BK7	#37-821	€29,50 Qty 10+ €26,50	3-4 days
30.00	30.00	26.13	Uncoated	N-SF11	#48-653	€39,25 Qty 10+ €35,25	3-4 days
30.00	40.00	37.20	Uncoated	N-SF11	#67-152	€37,75 Qty 10+ €34,00	3-4 days
30.00	50.00	46.17	Uncoated	N-SF5	#32-483	€37,75 Qty 10+ €34,00	3-4 days
30.00	60.00	56.03	Uncoated	N-BK7	#45-241	€36,25 Qty 10+ €32,75	In Stock
30.00	75.00	70.95	Uncoated	N-BK7	#32-485	€36,25 Qty 10+ €32,75	3-4 days
30.00	100.00	96.01	Uncoated	N-BK7	#32-487	€36,25 Qty 10+ €32,75	In Stock
30.00	120.00	116.04	Uncoated	N-BK7	#45-243	€36,25 Qty 10+ €32,75	In Stock
35.00	35.00	30.52	Uncoated	N-SF11	#37-824	€40,75 Qty 10+ €36,75	3-4 days
35.00	50.00	44.40	Uncoated	N-BK7	#37-825	€39,25 Qty 10+ €35,25	3-4 days
35.00	100.00	97.03	Uncoated	N-BK7	#37-828	€39,25 Qty 10+ €35,25	3-4 days
35.00	70.00	66.04	Uncoated	N-BK7	#37-827	€39,25 Qty 10+ €35,25	3-4 days
40.00	40.00	35.13	Uncoated	N-SF11	#48-654	€43,25 Qty 10+ €39,00	In Stock
40.00	60.00	53.90	Uncoated	N-BK7	#45-149	€43,25 Qty 10+ €39,00	Contact Us
40.00	80.00	74.73	Uncoated	N-BK7	#33-382	€42,25 Qty 10+ €38,00	3-4 days
40.00	100.00	95.39	Uncoated	N-BK7	#33-370	€42,25 Qty 10+ €38,00	3-4 days

40.00	200.00	196.7	Uncoated	N-BK7	#33-376	€42,25 Qty 10+ €38,00	3-4 days
40.00	300.00	296.70	Uncoated	N-BK7	#45-284	€42,25 Qty 10+ €38,00	3-4 days
40.00	400.00	396.70	Uncoated	N-BK7	#45-286	€42,25 Qty 10+ €38,00	3-4 days
50.00	50.00	43.28	Uncoated	N-SF11	#32-970	€48,50 Qty 10+ €43,75	3-4 days
50.00	75.00	67.75	Uncoated	N-BK7	#45-245	€46,50 Qty 10+ €41,75	In Stock
50.00	100.00	93.41	Uncoated	N-BK7	#32-972	€43,75 Qty 10+ €39,50	In Stock
50.00	125.00	118.39	Uncoated	N-BK7	#45-247	€43,75 Qty 10+ €39,50	3-4 days
50.00	150.00	144.07	Uncoated	N-BK7	#32-974	€43,75 Qty 10+ €39,50	In Stock
50.00	175.00	169.05	Uncoated	N-BK7	#45-249	€43,75 Qty 10+ €39,50	3-4 days
50.00	200.00	196.66	Uncoated	N-BK7	#45-151	€43,75 Qty 10+ €39,50	3-4 days
50.00	250.00	246.74	Uncoated	N-BK7	#45-153	€43,75 Qty 10+ €39,50	3-4 days
50.00	500.00	496.70	Uncoated	N-BK7	#45-288	€43,75 Qty 10+ €39,50	3-4 days
50.80	50.80	44.08	Uncoated	N-SF11	#29-094	€48,50 Qty 10+ €43,75	3-4 days
50.80	76.20	68.95	Uncoated	N-BK7	#29-095	€46,50 Qty 10+ €41,75	3-4 days
75.00	75.00	53.49	Uncoated	N-BK7	#45-367	€79,00 Qty 10+ €71,00	In Stock

[#71-834 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 100.00 87.57 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

[#71-835 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 125.00 115.99 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

75.00 150.00 142.45 Uncoated [N-BK7](#)

[#45-369](#)

€76,50
Qty 10+ €69,00

In Stock

[#71-836 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 175.00 168.68 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

75.00 200.00 194.24 Uncoated [N-BK7](#)

[#45-371](#)

€76,50
Qty 10+ €69,00

In Stock

75.00 250.00 244.73 Uncoated [N-BK7](#)

[#63-482](#)

€76,50
Qty 10+ €69,00

3-4 days

[#71-837 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 300.00 294.4 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

[#71-838 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 400.00 394.4 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

75.00 500.00 494.73 Uncoated [N-BK7](#)

[#63-483](#)

€76,50
Qty 10+ €69,00

3-4 days

[#71-839 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 750.00 745.35 Uncoated [N-BK7](#)

€76,50
Qty 10+ €69,00

3-4 days

[#70-952 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

€219,00
Qty 10+ €197,00

3-4 days

100.00 150.00 136.82 Uncoated N-BK7

100.00 200.00 190.77 Uncoated [N-BK7](#)

[#17-899](#)

€204,00
Qty 10+ €184,00

3-4 days

[#70-953 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

€189,00
Qty 10+ €170,00

3-4 days

100.00 300.00 293.41 Uncoated N-BK7

[#70-954 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

€179,00
Qty 10+ €161,00

3-4 days

100.00 400.00 393.41 Uncoated N-BK7

[#70-955 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

€306,00
Qty 10+ €275,00

3-4 days

125.00 250.00 238.13 Uncoated N-BK7

[#70-956 New](#)



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
[www.edmundoptics.com](#)

New
Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

150.00	200.00	285.50	Uncoated	N-BK7		€434,00	3-4 days
						Qty 10+ €391,00	

150.00	300.00	285.50	Uncoated	N-BK7	#17-915	€403,00	3-4 days
						Qty 10+ €363,00	
200.00	400.00	381.54	Uncoated	N-BK7	#17-931	€765,00	3-4 days
						Qty 10+ €689,00	