

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

TECHSPEC® $\lambda/4$ Precision Spherical Mirrors



- Ideal for Multispectral Focusing Applications
- Variety of Coating Options Offered
- Multiple Sizes Available
- [\$\lambda/8\$ Precision Spherical Mirrors](#) Also Available

Common Specifications

Physical & Mechanical Properties

Back Surface:	Ground
---------------	--------


Optical Properties

Focal Length Tolerance (%)	± 2
----------------------------	---------

Surface Quality:	60-40
------------------	-------

Surface Accuracy:	$\lambda/4$
-------------------	-------------

Technical Information

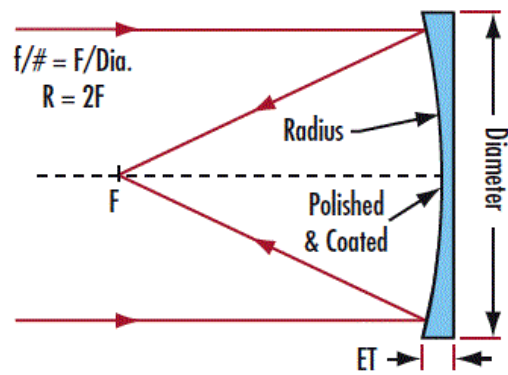

Products

Surface Accuracy	Dia. (mm)	EFL (mm)	Aperture (f/#)	Coating	Stock Number	Price	Buy
λ/4	25.40	25.40	f/1	Uncoated	#43-335	€105,00 Qty 10+ €87,50	3-4 days
λ/4	25.40	25.40	f/1	Protected Aluminum (400-2000nm)	#43-336	€116,00 Qty 10+ €97,50	3-4 days
λ/4	25.40	25.40	f/1	Enhanced Aluminum (250-700nm)	#43-535	€121,00 Qty 10+ €102,50	In Stock
λ/4	25.40	25.40	f/1	Enhanced Aluminum (450-650nm)	#43-536	€121,00 Qty 10+ €102,50	3-4 days
λ/4	25.40	25.40	f/1	Protected Gold (700-10000nm)	#43-337	€132,00 Qty 10+ €112,50	3-4 days
#71-794 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
λ/4	24.40	25.40	f/1	Protected Silver (450-10000nm)		€121,00 Qty 6+ €96,50	Contact Us
λ/4	25.40	50.80	f/2	Uncoated	#43-338	€105,00 Qty 10+ €87,50	3-4 days

$\lambda/4$	25.40	50.80	f/2	Protected Aluminum (400-2000nm)	#43-339	€116,00 Qty 10+ €97,50	3-4 days
$\lambda/4$	25.40	50.80	f/2	Enhanced Aluminum (250-700nm)	#43-537	€121,00 Qty 10+ €102,50	3-4 days
$\lambda/4$	25.40	50.80	f/2	Enhanced Aluminum (450-650nm)	#43-538	€121,00 Qty 10+ €102,50	Contact Us
$\lambda/4$	25.40	50.80	f/2	Protected Gold (700-10000nm)	#43-340	€132,00 Qty 10+ €112,50	3-4 days

[#71-795 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/4$	25.40	76.20	f/3	Uncoated	#43-341	€105,00 Qty 10+ €87,50	3-4 days
$\lambda/4$	25.40	76.20	f/3	Protected Aluminum (400-2000nm)	#43-342	€116,00 Qty 10+ €97,50	3-4 days
$\lambda/4$	25.40	76.20	f/3	Enhanced Aluminum (250-700nm)	#43-539	€121,00 Qty 10+ €102,50	3-4 days
$\lambda/4$	25.40	76.20	f/3	Enhanced Aluminum (450-650nm)	#43-540	€121,00 Qty 10+ €102,50	Contact Us

λ/4	25.40	76.20	f/3	Protected Gold (700-1000nm)	#43-343	€132,00 Qty 10+ €112,50	3-4 days
#71-796 New New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
λ/4	24.40	76.20	f/3	Protected Silver (450-1000nm)		€121,00 Qty 6+ €96,50	3-4 days
λ/4	25.40	101.60	f/4	Uncoated	#43-344	€105,00 Qty 10+ €87,50	3-4 days
λ/4	25.40	101.60	f/4	Protected Aluminum (400-2000nm)	#43-345	€116,00 Qty 10+ €97,50	3-4 days
λ/4	25.40	101.60	f/4	Enhanced Aluminum (250-700nm)	#43-541	€121,00 Qty 10+ €102,50	Contact Us
λ/4	25.40	101.60	f/4	Enhanced Aluminum (450-650nm)	#43-542	€121,00 Qty 10+ €102,50	Contact Us
λ/4	25.40	101.60	f/4	Protected Gold (700-1000nm)	#43-346	€132,00 Qty 10+ €112,50	Contact Us

[#71-797 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	24.40	101.60	f/4	Protected Silver (450-10000nm)		€121,00 Qty 6+ €96,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	--------------------------	----------

$\lambda/4$	25.40	152.40	f/6	Uncoated	#49-595	€105,00 Qty 10+ €87,50	In Stock
-------------	-------	--------	-----	----------	-------------------------	---------------------------	----------

$\lambda/4$	25.40	152.40	f/6	Protected Aluminum (400-2000nm)	#49-600	€116,00 Qty 10+ €97,50	3-4 days
-------------	-------	--------	-----	---------------------------------	-------------------------	---------------------------	----------

$\lambda/4$	25.40	152.40	f/6	Enhanced Aluminum (250-700nm)	#49-605	€121,00 Qty 10+ €102,50	3-4 days
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	25.40	152.40	f/6	Enhanced Aluminum (450-650nm)	#49-610	€121,00 Qty 10+ €102,50	Contact Us
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	25.40	152.40	f/6	Protected Gold (700-10000nm)	#49-615	€132,00 Qty 10+ €112,50	3-4 days
-------------	-------	--------	-----	------------------------------	-------------------------	----------------------------	----------

[#71-798 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	24.40	152.40	f/6	Protected Silver (450-10000nm)		€121,00 Qty 6+ €96,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	--------------------------	----------

$\lambda/4$	25.40	203.20	f/8	Uncoated	#49-596	€105,00 Qty 10+ €87,50	3-4 days
-------------	-------	--------	-----	----------	-------------------------	---------------------------	----------

$\lambda/4$	25.40	203.20	f/8	Protected Aluminum (400-2000nm)	#49-601	€116,00 Qty 10+ €97,50	3-4 days
-------------	-------	--------	-----	---------------------------------	-------------------------	---------------------------	----------

$\lambda/4$	25.40	203.20	f/8	Enhanced Aluminum (250-700nm)	#49-606	€121,00 Qty 10+ €102,50	3-4 days
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	25.40	203.20	f/8	Enhanced Aluminum (450-650nm)	#49-611	€121,00 Qty 10+ €102,50	Contact Us
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	25.40	203.20	f/8	Protected Gold (700-10000nm)	#49-616	€132,00 Qty 10+ €112,50	3-4 days
-------------	-------	--------	-----	------------------------------	-------------------------	----------------------------	----------

[#71-799 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/4$	24.40	203.20	f/8	Protected Silver (450-10000nm)		€121,00 Qty 6+ €96,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	--------------------------	----------

[#71-800 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/4$	50.80	50.80	f/1	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	3-4 days
-------------	-------	-------	-----	--------------------------------	--	---------------------------	----------

$\lambda/4$	50.80	50.80	f/1	Uncoated	#32-811	€126,00 Qty 10+ €107,00	3-4 days
-------------	-------	-------	-----	----------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	50.80	f/1	Protected Aluminum (400-2000nm)	#32-812	€154,00 Qty 10+ €130,50	3-4 days
-------------	-------	-------	-----	---------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	50.80	f/1	Enhanced Aluminum (250-700nm)	#43-543	€179,00 Qty 10+ €151,50	3-4 days
-------------	-------	-------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	50.80	f/1	Enhanced Aluminum (450-650nm)	#43-544	€179,00 Qty 10+ €151,50	Contact Us
$\lambda/4$	50.80	50.80	f/1	Protected Gold (700-10000nm)	#32-813	€232,00 Qty 10+ €197,00	3-4 days
#71-801 New							
				 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!			
$\lambda/4$	50.80	101.60	f/2	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	Contact Us
#71-802 New							
				 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!			
$\lambda/4$	50.80	152.40	f/3	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	3-4 days
$\lambda/4$	50.80	101.60	f/2	Uncoated	#32-814	€126,00 Qty 10+ €107,00	3-4 days

$\lambda/4$	50.80	101.60	f/2	Protected Aluminum (400-2000nm)	#32-815	€154,00 Qty 10+ €130,50	Contact Us
$\lambda/4$	50.80	101.60	f/2	Enhanced Aluminum (250-700nm)	#43-545	€179,00 Qty 10+ €151,50	Contact Us
$\lambda/4$	50.80	101.60	f/2	Enhanced Aluminum (450-650nm)	#43-546	€179,00 Qty 10+ €151,50	3-4 days
$\lambda/4$	50.80	101.60	f/2	Protected Gold (700-10000nm)	#32-816	€232,00 Qty 10+ €197,00	3-4 days
#71-803 New							
$\lambda/4$	50.80	203.20	f/4	Protected Silver (450-10000nm)	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€194,00 Qty 6+ €155,50	3-4 days
$\lambda/4$	50.80	152.40	f/3	Uncoated	#49-597	€126,00 Qty 10+ €107,00	3-4 days
$\lambda/4$	50.80	152.40	f/3	Protected Aluminum (400-2000nm)	#49-602	€154,00 Qty 10+ €130,50	3-4 days
$\lambda/4$	50.80	152.40	f/3	Enhanced Aluminum (250-700nm)	#49-607	€179,00 Qty 10+ €151,50	3-4 days
$\lambda/4$	50.80	152.40	f/3	Enhanced Aluminum (450-650nm)	#49-612	€179,00 Qty 10+ €151,50	3-4 days

λ/4	50.80	152.40	f/3	Protected Gold (700-10000nm)	#49-617	€232,00 Qty 10+ €197,00	3-4 days
#71-804 New × New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
λ/4	50.80	304.80	f/6	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	3-4 days
λ/4	50.80	203.20	f/4	Uncoated	#49-598	€126,00 Qty 10+ €107,00	3-4 days
λ/4	50.80	203.20	f/4	Protected Aluminum (400-2000nm)	#49-603	€154,00 Qty 10+ €130,50	3-4 days
λ/4	50.80	203.20	f/4	Enhanced Aluminum (250-700nm)	#49-608	€179,00 Qty 10+ €151,50	3-4 days
λ/4	50.80	203.20	f/4	Enhanced Aluminum (450-650nm)	#49-613	€179,00 Qty 10+ €151,50	Contact Us
λ/4	50.80	203.20	f/4	Protected Gold (700-10000nm)	#49-618	€232,00 Qty 10+ €197,00	3-4 days

[#71-805 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	50.80	508.00	f/10	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	3-4 days
-------------	-------	--------	------	--------------------------------	--	---------------------------	----------

$\lambda/4$	50.80	304.80	f/6	Uncoated	#32-817	€126,00 Qty 10+ €107,00	3-4 days
-------------	-------	--------	-----	----------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	304.80	f/6	Protected Aluminum (400-2000nm)	#32-818	€154,00 Qty 10+ €130,50	3-4 days
-------------	-------	--------	-----	---------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	304.80	f/6	Enhanced Aluminum (250-700nm)	#43-547	€179,00 Qty 10+ €151,50	In Stock
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	304.80	f/6	Enhanced Aluminum (450-650nm)	#43-548	€179,00 Qty 10+ €151,50	Contact Us
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	50.80	304.80	f/6	Protected Gold (700-10000nm)	#32-819	€232,00 Qty 10+ €197,00	3-4 days
-------------	-------	--------	-----	------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	508.00	f/10	Uncoated	#32-820	€126,00 Qty 10+ €107,00	3-4 days
-------------	-------	--------	------	----------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	508.00	f/10	Protected Aluminum (400-2000nm)	#32-821	€154,00 Qty 10+ €130,50	3-4 days
-------------	-------	--------	------	---------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	508.00	f/10	Enhanced Aluminum (250-700nm)	#43-549	€179,00 Qty 10+ €151,50	3-4 days
-------------	-------	--------	------	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	50.80	508.00	f/10	Enhanced Aluminum (450-650nm)	#43-550	€179,00 Qty 10+ €151,50	3-4 days
$\lambda/4$	50.80	508.00	f/10	Protected Gold (700-10000nm)	#32-822	€232,00 Qty 10+ €197,00	3-4 days
#71-806 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
$\lambda/4$	50.80	1,016.00	f/20	Protected Silver (450-10000nm)		€194,00 Qty 6+ €155,50	3-4 days
$\lambda/4$	50.80	1,016.00	f/20	Uncoated	#43-347	€126,00 Qty 10+ €107,00	3-4 days
$\lambda/4$	50.80	1,016.00	f/20	Protected Aluminum (400-2000nm)	#43-348	€154,00 Qty 10+ €130,50	Contact Us
$\lambda/4$	50.80	1,016.00	f/20	Enhanced Aluminum (250-700nm)	#43-551	€179,00 Qty 10+ €151,50	Contact Us
$\lambda/4$	50.80	1,016.00	f/20	Enhanced Aluminum (450-650nm)	#43-552	€179,00 Qty 10+ €151,50	3-4 days
$\lambda/4$	50.80	1,016.00	f/20	Protected Gold (700-10000nm)	#43-349	€232,00 Qty 10+ €197,00	3-4 days

[#71-807 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/4$

76.20

76.20

f/1

Protected Silver
(450-10000nm)

€299,00
Qty 6+ €239,50

3-4 days

[#71-808 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

$\lambda/4$

76.20

152.40

f/2

Protected Silver
(450-10000nm)

€299,00
Qty 6+ €239,50

3-4 days

[#71-809 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	76.20	203.20	f/2	Protected Silver (450-10000nm)		€299,00 Qty 6+ €239,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	---------------------------	----------

$\lambda/4$	76.20	76.20	f/1	Uncoated	#32-823	€201,00 Qty 10+ €170,00	3-4 days
-------------	-------	-------	-----	----------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	76.20	f/1	Protected Aluminum (400-2000nm)	#32-824	€242,00 Qty 10+ €205,50	3-4 days
-------------	-------	-------	-----	---------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	76.20	f/1	Enhanced Aluminum (250-700nm)	#43-553	€284,00 Qty 10+ €241,00	3-4 days
-------------	-------	-------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	76.20	f/1	Enhanced Aluminum (450-650nm)	#43-554	€284,00 Qty 10+ €241,00	3-4 days
-------------	-------	-------	-----	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	76.20	f/1	Protected Gold (700-10000nm)	#32-825	€337,00 Qty 10+ €286,00	Contact Us
-------------	-------	-------	-----	------------------------------	-------------------------	----------------------------	------------

[#71-810 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	76.20	304.80	f/4	Protected Silver (450-10000nm)		€299,00 Qty 6+ €239,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	---------------------------	----------

$\lambda/4$	76.20	152.40	f/2	Uncoated	#32-826	€201,00 Qty 10+ €170,00	3-4 days
-------------	-------	--------	-----	----------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	152.40	f/2	Protected Aluminum (400-2000nm)	#32-827	€242,00 Qty 10+ €205,50	Contact Us
-------------	-------	--------	-----	---------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	76.20	152.40	f/2	Enhanced Aluminum (250-700nm)	#43-555	€284,00 Qty 10+ €241,00	Contact Us
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	76.20	152.40	f/2	Enhanced Aluminum (450-650nm)	#43-556	€284,00 Qty 10+ €241,00	Contact Us
-------------	-------	--------	-----	-------------------------------	-------------------------	----------------------------	------------

$\lambda/4$	76.20	152.40	f/2	Protected Gold (700-10000nm)	#32-828	€337,00 Qty 10+ €286,00	3-4 days
-------------	-------	--------	-----	------------------------------	-------------------------	----------------------------	----------

[#71-811 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$	76.20	457.20	f/6	Protected Silver (450-10000nm)		€299,00 Qty 6+ €239,50	3-4 days
-------------	-------	--------	-----	--------------------------------	--	---------------------------	----------

$\lambda/4$	76.20	203.20	f/2.7	Uncoated	#43-582	€201,00 Qty 10+ €170,00	3-4 days
-------------	-------	--------	-------	----------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	203.20	f/2.7	Protected Aluminum (400-2000nm)	#43-583	€242,00 Qty 10+ €205,50	3-4 days
-------------	-------	--------	-------	---------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	203.20	f/2.7	Enhanced Aluminum (250-700nm)	#43-584	€284,00 Qty 10+ €241,00	3-4 days
-------------	-------	--------	-------	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	203.20	f/2.7	Enhanced Aluminum (450-650nm)	#43-585	€284,00 Qty 10+ €241,00	3-4 days
-------------	-------	--------	-------	-------------------------------	-------------------------	----------------------------	----------

$\lambda/4$	76.20	203.20	f/2.7	Protected Gold (700-10000nm)	#43-586	€337,00 Qty 10+ €286,00	3-4 days
-------------	-------	--------	-------	------------------------------	-------------------------	----------------------------	----------

[#71-812 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

$\lambda/4$

76.20

762.00

f/10

Protected
Silver
(450-
1000nm)

€299,00
Qty 6+ €239,50

3-4 days

$\lambda/4$

76.20

304.80

f/4

Uncoated

[#49-599](#)

€201,00
Qty 10+ €170,00

3-4 days

$\lambda/4$

76.20

304.80

f/4

Protected
Aluminum
(400-
2000nm)

[#49-604](#)

€242,00
Qty 10+ €205,50

Contact Us

$\lambda/4$

76.20

304.80

f/4

Enhanced
Aluminum
(250-
700nm)

[#49-609](#)

€284,00
Qty 10+ €241,00

Contact Us

$\lambda/4$

76.20

304.80

f/4

Enhanced
Aluminum
(450-
650nm)

[#49-614](#)

€284,00
Qty 10+ €241,00

3-4 days

$\lambda/4$

76.20

304.80

f/4

Protected
Gold
(700-
1000nm)

[#49-619](#)

€337,00
Qty 10+ €286,00

Contact Us

$\lambda/4$

76.20

457.20

f/6

Uncoated

[#32-829](#)

€201,00
Qty 10+ €170,00

3-4 days

$\lambda/4$

76.20

457.20

f/6

Protected
Aluminum
(400-
2000nm)

[#32-830](#)

€242,00
Qty 10+ €205,50

Contact Us

$\lambda/4$

76.20

457.20

f/6

Enhanced
Aluminum
(250-
700nm)

[#43-557](#)

€284,00
Qty 10+ €241,00

3-4 days

$\lambda/4$	76.20	457.20	f/6	Enhanced Aluminum (450-650nm)	#43-558	€284,00 Qty 10+ €241,00	Contact Us
$\lambda/4$	76.20	457.20	f/6	Protected Gold (700-10000nm)	#32-831	€337,00 Qty 10+ €286,00	3-4 days
$\lambda/4$	76.20	762.00	f/10	Uncoated	#32-832	€201,00 Qty 10+ €170,00	3-4 days
$\lambda/4$	76.20	762.00	f/10	Protected Aluminum (400-2000nm)	#32-833	€242,00 Qty 10+ €205,50	3-4 days
$\lambda/4$	76.20	762.00	f/10	Enhanced Aluminum (250-700nm)	#43-559	€284,00 Qty 10+ €241,00	3-4 days
$\lambda/4$	76.20	762.00	f/10	Enhanced Aluminum (450-650nm)	#43-560	€284,00 Qty 10+ €241,00	3-4 days
$\lambda/4$	76.20	762.00	f/10	Protected Gold (700-10000nm)	#32-834	€337,00 Qty 10+ €286,00	3-4 days
#71-813 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
$\lambda/4$	152.40	609.60	f/4	Protected Silver (450-10000nm)		€710,00 Qty 6+ €567,00	3-4 days
$\lambda/4$	152.40	609.60	f/4	Uncoated	#43-968	€505,00 Qty 5+ €430,50	3-4 days

$\lambda/4$	152.40	609.60	f/4	Protected Aluminum (400-2000nm)	#43-969	€585,00 Qty 5+ €496,50	3-4 days
$\lambda/4$	152.40	609.60	f/4	Enhanced Aluminum (250-700nm)	#43-970	€670,00 Qty 5+ €567,50	3-4 days
$\lambda/4$	152.40	609.60	f/4	Enhanced Aluminum (450-650nm)	#43-971	€670,00 Qty 5+ €567,50	Contact Us
$\lambda/4$	152.40	609.60	f/4	Protected Gold (700-10000nm)	#43-972	€770,00 Qty 5+ €653,50	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com