


[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Float Glass](#)

TECHSPEC®

First Surface Mirrors

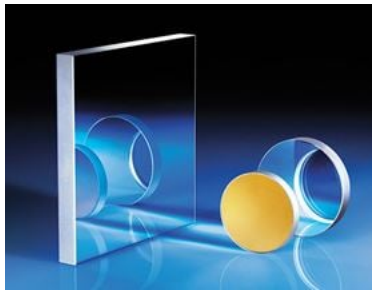


- Wide Variety of Shapes and Sizes Available
- Enhanced Aluminum, Protected Gold, and Protected Silver Coatings for high reflectivity from 450-10000nm
- [Contact Us](#) for Custom Sizes

Common Specifications

Optical Properties

Surface Flatness (P-V):	4 - 6λ	Substrate:	Float Glass
Surface Quality:	60-40	Coating Type:	Metal

Technical Information

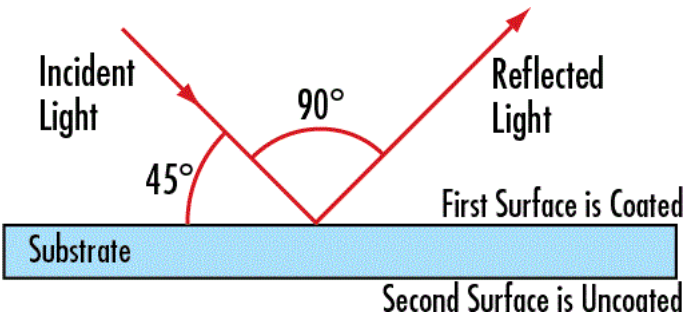

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Coating Specification	Surface Flatness (P-V)	Stock Number	Price	Buy
5.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-940	€25,50 Qty 6+ €19,25	In Stock
-	6.0 x 6.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-866	€25,50 Qty 6+ €19,25	In Stock
-	6.0 x 8.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-867	€25,50 Qty 6+ €19,25	In Stock
6.35	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-610	€25,50 Qty 6+ €19,25	3-4 days
10.00	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-941	€25,50 Qty 6+ €19,25	In Stock
-	10.0 x 10.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-517	€25,50 Qty 6+ €19,25	In Stock
-	10.0 x 14.0	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-449	€25,50 Qty 6+ €19,25	In Stock
12.50	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#32-942	€25,50 Qty 6+ €19,25	In Stock
-	12.5 x 12.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-790	€25,50 Qty 6+ €19,25	In Stock
-	12.5 x 17.5	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-869	€25,50 Qty 6+ €19,25	3-4 days
12.70	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-483	€25,50 Qty 6+ €19,25	In Stock
-	12.7 x 12.7	2.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-484	€25,50 Qty 6+ €19,25	In Stock

15.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#32-943	€25,50 Qty 6+ €19,25	In Stock
-	15.0 x 15.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-870	€25,50 Qty 6+ €19,25	In Stock
-	15.0 x 21.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-871	€25,50 Qty 6+ €19,25	In Stock
18.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#45-521	€25,50 Qty 6+ €19,25	3-4 days
20.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#32-944	€27,75 Qty 6+ €21,75	3-4 days
-	20.0 x 20.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-872	€27,75 Qty 6+ €21,75	In Stock
-	20.0 x 28.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-873	€27,75 Qty 6+ €21,75	In Stock
25.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#32-945	€27,75 Qty 6+ €21,75	In Stock
-	25.0 x 25.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-792	€27,75 Qty 6+ €21,75	In Stock
-	25.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#43-875	€27,75 Qty 6+ €21,75	In Stock
25.40	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#83-485	€27,75 Qty 6+ €21,75	In Stock
-	25.4 x 25.4	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#83-486	€27,75 Qty 6+ €21,75	In Stock
30.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#46-025	€32,00 Qty 6+ €25,00	In Stock
35.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#46-027	€32,00 Qty 6+ €25,00	In Stock

-	35.0 x 35.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-519	€32,00 Qty 6+ €25,00	3-4 days
-	35.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-450	€32,00 Qty 6+ €25,00	In Stock
38.10	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-487	€32,00 Qty 6+ €25,00	3-4 days
-	38.1 x 38.1	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-488	€32,00 Qty 6+ €25,00	In Stock
40.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-612	€41,00 Qty 6+ €31,75	In Stock
50.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-614	€41,00 Qty 6+ €31,75	3-4 days
-	50.0 x 50.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#43-876	€41,00 Qty 6+ €31,75	In Stock
-	50.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-451	€41,00 Qty 6+ €31,75	In Stock
50.80	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-489	€41,00 Qty 6+ €31,75	3-4 days
-	50.8 x 50.8	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-490	€41,00 Qty 6+ €31,75	In Stock
-	60.0 x 85.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#64-410	€49,50 Qty 6+ €37,50	In Stock
75.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#45-616	€49,50 Qty 6+ €37,50	3-4 days
-	75.0 x 75.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-452	€49,50 Qty 6+ €37,50	In Stock

-	75.0 x 100.0	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#48-453	€49,50 Qty 6+ €37,50	In Stock
76.20	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-491	€49,50 Qty 6+ €37,50	3-4 days
-	76.2 x 76.2	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#83-492	€49,50 Qty 6+ €37,50	3-4 days
100.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-920	€57,50 Qty 6+ €44,25	3-4 days
-	100.00 x 100.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-922	€57,50 Qty 6+ €44,25	In Stock
101.60	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-924	€57,50 Qty 6+ €44,25	3-4 days
-	101.60 x 101.60	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-926	€57,50 Qty 6+ €44,25	3-4 days
125.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-928	€74,00 Qty 6+ €57,25	3-4 days
-	125.00 x 125.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-930	€74,00 Qty 6+ €57,25	In Stock
127.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-932	€74,00 Qty 6+ €57,25	3-4 days
-	127.00 x 127.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#18-934	€74,00 Qty 6+ €57,25	In Stock
150.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-349	€92,00 Qty 6+ €69,75	In Stock
-	150.00 x 150.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-350	€92,00 Qty 6+ €69,75	In Stock

200.00	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-351	€122,00 Qty 6+ €94,00	3-4 days
-	200.00 x 200.00	3.00	Enhanced Aluminum (450-650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#19-352	€122,00 Qty 6+ €94,00	In Stock
5.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-728	€40,50 Qty 6+ €31,25	In Stock
-	6.0 x 6.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-877	€40,50 Qty 6+ €31,25	In Stock
-	6.0 x 8.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-878	€40,50 Qty 6+ €31,25	In Stock
6.35	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-611	€40,50 Qty 6+ €31,25	In Stock
10.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-729	€40,50 Qty 6+ €31,25	In Stock
-	10.0 x 10.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-518	€40,50 Qty 6+ €31,25	In Stock
-	10.0 x 14.0	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-454	€40,50 Qty 6+ €31,25	3-4 days
12.50	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-730	€40,50 Qty 6+ €31,25	3-4 days

-	12.5 x 12.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-791	€40,50 Qty 6+ €31,25	In Stock
-	12.5 x 17.5	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-880	€40,50 Qty 6+ €31,25	In Stock
12.70	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-493	€40,50 Qty 6+ €31,25	In Stock
-	12.7 x 12.7	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-494	€40,50 Qty 6+ €31,25	3-4 days
15.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-731	€40,50 Qty 6+ €31,25	In Stock
-	15.0 x 15.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-881	€40,50 Qty 6+ €31,25	3-4 days
-	15.0 x 21.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-882	€40,50 Qty 6+ €31,25	3-4 days
18.00	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-522	€40,50 Qty 6+ €31,25	3-4 days
20.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-732	€48,00 Qty 6+ €35,25	3-4 days
-	20.0 x 20.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-883	€48,00 Qty 6+ €35,25	3-4 days
-	20.0 x 28.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-884	€48,00 Qty 6+ €35,25	3-4 days

25.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-733	€48,00 Qty 6+ €35,25	In Stock
-	25.0 x 25.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-793	€48,00 Qty 6+ €35,25	3-4 days
-	25.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-886	€48,00 Qty 6+ €35,25	In Stock
25.40	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-495	€48,00 Qty 6+ €35,25	3-4 days
-	25.4 x 25.4	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-496	€48,00 Qty 6+ €35,25	3-4 days
30.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-026	€75,50 Qty 6+ €58,75	3-4 days
35.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#46-028	€75,50 Qty 6+ €58,75	3-4 days
-	35.0 x 35.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-520	€75,50 Qty 6+ €58,75	In Stock
-	35.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-455	€75,50 Qty 6+ €58,75	In Stock
38.10	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-497	€75,50 Qty 6+ €58,75	3-4 days
-	38.1 x 38.1	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-498	€75,50 Qty 6+ €58,75	3-4 days

40.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-613	€88,50 Qty 6+ €66,00	In Stock
50.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-615	€88,50 Qty 6+ €66,00	3-4 days
-	50.0 x 50.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#43-887	€88,50 Qty 6+ €66,00	In Stock
-	50.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-456	€88,50 Qty 6+ €66,00	Contact Us
50.80	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-499	€88,50 Qty 6+ €66,00	In Stock
-	50.8 x 50.8	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-500	€88,50 Qty 6+ €66,00	3-4 days
-	60.0 x 85.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#64-411	€117,00 Qty 6+ €88,00	3-4 days
75.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#45-617	€117,00 Qty 6+ €88,00	3-4 days
-	75.0 x 75.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-457	€117,00 Qty 6+ €88,00	3-4 days
-	75.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#48-458	€117,00 Qty 6+ €103,50	In Stock
76.20	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-501	€117,00 Qty 6+ €88,00	3-4 days

-	76.2 x 76.2	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#83-502	€117,00 Qty 6+ €103,50	3-4 days
100.00	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-431	€272,00 Qty 6+ €241,25	3-4 days
-	100.0 x 100.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	4 - 6λ	#22-432	€272,00 Qty 6+ €241,25	Contact Us
#71-427 New								
-	100.00 x 140.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€264,00	3-4 days
#71-426 New								
-	85.00 x 120.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€211,00 Qty 6+ €166,50	3-4 days

-	50.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-496	€49,50 Qty 6+ €43,75	In Stock
-	50.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-495	€49,50 Qty 6+ €37,00	In Stock
50.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-494	€49,50 Qty 6+ €37,00	In Stock
#71-424 New								
-	40.00 x 57.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€68,50 Qty 6+ €53,50	3-4 days
-	35.0 x 50.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-490	€38,25 Qty 6+ €28,50	Contact Us
-	35.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-489	€38,25 Qty 6+ €28,50	In Stock
35.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-488	€38,25 Qty 6+ €28,50	3-4 days

[#71-423 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	30.00 x 42.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ		€49,50	3-4 days
30.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-487	€38,25 Qty 6+ €28,50	In Stock
-	25.0 x 35.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-484	€33,50 Qty 6+ €24,50	In Stock
-	25.0 x 25.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-483	€33,50 Qty 6+ €24,50	3-4 days
25.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-482	€33,50 Qty 6+ €24,50	In Stock
-	20.0 x 28.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-481	€33,50 Qty 6+ €24,50	In Stock
-	20.0 x 20.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-480	€33,50 Qty 6+ €24,50	3-4 days
20.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-479	€33,50 Qty 6+ €24,50	3-4 days

-	15.0 x 21.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-477	€29,75 Qty 6+ €22,25	3-4 days
-	15.0 x 15.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-476	€29,75 Qty 6+ €22,25	In Stock
15.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-475	€29,75 Qty 6+ €22,25	3-4 days
#71-422 New								
-	17.50 x 25.00	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€33,50 Qty 6+ €26,25	3-4 days
-	12.5 x 17.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-472	€29,75 Qty 6+ €22,25	In Stock
-	12.5 x 12.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-471	€29,75 Qty 6+ €22,25	3-4 days
12.50	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-470	€29,75 Qty 6+ €22,25	In Stock
-	10.0 x 14.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-469	€29,75 Qty 6+ €22,25	3-4 days

-	10.0 x 10.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-468	€29,75 Qty 6+ €22,25	Contact Us
10.00	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-467	€29,75 Qty 6+ €22,25	In Stock
#71-421 New								
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!								
-	8.00 x 11.50	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ		€29,75 Qty 6+ €23,50	3-4 days
6.35	-	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-466	€29,75 Qty 6+ €22,25	3-4 days
-	6.0 x 8.5	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-465	€29,75 Qty 6+ €22,25	In Stock
-	6.0 x 6.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#89-464	€29,75 Qty 6+ €22,25	3-4 days

[#71-420 New](#)



New

-	5.00 x 7.50	2.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 800nm @ 0° AOI $R_{avg} > 98.5\%$ @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€29,75 Qty 6+ €23,50	3-4 days
---	-------------	------	--------------------------------	--	--------	--	-------------------------	----------

[#71-419 New](#)



New

-	5.00 x 5.00	2.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 800nm @ 0° AOI $R_{avg} > 98.5\%$ @ 2000 - 10,000nm @ 0° AOI	4 - 6λ	Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€29,75 Qty 6+ €23,50	3-4 days
---	-------------	------	--------------------------------	--	--------	--	-------------------------	----------

5.00	-	2.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	4 - 6λ	#89-463	€29,75 Qty 6+ €22,25	In Stock
------	---	------	--------------------------------	---	--------	-------------------------	-------------------------	----------

12.70	-	2.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	4 - 6λ	#36-040	€29,75 Qty 6+ €22,25	3-4 days
-------	---	------	--------------------------------	---	--------	-------------------------	-------------------------	----------

-	12.7 x 12.7	2.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	4 - 6λ	#36-041	€29,75 Qty 6+ €22,25	3-4 days
---	-------------	------	--------------------------------	---	--------	-------------------------	-------------------------	----------

18.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-042	€29,75 Qty 6+ €22,25	3-4 days
25.40	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-043	€33,50 Qty 6+ €24,50	In Stock
-	25.4 x 25.4	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-044	€33,50 Qty 6+ €24,50	3-4 days
38.10	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-045	€38,25 Qty 6+ €28,50	In Stock
-	38.1 x 38.1	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-046	€38,25 Qty 6+ €28,50	In Stock
40.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-048	€49,50 Qty 6+ €37,00	3-4 days
50.80	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-049	€49,50 Qty 6+ €37,00	In Stock
-	50.8 x 50.8	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-050	€49,50 Qty 6+ €37,00	Contact Us
-	60.0 x 85.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-051	€68,50 Qty 6+ €50,50	In Stock

[#71-425 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	63.50 x 88.90	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm @ 0° AOI R _{avg} >98.5% @ 2000 - 10,000nm @ 0° AOI	4 - 6λ		€80,00 Qty 6+ €62,50	3-4 days
75.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-053	€68,50 Qty 6+ €50,50	3-4 days
-	75.0 x 75.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-054	€68,50 Qty 6+ €60,75	In Stock
-	75.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-055	€68,50 Qty 6+ €60,75	In Stock
76.20	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-056	€68,50 Qty 6+ €60,75	In Stock
-	76.2 x 76.2	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#36-057	€68,50 Qty 6+ €60,75	3-4 days
100.00	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#22-443	€191,00 Qty 6+ €169,00	3-4 days
-	100.0 x 100.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	4 - 6λ	#22-444	€191,00 Qty 6+ €169,00	3-4 days

[#22-448 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	125.0 x 125.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	€264,00 Qty 6+ €208,00	3-4 days
---	---------------	------	--------------------------------	--	--------	---------------------------	----------

[#22-452 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	150.0 x 150.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 800nm R _{avg} >98.5% @ 2000 - 10,000nm	4 - 6λ	€369,00 Qty 6+ €291,25	Contact Us
---	---------------	------	--------------------------------	--	--------	---------------------------	------------

[#22-454 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	200.0 x 200.0	3.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 800nm $R_{avg} > 98.5\%$ @ 2000 - 10,000nm	4 - 6λ	€580,00	3-4 days
---	---------------	------	--------------------------------	--	--------	---------	----------

[#71-408 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5.0 x 5.0	2.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€25,50 Qty 6+ €20,00	3-4 days
---	-----------	------	-------------------------------	---	--------	-------------------------	----------

[#71-409 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	5.0 x 7.5	2.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€25,50 Qty 6+ €20,00	3-4 days
---	-----------	------	-------------------------------	---	--------	-------------------------	----------

[#71-410 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	8.0 x 11.5	2.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€25,50 Qty 6+ €20,00	3-4 days
---	------------	------	-------------------------------	---	--------	-------------------------	----------

[#71-411 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	17.5 x 25.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€25,50 Qty 6+ €20,00	3-4 days
---	-------------	------	-------------------------------	---	--------	-------------------------	----------

[#71-412 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	30.0 x 42.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€32,00 Qty 6+ €25,00	3-4 days
---	-------------	------	-------------------------------	---	--------	-------------------------	----------

[#71-413 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	40.0 x 57.5	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€41,00 Qty 6+ €32,00	3-4 days
---	-------------	------	-------------------------------	---	--------	-------------------------	----------

[#71-414 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	63.5 x 88.9	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\%$ @ 450 - 650nm @ 45°	4 - 6λ	€49,50 Qty 6+ €38,75	3-4 days
---	-------------	------	-------------------------------	---	--------	-------------------------	----------

[#71-415 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	85.0 x 120.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ		€53,50 Qty 6+ €41,50	3-4 days
---	--------------	------	-------------------------------	--	--------	--	-------------------------	----------

[#71-416 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	100.0 x 140.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ		€74,00 Qty 6+ €57,75	3-4 days
---	---------------	------	-------------------------------	--	--------	--	-------------------------	----------

-	125.00 x 175.00	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#29-413	€88,00 Qty 10+ €77,25	3-4 days
---	-----------------	------	-------------------------------	--	--------	-------------------------	--------------------------	----------

225.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#29-414	€137,00 Qty 10+ €121,75	3-4 days
--------	---	------	-------------------------------	--	--------	-------------------------	----------------------------	----------

-	225.00 x 225.00	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#29-415	€137,00 Qty 10+ €121,75	3-4 days
---	-----------------	------	-------------------------------	--	--------	-------------------------	----------------------------	----------

250.00	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} \geq 95\% @ 450 - 650nm @ 45^\circ$	4 - 6λ	#29-416	€153,00 Qty 10+ €135,75	3-4 days
--------	---	------	-------------------------------	--	--------	-------------------------	----------------------------	----------

-	250.00 x 250.00	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-417	€153,00 Qty 10+ €135,75	3-4 days
-	250.00 x 350.00	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-418	€200,00 Qty 10+ €177,75	3-4 days
300.00	-	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-419	€185,00 Qty 10+ €163,75	3-4 days
-	300.00 x 300.00	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	#29-420	€185,00 Qty 10+ €163,75	3-4 days
#71-417 New								
-	400.0 x 400.0	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€317,00 Qty 6+ €249,50	3-4 days
#71-418 New								
-	500.0 x 500.0	3.00	Enhanced Aluminum (450- 650nm)	R _{avg} ≥95% @ 450 - 650nm @ 45°	4 - 6λ	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€422,00 Qty 6+ €332,75	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com