

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Concave \(DCV\) Lenses](#)
TECHSPEC® Uncoated Double-Concave (DCV) Lenses


- Wavelength Range of 350-2200nm
- Precision Diameter and Centration Tolerances Allow for Easy OEM Integration
- Wide Variety of Diameters and Focal Lengths
- Additional AR Coating Options Available: [VIS-EXT](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), and [NIR II](#)

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Optical Properties

Coating:

Uncoated

**Focal Length
Specification
Wavelength (nm):**



587.6

**Focal Length Tolerance
(%):**
 ± 1
Surface Quality:

40-20

Power (P-V) @ 632.8nm:
 1.5λ
**Irregularity (P-V) @
632.8nm:**
 $\lambda/4$

Technical Information

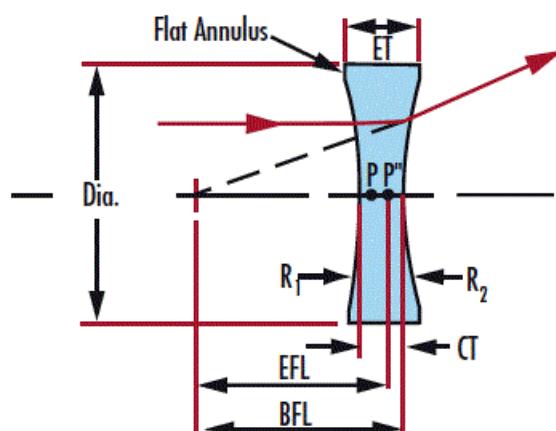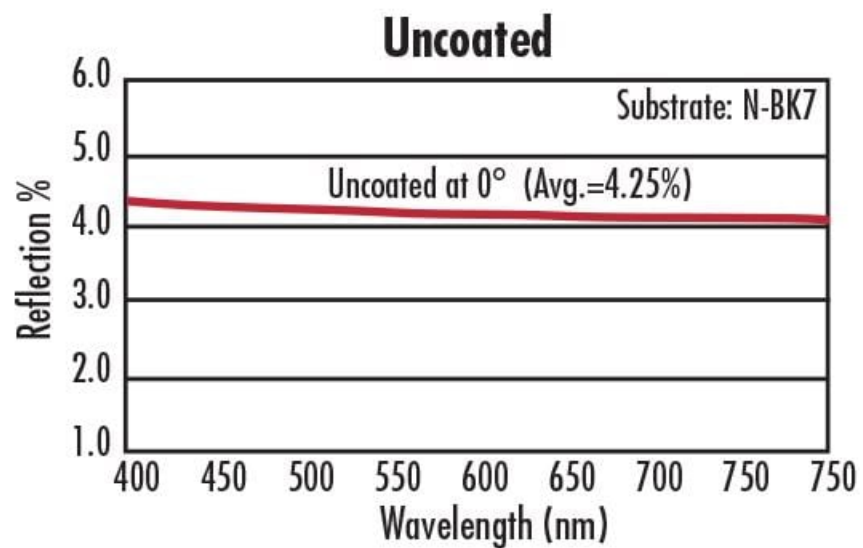

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	-6.00	-6.41	Uncoated	N-SF11	#32-986	€28,00 Qty 10+ €25,25	Contact Us
6.00	-9.00	-9.32	Uncoated	N-BK7	#48-932	€28,00 Qty 10+ €25,25	3-4 days
6.00	-12.00	-12.33	Uncoated	N-BK7	#48-681	€28,00 Qty 10+ €25,25	Contact Us
9.00	-9.00	-9.61	Uncoated	N-SF11	#48-336	€29,00 Qty 10+ €26,25	3-4 days
9.00	-12.00	-12.41	Uncoated	N-SF11	#48-933	€29,00 Qty 10+ €26,25	3-4 days
9.00	-18.00	-18.49	Uncoated	N-BK7	#48-682	€29,00 Qty 10+ €26,25	3-4 days
12.00	-12.00	-12.81	Uncoated	N-SF11	#32-988	€31,00 Qty 10+ €28,00	3-4 days
12.00	-18.00	-18.65	Uncoated	N-BK7	#48-934	€31,00 Qty 10+ €28,00	3-4 days
12.00	-24.00	-24.65	Uncoated	N-BK7	#48-683	€31,00 Qty 10+ €28,00	3-4 days
20.00	-20.00	-20.55	Uncoated	N-SF11	#32-990	€31,00 Qty 10+ €28,00	3-4 days
25.00	-25.00	-25.69	Uncoated	N-SF11	#32-992	€33,25 Qty 10+ €30,00	3-4 days
25.00	-50.00	-50.82	Uncoated	N-BK7	#32-996	€33,25 Qty 10+ €30,00	Contact Us
25.00	-100.00	-101.64	Uncoated	N-BK7	#32-994	€33,25 Qty 10+ €30,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com