

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

Traditional Coated 193 – 399nm Bandpass Interference Filters



- Available in UV, Visible, and IR Center Wavelengths
- 10 – 80nm Bandwidths Available
- Ideal for Biomedical Applications and Instrumentation Integration
- 193-399nm, [400-699nm](#), and [700-1650nm](#) CWL Options Available

Common Specifications




Physical & Mechanical Properties

Construction:	Mounted in Black Anodized Ring
---------------	--------------------------------

Optical Properties

Angle of Incidence (°):		0	
Coating:		Traditional Coated	
Surface Quality:		80-50	

Technical Information

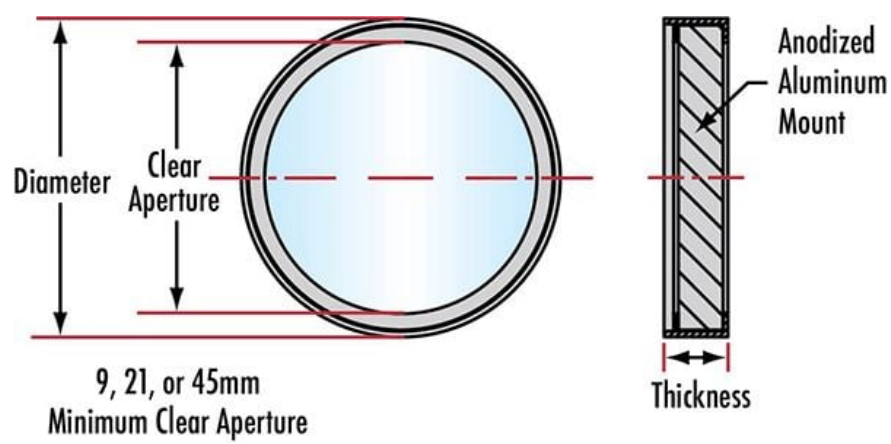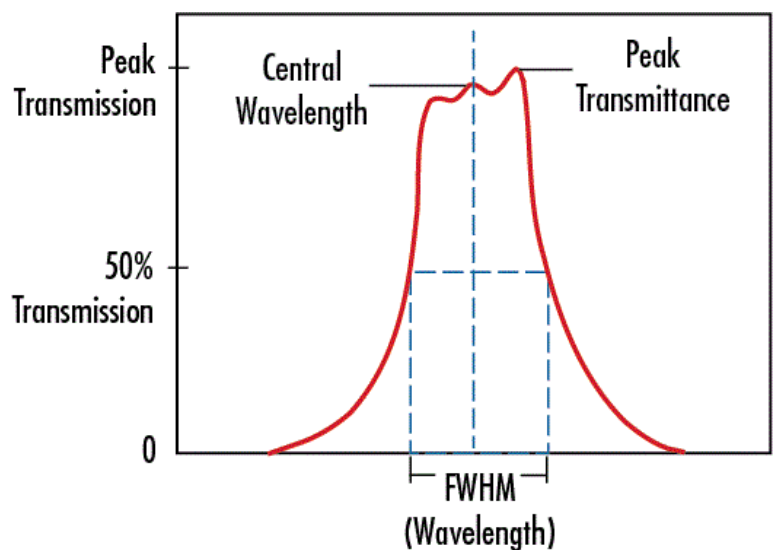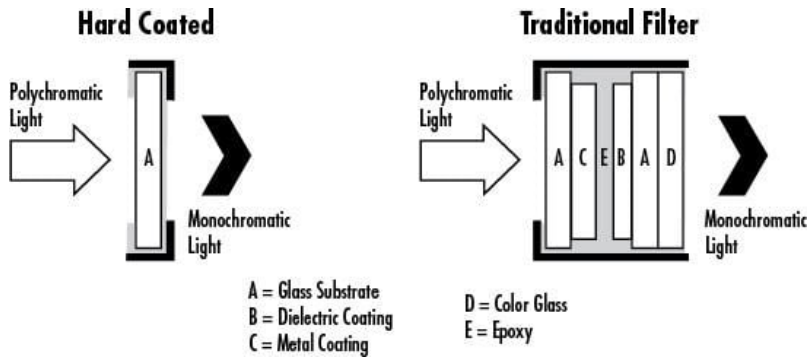

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Dimensions (mm)	Stock Number	Price	Buy
12.50	193.00	15.00	>12	200 - 10000	-	#67-732	€220,00 Qty 10+ €198,00	3-4 days
25.00	193.00	15.00	>12	200 - 10000	-	#67-799	€335,00 Qty 10+ €302,00	3-4 days
50.00	193.00	15.00	>12	200 - 10000	-	#67-866	€570,00 Qty 10+ €515,00	3-4 days
12.50	200.00	10.00	>12	200 - 10000	-	#67-733	€220,00 Qty 10+ €198,00	3-4 days
25.00	200.00	10.00	>12	200 - 10000	-	#67-800	€335,00 Qty 10+ €302,00	3-4 days
50.00	200.00	10.00	>12	200 - 10000	-	#67-867	€570,00 Qty 10+ €515,00	3-4 days
12.50	214.00	10.00	>12	200 - 10000	-	#67-734	€220,00 Qty 10+ €198,00	Contact Us
25.00	214.00	10.00	>12	200 - 10000	-	#67-801	€335,00 Qty 10+ €302,00	3-4 days
50.00	214.00	10.00	>12	200 - 10000	-	#67-868	€570,00 Qty 10+ €515,00	3-4 days
12.50	220.00	10.00	>12	200 - 10000	-	#67-735	€220,00 Qty 10+ €198,00	3-4 days
25.00	220.00	10.00	>12	200 - 10000	-	#67-802	€335,00 Qty 10+ €302,00	Contact Us
50.00	220.00	10.00	>12	200 - 10000	-	#67-869	€570,00 Qty 10+ €515,00	3-4 days
12.50	228.00	10.00	>15	200 - 10000	-	#67-736	€220,00 Qty 10+ €198,00	3-4 days
25.00	228.00	10.00	>15	200 - 10000	-	#67-803	€335,00 Qty 10+ €302,00	3-4 days
50.00	228.00	10.00	>15	200 - 10000	-	#67-870	€570,00 Qty 10+ €515,00	Contact Us
12.50	228.00	25.00	>20	200 - 10000	-	#68-336	€220,00 Qty 10+ €198,00	3-4 days
25.00	228.00	25.00	>20	200 - 10000	-	#68-337	€335,00 Qty 10+ €302,00	3-4 days

50.00	228.00	25.00	>20	200 - 10000	-	#68-338	€570,00 Qty 10+ €515,00	3-4 days
12.50	232.00	10.00	>15	200 - 10000	-	#67-737	€220,00 Qty 10+ €198,00	In Stock
25.00	232.00	10.00	>15	200 - 10000	-	#67-804	€335,00 Qty 10+ €302,00	3-4 days
50.00	232.00	10.00	>15	200 - 10000	-	#67-871	€570,00 Qty 10+ €515,00	3-4 days
12.50	239.00	10.00	>15	200 - 10000	-	#67-738	€220,00 Qty 10+ €198,00	3-4 days
25.00	239.00	10.00	>15	200 - 10000	-	#67-805	€335,00 Qty 10+ €302,00	3-4 days
50.00	239.00	10.00	>15	200 - 10000	-	#67-872	€570,00 Qty 10+ €515,00	3-4 days
12.50	248.00	10.00	>12	200 - 10000	-	#67-739	€220,00 Qty 10+ €198,00	3-4 days
25.00	248.00	10.00	>12	200 - 10000	-	#67-806	€335,00 Qty 10+ €302,00	3-4 days
50.00	248.00	10.00	>12	200 - 10000	-	#67-873	€570,00 Qty 10+ €515,00	3-4 days
12.50	250.00	10.00	>12	200 - 10000	-	#67-740	€162,00 Qty 10+ €146,00	3-4 days
25.00	250.00	10.00	>12	200 - 10000	-	#67-807	€277,00 Qty 10+ €249,00	3-4 days
50.00	250.00	10.00	>12	200 - 10000	-	#67-874	€510,00 Qty 10+ €459,00	3-4 days
12.50	254.00	10.00	>12	200 - 10000	-	#67-741	€162,00 Qty 10+ €146,00	Contact Us
25.00	254.00	10.00	>12	200 - 10000	-	#67-808	€277,00 Qty 10+ €249,00	3-4 days
50.00	254.00	10.00	>12	200 - 10000	-	#67-875	€510,00 Qty 10+ €459,00	3-4 days
12.50	254.00	40.00	>20	200 - 10000	-	#67-742	€162,00 Qty 10+ €146,00	3-4 days
25.00	254.00	40.00	>20	200 - 10000	-	#67-809	€277,00 Qty 10+ €249,00	3-4 days
50.00	254.00	40.00	>20	200 - 10000	-	#67-876	€510,00 Qty 10+ €459,00	3-4 days
12.50	260.00	10.00	>12	200 - 10000	-	#67-743	€162,00 Qty 10+ €146,00	3-4 days
25.00	260.00	10.00	>12	200 - 10000	-	#67-810	€277,00 Qty 10+ €249,00	In Stock

50.00	260.00	10.00	>12	200 - 10000	-	#67-877	€510,00 Qty 10+ €459,00	3-4 days
12.50	265.00	10.00	>12	200 - 10000	-	#67-744	€162,00 Qty 10+ €146,00	In Stock
25.00	265.00	10.00	>12	200 - 10000	-	#67-811	€277,00 Qty 10+ €249,00	3-4 days
50.00	265.00	10.00	>12	200 - 10000	-	#67-878	€510,00 Qty 10+ €459,00	3-4 days
12.50	270.00	10.00	>12	200 - 10000	-	#67-745	€162,00 Qty 10+ €146,00	3-4 days
25.00	270.00	10.00	>12	200 - 10000	-	#67-812	€277,00 Qty 10+ €249,00	3-4 days
50.00	270.00	10.00	>12	200 - 10000	-	#67-879	€510,00 Qty 10+ €459,00	3-4 days
12.50	280.00	10.00	>12	200 - 10000	-	#67-746	€162,00 Qty 10+ €146,00	In Stock
25.00	280.00	10.00	>12	200 - 10000	-	#67-813	€277,00 Qty 10+ €249,00	3-4 days
50.00	280.00	10.00	>12	200 - 10000	-	#67-880	€510,00 Qty 10+ €459,00	3-4 days
12.50	289.00	10.00	>15	200 - 10000	-	#67-747	€162,00 Qty 10+ €146,00	3-4 days
25.00	289.00	10.00	>15	200 - 10000	-	#67-814	€277,00 Qty 10+ €249,00	3-4 days
50.00	289.00	10.00	>15	200 - 10000	-	#67-881	€510,00 Qty 10+ €459,00	3-4 days
12.50	297.00	10.00	>15	200 - 10000	-	#67-748	€162,00 Qty 10+ €146,00	3-4 days
25.00	297.00	10.00	>15	200 - 10000	-	#67-815	€277,00 Qty 10+ €249,00	3-4 days
50.00	297.00	10.00	>15	200 - 10000	-	#67-882	€510,00 Qty 10+ €459,00	3-4 days
12.50	300.00	10.00	>15	200 - 10000	-	#67-749	€162,00 Qty 10+ €146,00	In Stock
12.50	300.00	40.00	>20	200 - 10000	-	#67-750	€162,00 Qty 10+ €146,00	3-4 days
25.00	300.00	10.00	>15	200 - 10000	-	#67-816	€277,00 Qty 10+ €249,00	3-4 days
25.00	300.00	40.00	>20	200 - 10000	-	#67-817	€277,00 Qty 10+ €249,00	3-4 days

50.00	300.00	10.00	>15	200 - 10000	-	#67-883	€510,00 Qty 10+ €459,00	3-4 days
50.00	300.00	40.00	>20	200 - 10000	-	#67-884	€510,00 Qty 10+ €459,00	3-4 days
25.00	320.00	10.00	>25	200 - 10000	-	#67-821	€277,00 Qty 10+ €249,00	3-4 days
12.50	307.00	10.00	>15	200 - 10000	-	#67-751	€162,00 Qty 10+ €146,00	3-4 days
25.00	307.00	10.00	>15	200 - 10000	-	#67-818	€277,00 Qty 10+ €249,00	3-4 days
50.00	307.00	10.00	>15	200 - 10000	-	#67-885	€510,00 Qty 10+ €459,00	3-4 days
12.50	310.00	10.00	>15	200 - 10000	-	#67-752	€162,00 Qty 10+ €146,00	3-4 days
25.00	310.00	10.00	>15	200 - 10000	-	#67-819	€277,00 Qty 10+ €249,00	Contact Us
50.00	310.00	10.00	>15	200 - 10000	-	#67-886	€510,00 Qty 10+ €459,00	3-4 days
12.50	313.00	10.00	>15	200 - 10000	-	#67-753	€162,00 Qty 10+ €146,00	In Stock
25.00	313.00	10.00	>15	200 - 10000	-	#67-820	€277,00 Qty 10+ €249,00	3-4 days
50.00	313.00	10.00	>15	200 - 10000	-	#67-887	€510,00 Qty 10+ €459,00	3-4 days
12.50	320.00	10.00	>25	200 - 10000	-	#67-754	€162,00 Qty 10+ €146,00	3-4 days
50.00	320.00	10.00	>25	200 - 10000	-	#67-888	€510,00 Qty 10+ €459,00	3-4 days
12.50	326.00	10.00	>25	200 - 10000	-	#67-755	€162,00 Qty 10+ €146,00	Contact Us
25.00	326.00	10.00	>25	200 - 10000	-	#67-822	€277,00 Qty 10+ €249,00	3-4 days
50.00	326.00	10.00	>25	200 - 10000	-	#67-889	€510,00 Qty 10+ €459,00	3-4 days
12.50	330.00	10.00	>25	200 - 10000	-	#67-756	€162,00 Qty 10+ €146,00	In Stock
25.00	330.00	10.00	>25	200 - 10000	-	#67-823	€277,00 Qty 10+ €249,00	3-4 days
50.00	330.00	10.00	>25	200 - 10000	-	#67-890	€510,00 Qty 10+ €459,00	3-4 days

12.50	350.00	10.00	>25	200 - 10000	-	#67-757	€162,00 Qty 10+ €146,00	3-4 days
12.50	350.00	40.00	>25	200 - 10000	-	#67-758	€162,00 Qty 10+ €146,00	In Stock
25.00	350.00	10.00	>25	200 - 10000	-	#67-824	€277,00 Qty 10+ €249,00	3-4 days
25.00	350.00	40.00	>25	200 - 10000	-	#67-825	€277,00 Qty 10+ €249,00	3-4 days
50.00	350.00	10.00	>25	200 - 10000	-	#67-891	€510,00 Qty 10+ €459,00	3-4 days
50.00	350.00	40.00	>25	200 - 10000	-	#67-892	€510,00 Qty 10+ €459,00	3-4 days
12.50	355.00	10.00	>25	200 - 10000	-	#67-759	€162,00 Qty 10+ €146,00	3-4 days
25.00	355.00	10.00	>25	200 - 10000	-	#67-826	€277,00 Qty 10+ €249,00	3-4 days
50.00	355.00	10.00	>25	200 - 10000	-	#67-893	€510,00 Qty 10+ €459,00	3-4 days
12.50	360.00	10.00	>25	200 - 10000	-	#67-760	€162,00 Qty 10+ €146,00	In Stock
25.00	360.00	10.00	>25	200 - 10000	-	#67-827	€277,00 Qty 10+ €249,00	3-4 days
50.00	360.00	10.00	>25	200 - 10000	-	#67-894	€510,00 Qty 10+ €459,00	3-4 days
12.50	370.00	10.00	>25	200 - 10000	-	#67-761	€162,00 Qty 10+ €146,00	3-4 days
25.00	370.00	10.00	>25	200 - 10000	-	#67-828	€277,00 Qty 10+ €249,00	3-4 days
50.00	370.00	10.00	>25	200 - 10000	-	#67-895	€510,00 Qty 10+ €459,00	3-4 days
12.50	380.00	10.00	>25	200 - 10000	-	#67-762	€162,00 Qty 10+ €146,00	3-4 days
25.00	380.00	10.00	>25	200 - 10000	-	#67-829	€277,00 Qty 10+ €249,00	3-4 days
50.00	380.00	10.00	>25	200 - 10000	-	#67-896	€510,00 Qty 10+ €459,00	3-4 days
12.50	390.00	10.00	>40	200 - 10000	-	#67-763	€162,00 Qty 10+ €146,00	3-4 days
25.00	390.00	10.00	>40	200 - 10000	-	#67-830	€277,00 Qty 10+ €249,00	3-4 days

50.00	390.00	10.00	>40	200 - 10000	-	#67-897	€510,00 Qty 10+ €459,00	3-4 days
12.50	394.00	10.00	≥30	200 - 1200	-	#65-616	€162,00 Qty 10+ €146,00	3-4 days
	Edmund optics worldwide	200 - 1200	-	#65-676	€277,00 Qty 10+ €249,00	3-4 days		

Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com