


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)

TECHSPEC® 1λ UV Fused Silica Windows

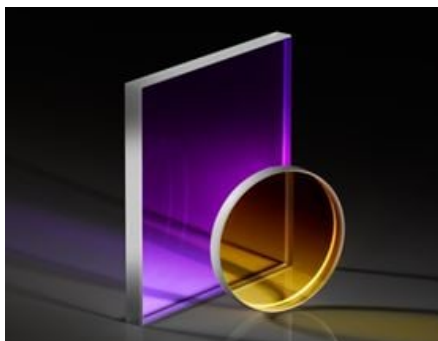

- Available Uncoated or with Broadband Anti-Reflection Coatings
- Ideal for Cost Sensitive Broadband Applications
- Circular and Square Sizes from 5mm to 100mm
- [λ/4](#) or [λ/10](#) UV Fused Silica Windows Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground	Knoop Hardness (kg/mm²):	522.00
Parallelism (arcmin):	<5	Poisson's Ratio:	0.16
Young's Modulus (GPa):	73		


Optical Properties

Abbe Number (v_d):	67.8		
Index of Refraction (n_d):	1.458	Surface Quality:	60-40



Material Properties

Coefficient of Thermal Expansion CTE (10⁻⁶/°C):	0.52 (+5 to +35°C) 0.57 (0 to +200°C) 0.48 (-100 to +200°C)	Density (g/cm³):	2.20
---	---	------------------------------------	------


Technical Information

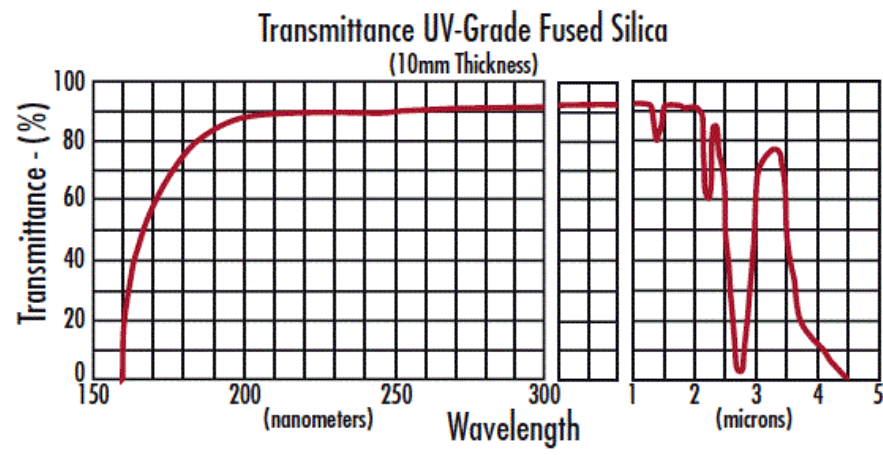


UV FS Transmission Curve

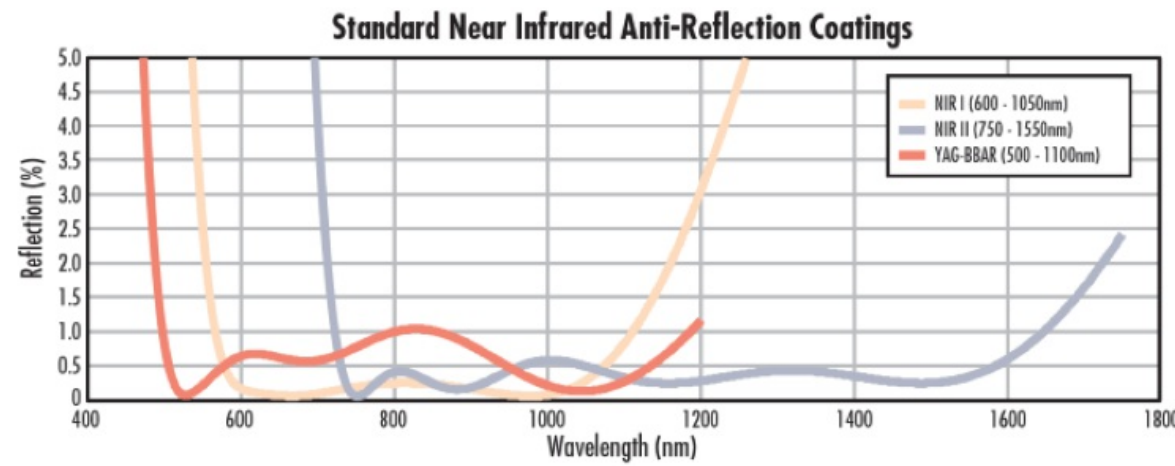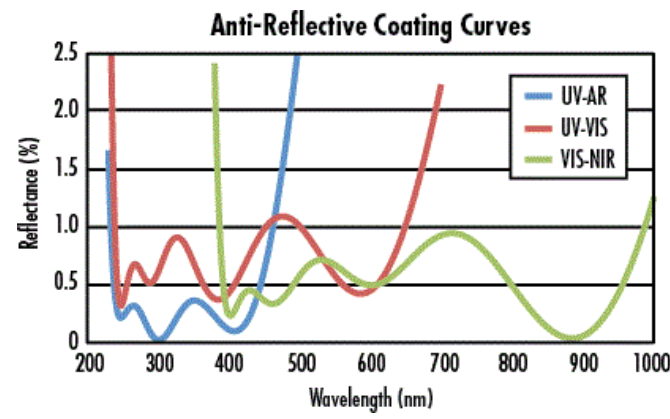

Standard Visible Anti-Reflection Coatings

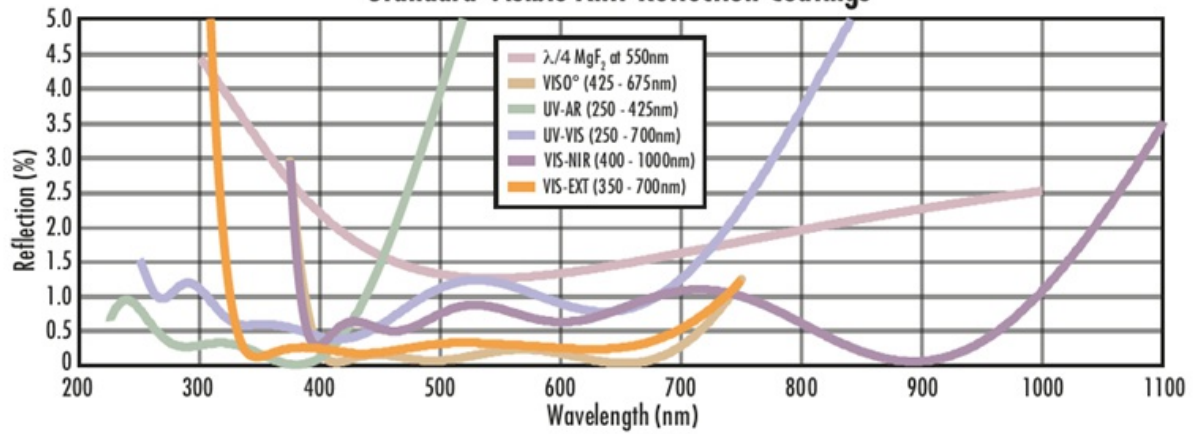

Standard Near Infrared Anti-Reflection Coatings

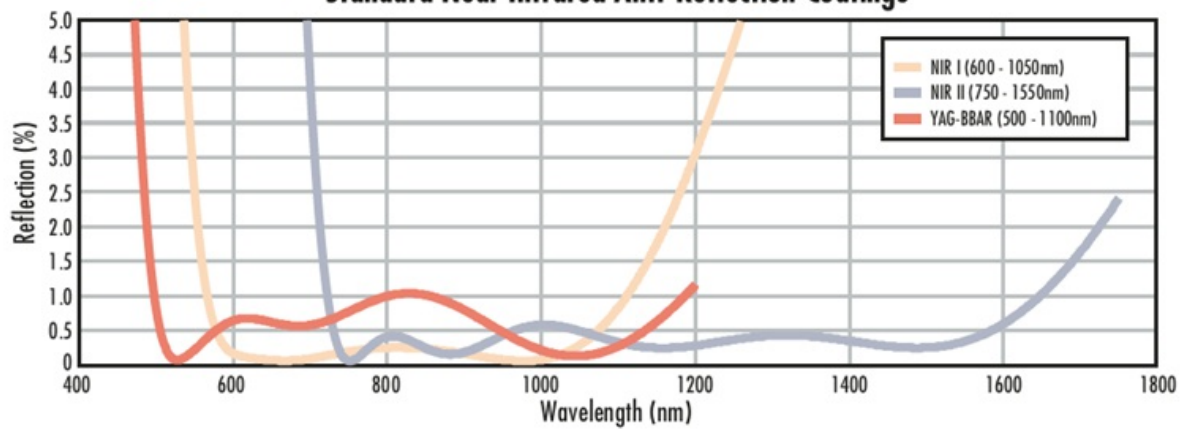

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.00	Uncoated	#45-463	€66,44 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-AR (250-425nm)	#45-807	€93,22 Volume Pricing	20+ In Stock
5.00	-	1.00	UV-VIS (250-700nm)	#84-469	€93,22 Volume Pricing	5 In Stock
5.00	-	1.00	VIS-EXT (350-700nm)	#25-184	€96,31 Volume Pricing	4 In Stock
5.00	-	1.00	MgF ₂ (400-700nm)	#11-917	€79,83 Volume Pricing	5 In Stock
5.00	-	1.00	VIS 0° (425-675nm)	#36-990	€90,64 Volume Pricing	20+ In Stock
5.00	-	1.00	VIS-NIR (400-1000nm)	#49-637	€96,31 Volume Pricing	9 In Stock
5.00	-	1.00	YAG-BBAR (500-1100nm)	#25-213	€96,31 Volume Pricing	8 In Stock
5.00	-	1.00	NIR I (600-1050nm)	#36-989	€90,64 Volume Pricing	20+ In Stock
5.00	-	1.00	NIR II (750-1550nm)	#39-293	€90,64 Volume Pricing	1 In Stock
10.00	-	1.00	Uncoated	#45-308	€66,44 Volume Pricing	20+ In Stock
10.00	-	1.00	UV-AR (250-425nm)	#45-808	€93,22 Volume Pricing	14 In Stock
10.00	-	1.00	UV-VIS (250-700nm)	#84-470	€93,22 Volume Pricing	1 In Stock

10.00	-	1.00	VIS-EXT (350-700nm)	#25-185	€96,31 Volume Pricing	3 In Stock
10.00	-	1.00	MgF ₂ (400-700nm)	#11-918	€79,83 Volume Pricing	8 In Stock
10.00	-	1.00	VIS 0° (425-675nm)	#36-968	€90,64 Volume Pricing	20+ In Stock
10.00	-	1.00	VIS-NIR (400-1000nm)	#49-638	€96,31 Volume Pricing	20+ In Stock
10.00	-	1.00	YAG-BBAR (500-1100nm)	#25-214	€96,31 Volume Pricing	11 In Stock
10.00	-	1.00	NIR I (600-1050nm)	#36-967	€90,64 Volume Pricing	Contact Us
10.00	-	1.00	NIR II (750-1550nm)	#39-294	€90,64 Volume Pricing	20+ In Stock
12.50	-	1.00	Uncoated	#22-692	€66,44 Volume Pricing	20+ In Stock
12.50	-	1.00	UV-AR (250-425nm)	#23-302	€93,22 Volume Pricing	1 In Stock
12.50	-	1.00	UV-VIS (250-700nm)	#23-303	€93,22 Volume Pricing	2 In Stock
12.50	-	1.00	VIS-EXT (350-700nm)	#25-186	€96,31 Volume Pricing	3 In Stock
12.50	-	1.00	MgF ₂ (400-700nm)	#23-301	€79,83 Volume Pricing	4 In Stock
12.50	-	1.00	VIS 0° (425-675nm)	#23-304	€90,64 Volume Pricing	9 In Stock
12.50	-	1.00	VIS-NIR (400-1000nm)	#23-305	€96,31 Volume Pricing	6 In Stock

12.50	-	1.00	YAG-BBAR (500-1100nm)	#25-215	€96,31 Volume Pricing	3 In Stock
12.50	-	1.00	NIR I (600-1050nm)	#23-306	€90,64 Volume Pricing	7 In Stock
12.50	-	1.00	NIR II (750-1550nm)	#23-307	€90,64 Volume Pricing	5 In Stock
12.50	-	2.00	Uncoated	#45-309	€66,44 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-AR (250-425nm)	#45-809	€93,22 Volume Pricing	20+ In Stock
12.50	-	2.00	UV-VIS (250-700nm)	#84-471	€93,22 Volume Pricing	11 In Stock
12.50	-	2.00	VIS-EXT (350-700nm)	#25-187	€96,31 Volume Pricing	5 In Stock
12.50	-	2.00	MgF ₂ (400-700nm)	#11-919	€79,83 Volume Pricing	5 In Stock
12.50	-	2.00	VIS 0° (425-675nm)	#36-970	€90,64 Volume Pricing	5 In Stock
12.50	-	2.00	VIS-NIR (400-1000nm)	#49-639	€96,31 Volume Pricing	11 In Stock
12.50	-	2.00	YAG-BBAR (500-1100nm)	#25-216	€96,31 Volume Pricing	4 In Stock
12.50	-	2.00	NIR I (600-1050nm)	#36-969	€90,64 Volume Pricing	9 In Stock
12.50	-	2.00	NIR II (750-1550nm)	#39-295	€90,64 Volume Pricing	20+ In Stock
-	12.50 x 12.50	2.00	Uncoated	#48-200	€69,01 Volume Pricing	20+ In Stock

-	12.50 x 12.50	2.00	UV-AR (250-425nm)	#48-202	€96,31 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	UV-VIS (250-700nm)	#84-472	€96,31 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	VIS-EXT (350-700nm)	#25-188	€98,88 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	MgF ₂ (400-700nm)	#11-920	€82,40 Volume Pricing	6 In Stock
-	12.50 x 12.50	2.00	VIS 0° (425-675nm)	#36-972	€93,22 Volume Pricing	Contact Us
-	12.50 x 12.50	2.00	VIS-NIR (400-1000nm)	#49-640	€98,88 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	YAG-BBAR (500-1100nm)	#25-217	€98,88 Volume Pricing	5 In Stock
-	12.50 x 12.50	2.00	NIR I (600-1050nm)	#36-971	€93,22 Volume Pricing	9 In Stock
-	12.50 x 12.50	2.00	NIR II (750-1550nm)	#39-296	€90,64 Volume Pricing	1 In Stock
-	12.50 x 17.50	2.00	Uncoated	#71-192	€70,04 Volume Pricing	8 In Stock
12.70	-	2.00	Uncoated	#15-307	€66,44 Volume Pricing	1 In Stock
12.70	-	2.00	UV-AR (250-425nm)	#25-252	€93,22 Volume Pricing	3 In Stock
12.70	-	2.00	UV-VIS (250-700nm)	#25-263	€93,22 Volume Pricing	2 In Stock
12.70	-	2.00	VIS-EXT (350-700nm)	#25-189	€96,31 Volume Pricing	3 In Stock

12.70	-	2.00	MgF ₂ (400-700nm)	#25-318	€79,83 Volume Pricing	5 In Stock
12.70	-	2.00	VIS 0° (425-675nm)	#25-274	€90,64 Volume Pricing	3 In Stock
12.70	-	2.00	VIS-NIR (400-1000nm)	#25-307	€96,31 Volume Pricing	2 In Stock
12.70	-	2.00	YAG-BBAR (500-1100nm)	#25-218	€96,31 Volume Pricing	5 In Stock
12.70	-	2.00	NIR I (600-1050nm)	#25-285	€90,64 Volume Pricing	3 In Stock
12.70	-	2.00	NIR II (750-1550nm)	#25-296	€90,64 Volume Pricing	4 In Stock
15.00	-	1.00	Uncoated	#22-693	€69,01 Volume Pricing	20+ In Stock
15.00	-	1.00	UV-AR (250-425nm)	#23-309	€96,31 Volume Pricing	1 In Stock
15.00	-	1.00	UV-VIS (250-700nm)	#23-310	€96,31 Volume Pricing	5 In Stock
15.00	-	1.00	VIS-EXT (350-700nm)	#25-190	€98,88 Volume Pricing	5 In Stock
15.00	-	1.00	MgF ₂ (400-700nm)	#23-308	€82,40 Volume Pricing	3 In Stock
15.00	-	1.00	VIS 0° (425-675nm)	#23-311	€93,22 Volume Pricing	4 In Stock
15.00	-	1.00	VIS-NIR (400-1000nm)	#23-312	€98,88 Volume Pricing	2 In Stock
15.00	-	1.00	YAG-BBAR (500-1100nm)	#25-219	€98,88 Volume Pricing	5 In Stock

15.00	-	1.00	NIR I (600-1050nm)	#23-313	€93,22 Volume Pricing	1 In Stock
15.00	-	1.00	NIR II (750-1550nm)	#23-314	€93,22 Volume Pricing	2 In Stock
15.00	-	2.00	Uncoated	#45-310	€69,01 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-AR (250-425nm)	#45-810	€96,31 Volume Pricing	20+ In Stock
15.00	-	2.00	UV-VIS (250-700nm)	#84-473	€96,31 Volume Pricing	5 In Stock
15.00	-	2.00	VIS-EXT (350-700nm)	#25-191	€98,88 Volume Pricing	6 In Stock
15.00	-	2.00	MgF ₂ (400-700nm)	#11-921	€82,40 Volume Pricing	2 In Stock
15.00	-	2.00	VIS 0° (425-675nm)	#36-974	€93,22 Volume Pricing	17 In Stock
15.00	-	2.00	VIS-NIR (400-1000nm)	#49-641	€98,88 Volume Pricing	2 In Stock
15.00	-	2.00	YAG-BBAR (500-1100nm)	#25-220	€98,88 Volume Pricing	2 In Stock
15.00	-	2.00	NIR I (600-1050nm)	#36-973	€93,22 Volume Pricing	5 In Stock
15.00	-	2.00	NIR II (750-1550nm)	#39-297	€93,22 Volume Pricing	3 In Stock
20.00	-	1.00	Uncoated	#22-694	€71,59 Volume Pricing	20+ In Stock
20.00	-	1.00	UV-AR (250-425nm)	#23-316	€98,88 Volume Pricing	5 In Stock
20.00	-	1.00	UV-VIS (250-700nm)	#23-317	€98,88 Volume Pricing	3 In Stock

20.00	-	1.00	VIS-EXT (350-700nm)	#25-192	€101,46 Volume Pricing	5 In Stock
20.00	-	1.00	MgF ₂ (400-700nm)	#23-315	€85,49 Volume Pricing	3 In Stock
20.00	-	1.00	VIS 0° (425-675nm)	#23-318	€96,31 Volume Pricing	Contact Us
20.00	-	1.00	VIS-NIR (400-1000nm)	#23-319	€101,46 Volume Pricing	Contact Us
20.00	-	1.00	YAG-BBAR (500-1100nm)	#25-221	€101,46 Volume Pricing	4 In Stock
20.00	-	1.00	NIR I (600-1050nm)	#23-320	€96,31 Volume Pricing	4 In Stock
20.00	-	1.00	NIR II (750-1550nm)	#23-321	€96,31 Volume Pricing	4 In Stock
20.00	-	2.00	Uncoated	#45-464	€71,59 Volume Pricing	20+ In Stock
20.00	-	2.00	UV-AR (250-425nm)	#45-811	€98,88 Volume Pricing	8 In Stock
20.00	-	2.00	UV-VIS (250-700nm)	#84-474	€98,88 Volume Pricing	20+ In Stock
20.00	-	2.00	VIS-EXT (350-700nm)	#25-193	€101,46 Volume Pricing	5 In Stock
20.00	-	2.00	MgF ₂ (400-700nm)	#11-922	€85,49 Volume Pricing	4 In Stock
20.00	-	2.00	VIS 0° (425-675nm)	#36-976	€96,31 Volume Pricing	20+ In Stock

20.00	-	2.00	VIS-NIR (400-1000nm)	#49-642	€101,46 Volume Pricing	20+ In Stock
20.00	-	2.00	YAG-BBAR (500-1100nm)	#25-222	€101,46 Volume Pricing	8 In Stock
20.00	-	2.00	NIR I (600-1050nm)	#36-975	€96,31 Volume Pricing	12 In Stock
20.00	-	2.00	NIR II (750-1550nm)	#39-298	€96,31 Volume Pricing	5 In Stock
25.00	-	1.00	Uncoated	#19-837	€76,22 Volume Pricing	1 In Stock
25.00	-	1.00	UV-AR (250-425nm)	#19-846	€103,00 Volume Pricing	7 In Stock
25.00	-	1.00	UV-VIS (250-700nm)	#19-847	€103,00 Volume Pricing	1 In Stock
25.00	-	2.00	VIS-EXT (350-700nm)	#25-195	€106,09 Volume Pricing	12 In Stock
25.00	-	1.00	MgF ₂ (400-700nm)	#19-845	€89,61 Volume Pricing	6 In Stock
25.00	-	1.00	VIS 0° (425-675nm)	#19-848	€100,43 Volume Pricing	5 In Stock
25.00	-	1.00	VIS-NIR (400-1000nm)	#19-849	€106,09 Volume Pricing	15 In Stock
25.00	-	2.00	YAG-BBAR (500-1100nm)	#25-224	€106,09 Volume Pricing	Contact Us
25.00	-	1.00	NIR I (600-1050nm)	#19-850	€100,43 Volume Pricing	4 In Stock
25.00	-	1.00	NIR II (750-1550nm)	#19-851	€100,43 Volume Pricing	6 In Stock

25.00	-	2.00	Uncoated	#45-311	€76,22 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-AR (250-425nm)	#45-812	€103,00 Volume Pricing	20+ In Stock
25.00	-	2.00	UV-VIS (250-700nm)	#84-475	€103,00 Volume Pricing	20+ In Stock
25.00	-	1.00	VIS-EXT (350-700nm)	#25-194	€106,09 Volume Pricing	8 In Stock
25.00	-	2.00	MgF ₂ (400-700nm)	#11-923	€89,61 Volume Pricing	17 In Stock
25.00	-	2.00	VIS 0° (425-675nm)	#36-978	€100,43 Volume Pricing	8 In Stock
25.00	-	2.00	VIS-NIR (400-1000nm)	#49-643	€106,09 Volume Pricing	20+ In Stock
25.00	-	1.00	YAG-BBAR (500-1100nm)	#25-223	€106,09 Volume Pricing	2 In Stock
25.00	-	2.00	NIR I (600-1050nm)	#36-977	€100,43 Volume Pricing	5 In Stock
25.00	-	2.00	NIR II (750-1550nm)	#39-299	€100,43 Volume Pricing	9 In Stock
25.00	-	3.00	Uncoated	#19-838	€76,22 Volume Pricing	14 In Stock
25.00	-	3.00	UV-AR (250-425nm)	#19-853	€103,00 Volume Pricing	5 In Stock
25.00	-	3.00	UV-VIS (250-700nm)	#19-854	€103,00 Volume Pricing	3 In Stock
25.00	-	3.00	VIS-EXT (350-700nm)	#25-196	€106,09 Volume Pricing	9 In Stock

25.00	-	3.00	MgF ₂ (400-700nm)	#19-852	€89,61 Volume Pricing	5 In Stock
25.00	-	3.00	VIS 0° (425-675nm)	#19-855	€100,43 Volume Pricing	1 In Stock
25.00	-	3.00	VIS-NIR (400-1000nm)	#19-856	€106,09 Volume Pricing	8 In Stock
25.00	-	3.00	YAG-BBAR (500-1100nm)	#25-225	€106,09 Volume Pricing	4 In Stock
25.00	-	3.00	NIR I (600-1050nm)	#19-857	€100,43 Volume Pricing	3 In Stock
25.00	-	3.00	NIR II (750-1550nm)	#19-858	€100,43 Volume Pricing	14 In Stock
25.00	-	4.00	Uncoated	#19-839	€76,22 Volume Pricing	16 In Stock
25.00	-	4.00	UV-AR (250-425nm)	#19-860	€103,00 Volume Pricing	3 In Stock
25.00	-	4.00	UV-VIS (250-700nm)	#19-861	€103,00 Volume Pricing	3 In Stock
25.00	-	4.00	VIS-EXT (350-700nm)	#25-197	€106,09 Volume Pricing	2 In Stock
25.00	-	4.00	MgF ₂ (400-700nm)	#19-859	€89,61 Volume Pricing	4 In Stock
25.00	-	4.00	VIS 0° (425-675nm)	#19-862	€100,43 Volume Pricing	1 In Stock
25.00	-	4.00	VIS-NIR (400-1000nm)	#19-863	€106,09 Volume Pricing	8 In Stock
25.00	-	4.00	YAG-BBAR (500-1100nm)	#25-226	€106,09 Volume Pricing	7 In Stock

25.00	-	4.00	NIR I (600-1050nm)	#19-864	€100,43 Volume Pricing	5 In Stock
25.00	-	4.00	NIR II (750-1550nm)	#19-865	€100,43 Volume Pricing	10 In Stock
25.00	-	5.00	Uncoated	#19-840	€76,22 Volume Pricing	1 In Stock
25.00	-	5.00	UV-AR (250-425nm)	#19-867	€103,00 Volume Pricing	4 In Stock
25.00	-	5.00	UV-VIS (250-700nm)	#19-868	€103,00 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-EXT (350-700nm)	#25-198	€106,09 Volume Pricing	5 In Stock
25.00	-	5.00	MgF ₂ (400-700nm)	#19-866	€89,61 Volume Pricing	5 In Stock
25.00	-	5.00	VIS 0° (425-675nm)	#19-869	€100,43 Volume Pricing	4 In Stock
25.00	-	5.00	VIS-NIR (400-1000nm)	#19-870	€106,09 Volume Pricing	Contact Us
25.00	-	5.00	YAG-BBAR (500-1100nm)	#25-227	€106,09 Volume Pricing	5 In Stock
25.00	-	5.00	NIR I (600-1050nm)	#19-871	€100,43 Volume Pricing	3 In Stock
25.00	-	5.00	NIR II (750-1550nm)	#19-872	€100,43 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	Uncoated	#48-201	€78,80 Volume Pricing	20+ In Stock
-	25.00 x 25.00	2.00	UV-AR (250-425nm)	#48-203	€106,09 Volume Pricing	Contact Us
-	25.00 x 25.00	2.00	UV-VIS (250-700nm)	#84-476	€106,09 Volume Pricing	6 In Stock

-	25.00 x 25.00	2.00	VIS-EXT (350-700nm)	#25-199	€109,18 Volume Pricing	9 In Stock
-	25.00 x 25.00	2.00	MgF ₂ (400-700nm)	#11-924	€92,19 Volume Pricing	15 In Stock
-	25.00 x 25.00	2.00	VIS 0° (425-675nm)	#36-980	€103,00 Volume Pricing	20+ In Stock
-	25.00 x 25.00	2.00	VIS-NIR (400-1000nm)	#49-644	€109,18 Volume Pricing	15 In Stock
-	25.00 x 25.00	2.00	YAG-BBAR (500-1100nm)	#25-228	€109,18 Volume Pricing	6 In Stock
-	25.00 x 25.00	2.00	NIR I (600-1050nm)	#36-979	€103,00 Volume Pricing	5 In Stock
-	25.00 x 25.00	2.00	NIR II (750-1550nm)	#39-300	€103,00 Volume Pricing	10 In Stock
-	25.00 x 35.00	3.00	Uncoated	#71-193	€83,43 Volume Pricing	11 In Stock
25.40	-	1.00	Uncoated	#25-244	€76,22 Volume Pricing	20+ In Stock
25.40	-	1.00	UV-AR (250-425nm)	#25-253	€103,00 Volume Pricing	9 In Stock
25.40	-	1.00	UV-VIS (250-700nm)	#25-264	€103,00 Volume Pricing	4 In Stock
25.40	-	1.00	VIS-EXT (350-700nm)	#25-329	€106,09 Volume Pricing	3 In Stock
25.40	-	1.00	MgF ₂ (400-700nm)	#25-319	€89,61 Volume Pricing	5 In Stock

25.40	-	1.00	VIS 0° (425-675nm)	#25-275	€100,43 Volume Pricing	6 In Stock
25.40	-	1.00	VIS-NIR (400-1000nm)	#25-308	€106,09 Volume Pricing	5 In Stock
25.40	-	1.00	YAG-BBAR (500-1100nm)	#25-337	€106,09 Volume Pricing	2 In Stock
25.40	-	1.00	NIR I (600-1050nm)	#25-286	€100,43 Volume Pricing	1 In Stock
25.40	-	1.00	NIR II (750-1550nm)	#25-297	€100,43 Volume Pricing	Contact Us
25.40	-	2.00	Uncoated	#15-308	€76,22 Volume Pricing	5 In Stock
25.40	-	2.00	UV-AR (250-425nm)	#25-254	€103,00 Volume Pricing	1 In Stock
25.40	-	2.00	UV-VIS (250-700nm)	#25-265	€103,00 Volume Pricing	3 In Stock
25.40	-	2.00	VIS-EXT (350-700nm)	#25-200	€106,09 Volume Pricing	5 In Stock
25.40	-	2.00	MgF ₂ (400-700nm)	#25-320	€89,61 Volume Pricing	1 In Stock
25.40	-	2.00	VIS 0° (425-675nm)	#25-276	€100,43 Volume Pricing	4 In Stock
25.40	-	2.00	VIS-NIR (400-1000nm)	#25-309	€106,09 Volume Pricing	1 In Stock
25.40	-	2.00	YAG-BBAR (500-1100nm)	#25-229	€106,09 Volume Pricing	4 In Stock
25.40	-	2.00	NIR I (600-1050nm)	#25-287	€100,43 Volume Pricing	4 In Stock

25.40	-	2.00	NIR II (750- 1550nm)	#25-298	€100,43 Volume Pricing	2 In Stock
25.40	-	3.00	Uncoated	#25-245	€76,22 Volume Pricing	20+ In Stock
25.40	-	3.00	UV-AR (250- 425nm)	#25-255	€103,00 Volume Pricing	5 In Stock
25.40	-	3.00	UV-VIS (250- 700nm)	#25-266	€103,00 Volume Pricing	2 In Stock
25.40	-	3.00	VIS-EXT (350- 700nm)	#25-330	€106,09 Volume Pricing	1 In Stock
25.40	-	3.00	MgF ₂ (400- 700nm)	#25-321	€89,61 Volume Pricing	3 In Stock
25.40	-	3.00	VIS 0° (425- 675nm)	#25-277	€100,43 Volume Pricing	5 In Stock
25.40	-	3.00	VIS-NIR (400- 1000nm)	#25-310	€106,09 Volume Pricing	2 In Stock
25.40	-	3.00	YAG- BBAR (500- 1100nm)	#25-338	€106,09 Volume Pricing	5 In Stock
25.40	-	3.00	NIR I (600- 1050nm)	#25-288	€100,43 Volume Pricing	3 In Stock
25.40	-	3.00	NIR II (750- 1550nm)	#25-299	€100,43 Volume Pricing	1 In Stock
25.40	-	4.00	Uncoated	#25-246	€76,22 Volume Pricing	20+ In Stock
25.40	-	4.00	UV-AR (250- 425nm)	#25-256	€103,00 Volume Pricing	4 In Stock
25.40	-	4.00	UV-VIS (250- 700nm)	#25-267	€103,00 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-EXT (350- 700nm)	#25-331	€106,09 Volume Pricing	5 In Stock

25.40	-	4.00	MgF ₂ (400-700nm)	#25-322	€89,61 Volume Pricing	5 In Stock
25.40	-	4.00	VIS 0° (425-675nm)	#25-278	€100,43 Volume Pricing	5 In Stock
25.40	-	4.00	VIS-NIR (400-1000nm)	#25-311	€106,09 Volume Pricing	14 In Stock
25.40	-	4.00	YAG-BBAR (500-1100nm)	#25-339	€106,09 Volume Pricing	5 In Stock
25.40	-	4.00	NIR I (600-1050nm)	#25-289	€100,43 Volume Pricing	4 In Stock
25.40	-	4.00	NIR II (750-1550nm)	#25-300	€100,43 Volume Pricing	2 In Stock
25.40	-	5.00	Uncoated	#25-247	€76,22 Volume Pricing	20+ In Stock
25.40	-	5.00	UV-AR (250-425nm)	#25-257	€103,00 Volume Pricing	5 In Stock
25.40	-	5.00	UV-VIS (250-700nm)	#25-268	€103,00 Volume Pricing	5 In Stock
25.40	-	5.00	VIS-EXT (350-700nm)	#25-332	€106,09 Volume Pricing	3 In Stock
25.40	-	5.00	MgF ₂ (400-700nm)	#25-323	€89,61 Volume Pricing	5 In Stock
25.40	-	5.00	VIS 0° (425-675nm)	#25-279	€100,43 Volume Pricing	2 In Stock
25.40	-	5.00	VIS-NIR (400-1000nm)	#25-312	€106,09 Volume Pricing	3 In Stock

25.40	-	5.00	YAG-BBAR (500-1100nm)	#25-340	€106,09 Volume Pricing	4 In Stock
25.40	-	5.00	NIR I (600-1050nm)	#25-290	€100,43 Volume Pricing	4 In Stock
25.40	-	5.00	NIR II (750-1550nm)	#25-301	€100,43 Volume Pricing	3 In Stock
30.00	-	1.00	Uncoated	#22-695	€89,61 Volume Pricing	5 In Stock
30.00	-	1.00	UV-AR (250-425nm)	#23-323	€122,57 Volume Pricing	3 In Stock
30.00	-	1.00	UV-VIS (250-700nm)	#23-324	€122,57 Volume Pricing	3 In Stock
30.00	-	1.00	VIS-EXT (350-700nm)	#25-201	€124,63 Volume Pricing	2 In Stock
30.00	-	1.00	MgF ₂ (400-700nm)	#23-322	€109,18 Volume Pricing	4 In Stock
30.00	-	1.00	VIS 0° (425-675nm)	#23-325	€119,48 Volume Pricing	2 In Stock
30.00	-	1.00	VIS-NIR (400-1000nm)	#23-326	€124,63 Volume Pricing	Contact Us
30.00	-	1.00	YAG-BBAR (500-1100nm)	#25-230	€124,63 Volume Pricing	2 In Stock
30.00	-	1.00	NIR I (600-1050nm)	#23-327	€119,48 Volume Pricing	1 In Stock
30.00	-	1.00	NIR II (750-1550nm)	#23-328	€119,48 Volume Pricing	5 In Stock
30.00	-	3.00	Uncoated	#45-569	€89,61 Volume Pricing	7 In Stock

30.00	-	3.00	UV-AR (250-425nm)	#45-813	€122,57 Volume Pricing	6 In Stock
30.00	-	3.00	UV-VIS (250-700nm)	#84-477	€122,57 Volume Pricing	17 In Stock
30.00	-	3.00	VIS-EXT (350-700nm)	#25-202	€124,63 Volume Pricing	1 In Stock
30.00	-	3.00	MgF ₂ (400-700nm)	#11-925	€109,18 Volume Pricing	14 In Stock
30.00	-	3.00	VIS 0° (425-675nm)	#36-982	€119,48 Volume Pricing	7 In Stock
30.00	-	3.00	VIS-NIR (400-1000nm)	#49-645	€124,63 Volume Pricing	7 In Stock
30.00	-	3.00	YAG-BBAR (500-1100nm)	#25-231	€124,63 Volume Pricing	3 In Stock
30.00	-	3.00	NIR I (600-1050nm)	#36-981	€119,48 Volume Pricing	8 In Stock
30.00	-	3.00	NIR II (750-1550nm)	#39-301	€119,48 Volume Pricing	5 In Stock
-	35.00 x 50.00	4.00	Uncoated	#71-194	€101,97 Volume Pricing	20+ In Stock
40.00	-	1.00	Uncoated	#22-696	€95,28 Volume Pricing	20+ In Stock
40.00	-	1.00	UV-AR (250-425nm)	#23-330	€127,72 Volume Pricing	2 In Stock
40.00	-	1.00	UV-VIS (250-700nm)	#23-331	€127,72 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-EXT (350-700nm)	#25-203	€130,81 Volume Pricing	2 In Stock

40.00	-	1.00	MgF ₂ (400-700nm)	#23-329	€114,33 Volume Pricing	4 In Stock
40.00	-	1.00	VIS 0° (425-675nm)	#23-332	€124,63 Volume Pricing	2 In Stock
40.00	-	1.00	VIS-NIR (400-1000nm)	#23-333	€130,81 Volume Pricing	3 In Stock
40.00	-	1.00	YAG-BBAR (500-1100nm)	#25-232	€130,81 Volume Pricing	Contact Us
40.00	-	1.00	NIR I (600-1050nm)	#23-334	€124,63 Volume Pricing	7 In Stock
40.00	-	1.00	NIR II (750-1550nm)	#23-335	€124,63 Volume Pricing	2 In Stock
40.00	-	4.00	Uncoated	#45-570	€95,28 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-AR (250-425nm)	#45-814	€127,72 Volume Pricing	20+ In Stock
40.00	-	4.00	UV-VIS (250-700nm)	#84-478	€127,72 Volume Pricing	3 In Stock
40.00	-	4.00	VIS-EXT (350-700nm)	#25-204	€130,81 Volume Pricing	3 In Stock
40.00	-	4.00	MgF ₂ (400-700nm)	#11-926	€114,33 Volume Pricing	1 In Stock
40.00	-	4.00	VIS 0° (425-675nm)	#36-984	€124,63 Volume Pricing	12 In Stock
40.00	-	4.00	VIS-NIR (400-1000nm)	#49-646	€130,81 Volume Pricing	7 In Stock
40.00	-	4.00	YAG-BBAR (500-1100nm)	#25-233	€130,81 Volume Pricing	4 In Stock

40.00	-	4.00	NIR I (600-1050nm)	#36-983	€124,63 Volume Pricing	3 In Stock
40.00	-	4.00	NIR II (750-1550nm)	#39-302	€124,63 Volume Pricing	5 In Stock
50.00	-	1.00	Uncoated	#19-841	€116,39 Volume Pricing	20+ In Stock
50.00	-	1.00	UV-AR (250-425nm)	#19-874	€154,50 Volume Pricing	4 In Stock
50.00	-	1.00	UV-VIS (250-700nm)	#19-875	€154,50 Volume Pricing	2 In Stock
50.00	-	1.00	VIS-EXT (350-700nm)	#25-205	€157,59 Volume Pricing	5 In Stock
50.00	-	1.00	MgF ₂ (400-700nm)	#19-873	€135,96 Volume Pricing	1 In Stock
50.00	-	1.00	VIS 0° (425-675nm)	#19-876	€152,44 Volume Pricing	2 In Stock
50.00	-	5.00	NIR II (750-1550nm)	#19-900	€152,44 Volume Pricing	1 In Stock
50.00	-	1.00	VIS-NIR (400-1000nm)	#19-877	€157,59 Volume Pricing	1 In Stock
50.00	-	1.00	YAG-BBAR (500-1100nm)	#25-234	€157,59 Volume Pricing	3 In Stock
50.00	-	5.00	NIR I (600-1050nm)	#19-899	€152,44 Volume Pricing	1 In Stock
50.00	-	2.00	Uncoated	#19-842	€116,39 Volume Pricing	14 In Stock
50.00	-	2.00	UV-AR (250-425nm)	#19-881	€154,50 Volume Pricing	3 In Stock
50.00	-	2.00	UV-VIS (250-700nm)	#19-882	€154,50 Volume Pricing	13 In Stock

50.00	-	2.00	VIS-EXT (350-700nm)	#25-206	€157,59 Volume Pricing	6 In Stock
50.00	-	2.00	MgF ₂ (400-700nm)	#19-880	€135,96 Volume Pricing	5 In Stock
50.00	-	2.00	VIS 0° (425-675nm)	#19-883	€152,44 Volume Pricing	3 In Stock
50.00	-	2.00	VIS-NIR (400-1000nm)	#19-884	€157,59 Volume Pricing	5 In Stock
50.00	-	2.00	YAG-BBAR (500-1100nm)	#25-235	€157,59 Volume Pricing	1 In Stock
50.00	-	1.00	NIR I (600-1050nm)	#19-878	€152,44 Volume Pricing	5 In Stock
50.00	-	1.00	NIR II (750-1550nm)	#19-879	€152,44 Volume Pricing	5 In Stock
50.00	-	3.00	Uncoated	#19-843	€116,39 Volume Pricing	20+ In Stock
50.00	-	3.00	UV-AR (250-425nm)	#19-888	€154,50 Volume Pricing	2 In Stock
50.00	-	3.00	UV-VIS (250-700nm)	#19-889	€154,50 Volume Pricing	2 In Stock
50.00	-	3.00	VIS-EXT (350-700nm)	#25-207	€157,59 Volume Pricing	8 In Stock
50.00	-	3.00	MgF ₂ (400-700nm)	#19-887	€135,96 Volume Pricing	1 In Stock
50.00	-	3.00	VIS 0° (425-675nm)	#19-890	€152,44 Volume Pricing	1 In Stock

50.00	-	3.00	VIS-NIR (400-1000nm)	#19-891	€157,59 Volume Pricing	4 In Stock
50.00	-	3.00	YAG-BBAR (500-1100nm)	#25-236	€157,59 Volume Pricing	Contact Us
50.00	-	2.00	NIR I (600-1050nm)	#19-885	€152,44 Volume Pricing	2 In Stock
50.00	-	2.00	NIR II (750-1550nm)	#19-886	€152,44 Volume Pricing	1 In Stock
50.00	-	4.00	Uncoated	#47-230	€116,39 Volume Pricing	20+ In Stock
50.00	-	4.00	UV-AR (250-425nm)	#49-635	€154,50 Volume Pricing	Contact Us
50.00	-	4.00	UV-VIS (250-700nm)	#84-479	€154,50 Volume Pricing	8 In Stock
50.00	-	4.00	VIS-EXT (350-700nm)	#25-208	€157,59 Volume Pricing	3 In Stock
50.00	-	4.00	MgF ₂ (400-700nm)	#11-927	€135,96 Volume Pricing	7 In Stock
50.00	-	4.00	VIS 0° (425-675nm)	#36-986	€152,44 Volume Pricing	4 In Stock
50.00	-	4.00	VIS-NIR (400-1000nm)	#49-647	€157,59 Volume Pricing	10 In Stock
50.00	-	4.00	YAG-BBAR (500-1100nm)	#25-237	€157,59 Volume Pricing	4 In Stock
50.00	-	3.00	NIR I (600-1050nm)	#19-892	€152,44 Volume Pricing	3 In Stock
50.00	-	3.00	NIR II (750-1550nm)	#19-893	€152,44 Volume Pricing	2 In Stock

50.00	-	5.00	Uncoated	#19-844	€116,39 Volume Pricing	20+ In Stock
50.00	-	5.00	UV-AR (250-425nm)	#19-895	€154,50 Volume Pricing	3 In Stock
50.00	-	5.00	UV-VIS (250-700nm)	#19-896	€154,50 Volume Pricing	3 In Stock
50.00	-	5.00	VIS-EXT (350-700nm)	#25-209	€157,59 Volume Pricing	4 In Stock
50.00	-	5.00	MgF ₂ (400-700nm)	#19-894	€135,96 Volume Pricing	5 In Stock
50.00	-	5.00	VIS 0° (425-675nm)	#19-897	€152,44 Volume Pricing	1 In Stock
50.00	-	5.00	VIS-NIR (400-1000nm)	#19-898	€157,59 Volume Pricing	5 In Stock
50.00	-	5.00	YAG-BBAR (500-1100nm)	#25-238	€157,59 Volume Pricing	3 In Stock
50.00	-	4.00	NIR I (600-1050nm)	#36-985	€152,44 Volume Pricing	5 In Stock
50.00	-	4.00	NIR II (750-1550nm)	#39-303	€152,44 Volume Pricing	2 In Stock
-	50.00 x 50.00	4.00	Uncoated	#47-231	€119,48 Volume Pricing	20+ In Stock
-	50.00 x 50.00	4.00	UV-AR (250-425nm)	#49-636	€157,59 Volume Pricing	3 In Stock
-	50.00 x 50.00	4.00	UV-VIS (250-700nm)	#84-480	€157,59 Volume Pricing	1 In Stock
-	50.00 x 50.00	4.00	VIS-EXT (350-700nm)	#25-210	€160,68 Volume Pricing	Contact Us

-	50.00 x 50.00	4.00	MgF ₂ (400-700nm)	#11-928	€139,05 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS 0° (425-675nm)	#36-988	€154,50 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	VIS-NIR (400-1000nm)	#49-648	€160,68 Volume Pricing	5 In Stock
-	50.00 x 50.00	4.00	YAG-BBAR (500-1100nm)	#25-239	€160,68 Volume Pricing	2 In Stock
-	50.00 x 50.00	4.00	NIR I (600-1050nm)	#36-987	€154,50 Volume Pricing	3 In Stock
-	50.00 x 50.00	4.00	NIR II (750-1550nm)	#39-304	€154,50 Volume Pricing	2 In Stock
50.80	-	1.00	Uncoated	#25-248	€116,39 Volume Pricing	20+ In Stock
50.80	-	1.00	UV-AR (250-425nm)	#25-258	€154,50 Volume Pricing	4 In Stock
50.80	-	1.00	UV-VIS (250-700nm)	#25-269	€154,50 Volume Pricing	Contact Us
50.80	-	1.00	VIS-EXT (350-700nm)	#25-333	€157,59 Volume Pricing	4 In Stock
50.80	-	1.00	MgF ₂ (400-700nm)	#25-324	€135,96 Volume Pricing	Contact Us
50.80	-	1.00	VIS 0° (425-675nm)	#25-280	€152,44 Volume Pricing	5 In Stock
50.80	-	1.00	VIS-NIR (400-1000nm)	#25-313	€157,59 Volume Pricing	3 In Stock
50.80	-	1.00	YAG-BBAR (500-1100nm)	#25-341	€157,59 Volume Pricing	6 In Stock

50.80	-	1.00	NIR I (600-1050nm)	#25-291	€152,44 Volume Pricing	5 In Stock
50.80	-	1.00	NIR II (750-1550nm)	#25-302	€152,44 Volume Pricing	3 In Stock
50.80	-	2.00	Uncoated	#25-249	€116,39 Volume Pricing	20+ In Stock
50.80	-	2.00	UV-AR (250-425nm)	#25-259	€154,50 Volume Pricing	2 In Stock
50.80	-	2.00	UV-VIS (250-700nm)	#25-270	€154,50 Volume Pricing	4 In Stock
50.80	-	2.00	VIS-EXT (350-700nm)	#25-334	€157,59 Volume Pricing	2 In Stock
50.80	-	2.00	MgF ₂ (400-700nm)	#25-325	€135,96 Volume Pricing	5 In Stock
50.80	-	2.00	VIS 0° (425-675nm)	#25-281	€152,44 Volume Pricing	5 In Stock
50.80	-	2.00	VIS-NIR (400-1000nm)	#25-314	€157,59 Volume Pricing	1 In Stock
50.80	-	2.00	YAG-BBAR (500-1100nm)	#25-342	€157,59 Volume Pricing	2 In Stock
50.80	-	2.00	NIR I (600-1050nm)	#25-292	€152,44 Volume Pricing	1 In Stock
50.80	-	2.00	NIR II (750-1550nm)	#25-303	€152,44 Volume Pricing	3 In Stock
50.80	-	3.00	Uncoated	#25-250	€116,39 Volume Pricing	Contact Us
50.80	-	3.00	UV-AR (250-425nm)	#25-260	€154,50 Volume Pricing	2 In Stock

50.80	-	3.00	UV-VIS (250-700nm)	#25-271	€154,50 Volume Pricing	2 In Stock
50.80	-	3.00	VIS-EXT (350-700nm)	#25-335	€157,59 Volume Pricing	Contact Us
50.80	-	3.00	MgF ₂ (400-700nm)	#25-326	€135,96 Volume Pricing	5 In Stock
50.80	-	3.00	VIS 0° (425-675nm)	#25-282	€152,44 Volume Pricing	5 In Stock
50.80	-	3.00	VIS-NIR (400-1000nm)	#25-315	€157,59 Volume Pricing	3 In Stock
50.80	-	3.00	YAG-BBAR (500-1100nm)	#25-343	€157,59 Volume Pricing	9 In Stock
50.80	-	3.00	NIR I (600-1050nm)	#25-293	€152,44 Volume Pricing	4 In Stock
50.80	-	3.00	NIR II (750-1550nm)	#25-304	€152,44 Volume Pricing	1 In Stock
50.80	-	4.00	Uncoated	#15-309	€116,39 Volume Pricing	Contact Us
50.80	-	4.00	UV-AR (250-425nm)	#25-261	€154,50 Volume Pricing	5 In Stock
50.80	-	4.00	UV-VIS (250-700nm)	#25-272	€154,50 Volume Pricing	6 In Stock
50.80	-	4.00	VIS-EXT (350-700nm)	#25-211	€157,59 Volume Pricing	5 In Stock
50.80	-	4.00	MgF ₂ (400-700nm)	#25-327	€135,96 Volume Pricing	5 In Stock
50.80	-	4.00	VIS 0° (425-675nm)	#25-283	€152,44 Volume Pricing	5 In Stock

50.80	-	4.00	VIS-NIR (400-1000nm)	#25-316	€157,59 Volume Pricing	3 In Stock
50.80	-	4.00	YAG-BBAR (500-1100nm)	#25-240	€157,59 Volume Pricing	5 In Stock
50.80	-	4.00	NIR I (600-1050nm)	#25-294	€152,44 Volume Pricing	4 In Stock
50.80	-	4.00	NIR II (750-1550nm)	#25-305	€152,44 Volume Pricing	5 In Stock
50.80	-	5.00	Uncoated	#25-251	€116,39 Volume Pricing	7 In Stock
50.80	-	5.00	UV-AR (250-425nm)	#25-262	€154,50 Volume Pricing	4 In Stock
50.80	-	5.00	UV-VIS (250-700nm)	#25-273	€154,50 Volume Pricing	3 In Stock
50.80	-	5.00	VIS-EXT (350-700nm)	#25-336	€157,59 Volume Pricing	6 In Stock
50.80	-	5.00	MgF ₂ (400-700nm)	#25-328	€135,96 Volume Pricing	5 In Stock
50.80	-	5.00	VIS 0° (425-675nm)	#25-284	€152,44 Volume Pricing	5 In Stock
50.80	-	5.00	VIS-NIR (400-1000nm)	#25-317	€157,59 Volume Pricing	5 In Stock
50.80	-	5.00	YAG-BBAR (500-1100nm)	#25-344	€157,59 Volume Pricing	5 In Stock
50.80	-	5.00	NIR I (600-1050nm)	#25-295	€152,44 Volume Pricing	5 In Stock
50.80	-	5.00	NIR II (750-1550nm)	#25-306	€152,44 Volume Pricing	5 In Stock

75.00	-	5.00	Uncoated	#39-291	€170,98 Volume Pricing	14 In Stock
-	75.00 x 75.00	5.00	Uncoated	#70-700	€189,52 Volume Pricing	7 In Stock
75.00	-	5.00	VIS-EXT (350-700nm)	#25-212	€247,20 Volume Pricing	2 In Stock
75.00	-	5.00	MgF ₂ (400-700nm)	#11-929	€209,09 Volume Pricing	Contact Us
75.00	-	5.00	YAG-BBAR (500-1100nm)	#25-241	€247,20 Volume Pricing	Contact Us
-	100.00 x 100.00	5.00	Uncoated	#70-701	€405,82 Volume Pricing	8 In Stock
100.00	-	8.00	Uncoated	#39-292	€407,88 Volume Pricing	20+ In Stock
100.00	-	8.00	UV-AR (250-425nm)	#23-614	€695,25 Volume Pricing	1 In Stock
100.00	-	8.00	UV-VIS (250-700nm)	#22-052	€695,25 Volume Pricing	Contact Us
100.00	-	8.00	MgF ₂ (400-700nm)	#11-930	€472,77 Volume Pricing	5 In Stock
100.00	-	8.00	VIS 0° (425-675nm)	#22-053	€679,80 Volume Pricing	2 In Stock
100.00	-	8.00	VIS-NIR (400-1000nm)	#22-054	€695,25 Volume Pricing	Contact Us
100.00	-	8.00	VIS-EXT (350-700nm)	#29-630	€695,25 Volume Pricing	Contact Us
100.00	-	8.00	NIR II (750-1550nm)	#29-629	€679,80 Volume Pricing	Contact Us
100.00	-	8.00	NIR I (600-1050nm)	#29-628	€679,80 Volume Pricing	Contact Us

[#29-631 New](#)



New

Copyright 2025 | Edmund Optics BV, De Maas 22B, 5641 PH Eindhoven, The Netherlands
Phone: 1-800-363-1992 : www.edmundoptics.com

100.00	-	8.00	YAG-BBAR (500-1100nm)	564-1100 on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€695,25 Volume Pricing	4 In Stock
--------	---	------	--------------------------	---	---	------------
