

[All Products](#) / [Optics](#) / [Beamsplitters](#) / [Plate Beamsplitters](#)
TECHSPEC® C-Mounted Plate Beamsplitters


- Pre-Mounted 90 Degree Interface
- Four C-Threaded Mounting Holes
- Several Beamsplitting Options Available
- Additional C-Mounted [Beamsplitters](#), [Filters](#), and [Mirrors](#) Available

Common Specifications

Physical & Mechanical Properties

Construction:	Plate	Extension Length (mm):	38.0
Housing:	Black Anodized Aluminum	Housing Dimension:	38 x 38 x 50


Optical Properties

Reflection/Transmission Tolerance (%):	±5
---	----

Threading & Mounting

Mount:	C-Mount Enclosure
Thread Type:	C-Mount (1" x 32 TPI)

Technical Information

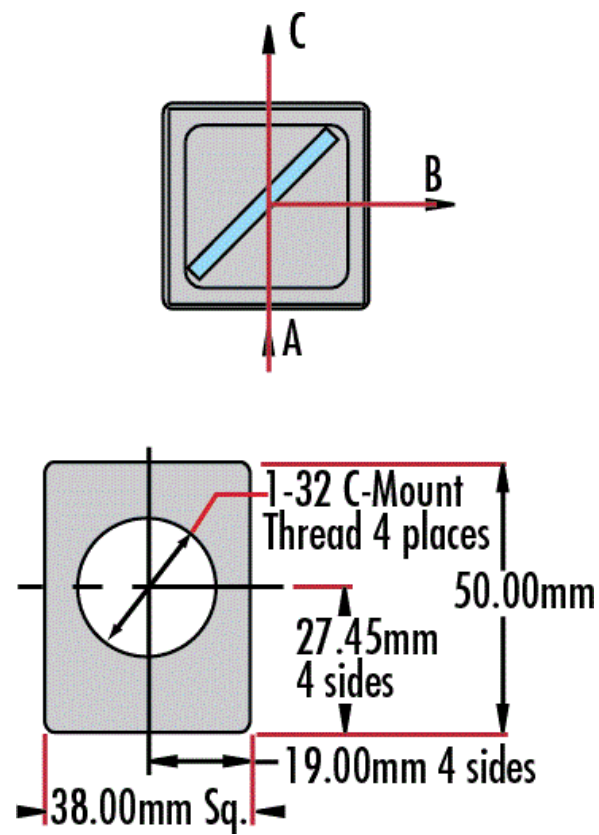

Products

Substrate	Reflection/Transmission Ratio (R/T)	Wavelength Range (nm)	Stock Number	Price	Buy
Float Glass	50/50	400 - 700	#54-824	€307,00 Qty 5+ €269,00	3-4 days
N-BK7	30/70	400 - 700	#49-684	€307,00 Qty 5+ €269,00	3-4 days
N-BK7	50/50	400 - 700	#49-685	€307,00 Qty 5+ €269,00	In Stock
N-BK7	70/30	400 - 700	#49-686	€307,00 Qty 5+ €269,00	In Stock
N-BK7	30/70	700 - 1100	#49-687	€307,00 Qty 5+ €269,00	Contact Us
N-BK7	50/50	700 - 1100	#49-688	€307,00 Qty 5+ €269,00	3-4 days
N-BK7	70/30	700 - 1100	#49-689	€307,00 Qty 5+ €269,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com