

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Double-Convex \(DCX\) Lenses](#)

ISP Optics Calcium Fluoride Double-Convex (DCX) Lenses See

More by [ISP Optics](#)




- Greater than 90% Transmission from 350nm-7 μ m
- Low Index of Refraction
- High Laser Damage Threshold


Common Specifications

Centering (arcmin):	<3	Bevel:	Protective as needed
Coating:	Uncoated	Substrate:	Calcium Fluoride (CaF₂)
Surface Quality:	60-40	Irregularity (P-V) @ 632.8nm:	λ
Focal Length Tolerance (%):	± 2	Wavelength Range (nm):	300 - 8000


Technical Information

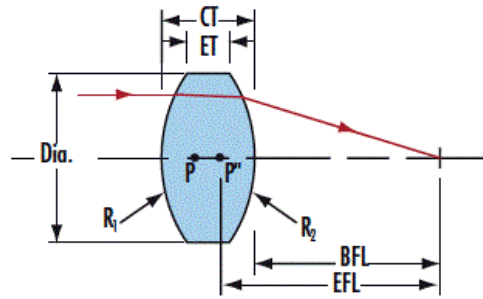

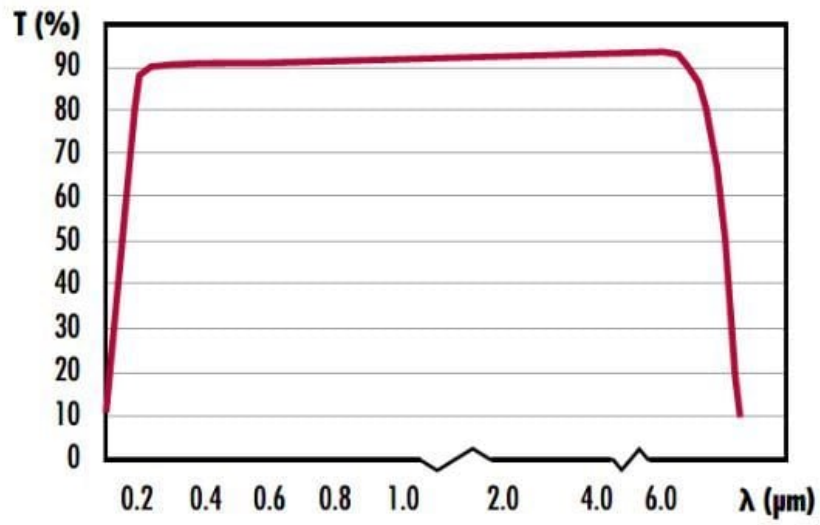

Calcium Fluoride

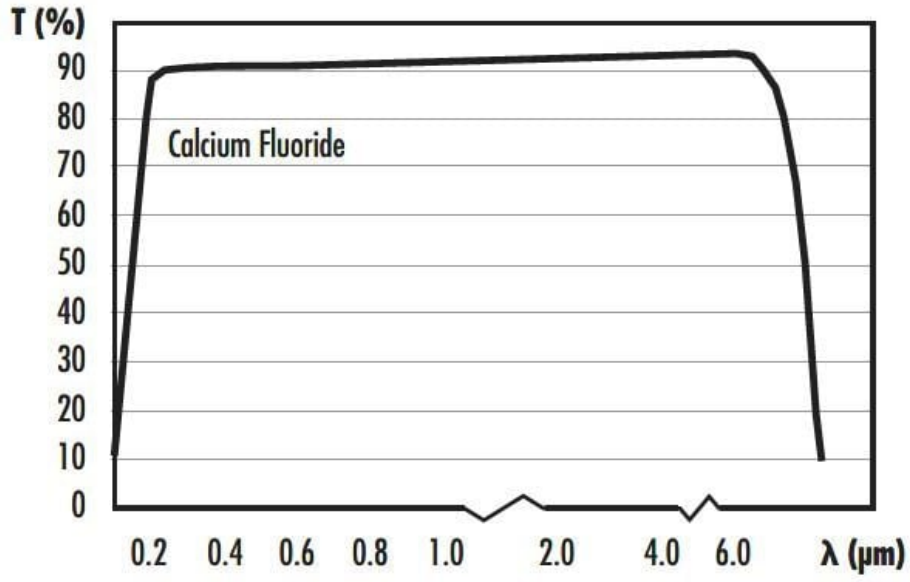

Uncoated



Products

Dia. (mm)	EFL (mm)	Coating	Substrate	Model Number	Stock Number	Price	Buy
#24-765 Clearance							
25.40	150.00	Uncoated	Calcium Fluoride (CaF₂)	CF-BX-25-150	 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	€299,00 Volume Pricing	4 In Stock
#24-767 Clearance							
38.10	50.80	Uncoated	Calcium Fluoride (CaF₂)	CF-BX-38-50	 Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.	€449,00 Volume Pricing	3 In Stock

[#24-768 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

38.10 63.50 Uncoated

[Calcium Fluoride \(CaF₂\)](#)

CF-BX-38-63

€449,00
[Volume Pricing](#)

7 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com