

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)

TECHSPEC® UV-to-NIR Corrected Triplet Lenses



- Calcium Fluoride and UV Fused Silica Elements
- Broadband Color-Corrected Design from 193nm to 1000nm
- Ideal for Fluorescence and Spectroscopy Applications

Common Specifications

Physical & Mechanical Properties

Housing Diameter (mm):	30.00 ±0.05
------------------------	-------------


Optical Properties

Substrate:	CaF ₂ / Fused Silica / CaF ₂
------------	--

Surface Quality:	60-40
------------------	-------

Wavelength Range (nm):	193 - 1000
------------------------	------------

Technical Information

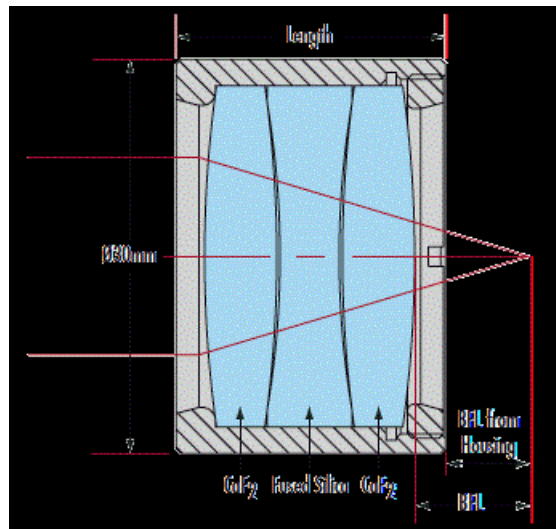

Products

EFL (mm)	BFL (mm)	Substrate	Coating	Housing Diameter (mm)	Stock Number	Price	Buy
36.00	24.98	CaF ₂ / Fused Silica / CaF ₂	Uncoated	30.00 ±0.05	#65-029	€2.482,30 Volume Pricing	1 In Stock
36.00	24.98	CaF ₂ / Fused Silica / CaF ₂	MgF ₂ (193- 1000nm)	30.00 ±0.05	#65-033	€2.693,45 Volume Pricing	Contact Us
45.00	34.84	CaF ₂ / Fused Silica / CaF ₂	Uncoated	30.00 ±0.05	#47-613	€2.482,30 Volume Pricing	Contact Us
45.00	34.84	CaF ₂ / Fused Silica / CaF ₂	MgF ₂ (193- 1000nm)	30.00 ±0.05	#64-837	€2.693,45 Volume Pricing	14 In Stock
90.00	84.76	CaF ₂ / Fused Silica / CaF ₂	Uncoated	30.00 ±0.05	#47-311	€1.489,38 €2.482,30 Volume Pricing	5 In Stock
90.00	84.76	CaF ₂ / Fused Silica / CaF ₂	MgF ₂ (193- 1000nm)	30.00 ±0.05	#64-838	€2.693,45 Volume Pricing	Contact Us
135.00	129.31	CaF ₂ / Fused Silica / CaF ₂	Uncoated	30.00 ±0.05	#47-312	€2.482,30 Volume Pricing	3 In Stock
135.00	129.31	CaF ₂ / Fused Silica / CaF ₂	MgF ₂ (193- 1000nm)	30.00 ±0.05	#64-839	€2.693,45 Volume Pricing	2 In Stock
180.00	174.62	CaF ₂ / Fused Silica / CaF ₂	Uncoated	30.00 ±0.05	#47-313	€2.482,30 Volume Pricing	1 In Stock
180.00	174.62	CaF ₂ / Fused Silica / CaF ₂	MgF ₂ (193- 1000nm)	30.00 ±0.05	#64-840	€2.693,45 Volume Pricing	Contact Us



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands

Phone: 1-800-363-1992 :

www.edmundoptics.com