

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® VIS 0° Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.4% Reflectance per Surface for 425 - 675nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS-NIR](#), [NIR-I](#), [NIR-II](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel:



Protective bevel as needed

Optical Properties

Wavelength Range (nm):

425 - 675

Technical Information

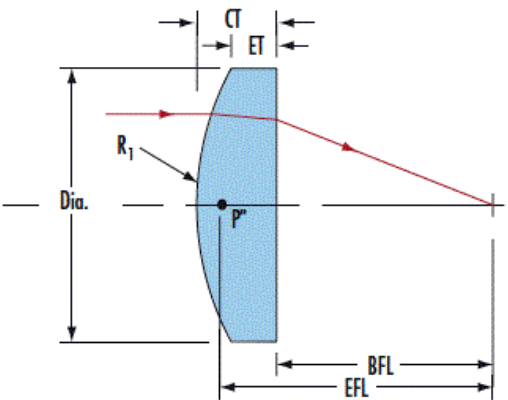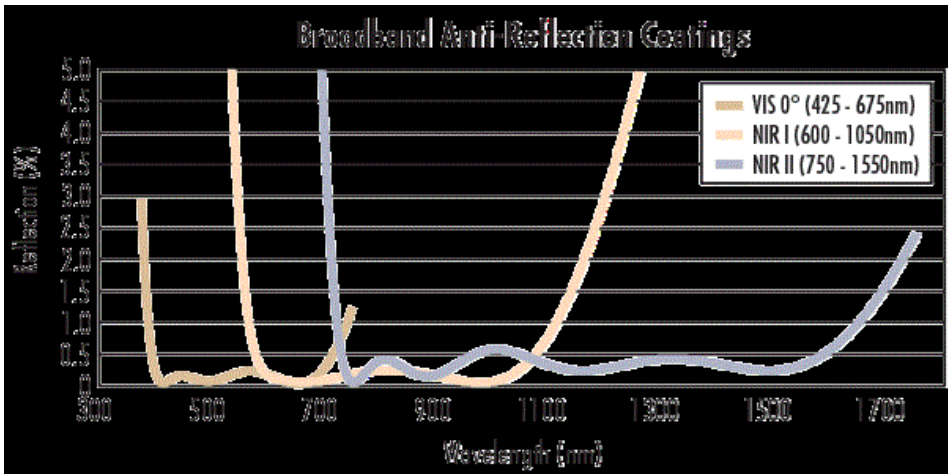

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	VIS 0° (425-675nm)	N-LASF9	#65-273	€80,00 Qty 10+ €72,00	3-4 days
1.00	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-274	€80,00 Qty 10+ €72,00	Contact Us
1.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-275	€80,00 Qty 10+ €72,00	3-4 days
1.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-276	€80,00 Qty 10+ €72,00	3-4 days
1.50	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-277	€80,00 Qty 10+ €72,00	3-4 days
1.50	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-278	€80,00 Qty 10+ €72,00	3-4 days
1.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-279	€80,00 Qty 10+ €72,00	In Stock
2.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-280	€79,00 Qty 10+ €71,00	3-4 days
2.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-281	€79,00 Qty 10+ €71,00	Contact Us
2.00	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-282	€79,00 Qty 10+ €71,00	3-4 days
2.00	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-283	€79,00 Qty 10+ €71,00	3-4 days
2.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-284	€79,00 Qty 10+ €71,00	3-4 days

2.50	2.50	2.05	VIS 0° (425-675nm)	N-LASF9	#65-285	€79,00 Qty 10+ €71,00	3-4 days
2.50	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-286	€79,00 Qty 10+ €71,00	3-4 days
2.50	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-287	€79,00 Qty 10+ €71,00	3-4 days
2.50	5.00	4.57	VIS 0° (425-675nm)	N-LASF9	#65-288	€79,00 Qty 10+ €71,00	3-4 days
3.00	3.00	1.88	VIS 0° (425-675nm)	N-SF11	#49-167	€66,50 Qty 10+ €60,00	3-4 days
3.00	4.50	3.50	VIS 0° (425-675nm)	N-LASF44	#49-168	€66,50 Qty 10+ €60,00	3-4 days
3.00	6.00	4.81	VIS 0° (425-675nm)	N-BK7	#49-169	€61,50 Qty 10+ €55,50	3-4 days
3.00	7.50	6.51	VIS 0° (425-675nm)	N-BK7	#49-170	€61,50 Qty 10+ €55,50	3-4 days
3.00	9.00	8.01	VIS 0° (425-675nm)	N-BK7	#49-171	€61,50 Qty 10+ €55,50	3-4 days
3.00	12.00	11.29	VIS 0° (425-675nm)	N-BK7	#49-172	€61,50 Qty 10+ €55,50	Contact Us
3.00	15.00	14.17	VIS 0° (425-675nm)	N-BK7	#49-173	€61,50 Qty 10+ €55,50	3-4 days
4.00	4.00	3.06	VIS 0° (425-675nm)	N-LASF44	#47-861	€64,00 Qty 10+ €57,50	In Stock
4.00	6.00	4.51	VIS 0° (425-675nm)	N-BK7	#47-862	€64,00 Qty 10+ €57,50	In Stock
4.00	8.00	7.17	VIS 0° (425-675nm)	N-BAF10	#47-863	€60,00 Qty 10+ €54,00	3-4 days

4.00	10.00	8.92	VIS 0° (425-675nm)	N-BK7	#47-864	€60,00 Qty 10+ €54,00	3-4 days
4.00	12.00	11.00	VIS 0° (425-675nm)	N-BK7	#47-865	€60,00 Qty 10+ €54,00	3-4 days
4.50	4.50	3.05	VIS 0° (425-675nm)	N-LASF44	#47-866	€64,00 Qty 10+ €57,50	3-4 days
4.50	9.00	7.41	VIS 0° (425-675nm)	N-BK7	#47-867	€60,00 Qty 10+ €54,00	3-4 days
5.00	5.00	3.96	VIS 0° (425-675nm)	N-LASF44	#47-868	€48,25 Qty 10+ €43,25	3-4 days
5.00	7.50	6.43	VIS 0° (425-675nm)	N-SF11	#48-658	€47,75 Qty 10+ €43,00	In Stock
5.00	10.00	8.91	VIS 0° (425-675nm)	N-BK7	#47-869	€47,75 Qty 10+ €43,00	3-4 days
5.00	12.00	10.83	VIS 0° (425-675nm)	N-BK7	#47-870	€47,75 Qty 10+ €43,00	In Stock
5.00	15.00	13.94	VIS 0° (425-675nm)	N-BK7	#47-871	€47,75 Qty 10+ €43,00	In Stock
5.00	20.00	19.02	VIS 0° (425-675nm)	N-BK7	#49-893	€47,75 Qty 10+ €43,00	Contact Us
5.00	25.00	23.95	VIS 0° (425-675nm)	N-BK7	#87-915	€47,75 Qty 10+ €43,00	3-4 days
5.00	30.00	28.95	VIS 0° (425-675nm)	N-BK7	#87-916	€47,75 Qty 10+ €43,00	3-4 days
6.00	6.00	4.60	VIS 0° (425-675nm)	N-SF11	#47-460	€40,00 Qty 10+ €36,00	In Stock
6.00	7.50	6.10	VIS 0° (425-675nm)	N-SF11	#49-894	€39,50 Qty 10+ €35,50	3-4 days

6.00	9.00	7.95	VIS 0° (425-675nm)	N-SF5	#47-461	€39,50 Qty 10+ €35,50	In Stock
6.00	10.00	8.82	VIS 0° (425-675nm)	N-BK7	#38-272	€39,50 Qty 10+ €35,50	In Stock
6.00	12.00	10.94	VIS 0° (425-675nm)	N-BK7	#47-462	€38,50 Qty 10+ €34,50	3-4 days
6.00	15.00	13.68	VIS 0° (425-675nm)	N-BK7	#47-463	€38,50 Qty 10+ €34,50	In Stock
6.00	18.00	17.07	VIS 0° (425-675nm)	N-BK7	#47-464	€38,50 Qty 10+ €34,50	In Stock
6.00	20.00	19.04	VIS 0° (425-675nm)	N-BK7	#38-273	€38,50 Qty 10+ €34,50	3-4 days
6.00	21.00	20.06	VIS 0° (425-675nm)	N-BK7	#47-465	€38,50 Qty 10+ €34,50	In Stock
6.00	24.00	23.01	VIS 0° (425-675nm)	N-BK7	#47-466	€38,50 Qty 10+ €34,50	3-4 days
6.00	25.00	24.04	VIS 0° (425-675nm)	N-BK7	#38-275	€38,50 Qty 10+ €34,50	In Stock
6.00	30.00	29.14	VIS 0° (425-675nm)	N-BK7	#47-467	€38,50 Qty 10+ €34,50	3-4 days
6.00	36.00	34.95	VIS 0° (425-675nm)	N-BK7	#47-468	€38,50 Qty 10+ €34,50	In Stock
6.00	48.00	46.95	VIS 0° (425-675nm)	N-BK7	#47-469	€38,50 Qty 10+ €34,50	3-4 days
6.00	60.00	58.95	VIS 0° (425-675nm)	N-BK7	#67-162	€38,50 Qty 10+ €34,50	3-4 days
6.00	72.00	70.97	VIS 0° (425-675nm)	N-BK7	#47-470	€38,50 Qty 10+ €34,50	In Stock

[#71-294 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 7.00 5.50
VIS 0°
(425-675nm)

[N-LASF9](#)

€40,00
Qty 11+ €36,00

3-4 days

[#71-301 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 10.00 8.10
VIS 0°
(425-675nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-308 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 12.00 10.30

VIS 0°
(425-675nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-315 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 8.00 6.40

VIS 0°
(425-675nm)

[N-LASF9](#)

€40,00
Qty 11+ €36,00

3-4 days

[#71-322 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 10.00 7.60

VIS 0°
(425-675nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-329 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 12.00 10.00

VIS 0°
(425-675nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

9.00 9.00 7.32

VIS 0°
(425-675nm)

[N-SF11](#)

[#47-471](#)

€40,50
Qty 10+ €36,25

In Stock

9.00 10.00 8.49

VIS 0°
(425-675nm)

[N-SF11](#)

[#38-276](#)

€40,50
Qty 10+ €36,25

3-4 days

9.00 12.00 10.60

VIS 0°
(425-675nm)

[N-SF11](#)

[#49-895](#)

€40,50
Qty 10+ €36,25

In Stock

9.00	13.50	11.94	VIS 0° (425-675nm)	N-SF5	#47-472	€40,50 Qty 10+ €36,25	Contact Us
9.00	15.00	13.02	VIS 0° (425-675nm)	N-BK7	#49-896	€40,50 Qty 10+ €36,25	In Stock
9.00	18.00	16.41	VIS 0° (425-675nm)	N-BK7	#47-473	€39,50 Qty 10+ €35,50	In Stock
9.00	20.00	18.55	VIS 0° (425-675nm)	N-BK7	#38-277	€39,50 Qty 10+ €35,50	In Stock
9.00	22.00	20.73	VIS 0° (425-675nm)	N-BK7	#47-474	€39,50 Qty 10+ €35,50	3-4 days
9.00	25.00	23.68	VIS 0° (425-675nm)	N-BK7	#38-278	€39,50 Qty 10+ €35,50	3-4 days
9.00	27.00	25.34	VIS 0° (425-675nm)	N-BK7	#47-475	€39,50 Qty 10+ €35,50	3-4 days
9.00	36.00	34.48	VIS 0° (425-675nm)	N-BK7	#47-476	€39,50 Qty 10+ €35,50	3-4 days
9.00	45.00	43.98	VIS 0° (425-675nm)	N-BK7	#47-477	€39,50 Qty 10+ €35,50	In Stock
9.00	54.00	52.69	VIS 0° (425-675nm)	N-BK7	#67-163	€39,50 Qty 10+ €35,50	3-4 days
9.00	72.00	70.68	VIS 0° (425-675nm)	N-BK7	#67-164	€39,50 Qty 10+ €35,50	3-4 days
9.00	90.00	88.68	VIS 0° (425-675nm)	N-BK7	#67-165	€39,50 Qty 10+ €35,50	In Stock
10.00	10.00	8.18	VIS 0° (425-675nm)	N-SF11	#63-497	€40,50 Qty 10+ €36,25	3-4 days
10.00	12.50	10.99	VIS 0° (425-675nm)	N-SF11	#38-279	€40,50 Qty 10+ €36,25	3-4 days

10.00	15.00	13.32	VIS 0° (425-675nm)	N-SF11	#63-498	€40,50 Qty 10+ €36,25	Contact Us
10.00	17.50	15.66	VIS 0° (425-675nm)	N-BK7	#38-280	€39,50 Qty 10+ €35,50	3-4 days
10.00	20.00	18.03	VIS 0° (425-675nm)	N-BK7	#63-499	€39,50 Qty 10+ €35,50	In Stock
10.00	25.00	23.02	VIS 0° (425-675nm)	N-BK7	#63-500	€39,50 Qty 10+ €35,50	3-4 days
10.00	30.00	28.01	VIS 0° (425-675nm)	N-BK7	#63-501	€39,50 Qty 10+ €35,50	In Stock
10.00	40.00	38.02	VIS 0° (425-675nm)	N-BK7	#63-502	€39,50 Qty 10+ €35,50	In Stock
10.00	50.00	48.02	VIS 0° (425-675nm)	N-BK7	#63-503	€39,50 Qty 10+ €35,50	In Stock
10.00	75.00	73.02	VIS 0° (425-675nm)	N-BK7	#63-504	€39,50 Qty 10+ €35,50	In Stock
10.00	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#63-505	€39,50 Qty 10+ €35,50	In Stock
12.00	12.00	9.76	VIS 0° (425-675nm)	N-SF11	#47-329	€44,00 Qty 10+ €39,50	3-4 days
12.00	15.00	12.03	VIS 0° (425-675nm)	N-BK7	#47-330	€44,00 Qty 10+ €39,50	3-4 days
12.00	18.00	16.22	VIS 0° (425-675nm)	N-SF5	#47-331	€44,00 Qty 10+ €39,50	3-4 days
12.00	20.00	17.69	VIS 0° (425-675nm)	N-BK7	#49-897	€44,00 Qty 10+ €39,50	In Stock
12.00	24.00	22.15	VIS 0° (425-675nm)	N-BK7	#47-332	€43,00 Qty 10+ €38,50	In Stock

12.00	25.00	23.22	VIS 0° (425-675nm)	N-BK7	#38-281	€43,00 Qty 10+ €38,50	3-4 days
12.00	30.00	28.02	VIS 0° (425-675nm)	N-BK7	#47-333	€43,00 Qty 10+ €38,50	3-4 days
12.00	36.00	34.02	VIS 0° (425-675nm)	N-BK7	#33-354	€43,00 Qty 10+ €38,50	Contact Us
12.00	42.00	40.22	VIS 0° (425-675nm)	N-BK7	#47-335	€43,00 Qty 10+ €38,50	In Stock
12.00	48.00	46.36	VIS 0° (425-675nm)	N-BK7	#47-336	€43,00 Qty 10+ €38,50	In Stock
12.00	50.00	48.75	VIS 0° (425-675nm)	N-BK7	#38-282	€43,00 Qty 10+ €38,50	3-4 days
12.00	54.00	52.02	VIS 0° (425-675nm)	N-BK7	#47-337	€43,00 Qty 10+ €38,50	In Stock
12.00	60.00	58.37	VIS 0° (425-675nm)	N-BK7	#47-338	€43,00 Qty 10+ €38,50	In Stock
12.00	72.00	70.42	VIS 0° (425-675nm)	N-BK7	#47-339	€43,00 Qty 10+ €38,50	In Stock
12.00	84.00	82.39	VIS 0° (425-675nm)	N-BK7	#47-340	€43,00 Qty 10+ €38,50	In Stock
12.00	100.00	98.35	VIS 0° (425-675nm)	N-BK7	#47-341	€43,00 Qty 10+ €38,50	In Stock
12.50	12.50	10.40	VIS 0° (425-675nm)	N-SF11	#38-283	€43,00	In Stock
12.50	15.00	13.26	VIS 0° (425-675nm)	N-SF11	#38-285	€43,00	3-4 days
12.50	17.50	15.00	VIS 0° (425-675nm)	N-BK7	#38-287	€43,00	3-4 days

12.50	20.00	17.69	VIS 0° (425-675nm)	N-BK7	#38-288	€43,00	In Stock
12.50	25.00	22.96	VIS 0° (425-675nm)	N-BK7	#38-290	€42,00 Qty 10+ €37,75	3-4 days
12.50	30.00	28.22	VIS 0° (425-675nm)	N-BK7	#38-291	€42,00 Qty 10+ €37,75	3-4 days
12.50	35.00	33.42	VIS 0° (425-675nm)	N-BK7	#38-292	€42,00	3-4 days
12.50	40.00	38.55	VIS 0° (425-675nm)	N-BK7	#38-293	€42,00 Qty 10+ €37,75	3-4 days
12.50	45.00	43.68	VIS 0° (425-675nm)	N-BK7	#38-294	€42,00 Qty 10+ €37,75	3-4 days
12.50	50.00	48.68	VIS 0° (425-675nm)	N-BK7	#38-296	€42,00 Qty 10+ €37,75	3-4 days
12.50	75.00	73.88	VIS 0° (425-675nm)	N-BK7	#38-297	€42,00 Qty 10+ €37,75	In Stock
12.50	100.00	98.95	VIS 0° (425-675nm)	N-BK7	#38-298	€42,00 Qty 10+ €37,75	3-4 days
12.70	12.70	10.46	VIS 0° (425-675nm)	N-SF11	#62-561	€43,00 Qty 10+ €38,50	3-4 days
12.70	15.00	11.53	VIS 0° (425-675nm)	N-BK7	#62-562	€43,00 Qty 10+ €38,50	3-4 days
12.70	19.10	16.46	VIS 0° (425-675nm)	N-BK7	#62-563	€43,00 Qty 10+ €38,50	3-4 days
12.70	20.00	17.49	VIS 0° (425-675nm)	N-BK7	#38-299	€43,00 Qty 10+ €38,50	3-4 days
12.70	25.40	23.43	VIS 0° (425-675nm)	N-BK7	#62-564	€42,00 Qty 10+ €37,75	Contact Us

12.70	30.00	28.22	VIS 0° (425-675nm)	N-BK7	#38-300	€42,00 Qty 10+ €37,75	3-4 days
12.70	31.80	29.81	VIS 0° (425-675nm)	N-BK7	#62-565	€42,00 Qty 10+ €37,75	In Stock
12.70	38.10	36.12	VIS 0° (425-675nm)	N-BK7	#62-566	€42,00 Qty 10+ €37,75	3-4 days
12.70	40.00	38.48	VIS 0° (425-675nm)	N-BK7	#38-309	€42,00 Qty 10+ €37,75	3-4 days
12.70	44.50	42.69	VIS 0° (425-675nm)	N-BK7	#62-567	€42,00 Qty 10+ €37,75	In Stock
12.70	50.80	49.15	VIS 0° (425-675nm)	N-BK7	#62-568	€42,00 Qty 10+ €37,75	3-4 days
12.70	100.00	98.88	VIS 0° (425-675nm)	N-BK7	#38-310	€42,00 Qty 10+ €37,75	3-4 days
15.00	15.00	11.71	VIS 0° (425-675nm)	N-SF5	#47-872	€44,00 Qty 10+ €39,50	In Stock
15.00	18.00	15.61	VIS 0° (425-675nm)	N-SF5	#49-898	€44,00 Qty 10+ €39,50	3-4 days
15.00	20.00	17.74	VIS 0° (425-675nm)	N-SF5	#63-506	€44,00 Qty 10+ €39,50	3-4 days
15.00	22.50	20.50	VIS 0° (425-675nm)	N-SF5	#47-873	€44,00 Qty 10+ €39,50	In Stock
15.00	25.00	22.50	VIS 0° (425-675nm)	N-BK7	#38-311	€43,00 Qty 10+ €38,50	3-4 days
15.00	30.00	27.90	VIS 0° (425-675nm)	N-BK7	#47-874	€43,00 Qty 10+ €38,50	3-4 days
15.00	40.00	38.02	VIS 0° (425-675nm)	N-BK7	#47-875	€43,00 Qty 10+ €38,50	3-4 days

15.00	45.00	43.35	VIS 0° (425-675nm)	N-BK7	#49-899	€43,00 Qty 10+ €38,50	In Stock
15.00	50.00	48.35	VIS 0° (425-675nm)	N-BK7	#38-312	€43,00 Qty 10+ €38,50	3-4 days
15.00	60.00	58.65	VIS 0° (425-675nm)	N-BK7	#47-876	€43,00 Qty 10+ €38,50	3-4 days
15.00	75.00	73.79	VIS 0° (425-675nm)	N-BK7	#47-877	€43,00 Qty 10+ €38,50	3-4 days
15.00	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#47-878	€43,00 Qty 10+ €38,50	3-4 days
15.00	200.00	197.89	VIS 0° (425-675nm)	N-BK7	#14-376	€43,00 Qty 10+ €38,50	3-4 days
15.00	250.00	248.02	VIS 0° (425-675nm)	N-BK7	#14-384	€43,00 Qty 10+ €38,50	3-4 days
18.00	18.00	15.20	VIS 0° (425-675nm)	N-SF11	#48-425	€44,50 Qty 10+ €40,00	3-4 days
18.00	20.00	17.59	VIS 0° (425-675nm)	N-SF11	#38-313	€44,00 Qty 10+ €39,50	3-4 days
18.00	22.50	20.26	VIS 0° (425-675nm)	N-SF11	#49-900	€44,00 Qty 10+ €39,50	3-4 days
18.00	25.00	21.51	VIS 0° (425-675nm)	N-BK7	#38-314	€44,00 Qty 10+ €39,50	3-4 days
18.00	27.00	24.73	VIS 0° (425-675nm)	N-SF5	#47-880	€44,00 Qty 10+ €39,50	3-4 days
18.00	30.00	27.10	VIS 0° (425-675nm)	N-BK7	#38-315	€42,50 Qty 10+ €38,25	3-4 days
18.00	36.00	33.65	VIS 0° (425-675nm)	N-BK7	#47-881	€42,50 Qty 10+ €38,25	3-4 days

18.00	50.00	48.09	VIS 0° (425-675nm)	N-BK7	#38-316	€42,50 Qty 10+ €38,25	In Stock
18.00	54.00	52.02	VIS 0° (425-675nm)	N-BK7	#47-882	€42,50 Qty 10+ €38,25	In Stock
18.00	72.00	70.05	VIS 0° (425-675nm)	N-BK7	#47-883	€42,50 Qty 10+ €38,25	3-4 days
20.00	20.00	17.42	VIS 0° (425-675nm)	N-SF11	#47-884	€45,00 Qty 10+ €40,50	In Stock
20.00	25.00	22.76	VIS 0° (425-675nm)	N-SF11	#49-901	€44,50 Qty 10+ €40,00	In Stock
20.00	30.00	27.30	VIS 0° (425-675nm)	N-BAF10	#47-885	€44,50 Qty 10+ €40,00	3-4 days
20.00	35.00	32.04	VIS 0° (425-675nm)	N-BK7	#49-902	€44,50 Qty 10+ €40,00	In Stock
20.00	40.00	36.77	VIS 0° (425-675nm)	N-BK7	#47-886	€43,00 Qty 10+ €38,50	3-4 days
20.00	50.00	47.87	VIS 0° (425-675nm)	N-BK7	#47-887	€43,00 Qty 10+ €38,50	In Stock
20.00	60.00	57.03	VIS 0° (425-675nm)	N-BK7	#47-888	€43,00 Qty 10+ €38,50	3-4 days
20.00	70.00	68.03	VIS 0° (425-675nm)	N-BK7	#47-889	€43,00 Qty 10+ €38,50	3-4 days
20.00	80.00	78.45	VIS 0° (425-675nm)	N-BK7	#47-890	€43,00 Qty 10+ €38,50	In Stock
20.00	100.00	97.13	VIS 0° (425-675nm)	N-BK7	#47-891	€43,00 Qty 10+ €38,50	3-4 days
20.00	150.00	148.02	VIS 0° (425-675nm)	N-BK7	#47-892	€43,00 Qty 10+ €38,50	3-4 days

25.00	25.00	20.22	VIS 0° (425-675nm)	N-SF5	#47-342	€45,00 Qty 10+ €40,50	In Stock
25.00	30.00	24.69	VIS 0° (425-675nm)	N-BK7	#47-343	€45,00 Qty 10+ €40,50	3-4 days
25.00	35.00	30.42	VIS 0° (425-675nm)	N-BK7	#47-344	€45,00 Qty 10+ €40,50	In Stock
25.00	40.00	36.31	VIS 0° (425-675nm)	N-BK7	#47-345	€45,00 Qty 10+ €40,50	In Stock
25.00	50.00	46.75	VIS 0° (425-675nm)	N-BK7	#47-346	€43,00 Qty 10+ €38,50	In Stock
25.00	60.00	56.90	VIS 0° (425-675nm)	N-BK7	#47-347	€43,00 Qty 10+ €38,50	In Stock
25.00	75.00	72.00	VIS 0° (425-675nm)	N-BK7	#47-348	€43,00 Qty 10+ €38,50	3-4 days
25.00	85.00	82.17	VIS 0° (425-675nm)	N-BK7	#47-349	€43,00 Qty 10+ €38,50	3-4 days
25.00	100.00	97.17	VIS 0° (425-675nm)	N-BK7	#47-350	€43,00 Qty 10+ €38,50	In Stock
25.00	125.00	122.70	VIS 0° (425-675nm)	N-BK7	#47-351	€43,00 Qty 10+ €38,50	3-4 days
25.00	150.00	147.81	VIS 0° (425-675nm)	N-BK7	#47-352	€43,00 Qty 10+ €38,50	In Stock
25.00	175.00	172.85	VIS 0° (425-675nm)	N-BK7	#47-353	€43,00 Qty 10+ €38,50	3-4 days
25.00	200.00	197.89	VIS 0° (425-675nm)	N-BK7	#33-360	€43,00 Qty 10+ €38,50	3-4 days
25.00	250.00	248.02	VIS 0° (425-675nm)	N-BK7	#67-166	€43,00 Qty 10+ €38,50	In Stock

25.00	300.00	298.02	VIS 0° (425-675nm)	N-BK7	#67-167	€43,00 Qty 10+ €38,50	3-4 days
25.00	400.00	397.89	VIS 0° (425-675nm)	N-BK7	#33-366	€43,00 Qty 10+ €38,50	Contact Us
25.00	500.00	497.89	VIS 0° (425-675nm)	N-BK7	#47-356	€43,00 Qty 10+ €38,50	In Stock
25.00	750.00	747.89	VIS 0° (425-675nm)	N-BK7	#47-357	€43,00 Qty 10+ €38,50	3-4 days
25.40	25.40	21.48	VIS 0° (425-675nm)	N-SF11	#62-569	€45,00 Qty 10+ €40,50	3-4 days
25.40	35.00	30.46	VIS 0° (425-675nm)	N-BK7	#38-317	€45,00 Qty 10+ €40,50	3-4 days
25.40	38.10	33.48	VIS 0° (425-675nm)	N-BK7	#62-570	€45,00 Qty 10+ €40,50	Contact Us
25.40	40.00	36.11	VIS 0° (425-675nm)	N-BK7	#38-318	€45,00 Qty 10+ €40,50	3-4 days
25.40	50.80	47.50	VIS 0° (425-675nm)	N-BK7	#62-571	€43,00 Qty 10+ €38,50	3-4 days
25.40	63.50	60.37	VIS 0° (425-675nm)	N-BK7	#62-572	€43,00 Qty 10+ €38,50	3-4 days
25.40	75.00	72.69	VIS 0° (425-675nm)	N-BK7	#38-319	€43,00 Qty 10+ €38,50	3-4 days
25.40	76.20	73.56	VIS 0° (425-675nm)	N-BK7	#62-573	€43,00 Qty 10+ €38,50	In Stock
25.40	88.90	86.26	VIS 0° (425-675nm)	N-BK7	#62-574	€43,00 Qty 10+ €38,50	Contact Us
25.40	100.00	98.02	VIS 0° (425-675nm)	N-BK7	#38-321	€43,00 Qty 10+ €38,50	3-4 days

25.40	101.60	98.97	VIS 0° (425-675nm)	N-BK7	#62-575	€43,00 Qty 10+ €38,50	3-4 days
25.40	125.00	123.02	VIS 0° (425-675nm)	N-BK7	#38-322	€43,00 Qty 10+ €38,50	3-4 days
25.40	150.00	148.02	VIS 0° (425-675nm)	N-BK7	#38-323	€43,00 Qty 10+ €38,50	3-4 days
30.00	30.00	26.13	VIS 0° (425-675nm)	N-SF11	#48-659	€55,50 Qty 10+ €50,00	3-4 days
30.00	40.00	37.20	VIS 0° (425-675nm)	N-SF11	#67-168	€53,50 Qty 10+ €48,00	In Stock
30.00	50.00	46.17	VIS 0° (425-675nm)	N-SF5	#48-233	€53,50 Qty 10+ €48,00	3-4 days
30.00	60.00	56.03	VIS 0° (425-675nm)	N-BK7	#48-234	€52,00 Qty 10+ €46,75	In Stock
30.00	75.00	70.95	VIS 0° (425-675nm)	N-BK7	#48-235	€52,00 Qty 10+ €46,75	Contact Us
30.00	100.00	96.01	VIS 0° (425-675nm)	N-BK7	#48-236	€52,00 Qty 10+ €46,75	In Stock
30.00	120.00	116.04	VIS 0° (425-675nm)	N-BK7	#48-237	€52,00 Qty 10+ €46,75	In Stock
35.00	35.00	30.52	VIS 0° (425-675nm)	N-SF11	#38-324	€57,00 Qty 10+ €51,50	3-4 days
35.00	50.00	44.40	VIS 0° (425-675nm)	N-BK7	#38-325	€55,50 Qty 10+ €50,00	3-4 days
35.00	70.00	66.04	VIS 0° (425-675nm)	N-BK7	#38-326	€55,50 Qty 10+ €50,00	3-4 days
35.00	100.00	97.03	VIS 0° (425-675nm)	N-BK7	#38-327	€55,50 Qty 10+ €50,00	3-4 days

40.00	40.00	35.13	VIS 0° (425-675nm)	N-SF11	#48-660	€62,00 Qty 10+ €56,00	3-4 days
40.00	60.00	53.90	VIS 0° (425-675nm)	N-BK7	#48-238	€62,00 Qty 10+ €56,00	In Stock
40.00	80.00	74.73	VIS 0° (425-675nm)	N-BK7	#33-384	€61,00 Qty 10+ €55,00	3-4 days
40.00	100.00	95.39	VIS 0° (425-675nm)	N-BK7	#33-372	€61,00 Qty 10+ €55,00	3-4 days
40.00	200.00	196.7	VIS 0° (425-675nm)	N-BK7	#33-378	€61,00 Qty 10+ €55,00	In Stock
40.00	300.00	296.70	VIS 0° (425-675nm)	N-BK7	#48-242	€61,00 Qty 10+ €55,00	3-4 days
40.00	400.00	396.70	VIS 0° (425-675nm)	N-BK7	#48-243	€61,00 Qty 10+ €55,00	3-4 days
50.00	50.00	43.28	VIS 0° (425-675nm)	N-SF11	#48-244	€67,00 Qty 10+ €60,50	3-4 days
50.00	75.00	67.75	VIS 0° (425-675nm)	N-BK7	#48-245	€65,00 Qty 10+ €58,50	3-4 days
50.00	100.00	93.41	VIS 0° (425-675nm)	N-BK7	#48-246	€62,50 Qty 10+ €56,50	In Stock
50.00	125.00	118.39	VIS 0° (425-675nm)	N-BK7	#48-247	€62,50 Qty 10+ €56,50	3-4 days
50.00	150.00	144.07	VIS 0° (425-675nm)	N-BK7	#48-248	€62,50 Qty 10+ €56,50	In Stock
50.00	175.00	169.05	VIS 0° (425-675nm)	N-BK7	#48-249	€62,50 Qty 10+ €56,50	3-4 days
50.00	200.00	196.66	VIS 0° (425-675nm)	N-BK7	#48-250	€62,50 Qty 10+ €56,50	Contact Us

50.00	250.00	246.74	VIS 0° (425-675nm)	N-BK7	#48-251	€62,50 Qty 10+ €56,50	3-4 days
50.00	500.00	496.70	VIS 0° (425-675nm)	N-BK7	#48-252	€62,50 Qty 10+ €56,50	3-4 days
#71-336 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
50.80	50.81	44.08	VIS 0° (425-675nm)	N-LASF9		€67,00 Qty 11+ €60,50	3-4 days
#71-343 New							
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
50.80	76.20	68.95	VIS 0° (425-675nm)	N-LASF9		€65,00 Qty 11+ €58,50	3-4 days
75.00	75.00	53.49	VIS 0° (425-675nm)	N-BK7	#86-907	€130,00 Qty 10+ €117,00	3-4 days

[#71-846 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 100.00 87.57

VIS 0°
(425-675nm)

[N-BK7](#)

€128,00

3-4 days

[#71-847 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 125.00 115.99

VIS 0°
(425-675nm)

[N-BK7](#)

€128,00

3-4 days

75.00 150.00 142.45

VIS 0°
(425-675nm)

[N-BK7](#)

[#86-908](#)

€128,00
Qty 10+ €115,00

In Stock

[#71-848 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00	175.00	168.68	VIS 0° (425-675nm)	N-BK7		€128,00	3-4 days
-------	--------	--------	-----------------------	-----------------------	--	---------	----------

75.00	200.00	194.24	VIS 0° (425-675nm)	N-BK7	#86-909	€128,00 Qty 10+ €115,00	3-4 days
-------	--------	--------	-----------------------	-----------------------	-------------------------	----------------------------	----------

75.00	250.00	244.73	VIS 0° (425-675nm)	N-BK7	#86-910	€128,00 Qty 10+ €115,00	3-4 days
-------	--------	--------	-----------------------	-----------------------	-------------------------	----------------------------	----------

[#71-849 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00	300.00	294.4	VIS 0° (425-675nm)	N-BK7		€128,00	3-4 days
-------	--------	-------	-----------------------	-----------------------	--	---------	----------

[#71-850 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	400.00	394.4	VIS 0° (425-675nm)	N-BK7	€128,00	3-4 days
-------	--------	-------	-----------------------	-----------------------	---------	----------

75.00	500.00	494.73	VIS 0° (425-675nm)	N-BK7	#86-084	€128,00 Qty 10+ €115,00	Contact Us
-------	--------	--------	-----------------------	-----------------------	-------------------------	----------------------------	------------

[#71-851 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	750.00	745.35	VIS 0° (425-675nm)	N-BK7	€128,00	3-4 days
-------	--------	--------	-----------------------	-----------------------	---------	----------



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com