

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Achromatic Lenses](#)
TECHSPEC® VIS 0° Coated Achromatic Lenses


- Designed for 0° Angle of Incidence
- Less Than 0.4% Reflectance Per Surface from 425 - 675nm
- [MgF₂](#) and [VIS-NIR](#) Coated Achromats Also Available

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Optical Properties

 Focal Length
 Specification

587.6

Wavelength (nm):

Coating:

VIS 0° (425-675nm)

Coating Specification:

 $R_{avg} \leq 0.4\% @ 425 - 675nm$

Power (P-V) @ 632.8nm:

 1.5λ


 Irregularity (P-V) @
 632.8nm:

 $\lambda/4$

Wavelength Range (nm):

425 - 675

Technical Information

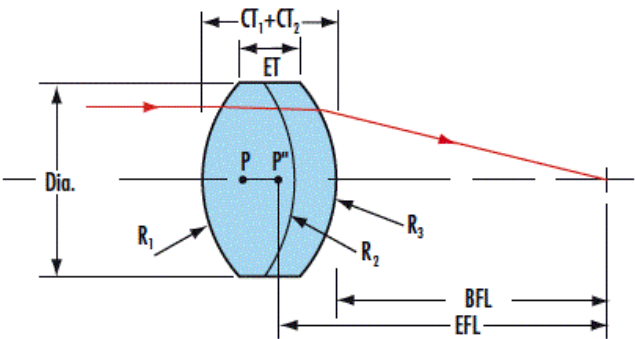

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Substrate	Coating	Stock Number	Price	Buy
#84-125 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	4.00	2.92	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		€216,00	3-4 days
#83-978 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	9.00	8.00	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		€216,00	3-4 days

[#83-979 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

2.00	12.00	11.00	N-PSK53A / N-LASF9	VIS 0° (425-675nm)		€216,00	3-4 days
3.00	4.50	2.99	N-LAK22 / N-SF6	VIS 0° (425-675nm)	#49-270	€121,00 Qty 6+ €97,00	3-4 days
3.00	6.00	4.33	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-271	€121,00 Qty 6+ €97,00	In Stock
3.00	9.00	7.79	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-272	€121,00 Qty 6+ €97,00	3-4 days
3.00	12.00	10.77	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-273	€121,00 Qty 6+ €97,00	3-4 days
4.00	6.00	3.92	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-702	€108,00 Qty 6+ €86,00	In Stock
4.00	8.00	6.69	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-274	€108,00 Qty 6+ €86,00	3-4 days
4.00	10.00	8.40	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-703	€108,00 Qty 6+ €86,00	3-4 days
4.00	12.00	10.70	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-704	€108,00 Qty 6+ €86,00	3-4 days

5.00	7.50	5.01	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-275	€83,50 Qty 6+ €67,00	In Stock
5.00	10.00	8.56	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-276	€83,50 Qty 6+ €67,00	3-4 days
5.00	12.50	10.89	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-935	€83,50 Qty 6+ €67,00	3-4 days
5.00	15.00	13.64	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-277	€83,50 Qty 6+ €67,00	In Stock
5.00	20.00	18.60	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-278	€83,50 Qty 6+ €67,00	3-4 days
6.25	7.50	4.45	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-936	€68,50 Qty 6+ €55,00	3-4 days
6.25	10.00	7.83	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-689	€68,50 Qty 6+ €55,00	3-4 days
6.25	12.50	10.36	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-690	€68,50 Qty 6+ €55,00	3-4 days
6.25	15.00	12.73	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-691	€68,50 Qty 6+ €55,00	In Stock
6.25	17.50	15.46	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-937	€68,50 Qty 6+ €55,00	In Stock
6.25	20.00	18.23	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-692	€68,50 Qty 6+ €55,00	Contact Us
6.25	25.00	23.45	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-693	€68,50 Qty 6+ €55,00	In Stock
6.25	30.00	28.43	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-694	€68,50 Qty 6+ €55,00	In Stock
6.25	35.00	33.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-695	€68,50 Qty 6+ €55,00	3-4 days

6.25	40.00	38.46	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-696	€68,50 Qty 6+ €55,00	3-4 days
6.25	50.00	48.61	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-697	€68,50 Qty 6+ €55,00	In Stock
6.25	60.00	58.46	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-698	€68,50 Qty 6+ €55,00	In Stock
9.00	12.00	8.33	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#47-652	€73,50 Qty 6+ €59,00	3-4 days
9.00	15.00	12.08	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-938	€73,50 Qty 6+ €59,00	In Stock
9.00	18.00	14.91	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-653	€73,50 Qty 6+ €59,00	In Stock
9.00	22.50	20.21	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-939	€73,50 Qty 6+ €59,00	In Stock
9.00	27.00	24.22	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-654	€73,50 Qty 6+ €59,00	In Stock
9.00	36.00	34.17	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-655	€73,50 Qty 6+ €59,00	3-4 days
9.00	40.00	37.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-656	€73,50 Qty 6+ €59,00	3-4 days
9.00	45.00	42.97	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-657	€73,50 Qty 6+ €59,00	3-4 days
9.00	60.00	57.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-658	€73,50 Qty 6+ €59,00	3-4 days
9.00	75.00	72.35	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-659	€73,50 Qty 6+ €59,00	3-4 days
10.00	15.00	10.66	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-705	€75,50 Qty 6+ €60,00	In Stock

10.00	20.00	17.24	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#63-706	€75,50 Qty 6+ €60,00	3-4 days
10.00	25.00	22.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-707	€75,50 Qty 6+ €60,00	3-4 days
10.00	30.00	27.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-708	€75,50 Qty 6+ €60,00	In Stock
10.00	40.00	37.79	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-709	€75,50 Qty 6+ €60,00	3-4 days
10.00	50.00	47.45	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-710	€75,50 Qty 6+ €60,00	3-4 days
10.00	100.00	98.16	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-711	€75,50 Qty 6+ €60,00	In Stock
12.50	15.00	10.82	N-LAK22 / N-SF6	VIS 0° (425-675nm)	#63-712	€83,00 Qty 6+ €66,00	3-4 days
12.50	14.00	9.92	N-BAF10 / N-SF5	VIS 0° (425-675nm)	#47-660	€83,00 Qty 6+ €66,00	3-4 days
12.50	17.50	13.59	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-940	€83,00 Qty 6+ €66,00	In Stock
12.50	20.00	16.45	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-661	€83,00 Qty 6+ €66,00	In Stock
12.50	25.00	21.47	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-662	€83,00 Qty 6+ €66,00	In Stock
12.50	30.00	26.12	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-663	€83,00 Qty 6+ €66,00	In Stock
12.50	35.00	32.50	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-664	€83,00 Qty 6+ €66,00	In Stock
12.50	40.00	37.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-665	€83,00 Qty 6+ €66,00	In Stock

12.50	45.00	42.52	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-666	€83,00 Qty 6+ €66,00	In Stock
12.50	50.00	47.61	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-667	€83,00 Qty 6+ €66,00	In Stock
12.50	60.00	57.59	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-668	€83,00 Qty 6+ €66,00	In Stock
12.50	75.00	72.35	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-669	€83,00 Qty 6+ €66,00	In Stock
12.50	80.00	78.40	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-670	€83,00 Qty 6+ €66,00	3-4 days
12.50	90.00	88.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-671	€83,00 Qty 6+ €66,00	3-4 days
12.50	100.00	97.92	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-672	€83,00 Qty 6+ €66,00	3-4 days
12.70	15.00	10.56	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-771	€83,00 Qty 6+ €66,00	3-4 days
12.70	19.10	15.38	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-772	€83,00 Qty 6+ €66,00	3-4 days
12.70	25.40	22.45	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-773	€83,00 Qty 6+ €66,00	3-4 days
12.70	31.75	28.83	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-774	€83,00 Qty 6+ €66,00	3-4 days
12.70	38.10	35.57	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-775	€83,00 Qty 6+ €66,00	In Stock
12.70	44.45	41.98	N-BAK1 / N-SF8	VIS 0° (425-675nm)	#49-776	€83,00 Qty 6+ €66,00	3-4 days
12.70	50.80	48.86	N-BAK1 / N-SF15	VIS 0° (425-675nm)	#49-777	€83,00 Qty 6+ €66,00	3-4 days

12.70	125.00	121.95	N-BK7 / N-SF5	VIS 0° (425-675nm)	#69-922	€83,00 Qty 6+ €66,00	In Stock
15.00	20.00	15.34	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-941	€99,00 Qty 6+ €79,00	3-4 days
15.00	25.00	20.98	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-699	€99,00 Qty 6+ €79,00	In Stock
15.00	30.00	25.78	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-700	€99,00 Qty 6+ €79,00	3-4 days
15.00	40.00	35.63	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-701	€99,00 Qty 6+ €79,00	In Stock
15.00	50.00	46.17	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-702	€99,00 Qty 6+ €79,00	In Stock
15.00	60.00	57.48	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-942	€99,00 Qty 6+ €79,00	3-4 days
15.00	75.00	70.78	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-703	€99,00 Qty 6+ €79,00	3-4 days
18.00	22.50	16.39	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#49-943	€100,00 Qty 6+ €80,00	In Stock
18.00	27.00	21.74	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-704	€100,00 Qty 6+ €80,00	3-4 days
18.00	30.00	24.97	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-705	€100,00 Qty 6+ €80,00	3-4 days
18.00	35.00	30.72	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-706	€100,00 Qty 6+ €80,00	In Stock
18.00	40.00	35.63	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-707	€100,00 Qty 6+ €80,00	In Stock
18.00	50.00	45.24	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-708	€100,00 Qty 6+ €80,00	3-4 days

18.00	60.00	56.79	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-709	€100,00 Qty 6+ €80,00	3-4 days
18.00	75.00	72.15	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-710	€100,00 Qty 6+ €80,00	In Stock
18.00	80.00	76.52	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-711	€100,00 Qty 6+ €80,00	3-4 days
18.00	125.00	121.95	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-712	€100,00 Qty 6+ €80,00	In Stock
20.00	25.00	18.71	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-944	€102,00 Qty 6+ €82,00	3-4 days
20.00	30.00	24.70	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-733	€102,00 Qty 6+ €82,00	3-4 days
20.00	35.00	29.90	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-734	€102,00 Qty 6+ €82,00	3-4 days
20.00	40.00	34.40	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-735	€102,00 Qty 6+ €82,00	3-4 days
20.00	50.00	46.93	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-945	€102,00 Qty 6+ €82,00	In Stock
20.00	60.00	56.51	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-736	€102,00 Qty 6+ €82,00	In Stock
20.00	80.00	77.26	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-946	€102,00 Qty 6+ €82,00	In Stock
25.00	30.00	22.23	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-633	€116,00 Qty 6+ €93,00	In Stock
25.00	35.00	27.55	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-634	€116,00 Qty 6+ €93,00	3-4 days
25.00	40.00	33.26	S-BAH11 / N-SF10	VIS 0° (425-675nm)	#47-635	€114,00 Qty 6+ €91,00	In Stock

25.00	45.00	39.28	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-636	€114,00 Qty 6+ €91,00	In Stock
25.00	50.00	43.53	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-637	€114,00 Qty 6+ €91,00	In Stock
25.00	60.00	52.23	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-638	€114,00 Qty 6+ €91,00	In Stock
25.00	75.00	70.39	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-639	€114,00 Qty 6+ €91,00	In Stock
25.00	85.00	81.21	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-640	€114,00 Qty 6+ €91,00	In Stock
25.00	100.00	95.92	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-641	€114,00 Qty 6+ €91,00	In Stock
25.00	125.00	120.89	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-642	€114,00 Qty 6+ €91,00	In Stock
25.00	150.00	146.10	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-643	€114,00 Qty 6+ €91,00	In Stock
25.00	160.00	157.87	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-331	€114,00 Qty 6+ €91,00	In Stock
25.00	175.00	170.84	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-644	€114,00 Qty 6+ €91,00	3-4 days
25.00	200.00	194.14	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-645	€114,00 Qty 6+ €91,00	3-4 days
25.00	225.00	222.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-646	€114,00 Qty 6+ €91,00	3-4 days
25.00	250.00	246.63	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-647	€114,00 Qty 6+ €91,00	In Stock
25.00	275.00	271.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-648	€114,00 Qty 6+ €91,00	3-4 days

25.00	300.00	297.73	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-649	€114,00 Qty 6+ €91,00	3-4 days
25.00	400.00	397.84	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-650	€114,00 Qty 6+ €91,00	In Stock
25.00	500.00	497.57	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-651	€114,00 Qty 6+ €91,00	3-4 days
25.00	750.00	746.47	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-332	€114,00 Qty 6+ €91,00	3-4 days
25.40	38.10	30.77	N-BAF10 / N-SF6	VIS 0° (425-675nm)	#49-778	€114,00 Qty 6+ €91,00	3-4 days
25.40	50.80	44.90	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-779	€114,00 Qty 6+ €91,00	3-4 days
25.40	63.50	57.67	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-780	€114,00 Qty 6+ €91,00	In Stock
25.40	76.20	71.14	N-SSK8 / N-SF56	VIS 0° (425-675nm)	#49-781	€114,00 Qty 6+ €91,00	3-4 days
25.40	88.90	83.96	N-BAK1 / N-SF8	VIS 0° (425-675nm)	#49-782	€114,00 Qty 6+ €91,00	In Stock
25.40	101.60	97.72	N-BAK1 / N-SF15	VIS 0° (425-675nm)	#49-783	€114,00 Qty 6+ €91,00	3-4 days
30.00	40.00	31.14	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-920	€141,00 Qty 6+ €113,00	3-4 days
30.00	50.00	42.57	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-713	€141,00 Qty 6+ €113,00	In Stock
30.00	60.00	52.50	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-714	€141,00 Qty 6+ €113,00	In Stock
30.00	75.00	67.44	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-715	€141,00 Qty 6+ €113,00	In Stock

30.00	100.00	94.54	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-716	€141,00 Qty 6+ €113,00	3-4 days
30.00	125.00	121.32	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-717	€141,00 Qty 6+ €113,00	In Stock
30.00	150.00	144.63	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-718	€141,00 Qty 6+ €113,00	In Stock
30.00	200.00	196.57	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-719	€141,00 Qty 6+ €113,00	3-4 days
40.00	50.00	34.46	N-SK11 / N-SF5	VIS 0° (425-675nm)	#89-682	€174,00 Qty 6+ €139,00	3-4 days
40.00	60.00	50.29	N-SK11 / N-SF5	VIS 0° (425-675nm)	#47-737	€174,00 Qty 6+ €139,00	3-4 days
40.00	80.00	70.75	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#47-738	€174,00 Qty 6+ €139,00	In Stock
40.00	100.00	91.24	N-BK7 / N-SF5	VIS 0° (425-675nm)	#63-713	€174,00 Qty 6+ €139,00	3-4 days
40.00	120.00	111.00	N-SSK8 / N-SF10	VIS 0° (425-675nm)	#47-739	€174,00 Qty 6+ €139,00	3-4 days
40.00	160.00	154.10	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-740	€174,00 Qty 6+ €139,00	In Stock
40.00	200.00	194.21	N-BK7 / N-SF5	VIS 0° (425-675nm)	#47-741	€174,00 Qty 6+ €139,00	In Stock
40.00	250.00	244.32	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-279	€174,00 Qty 6+ €139,00	3-4 days
40.00	300.00	293.63	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-280	€174,00 Qty 6+ €139,00	In Stock
40.00	400.00	394.33	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-281	€174,00 Qty 6+ €139,00	3-4 days

40.00	450.00	445.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-282	€174,00 Qty 6+ €139,00	3-4 days
40.00	500.00	495.60	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-283	€174,00 Qty 6+ €139,00	In Stock
40.00	750.00	744.37	N-BK7 / N-SF5	VIS 0° (425-675nm)	#67-333	€174,00 Qty 6+ €139,00	3-4 days
50.00	75.00	61.17	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-292	€193,00 Qty 6+ €154,00	3-4 days
50.00	100.00	89.94	N-BAF10 / N-SF10	VIS 0° (425-675nm)	#49-284	€186,00 Qty 6+ €149,00	In Stock
50.00	150.00	143.17	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-285	€186,00 Qty 6+ €149,00	In Stock
50.00	200.00	194.45	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-286	€186,00 Qty 6+ €149,00	In Stock
50.00	250.00	243.41	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-287	€186,00 Qty 6+ €149,00	3-4 days
50.00	300.00	292.91	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-288	€186,00 Qty 6+ €149,00	3-4 days
50.00	350.00	344.32	N-BAK4 / N-SF10	VIS 0° (425-675nm)	#49-289	€186,00 Qty 6+ €149,00	In Stock
50.00	500.00	494.50	N-BK7 / N-SF5	VIS 0° (425-675nm)	#49-290	€186,00 Qty 6+ €149,00	3-4 days
75.00	100.00	78.32	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-921	€352,00 Qty 6+ €282,00	3-4 days
75.00	150.00	126.46	N-BAF10 / N-SF57	VIS 0° (425-675nm)	#33-922	€352,00 Qty 6+ €282,00	3-4 days
75.00	200.00	187.69	N-BK7 / N-SF5	VIS 0° (425-675nm)	#88-593	€352,00 Qty 6+ €282,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com