


[All Products](#) / [Test Targets](#) / [Distortion Test Targets](#)

Diffuse Reflectance Grid Distortion Targets

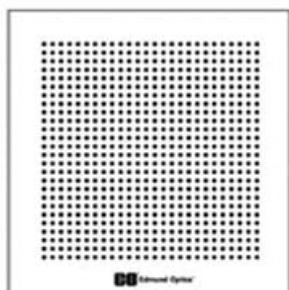

- Diffuse Reflectance Treatment Mimics Ceramic Targets
- Chrome Pattern on Substrate
- No Glare with On or Off Axis Lighting
- Perfect for Front Illuminated Measuring

Common Specifications

General

NIST Certification:	No
---------------------	----

Physical & Mechanical Properties

Thickness (mm):	2.00 ±0.2
-----------------	-----------

Center to Center Spacing Tolerance (μm):	± 1
--	-----

Dot Diameter Tolerance (μm):	±3
---------------------------------	----

Optical Properties

Coating:	Low Reflective Chrome
----------	-----------------------

Substrate:	Float Glass
------------	-------------

Technical Information

Products

Title	Stock Number	Price	Buy
2" x 2" 0.0625mm Dot, Low Reflect Grid Distortion Target	#62-949	€710,00 Qty 5+ €675,00	In Stock
2" x 2" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-950	€685,00 Qty 5+ €651,20	3-4 days
2" x 2" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-951	€665,00 Qty 5+ €632,10	3-4 days
3" x 3" 0.125mm Dot, Low Reflect Grid Distortion Target	#62-952	€855,00 Qty 5+ €812,60	3-4 days
3" x 3" 0.25mm Dot, Low Reflect Grid Distortion Target	#62-953	€815,00 Qty 5+ €774,80	3-4 days
3" x 3" 0.5mm Dot, Low Reflect Grid Distortion Target	#62-954	€785,00 Qty 5+ €745,90	Contact Us



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com