

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Focusing \(Concave\) Mirrors](#)

Precision Parabolic Reflectors



- Precision Polished Substrate
- Protected Aluminum and Cold Mirror Coating Options
- Ideal for Highly Divergent Light Sources
- [Precision Ellipsoidal Reflectors](#) Also Available


Common Specifications

Optical Properties

Substrate: [BOROFLOAT®](#)

Coating Type: Metal

Technical Information

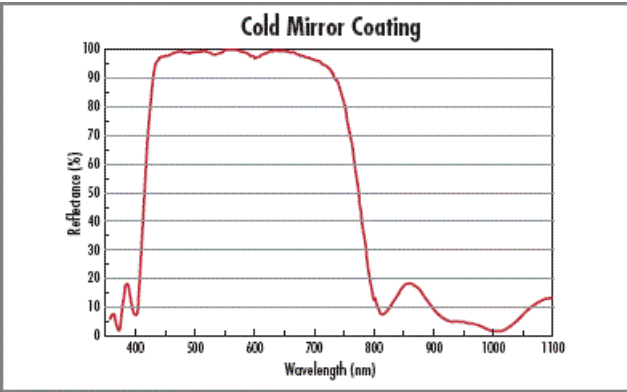

Products

Dia. (mm)	FL (mm)	Aperture (f/#)	Coating	Stock Number	Price	Buy
100.00	12.50	0.125	Protected Aluminum (400-700nm)	#90-964	€370,00 Qty 11+ €326,00	3-4 days
100.00	19.00	0.190	Protected Aluminum (400-700nm)	#68-791	€370,00 Qty 11+ €326,00	3-4 days
152.00	17.00	0.112	Protected Aluminum (400-700nm)	#68-792	€790,00 Qty 11+ €695,00	Contact Us
152.00	30.00	0.197	Protected Aluminum (400-700nm)	#90-965	€700,00 Qty 11+ €620,00	Contact Us
220.00	100.00	0.455	Protected Aluminum (400-700nm)	#68-793	€870,00 Qty 11+ €765,00	3-4 days
300.00	42.00	0.140	Protected Aluminum (400-700nm)	#90-966	€1.450,00 Qty 11+ €1.280,00	3-4 days
100.00	12.50	0.125	Cold Mirror, 0°	#90-967	€505,00 Qty 11+ €445,00	Contact Us
100.00	19.00	0.190	Cold Mirror, 0°	#68-795	€505,00 Qty 11+ €445,00	Contact Us



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com