

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Flat Mirrors](#) / [Precision Polished Metal Coatings](#)

TECHSPEC® $\lambda/10$ First Surface Mirrors



- Precision Fused Silica Substrate
- Variety of Sizes and Coating Options Available
- Low Coefficient of Thermal Expansion

Common Specifications


Physical & Mechanical Properties

Back Surface:	Commercial Polish	Bevel:	Protective bevel as needed
Clear Aperture (%):	90	Edges:	Ground


Optical Properties

Surface Flatness (P-V):	$\lambda/10$	Surface Quality:	20-10
--------------------------------	--------------	-------------------------	-------

Technical Information

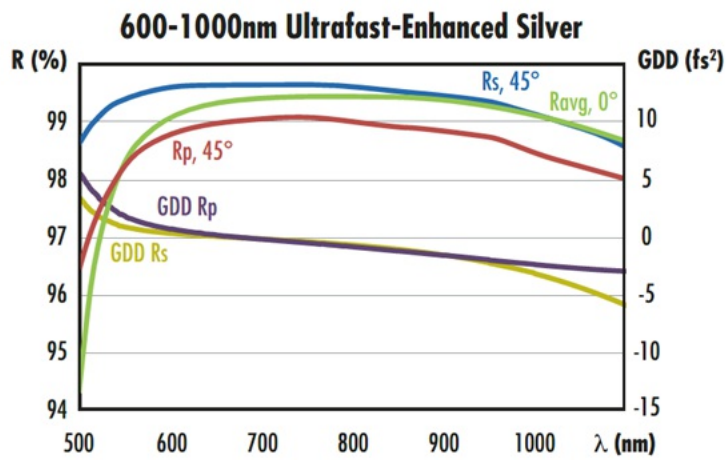

600-1000nm Ultrafast-Enhanced Silver

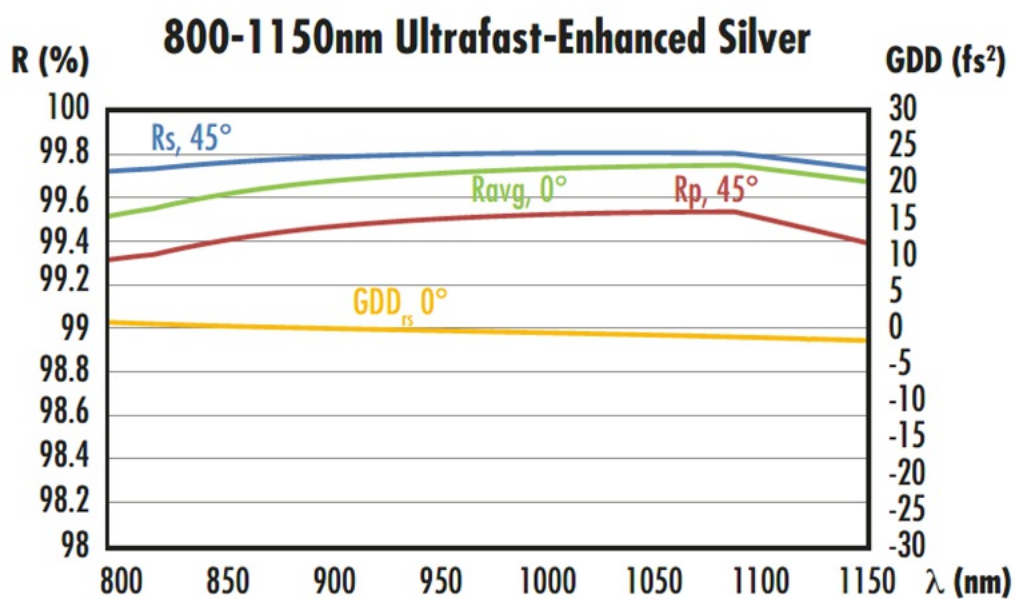

800-1150nm Ultrafast-Enhanced Silver

Products

Dia. (mm)	Surface Flatness (P-V)	Dimensions (mm)	Thickness (mm)	Coating	Coating Specification	Stock Number	Price	Buy
5.00	$\lambda/10$	-	2.00	Enhanced Aluminum (450- 650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#64-007	€79,50 Qty 6+ €63,50	In Stock
5.00	$\lambda/10$	-	2.00	Enhanced Aluminum (250- 700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#68-307	€79,50 Qty 6+ €63,50	3-4 days
5.00	$\lambda/10$	-	2.00	Protected Gold (700- 10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#64-021	€99,00 Qty 6+ €79,00	3-4 days
5.00	$\lambda/10$	-	2.00	Protected Silver (450- 10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#68-321	€95,00 Qty 6+ €76,00	3-4 days
5.00	$\lambda/10$	-	2.00	Ultrafast- Enhanced Silver (600- 1000nm)	$R_{avg} >99\%$ @ 600 - 1000nm, 0° $R_s >99\%$ @ 540 - 1000nm, 45° $R_p >98.5\%$ @ ~730 - 870nm, 45°	#21-976	€97,50 Qty 6+ €78,00	3-4 days
5.00	$\lambda/10$	-	2.00	Ultrafast- Enhanced Silver (800- 1150nm)	$R_{avg} >99\%$ @ 850 - 1150nm, 0° $R_s >99\%$ @ 800 - 1150nm, 45° $R_p >98.5\%$ @ ~850 - 1100nm, 45°	#22-006	€97,50 Qty 6+ €78,00	3-4 days
-	$\lambda/10$	5.0 x 5.0	2.00	Enhanced Aluminum (450- 650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#64-008	€79,50 Qty 6+ €63,50	3-4 days
-	$\lambda/10$	5.0 x 5.0	2.00	Enhanced Aluminum (250- 700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#68-308	€79,50 Qty 6+ €63,50	Contact Us
-	$\lambda/10$	5.0 x 5.0	2.00	Protected Gold (700- 10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#64-022	€99,00 Qty 6+ €79,00	Contact Us

-	$\lambda/10$	5.0 x 5.0	2.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-322	€95,00 Qty 6+ €76,00	Contact Us
-	$\lambda/10$	5.0 x 5.0	2.00	Ultrafast-Enhanced Silver (600-1000nm)	R _{avg} >99% @ 600 - 1000nm, 0° R _s >99% @ 540 - 1000nm, 45° R _p >98.5% @ ~730 - 870nm, 45°	#21-977	€97,50 Qty 6+ €78,00	3-4 days
-	$\lambda/10$	5.0 x 5.0	2.00	Ultrafast-Enhanced Silver (800-1150nm)	R _{avg} >99% @ 850 - 1150nm, 0° R _s >99% @ 800 - 1150nm, 45° R _p >98.5% @ ~850 - 1100nm, 45°	#22-007	€97,50 Qty 6+ €78,00	3-4 days
6.35	$\lambda/10$	-	4.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#39-189	€79,50 Qty 6+ €63,50	3-4 days
6.35	$\lambda/10$	-	4.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#39-188	€79,50 Qty 6+ €63,50	3-4 days
6.35	$\lambda/10$	-	4.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#39-186	€99,00 Qty 6+ €79,00	Contact Us
6.35	$\lambda/10$	-	4.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#39-187	€95,00 Qty 6+ €76,00	3-4 days
10.00	$\lambda/10$	-	2.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#64-009	€79,50 Qty 6+ €63,50	3-4 days
10.00	$\lambda/10$	-	2.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#68-309	€79,50 Qty 6+ €63,50	3-4 days
10.00	$\lambda/10$	-	2.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-023	€99,00 Qty 6+ €79,00	Contact Us

10.00	$\lambda/10$	-	2.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#68-323	€95,00 Qty 6+ €76,00	In Stock
#70-233 New								
								
						New		
						Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!		
10.00	$\lambda/10$	-	2.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} >90\%$ @ 350 - 400nm $R_{avg} >96\%$ @ 400 - 3,000nm		€99,00 Qty 6+ €79,00	3-4 days
10.00	$\lambda/10$	-	2.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} >99\%$ @ 600 - 1000nm, 0° $R_s >99\%$ @ 540 - 1000nm, 45° $R_p >98.5\%$ @ ~730 - 870nm, 45°	#21-979	€97,50 Qty 6+ €78,00	3-4 days
10.00	$\lambda/10$	-	2.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} >99\%$ @ 850 - 1150nm, 0° $R_s >99\%$ @ 800 - 1150nm, 45° $R_p >98.5\%$ @ ~850 - 1100nm, 45°	#22-009	€97,50 Qty 6+ €78,00	3-4 days
-	$\lambda/10$	10.0 x 10.0	2.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#64-010	€79,50 Qty 6+ €63,50	In Stock
-	$\lambda/10$	10.0 x 10.0	2.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#68-310	€79,50 Qty 6+ €63,50	In Stock
-	$\lambda/10$	10.0 x 10.0	2.00	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#64-024	€99,00 Qty 6+ €79,00	3-4 days

-	$\lambda/10$	10.0 x 10.0	2.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#68-324	€95,00 Qty 6+ €76,00	In Stock
12.50	$\lambda/10$	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#84-409	€79,50 Qty 6+ €63,50	In Stock
12.50	$\lambda/10$	-	3.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#84-419	€79,50 Qty 6+ €63,50	3-4 days
12.50	$\lambda/10$	-	3.00	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#84-429	€99,00 Qty 6+ €79,00	Contact Us
12.50	$\lambda/10$	-	3.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#84-439	€95,00 Qty 6+ €76,00	Contact Us

[#70-234 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50	$\lambda/10$	-	3.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} >99\%$ @ 600 - 1000nm, 0° $R_s >99\%$ @ 540 - 1000nm, 45° $R_p >98.5\%$ @ ~730 - 870nm, 45°	#21-980	€97,50 Qty 6+ €78,00	3-4 days
-------	--------------	---	------	--	--	-------------------------	-------------------------	----------

12.50	$\lambda/10$	-	3.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} >99\%$ @ 850 - 1150nm, 0° $R_s >99\%$ @ 800 - 1150nm, 45° $R_p >98.5\%$ @ ~850 - 1100nm, 45°	#22-010	€97,50 Qty 6+ €78,00	3-4 days
-	$\lambda/10$	12.5 x 12.5	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#84-410	€79,50 Qty 6+ €63,50	3-4 days
-	$\lambda/10$	12.5 x 12.5	3.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#84-420	€79,50 Qty 6+ €63,50	Contact Us
-	$\lambda/10$	12.5 x 12.5	3.00	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#84-430	€99,00 Qty 6+ €79,00	Contact Us
-	$\lambda/10$	12.5 x 12.5	3.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#84-440	€95,00 Qty 6+ €76,00	3-4 days
12.70	$\lambda/10$	-	6.35	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#39-196	€79,50 Qty 6+ €63,50	3-4 days
12.70	$\lambda/10$	-	6.35	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#39-195	€79,50 Qty 6+ €63,50	3-4 days
12.70	$\lambda/10$	-	6.35	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#39-193	€99,00 Qty 6+ €79,00	3-4 days
12.70	$\lambda/10$	-	6.35	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#39-194	€95,00 Qty 6+ €76,00	In Stock
15.00	$\lambda/10$	-	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#64-011	€85,50 Qty 6+ €68,50	In Stock
15.00	$\lambda/10$	-	3.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#68-311	€85,50 Qty 6+ €68,50	3-4 days

15.00	$\lambda/10$	-	3.00	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#64-025	€105,00 Qty 6+ €84,00	3-4 days
15.00	$\lambda/10$	-	3.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#68-325	€102,50 Qty 6+ €82,00	In Stock
#70-235 New								
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!								
15.00	$\lambda/10$	-	3.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} >90\%$ @ 350 - 400nm $R_{avg} >96\%$ @ 400 - 3,000nm		€115,00 Qty 6+ €92,00	3-4 days
15.00	$\lambda/10$	-	3.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} >99\%$ @ 600 - 1000nm, 0° $R_s >99\%$ @ 540 - 1000nm, 45° $R_p >98.5\%$ @ ~730 - 870nm, 45°	#21-982	€105,00 Qty 6+ €84,00	3-4 days
15.00	$\lambda/10$	-	3.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} >99\%$ @ 850 - 1150nm, 0° $R_s >99\%$ @ 800 - 1150nm, 45° $R_p >98.5\%$ @ ~850 - 1100nm, 45°	#22-012	€105,00 Qty 6+ €84,00	3-4 days
-	$\lambda/10$	15.0 x 15.0	3.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#64-012	€85,50 Qty 6+ €68,50	Contact Us
-	$\lambda/10$	15.0 x 15.0	3.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#68-312	€92,50 Qty 6+ €74,00	3-4 days

-	$\lambda/10$	15.0 x 15.0	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-026	€105,00 Qty 6+ €84,00	3-4 days
-	$\lambda/10$	15.0 x 15.0	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-326	€102,50 Qty 6+ €82,00	In Stock
-	$\lambda/10$	15.0 x 15.0	3.00	Ultrafast-Enhanced Silver (600-1000nm)	R _{avg} >99% @ 600 - 1000nm, 0° R _s >99% @ 540 - 1000nm, 45° R _p >98.5% @ ~730 - 870nm, 45°	#21-997	€105,00 Qty 6+ €84,00	3-4 days
19.10	$\lambda/10$	-	6.35	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#39-203	€92,50 Qty 6+ €74,00	3-4 days
19.10	$\lambda/10$	-	6.35	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#39-202	€92,50 Qty 6+ €74,00	Contact Us
19.10	$\lambda/10$	-	6.35	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#39-200	€115,00 Qty 6+ €92,00	3-4 days
19.10	$\lambda/10$	-	6.35	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#39-201	€107,50 Qty 6+ €86,00	Contact Us
20.00	$\lambda/10$	-	3.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#64-013	€92,50 Qty 6+ €74,00	In Stock
20.00	$\lambda/10$	-	3.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#68-313	€92,50 Qty 6+ €74,00	3-4 days
20.00	$\lambda/10$	-	3.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-027	€115,00 Qty 6+ €92,00	In Stock
20.00	$\lambda/10$	-	3.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-327	€107,50 Qty 6+ €86,00	3-4 days

[#70-236 New](#)

New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

20.00	$\lambda/10$	-	3.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} > 90\% @$ 350 - 400nm $R_{avg} > 96\% @$ 400 - 3,000nm		€115,00 Qty 6+ €92,00	3-4 days
20.00	$\lambda/10$	-	3.00	Ultrafast- Enhanced Silver (600- 1000nm)	$R_{avg} > 99\% @$ 600 - 1000nm, 0° $R_s > 99\% @$ 540 - 1000nm, 45° $R_p > 98.5\% @$ ~730 - 870nm, 45°	#21-984	€112,50 Qty 6+ €90,00	3-4 days
20.00	$\lambda/10$	-	3.00	Ultrafast- Enhanced Silver (800- 1150nm)	$R_{avg} > 99\% @$ 850 - 1150nm, 0° $R_s > 99\% @$ 800 - 1150nm, 45° $R_p > 98.5\% @$ ~850 - 1100nm, 45°	#22-014	€112,50 Qty 6+ €90,00	3-4 days
-	$\lambda/10$	20.0 x 20.0	3.00	Enhanced Aluminum (450- 650nm)	$R_{avg} > 95\% @$ 450 - 650nm	#64-014	€92,50 Qty 6+ €74,00	3-4 days
-	$\lambda/10$	20.0 x 20.0	3.00	Enhanced Aluminum (250- 700nm)	$R_{avg} > 89\% @$ 250 - 450nm $R_{avg} > 85\% @$ 250 - 700nm	#68-314	€92,50 Qty 6+ €74,00	Contact Us
-	$\lambda/10$	20.0 x 20.0	3.00	Protected Gold (700- 10000nm)	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	#64-028	€115,00 Qty 6+ €92,00	3-4 days
-	$\lambda/10$	20.0 x 20.0	3.00	Protected Silver (450- 10000nm)	$R_{avg} > 98\% @$ 450 - 2000nm $R_{avg} > 98\% @$ 2000 - 10,000nm	#68-328	€107,50 Qty 6+ €86,00	Contact Us

-	$\lambda/10$	20.0 x 20.0	3.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#21-998	€112,50 Qty 6+ €90,00	3-4 days
25.00	$\lambda/10$	-	4.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#64-015	€97,50 Qty 6+ €78,00	In Stock
25.00	$\lambda/10$	-	4.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#68-315	€97,50 Qty 6+ €78,00	In Stock
25.00	$\lambda/10$	-	4.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#64-029	€135,00 Qty 6+ €108,00	In Stock
25.00	$\lambda/10$	-	4.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#68-329	€125,00 Qty 6+ €100,00	In Stock
#70-237 New								
25.00	$\lambda/10$	-	4.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} > 90\% @ 350 - 400nm$ $R_{avg} > 96\% @ 400 - 3,000nm$	 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!	€129,00 Qty 6+ €103,00	3-4 days
25.00	$\lambda/10$	-	4.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#21-985	€129,00 Qty 6+ €103,00	3-4 days

25.00	$\lambda/10$	-	4.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} > 99\% @ 850 - 1150nm, 0^\circ$ $R_s > 99\% @ 800 - 1150nm, 45^\circ$ $R_p > 98.5\% @ \sim 850 - 1100nm, 45^\circ$	#22-015	€129,00 Qty 6+ €103,00	In Stock
-	$\lambda/10$	25.0 x 25.0	4.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#64-016	€97,50 Qty 6+ €78,00	In Stock
-	$\lambda/10$	25.0 x 25.0	4.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#68-316	€97,50 Qty 6+ €78,00	3-4 days
-	$\lambda/10$	25.0 x 25.0	4.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#64-030	€135,00 Qty 6+ €108,00	3-4 days
-	$\lambda/10$	25.0 x 25.0	4.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#68-330	€125,00 Qty 6+ €100,00	In Stock
-	$\lambda/10$	25.0 x 35.0	5.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#25-549	€165,00 Qty 6+ €132,00	Contact Us
-	$\lambda/10$	25.0 x 25.0	4.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#21-999	€129,00 Qty 6+ €103,00	3-4 days
25.40	$\lambda/10$	-	6.35	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#39-210	€97,50 Qty 6+ €78,00	3-4 days
25.40	$\lambda/10$	-	6.35	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#39-209	€97,50 Qty 6+ €78,00	In Stock
25.40	$\lambda/10$	-	6.35	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#39-207	€135,00 Qty 6+ €108,00	In Stock

25.40	$\lambda/10$	-	6.35	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#39-208	€125,00 Qty 6+ €100,00	In Stock
30.00	$\lambda/10$	-	5.00	Enhanced Aluminum (450-650nm)	$R_{avg} >95\%$ @ 450 - 650nm	#84-411	€125,00 Qty 6+ €100,00	3-4 days
30.00	$\lambda/10$	-	5.00	Enhanced Aluminum (250-700nm)	$R_{avg} >89\%$ @ 250 - 450nm $R_{avg} >85\%$ @ 250 - 700nm	#84-421	€125,00 Qty 6+ €100,00	In Stock
30.00	$\lambda/10$	-	5.00	Protected Gold (700-10000nm)	$R_{avg} >96\%$ @ 700 - 2000nm $R_{avg} >96\%$ @ 2000 - 10,000nm	#84-431	€170,00 Qty 6+ €136,00	3-4 days
30.00	$\lambda/10$	-	5.00	Protected Silver (450-10000nm)	$R_{avg} >98\%$ @ 450 - 2000nm $R_{avg} >98\%$ @ 2000 - 10,000nm	#84-441	€135,00 Qty 6+ €108,00	In Stock
#70-238 New								
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!								
30.00	$\lambda/10$	-	5.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} >90\%$ @ 350 - 400nm $R_{avg} >96\%$ @ 400 - 3,000nm		€145,00 Qty 6+ €116,00	3-4 days
30.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} >99\%$ @ 600 - 1000nm, 0° $R_s >99\%$ @ 540 - 1000nm, 45° $R_p >98.5\%$ @ ~730 - 870nm, 45°	#21-987	€145,00 Qty 6+ €116,00	3-4 days

30.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} > 99\% @ 850 - 1150nm, 0^\circ$ $R_s > 99\% @ 800 - 1150nm, 45^\circ$ $R_p > 98.5\% @ \sim 850 - 1100nm, 45^\circ$	#22-017	€145,00 Qty 6+ €116,00	3-4 days
-	$\lambda/10$	30.0 x 30.0	5.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#84-412	€125,00 Qty 6+ €100,00	3-4 days
-	$\lambda/10$	30.0 x 30.0	5.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#84-422	€125,00 Qty 6+ €100,00	Contact Us
-	$\lambda/10$	30.0 x 30.0	5.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#84-432	€170,00 Qty 6+ €136,00	3-4 days
-	$\lambda/10$	30.0 x 30.0	5.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#84-442	€135,00 Qty 6+ €108,00	In Stock
-	$\lambda/10$	30.0 x 30.0	5.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#22-000	€145,00 Qty 6+ €116,00	3-4 days
35.00	$\lambda/10$	-	5.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#84-413	€140,00 Qty 6+ €112,00	3-4 days
35.00	$\lambda/10$	-	5.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#84-423	€140,00 Qty 6+ €112,00	In Stock
35.00	$\lambda/10$	-	5.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#84-433	€180,00 Qty 6+ €144,00	In Stock
35.00	$\lambda/10$	-	5.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#84-443	€165,00 Qty 6+ €132,00	3-4 days

[#70-239 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00	$\lambda/10$	-	5.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} > 90\% @$ 350 - 400nm $R_{avg} > 96\% @$ 400 - 3,000nm		€175,00 Qty 6+ €140,00	3-4 days
35.00	$\lambda/10$	-	5.00	Ultrafast- Enhanced Silver (600- 1000nm)	$R_{avg} > 99\% @$ 600 - 1000nm, 0° $R_s > 99\% @$ 540 - 1000nm, 45° $R_p > 98.5\% @$ ~730 - 870nm, 45°	#21-988	€170,00 Qty 6+ €136,00	3-4 days
-	$\lambda/10$	25.0 x 35.0	5.00	Enhanced Aluminum (450- 650nm)	$R_{avg} > 95\% @$ 450 - 650nm	#25-546	€140,00 Qty 6+ €112,00	Contact Us
-	$\lambda/10$	25.0 x 35.0	5.00	Enhanced Aluminum (250- 700nm)	$R_{avg} > 89\% @$ 250 - 450nm $R_{avg} > 85\% @$ 250 - 700nm	#25-547	€140,00 Qty 6+ €112,00	Contact Us
-	$\lambda/10$	25.0 x 35.0	5.00	Protected Gold (700- 10000nm)	$R_{avg} > 96\% @$ 700 - 2000nm $R_{avg} > 96\% @$ 2000 - 10,000nm	#25-548	€180,00 Qty 6+ €144,00	3-4 days
-	$\lambda/10$	35.0 x 35.0	5.00	Ultrafast- Enhanced Silver (800- 1150nm)	$R_{avg} > 99\% @$ 850 - 1150nm, 0° $R_s > 99\% @$ 800 - 1150nm, 45° $R_p > 98.5\% @$ ~850 - 1100nm, 45°	#22-031	€170,00 Qty 6+ €136,00	3-4 days

35.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} > 99\% @ 850 - 1150nm, 0^\circ$ $R_s > 99\% @ 800 - 1150nm, 45^\circ$ $R_p > 98.5\% @ \sim 850 - 1100nm, 45^\circ$	#22-018	€170,00 Qty 6+ €136,00	3-4 days
-	$\lambda/10$	35.0 x 35.0	5.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#84-414	€140,00 Qty 6+ €112,00	In Stock
-	$\lambda/10$	35.0 x 35.0	5.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#84-424	€140,00 Qty 6+ €112,00	In Stock
-	$\lambda/10$	35.0 x 35.0	5.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#84-434	€180,00 Qty 6+ €144,00	3-4 days
-	$\lambda/10$	35.0 x 35.0	5.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#84-444	€165,00 Qty 6+ €132,00	In Stock
-	$\lambda/10$	35.0 x 35.0	5.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#22-001	€170,00 Qty 6+ €136,00	3-4 days
38.10	$\lambda/10$	-	6.35	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#39-217	€150,00 Qty 6+ €120,00	Contact Us
38.10	$\lambda/10$	-	6.35	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#39-216	€150,00 Qty 6+ €120,00	3-4 days
38.10	$\lambda/10$	-	6.35	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#39-214	€199,00 Qty 6+ €159,00	Contact Us
38.10	$\lambda/10$	-	6.35	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#39-215	€185,00 Qty 6+ €148,00	Contact Us

40.00	$\lambda/10$	-	5.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	#64-017	€150,00 Qty 6+ €120,00	In Stock
40.00	$\lambda/10$	-	5.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	#68-317	€150,00 Qty 6+ €120,00	3-4 days
40.00	$\lambda/10$	-	5.00	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	#64-031	€199,00 Qty 6+ €159,00	3-4 days
40.00	$\lambda/10$	-	5.00	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	#68-331	€185,00 Qty 6+ €148,00	In Stock
#70-240 New								
 New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!								
40.00	$\lambda/10$	-	5.00	UV Enhanced Silver (350 - 3,000nm)	$R_{avg} > 90\% @ 350 - 400nm$ $R_{avg} > 96\% @ 400 - 3,000nm$		€200,00 Qty 6+ €160,00	3-4 days
40.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (600-1000nm)	$R_{avg} > 99\% @ 600 - 1000nm, 0^\circ$ $R_s > 99\% @ 540 - 1000nm, 45^\circ$ $R_p > 98.5\% @ \sim 730 - 870nm, 45^\circ$	#21-990	€190,00 Qty 6+ €152,00	3-4 days
40.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (800-1150nm)	$R_{avg} > 99\% @ 850 - 1150nm, 0^\circ$ $R_s > 99\% @ 800 - 1150nm, 45^\circ$ $R_p > 98.5\% @ \sim 850 - 1100nm, 45^\circ$	#22-020	€190,00 Qty 6+ €152,00	3-4 days

-	$\lambda/10$	40.0 x 40.0	5.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#64-018	€150,00 Qty 6+ €120,00	Contact Us
-	$\lambda/10$	40.0 x 40.0	5.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#68-318	€150,00 Qty 6+ €120,00	Contact Us
-	$\lambda/10$	40.0 x 40.0	5.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-032	€199,00 Qty 6+ €159,00	3-4 days
-	$\lambda/10$	40.0 x 40.0	5.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-332	€185,00 Qty 6+ €148,00	In Stock
50.00	$\lambda/10$	-	5.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#64-019	€165,00 Qty 6+ €132,00	In Stock
50.00	$\lambda/10$	-	5.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#68-319	€165,00 Qty 6+ €132,00	3-4 days
50.00	$\lambda/10$	-	5.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-033	€220,00 Qty 6+ €176,00	Contact Us
50.00	$\lambda/10$	-	5.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-333	€205,00 Qty 6+ €164,00	In Stock

[#70-241 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00	$\lambda/10$	-	5.00	UV Enhanced Silver (350 - 3,000nm)	R _{avg} >90% @ 350 - 400nm R _{avg} >96% @ 400 - 3,000nm		€235,00 Qty 6+ €188,00	3-4 days
-------	--------------	---	------	------------------------------------	--	--	---------------------------	----------

50.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (600-1000nm)	R _{avg} >99% @ 600 - 1000nm, 0° R _s >99% @ 540 - 1000nm, 45° R _p >98.5% @ ~730 - 870nm, 45°	#21-991	€210,00 Qty 6+ €168,00	3-4 days
50.00	$\lambda/10$	-	5.00	Ultrafast-Enhanced Silver (800-1150nm)	R _{avg} >99% @ 850 - 1150nm, 0° R _s >99% @ 800 - 1150nm, 45° R _p >98.5% @ ~850 - 1100nm, 45°	#22-021	€210,00 Qty 6+ €168,00	3-4 days
-	$\lambda/10$	50.0 x 50.0	5.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#64-020	€165,00 Qty 6+ €132,00	In Stock
-	$\lambda/10$	50.0 x 50.0	5.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#68-320	€165,00 Qty 6+ €132,00	In Stock
-	$\lambda/10$	50.0 x 50.0	5.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#64-034	€220,00 Qty 6+ €176,00	In Stock
-	$\lambda/10$	50.0 x 50.0	5.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#68-334	€205,00 Qty 6+ €164,00	3-4 days
50.80	$\lambda/10$	-	9.53	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#39-224	€165,00 Qty 6+ €132,00	3-4 days
50.80	$\lambda/10$	-	9.53	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#39-223	€165,00 Qty 6+ €132,00	In Stock
50.80	$\lambda/10$	-	9.53	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#39-221	€220,00 Qty 6+ €176,00	3-4 days
50.80	$\lambda/10$	-	9.53	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#39-222	€205,00 Qty 6+ €164,00	In Stock

75.00	$\lambda/10$	-	7.50	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#84-415	€340,00 Qty 6+ €272,00	In Stock
75.00	$\lambda/10$	-	7.50	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#84-425	€340,00 Qty 6+ €272,00	3-4 days
75.00	$\lambda/10$	-	7.50	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#84-435	€440,00 Qty 6+ €352,00	3-4 days
75.00	$\lambda/10$	-	7.50	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#84-445	€410,00 Qty 6+ €328,00	In Stock
-	$\lambda/10$	75.0 x 75.0	7.50	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#84-416	€340,00 Qty 6+ €272,00	In Stock
-	$\lambda/10$	75.0 x 75.0	7.50	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#84-426	€340,00 Qty 6+ €272,00	3-4 days
-	$\lambda/10$	75.0 x 75.0	7.50	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#84-436	€440,00 Qty 6+ €352,00	3-4 days
-	$\lambda/10$	75.0 x 75.0	7.50	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#84-446	€410,00 Qty 6+ €328,00	In Stock
100.00	$\lambda/10$	-	10.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#84-417	€499,00 Qty 6+ €399,00	In Stock
100.00	$\lambda/10$	-	10.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#84-427	€499,00 Qty 6+ €399,00	3-4 days
100.00	$\lambda/10$	-	10.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#84-437	€720,00 Qty 6+ €576,00	In Stock
100.00	$\lambda/10$	-	10.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#84-447	€650,00 Qty 6+ €520,00	In Stock

-	$\lambda/10$	100.0 x 100.0	10.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#84-418	€499,00 Qty 6+ €399,00	In Stock
-	$\lambda/10$	100.0 x 100.0	10.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#84-428	€499,00 Qty 6+ €399,00	Contact Us
-	$\lambda/10$	100.0 x 100.0	10.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#84-438	€720,00 Qty 6+ €576,00	3-4 days
-	$\lambda/10$	100.0 x 100.0	10.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#84-448	€650,00 Qty 6+ €520,00	In Stock
5.00	$\lambda/10$	-	1.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#26-094	€79,50 Qty 6+ €63,50	3-4 days
5.00	$\lambda/10$	-	1.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#26-098	€79,50 Qty 6+ €63,50	3-4 days
5.00	$\lambda/10$	-	1.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#26-099	€99,00 Qty 6+ €79,00	Contact Us
5.00	$\lambda/10$	-	1.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#26-100	€95,00 Qty 6+ €76,00	Contact Us
10.00	$\lambda/10$	-	1.00	Enhanced Aluminum (450-650nm)	R _{avg} >95% @ 450 - 650nm	#26-101	€79,50 Qty 6+ €63,50	3-4 days
10.00	$\lambda/10$	-	1.00	Enhanced Aluminum (250-700nm)	R _{avg} >89% @ 250 - 450nm R _{avg} >85% @ 250 - 700nm	#26-102	€79,50 Qty 6+ €63,50	3-4 days
10.00	$\lambda/10$	-	1.00	Protected Gold (700-10000nm)	R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm	#26-103	€99,00 Qty 6+ €79,00	3-4 days
10.00	$\lambda/10$	-	1.00	Protected Silver (450-10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm	#26-104	€95,00 Qty 6+ €76,00	Contact Us

12.50	λ/10	-	1.50	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm	#26-105	€79,50 Qty 6+ €63,50	3-4 days
12.50	λ/10	-	1.50	Enhanced Aluminum (250-700nm)	Ravg >89% @ 250 - 450nm Ravg >85% @ 250 - 700nm	#26-364	€79,50 Qty 6+ €63,50	3-4 days
12.50	λ/10	-	1.50	Protected Gold (700-10000nm)	Ravg >96% @ 700 - 2000nm Ravg >96% @ 2000 - 10,000nm	#26-365	€99,00 Qty 6+ €79,00	3-4 days
12.50	λ/10	-	1.50	Protected Silver (450-10000nm)	Ravg >98% @ 450 - 2000nm Ravg >98% @ 2000 - 10,000nm	#26-366	€95,00 Qty 6+ €76,00	In Stock
15.00	λ/10	-	1.50	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm	#26-367	€85,50 Qty 6+ €68,50	3-4 days
15.00	λ/10	-	1.50	Enhanced Aluminum (250-700nm)	Ravg >89% @ 250 - 450nm Ravg >85% @ 250 - 700nm	#26-368	€85,50 Qty 6+ €68,50	3-4 days
15.00	λ/10	-	1.50	Protected Gold (700-10000nm)	Ravg >96% @ 700 - 2000nm Ravg >96% @ 2000 - 10,000nm	#26-369	€105,00 Qty 6+ €84,00	3-4 days
15.00	λ/10	-	1.50	Protected Silver (450-10000nm)	Ravg >98% @ 450 - 2000nm Ravg >98% @ 2000 - 10,000nm	#26-370	€102,50 Qty 6+ €82,00	Contact Us
20.00	λ/10	-	2.00	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm	#26-371	€92,50 Qty 6+ €74,00	3-4 days
20.00	λ/10	-	2.00	Enhanced Aluminum (250-700nm)	Ravg >89% @ 250 - 450nm Ravg >85% @ 250 - 700nm	#26-372	€92,50 Qty 6+ €74,00	3-4 days
20.00	λ/10	-	2.00	Protected Gold (700-10000nm)	Ravg >96% @ 700 - 2000nm Ravg >96% @ 2000 - 10,000nm	#26-373	€115,00 Qty 6+ €92,00	3-4 days
20.00	λ/10	-	2.00	Protected Silver (450-10000nm)	Ravg >98% @ 450 - 2000nm Ravg >98% @ 2000 - 10,000nm	#26-374	€107,50 Qty 6+ €86,00	3-4 days

25.00	$\lambda/10$	-	3.00	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm	#26-375	€97,50 Qty 6+ €78,00	3-4 days
25.00	$\lambda/10$	-	3.00	Enhanced Aluminum (250-700nm)	Ravg >89% @ 250 - 450nm Ravg >85% @ 250 - 700nm	#26-376	€97,50 Qty 6+ €78,00	3-4 days
25.00	$\lambda/10$	-	3.00	Protected Gold (700-10000nm)	Ravg >96% @ 700 - 2000nm Ravg >96% @ 2000 - 10,000nm	#26-377	€135,00 Qty 6+ €108,00	3-4 days
25.00	$\lambda/10$	-	3.00	Protected Silver (450-10000nm)	Ravg >98% @ 450 - 2000nm Ravg >98% @ 2000 - 10,000nm	#26-378	€125,00 Qty 6+ €100,00	3-4 days
30.00	$\lambda/10$	-	3.00	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm	#26-379	€125,00 Qty 6+ €100,00	3-4 days
30.00	$\lambda/10$	-	3.00	Enhanced Aluminum (250-700nm)	Ravg >89% @ 250 - 450nm Ravg >85% @ 250 - 700nm	#26-380	€125,00 Qty 6+ €100,00	Contact Us
30.00	$\lambda/10$	-	3.00	Protected Gold (700-10000nm)	Ravg >96% @ 700 - 2000nm Ravg >96% @ 2000 - 10,000nm	#26-381	€170,00 Qty 6+ €136,00	3-4 days
30.00	$\lambda/10$	-	3.00	Protected Silver (450-10000nm)	Ravg >98% @ 450 - 2000nm Ravg >98% @ 2000 - 10,000nm	#26-382	€135,00 Qty 6+ €108,00	Contact Us

[#70-924 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

125.00	$\lambda/10$	-	12.50	Enhanced Aluminum (450-650nm)	Ravg >95% @ 450 - 650nm		€850,00 Qty 6+ €680,00	3-4 days
--------	--------------	---	-------	-------------------------------	-------------------------	--	---------------------------	----------

[#70-925 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

125.00	$\lambda/10$	-	12.50	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\%$ @ 250 - 450nm $R_{avg} > 85\%$ @ 250 - 700nm	€850,00 Qty 6+ €680,00	3-4 days
--------	--------------	---	-------	-------------------------------	--	---------------------------	----------

[#70-926 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

125.00	$\lambda/10$	-	12.50	Protected Gold (700-10000nm)	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	€975,00 Qty 6+ €780,00	3-4 days
--------	--------------	---	-------	------------------------------	---	---------------------------	----------

[#70-927 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

125.00	$\lambda/10$	-	12.50	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	€925,00 Qty 6+ €740,00	Contact Us
--------	--------------	---	-------	--------------------------------	---	---------------------------	------------

[#70-928 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	125 x 125	12.50	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	€850,00 Qty 6+ €680,00	3-4 days
---	--------------	-----------	-------	-------------------------------	--------------------------------	---------------------------	----------

[#70-929 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	125 x 125	12.50	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	€850,00 Qty 6+ €680,00	3-4 days
---	--------------	-----------	-------	-------------------------------	--	---------------------------	----------

[#70-930 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	125 x 125	12.50	Protected Gold (700-10000nm)	$R_{avg} > 96\% @ 700 - 2000nm$ $R_{avg} > 96\% @ 2000 - 10,000nm$	€975,00 Qty 6+ €780,00	3-4 days
---	--------------	-----------	-------	------------------------------	---	---------------------------	----------

[#70-931 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	125 x 125	12.50	Protected Silver (450-10000nm)	$R_{avg} > 98\% @ 450 - 2000nm$ $R_{avg} > 98\% @ 2000 - 10,000nm$	€925,00 Qty 6+ €740,00	Contact Us
---	--------------	-----------	-------	--------------------------------	---	---------------------------	------------

[#70-932 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

150.00	$\lambda/10$	-	15.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\% @ 450 - 650nm$	€1.300,00 Qty 6+ €1.040,00	Contact Us
--------	--------------	---	-------	-------------------------------	--------------------------------	-------------------------------	------------

[#70-933 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

150.00	$\lambda/10$	-	15.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\% @ 250 - 450nm$ $R_{avg} > 85\% @ 250 - 700nm$	€1.300,00 Qty 6+ €1.040,00	3-4 days
--------	--------------	---	-------	-------------------------------	--	-------------------------------	----------

[#70-934 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

150.00	$\lambda/10$	-	15.00	Protected Gold (700-10000nm)	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	€1.500,00 Qty 6+ €1.200,00	3-4 days
--------	--------------	---	-------	------------------------------	---	-------------------------------	----------

[#70-935 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

150.00	$\lambda/10$	-	15.00	Protected Silver (450-10000nm)	$R_{avg} > 98\%$ @ 450 - 2000nm $R_{avg} > 98\%$ @ 2000 - 10,000nm	€1.400,00 Qty 6+ €1.120,00	3-4 days
--------	--------------	---	-------	--------------------------------	---	-------------------------------	----------

[#70-936 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	150 x 150	15.00	Enhanced Aluminum (450-650nm)	$R_{avg} > 95\%$ @ 450 - 650nm	€1.300,00 Qty 6+ €1.040,00	3-4 days
---	--------------	-----------	-------	-------------------------------	--------------------------------	-------------------------------	----------

[#70-937 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	150 x 150	15.00	Enhanced Aluminum (250-700nm)	$R_{avg} > 89\%$ @ 250 - 450nm $R_{avg} > 85\%$ @ 250 - 700nm	€1.300,00 Qty 6+ €1.040,00	3-4 days
---	--------------	-----------	-------	-------------------------------	--	-------------------------------	----------

[#70-938 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

-	$\lambda/10$	150 x 150	15.00	Protected Gold (700-10000nm)	$R_{avg} > 96\%$ @ 700 - 2000nm $R_{avg} > 96\%$ @ 2000 - 10,000nm	€1.500,00 Qty 6+ €1.200,00	3-4 days
---	--------------	-----------	-------	------------------------------	---	-------------------------------	----------

[#70-939 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

€1.400,00
Qty 6+ €1.120,00

3-4 days

-	λ/10	150 x 150	15.00	Protected Silver (450- 10000nm)	R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
---	------	-----------	-------	--	--





Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com