

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Bandpass Filters](#)

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters



- Ideal for Life Sciences or Chemical Analysis
- Available in UV, VIS, and IR Center Wavelengths
- Feature High Performance Hard Coatings
- Hard Coated OD 4.0 [5nm](#), [25nm](#), and [50nm](#) Bandpass Filters Also Available

Common Specifications

Physical & Mechanical Properties



Construction:	Mounted in Black Anodized Ring	Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2
---------------	--------------------------------	----------------------	--

Optical Properties			
Angle of Incidence (°):	0	Optical Density OD (Average):	≥4.0
Full Width-Half Max FWHM (nm):	10.00 ±2.0	Full Width-Half Max FWHM Tolerance (nm):	±2.0
Coating:	Hard Coated	Surface Quality:	80-50

Threading & Mounting	
Mount Thickness (mm):	5.0 ±0.1

Environmental & Durability Factors	
Environmental Durability:	Humidity per MIL-STD-810H, Section 507.6 Temperature per MIL-STD-810H, Section 501.7 and 502.7


Technical Information

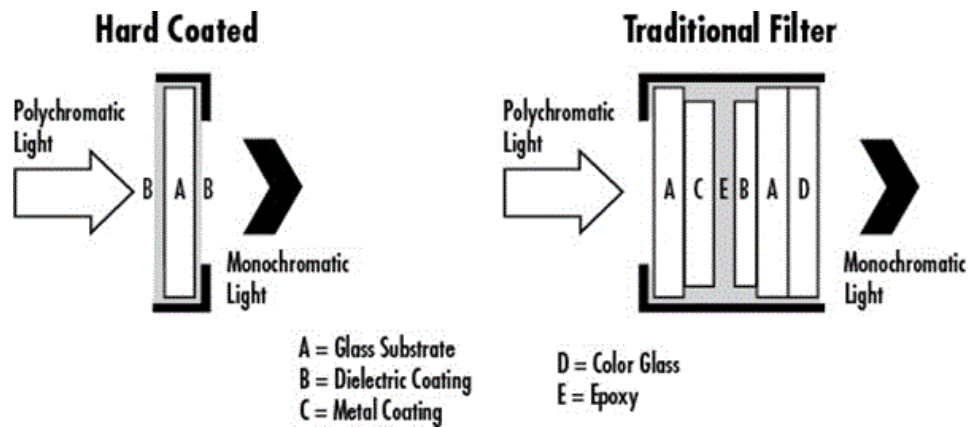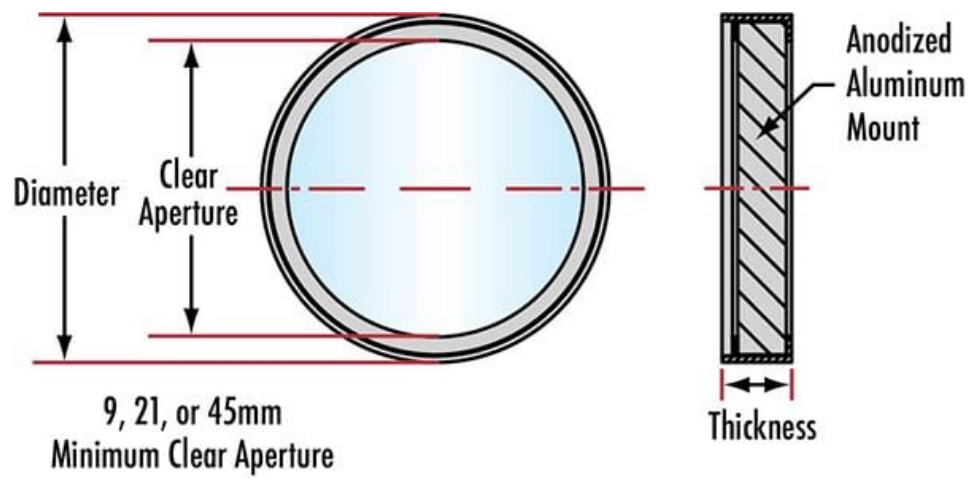




All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is applied to S2.


TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters UV

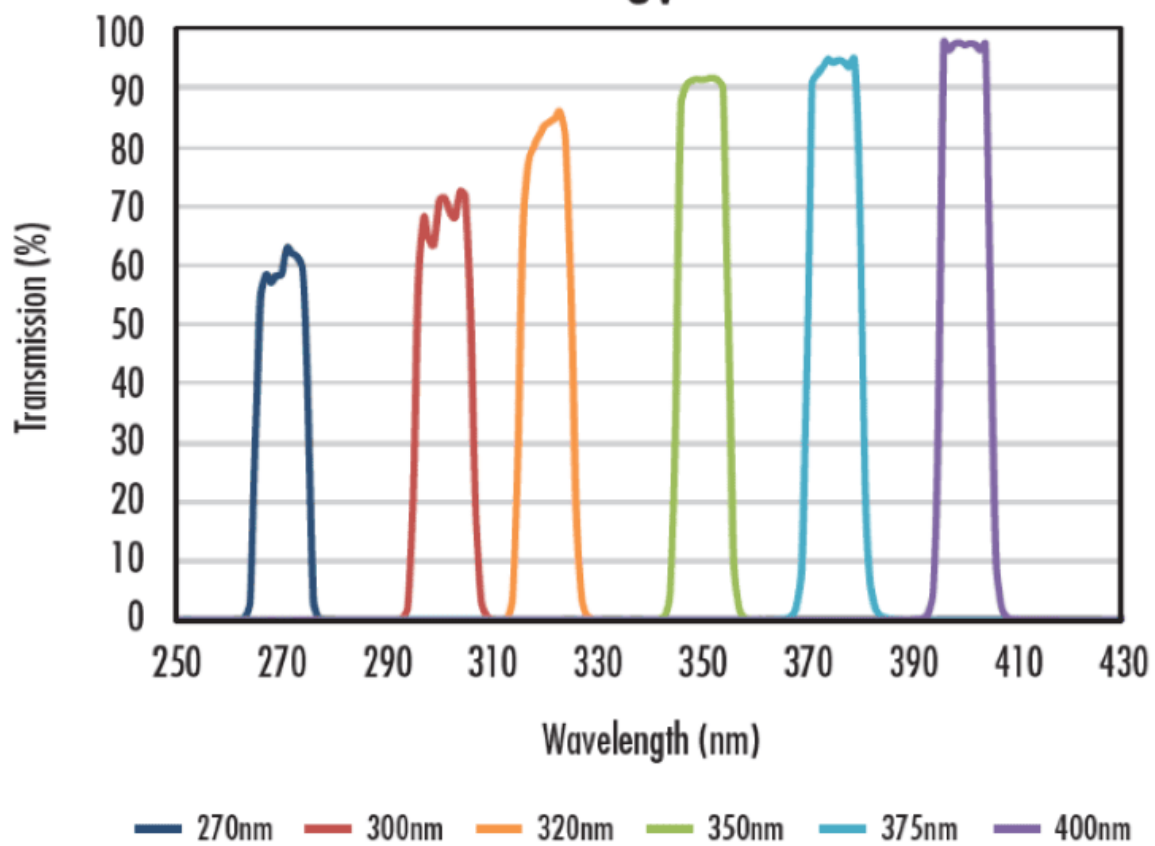

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters
VIS

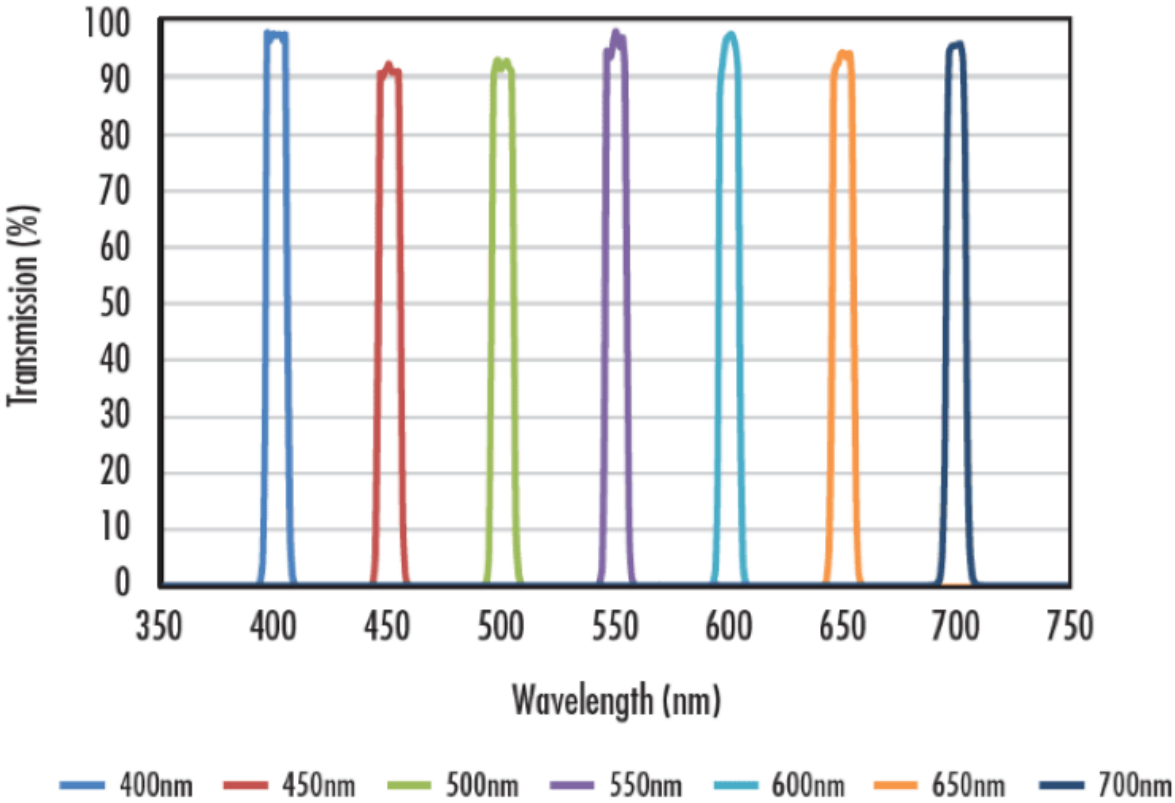

TECHSPEC® Hard Coated OD 4.0 10nm Bandpass Filters IR

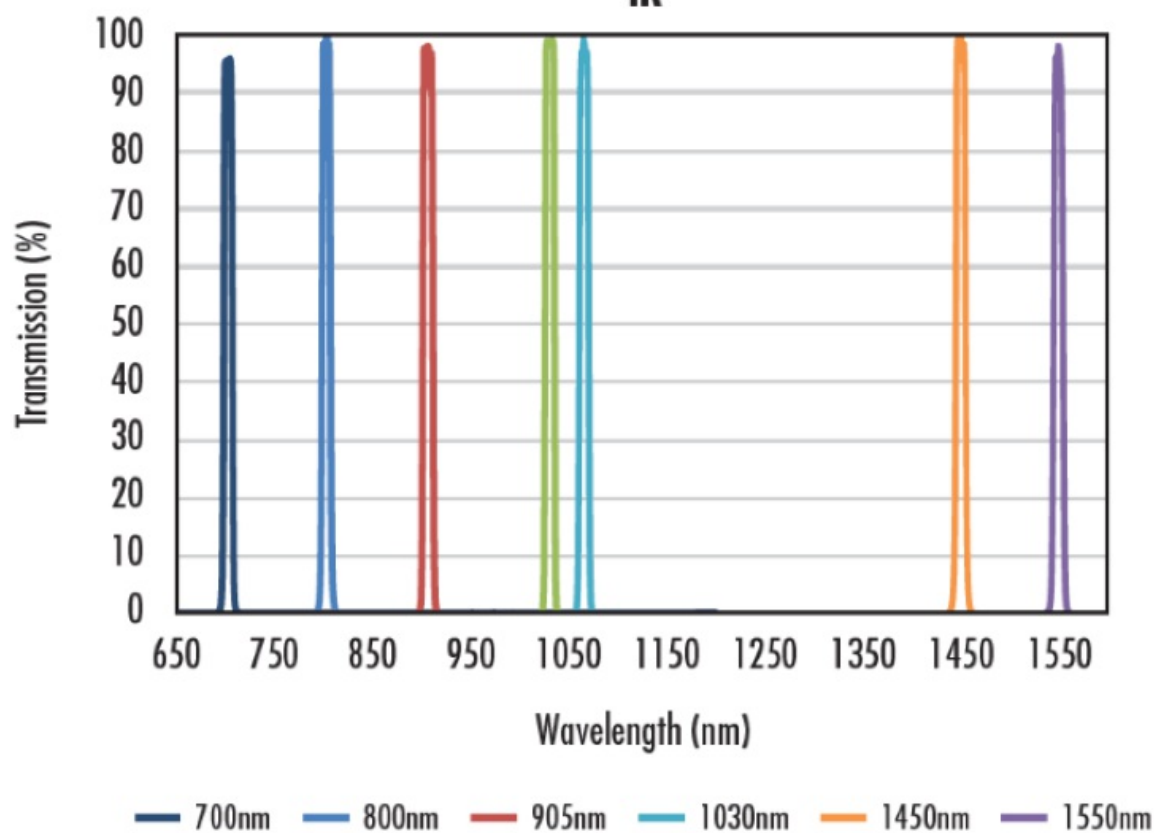

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Minimum Transmission (%)	Blocking Wavelength Range (nm)	Stock Number	Price	Buy
12.50	250.00	10.00	>50	200 - 650	#35-871	€214,24 Volume Pricing	6 In Stock
25.00	250.00	10.00	>50	200 - 650	#35-878	€322,39 Volume Pricing	4 In Stock
50.00	250.00	10.00	>50	200 - 650	#35-885	€770,44 Volume Pricing	4 In Stock
12.50	254.00	10.00	≥50	200 - 650	#39-305	€214,24 Volume Pricing	7 In Stock
25.00	254.00	10.00	≥50	200 - 650	#39-312	€322,39 Volume Pricing	5 In Stock
50.00	254.00	10.00	≥50	200 - 650	#39-319	€770,44 Volume Pricing	1 In Stock
12.50	260.00	10.00	>50	200 - 650	#35-872	€214,24 Volume Pricing	5 In Stock
25.00	260.00	10.00	>50	200 - 650	#35-879	€322,39 Volume Pricing	14 In Stock
12.50	266.00	10.00	≥50	200 - 650	#39-306	€214,24 Volume Pricing	8 In Stock
25.00	266.00	10.00	≥50	200 - 650	#39-313	€322,39 Volume Pricing	10 In Stock
50.00	266.00	10.00	≥50	200 - 650	#39-320	€770,44 Volume Pricing	Contact Us
12.50	270.00	10.00	>60	200 - 650	#35-873	€214,24 Volume Pricing	20+ In Stock
25.00	270.00	10.00	>60	200 - 650	#35-880	€322,39 Volume Pricing	1 In Stock
50.00	270.00	10.00	>60	200 - 650	#35-887	€770,44 Volume Pricing	1 In Stock
12.50	280.00	10.00	>60	200 - 650	#35-874	€214,24 Volume Pricing	20+ In Stock
25.00	280.00	10.00	>60	200 - 650	#35-881	€322,39 Volume Pricing	16 In Stock
50.00	280.00	10.00	>60	200 - 650	#35-888	€770,44 Volume Pricing	2 In Stock

12.50	285.00	10.00	>65	200 - 650	#35-875	€214,24 Volume Pricing	Contact Us
25.00	285.00	10.00	>65	200 - 650	#35-882	€322,39 Volume Pricing	20+ In Stock
50.00	285.00	10.00	>65	200 - 650	#35-889	€770,44 Volume Pricing	1 In Stock
12.50	290.00	10.00	>70	200 - 700	#35-876	€214,24 Volume Pricing	5 In Stock
25.00	290.00	10.00	>70	200 - 700	#35-883	€322,39 Volume Pricing	8 In Stock
50.00	290.00	10.00	>70	200 - 700	#35-890	€770,44 Volume Pricing	5 In Stock
12.50	300.00	10.00	>65	200 - 700	#35-877	€214,24 Volume Pricing	7 In Stock
25.00	300.00	10.00	>65	200 - 700	#35-884	€322,39 Volume Pricing	15 In Stock
50.00	300.00	10.00	>65	200 - 700	#35-891	€770,44 Volume Pricing	1 In Stock
12.50	310.00	10.00	≥70	200 - 1200	#34-972	€194,67 Volume Pricing	11 In Stock
25.00	310.00	10.00	≥70	200 - 1200	#34-976	€282,22 Volume Pricing	1 In Stock
50.00	310.00	10.00	≥70	200 - 1200	#34-980	€669,50 Volume Pricing	8 In Stock
12.50	313.00	10.00	≥75	200 - 1200	#34-973	€194,67 Volume Pricing	2 In Stock
25.00	313.00	10.00	≥75	200 - 1200	#34-977	€282,22 Volume Pricing	20+ In Stock
50.00	313.00	10.00	≥75	200 - 1200	#34-981	€669,50 Volume Pricing	5 In Stock
12.50	320.00	10.00	≥75	200 - 1200	#34-974	€194,67 Volume Pricing	20+ In Stock
25.00	320.00	10.00	≥75	200 - 1200	#34-978	€282,22 Volume Pricing	5 In Stock
50.00	320.00	10.00	≥75	200 - 1200	#34-982	€669,50 Volume Pricing	1 In Stock
12.50	330.00	10.00	≥75	200 - 1200	#34-975	€194,67 Volume Pricing	3 In Stock
25.00	330.00	10.00	≥75	200 - 1200	#34-979	€282,22 Volume Pricing	2 In Stock

50.00	330.00	10.00	≥75	200 - 1200	#34-983	€669,50 Volume Pricing	11 In Stock
12.50	337.00	10.00	≥85	200 - 1200	#65-067	€194,67 Volume Pricing	10 In Stock
25.00	337.00	10.00	≥85	200 - 1200	#65-128	€282,22 Volume Pricing	5 In Stock
50.00	337.00	10.00	≥85	200 - 1200	#65-189	€669,50 Volume Pricing	1 In Stock
12.50	340.00	10.00	≥85	200 - 1200	#65-068	€194,67 Volume Pricing	20+ In Stock
25.00	340.00	10.00	≥85	200 - 1200	#65-129	€282,22 Volume Pricing	3 In Stock
50.00	340.00	10.00	≥85	200 - 1200	#65-190	€669,50 Volume Pricing	1 In Stock
12.50	343.00	10.00	≥85	200 - 1200	#39-307	€194,67 Volume Pricing	16 In Stock
25.00	343.00	10.00	≥85	200 - 1200	#39-314	€282,22 Volume Pricing	2 In Stock
50.00	343.00	10.00	≥85	200 - 1200	#39-321	€669,50 Volume Pricing	1 In Stock
12.50	350.00	10.00	>50	200 - 1200	#39-183	€194,67 Volume Pricing	5 In Stock
25.00	350.00	10.00	>50	200 - 1200	#39-184	€282,22 Volume Pricing	3 In Stock
50.00	350.00	10.00	>50	200 - 1200	#39-185	€669,50 Volume Pricing	3 In Stock
12.50	355.00	10.00	≥85	200 - 1200	#34-490	€194,67 Volume Pricing	1 In Stock
25.00	355.00	10.00	≥85	200 - 1200	#34-491	€282,22 Volume Pricing	4 In Stock
50.00	355.00	10.00	≥85	200 - 1200	#34-492	€669,50 Volume Pricing	12 In Stock
12.50	365.00	10.00	≥85	200 - 1200	#65-069	€194,67 Volume Pricing	9 In Stock
25.00	365.00	10.00	≥85	200 - 1200	#65-130	€282,22 Volume Pricing	10 In Stock
50.00	365.00	10.00	≥85	200 - 1200	#65-191	€669,50 Volume Pricing	3 In Stock
12.50	372.00	10.00	≥85	200 - 1200	#12-147	€194,67 Volume Pricing	20+ In Stock

25.00	372.00	10.00	≥85	200 - 1200	#12-151	€282,22 Volume Pricing	20+ In Stock
50.00	372.00	10.00	≥85	200 - 1200	#12-155	€669,50 Volume Pricing	1 In Stock
12.50	375.00	10.00	≥85	200 - 1200	#86-732	€194,67 Volume Pricing	10 In Stock
25.00	375.00	10.00	≥85	200 - 1200	#86-736	€282,22 Volume Pricing	2 In Stock
50.00	375.00	10.00	≥85	200 - 1200	#86-740	€669,50 Volume Pricing	1 In Stock
12.50	394.00	10.00	≥85	200 - 1200	#65-070	€194,67 Volume Pricing	20+ In Stock
25.00	394.00	10.00	≥85	200 - 1200	#65-131	€282,22 Volume Pricing	3 In Stock
50.00	394.00	10.00	≥85	200 - 1200	#65-192	€669,50 Volume Pricing	6 In Stock
12.50	400.00	10.00	≥85	200 - 1200	#65-071	€177,16 Volume Pricing	6 In Stock
25.00	400.00	10.00	≥85	200 - 1200	#65-132	€264,71 Volume Pricing	3 In Stock
50.00	400.00	10.00	≥85	200 - 1200	#65-193	€640,66 Volume Pricing	5 In Stock
12.50	405.00	10.00	≥85	200 - 1200	#65-072	€177,16 Volume Pricing	20+ In Stock
25.00	405.00	10.00	≥85	200 - 1200	#65-133	€264,71 Volume Pricing	20+ In Stock
50.00	405.00	10.00	≥85	200 - 1200	#65-194	€640,66 Volume Pricing	6 In Stock
12.50	413.00	10.00	≥85	200 - 1200	#34-493	€177,16 Volume Pricing	11 In Stock
25.00	413.00	10.00	≥85	200 - 1200	#34-494	€264,71 Volume Pricing	20+ In Stock
50.00	413.00	10.00	≥85	200 - 1200	#34-495	€640,66 Volume Pricing	8 In Stock
12.50	420.00	10.00	≥85	200 - 1200	#65-075	€177,16 Volume Pricing	4 In Stock
25.00	420.00	10.00	≥85	200 - 1200	#65-136	€264,71 Volume Pricing	20+ In Stock
50.00	420.00	10.00	≥85	200 - 1200	#65-197	€640,66 Volume Pricing	12 In Stock

12.50	422.00	10.00	≥85	200 - 1200	#34-496	€177,16 Volume Pricing	5 In Stock
25.00	422.00	10.00	≥85	200 - 1200	#34-497	€264,71 Volume Pricing	5 In Stock
50.00	422.00	10.00	≥85	200 - 1200	#34-498	€640,66 Volume Pricing	10 In Stock
12.50	430.00	10.00	≥85	200 - 1200	#65-076	€177,16 Volume Pricing	13 In Stock
25.00	430.00	10.00	≥85	200 - 1200	#65-137	€264,71 Volume Pricing	4 In Stock
50.00	430.00	10.00	≥85	200 - 1200	#65-198	€640,66 Volume Pricing	1 In Stock
12.50	436.00	10.00	≥85	200 - 1200	#65-077	€177,16 Volume Pricing	20+ In Stock
25.00	436.00	10.00	≥85	200 - 1200	#65-138	€264,71 Volume Pricing	3 In Stock
50.00	436.00	10.00	≥85	200 - 1200	#65-199	€640,66 Volume Pricing	7 In Stock
12.50	440.00	10.00	>85	200 - 1200	#88-567	€177,16 Volume Pricing	3 In Stock
25.00	440.00	10.00	>85	200 - 1200	#88-570	€264,71 Volume Pricing	16 In Stock
50.00	440.00	10.00	>85	200 - 1200	#88-573	€640,66 Volume Pricing	1 In Stock
12.50	442.00	10.00	≥85	200 - 1200	#65-078	€177,16 Volume Pricing	2 In Stock
25.00	442.00	10.00	≥85	200 - 1200	#65-139	€264,71 Volume Pricing	3 In Stock
50.00	442.00	10.00	≥85	200 - 1200	#65-200	€640,66 Volume Pricing	1 In Stock
12.50	445.00	10.00	≥85	200 - 1200	#34-499	€177,16 Volume Pricing	3 In Stock
25.00	445.00	10.00	≥85	200 - 1200	#34-500	€264,71 Volume Pricing	2 In Stock
50.00	445.00	10.00	≥85	200 - 1200	#34-501	€640,66 Volume Pricing	1 In Stock
12.50	450.00	10.00	≥85	200 - 1200	#65-079	€177,16 Volume Pricing	20+ In Stock
25.00	450.00	10.00	≥85	200 - 1200	#65-140	€264,71 Volume Pricing	6 In Stock

50.00	450.00	10.00	≥85	200 - 1200	#65-201	€640,66 Volume Pricing	7 In Stock
12.50	455.00	10.00	≥85	200 - 1200	#65-080	€177,16 Volume Pricing	20+ In Stock
25.00	455.00	10.00	≥85	200 - 1200	#65-141	€264,71 Volume Pricing	20+ In Stock
50.00	455.00	10.00	≥85	200 - 1200	#65-202	€640,66 Volume Pricing	3 In Stock
12.50	458.00	10.00	≥85	200 - 1200	#65-081	€177,16 Volume Pricing	20+ In Stock
25.00	458.00	10.00	≥85	200 - 1200	#65-142	€264,71 Volume Pricing	1 In Stock
50.00	458.00	10.00	≥85	200 - 1200	#65-203	€640,66 Volume Pricing	3 In Stock
12.50	460.00	10.00	>85	200 - 1200	#87-886	€177,16 Volume Pricing	3 In Stock
25.00	460.00	10.00	>85	200 - 1200	#88-010	€264,71 Volume Pricing	14 In Stock
50.00	460.00	10.00	>85	200 - 1200	#88-016	€640,66 Volume Pricing	9 In Stock
12.50	467.00	10.00	≥85	200 - 1200	#39-308	€177,16 Volume Pricing	4 In Stock
25.00	467.00	10.00	≥85	200 - 1200	#39-315	€264,71 Volume Pricing	20+ In Stock
50.00	467.00	10.00	≥85	200 - 1200	#39-322	€640,66 Volume Pricing	2 In Stock
12.50	470.00	10.00	≥85	200 - 1200	#65-083	€177,16 Volume Pricing	20+ In Stock
25.00	470.00	10.00	≥85	200 - 1200	#65-144	€264,71 Volume Pricing	20+ In Stock
50.00	470.00	10.00	≥85	200 - 1200	#65-205	€640,66 Volume Pricing	1 In Stock
12.50	473.00	10.00	≥85	200 - 1200	#34-502	€177,16 Volume Pricing	2 In Stock
25.00	473.00	10.00	≥85	200 - 1200	#34-503	€264,71 Volume Pricing	5 In Stock
50.00	473.00	10.00	≥85	200 - 1200	#34-504	€640,66 Volume Pricing	11 In Stock
12.50	480.00	10.00	≥85	200 - 1200	#65-084	€177,16 Volume Pricing	20+ In Stock

25.00	480.00	10.00	≥85	200 - 1200	#65-145	€264,71 Volume Pricing	20+ In Stock
50.00	480.00	10.00	≥85	200 - 1200	#65-206	€640,66 Volume Pricing	1 In Stock
12.50	486.00	10.00	≥85	200 - 1200	#65-085	€177,16 Volume Pricing	3 In Stock
25.00	486.00	10.00	≥85	200 - 1200	#65-146	€264,71 Volume Pricing	14 In Stock
50.00	486.00	10.00	≥85	200 - 1200	#65-207	€640,66 Volume Pricing	5 In Stock
12.50	488.00	10.00	≥85	200 - 1200	#65-086	€177,16 Volume Pricing	14 In Stock
25.00	488.00	10.00	≥85	200 - 1200	#65-147	€264,71 Volume Pricing	10 In Stock
50.00	488.00	10.00	≥85	200 - 1200	#65-208	€640,66 Volume Pricing	5 In Stock
12.50	492.00	10.00	≥85	200 - 1200	#65-087	€177,16 Volume Pricing	9 In Stock
25.00	492.00	10.00	≥85	200 - 1200	#65-148	€264,71 Volume Pricing	3 In Stock
50.00	492.00	10.00	≥85	200 - 1200	#65-209	€640,66 Volume Pricing	6 In Stock
12.50	500.00	10.00	≥85	200 - 1200	#65-088	€177,16 Volume Pricing	20+ In Stock
25.00	500.00	10.00	≥85	200 - 1200	#65-149	€264,71 Volume Pricing	20+ In Stock
50.00	500.00	10.00	≥85	200 - 1200	#65-210	€640,66 Volume Pricing	3 In Stock
12.50	505.00	10.00	≥85	200 - 1200	#34-505	€177,16 Volume Pricing	9 In Stock
25.00	505.00	10.00	≥85	200 - 1200	#34-506	€264,71 Volume Pricing	3 In Stock
50.00	505.00	10.00	≥85	200 - 1200	#34-507	€640,66 Volume Pricing	5 In Stock
12.50	508.00	10.00	≥85	200 - 1200	#65-090	€177,16 Volume Pricing	20+ In Stock
25.00	508.00	10.00	≥85	200 - 1200	#65-151	€264,71 Volume Pricing	2 In Stock
12.50	510.00	10.00	≥85	200 - 1200	#65-091	€177,16 Volume Pricing	20+ In Stock

25.00	510.00	10.00	≥85	200 - 1200	#65-152	€264,71 Volume Pricing	1 In Stock
50.00	510.00	10.00	≥85	200 - 1200	#65-213	€640,66 Volume Pricing	1 In Stock
12.50	515.00	10.00	≥85	200 - 1200	#65-092	€177,16 Volume Pricing	3 In Stock
25.00	515.00	10.00	≥85	200 - 1200	#65-153	€264,71 Volume Pricing	6 In Stock
50.00	515.00	10.00	≥85	200 - 1200	#65-214	€640,66 Volume Pricing	Contact Us
12.50	520.00	10.00	≥85	200 - 1200	#65-093	€177,16 Volume Pricing	20+ In Stock
25.00	520.00	10.00	≥85	200 - 1200	#65-154	€264,71 Volume Pricing	6 In Stock
50.00	520.00	10.00	≥85	200 - 1200	#65-215	€640,66 Volume Pricing	4 In Stock
12.50	532.00	10.00	≥85	200 - 1200	#65-094	€177,16 Volume Pricing	20+ In Stock
25.00	532.00	10.00	≥85	200 - 1200	#65-155	€264,71 Volume Pricing	3 In Stock
50.00	532.00	10.00	≥85	200 - 1200	#65-216	€640,66 Volume Pricing	10 In Stock
12.50	535.00	10.00	≥85	200 - 1200	#65-095	€177,16 Volume Pricing	3 In Stock
25.00	535.00	10.00	≥85	200 - 1200	#65-156	€264,71 Volume Pricing	8 In Stock
50.00	535.00	10.00	≥85	200 - 1200	#65-217	€640,66 Volume Pricing	3 In Stock
12.50	540.00	10.00	≥85	200 - 1200	#65-096	€177,16 Volume Pricing	20+ In Stock
25.00	540.00	10.00	≥85	200 - 1200	#65-157	€264,71 Volume Pricing	20+ In Stock
50.00	540.00	10.00	≥85	200 - 1200	#65-218	€640,66 Volume Pricing	8 In Stock
12.50	546.00	10.00	≥85	200 - 1200	#65-097	€177,16 Volume Pricing	8 In Stock
25.00	546.00	10.00	≥85	200 - 1200	#65-158	€264,71 Volume Pricing	16 In Stock
50.00	546.00	10.00	≥85	200 - 1200	#65-219	€640,66 Volume Pricing	5 In Stock

12.50	550.00	10.00	≥85	200 - 1200	#65-098	€177,16 Volume Pricing	3 In Stock
25.00	550.00	10.00	≥85	200 - 1200	#65-159	€264,71 Volume Pricing	20+ In Stock
50.00	550.00	10.00	≥85	200 - 1200	#65-220	€640,66 Volume Pricing	4 In Stock
12.50	560.00	10.00	>85	200 - 1200	#87-887	€177,16 Volume Pricing	20+ In Stock
25.00	560.00	10.00	>85	200 - 1200	#88-011	€264,71 Volume Pricing	10 In Stock
50.00	560.00	10.00	>85	200 - 1200	#88-017	€640,66 Volume Pricing	Contact Us
12.50	561.00	10.00	≥85	200 - 1200	#12-148	€177,16 Volume Pricing	20+ In Stock
25.00	561.00	10.00	≥85	200 - 1200	#12-152	€264,71 Volume Pricing	3 In Stock
50.00	561.00	10.00	≥85	200 - 1200	#12-156	€640,66 Volume Pricing	2 In Stock
12.50	568.00	10.00	≥85	200 - 1200	#65-099	€177,16 Volume Pricing	20+ In Stock
25.00	568.00	10.00	≥85	200 - 1200	#65-160	€264,71 Volume Pricing	11 In Stock
50.00	568.00	10.00	≥85	200 - 1200	#65-221	€640,66 Volume Pricing	11 In Stock
12.50	580.00	10.00	≥85	200 - 1200	#65-100	€177,16 Volume Pricing	20+ In Stock
25.00	580.00	10.00	≥85	200 - 1200	#65-161	€264,71 Volume Pricing	20+ In Stock
50.00	580.00	10.00	≥85	200 - 1200	#65-222	€640,66 Volume Pricing	Contact Us
12.50	589.00	10.00	≥85	200 - 1200	#65-101	€177,16 Volume Pricing	20+ In Stock
25.00	589.00	10.00	≥85	200 - 1200	#65-162	€264,71 Volume Pricing	4 In Stock
50.00	589.00	10.00	≥85	200 - 1200	#65-223	€640,66 Volume Pricing	Contact Us
12.50	594.00	10.00	≥85	200 - 1200	#86-733	€177,16 Volume Pricing	Contact Us
25.00	594.00	10.00	≥85	200 - 1200	#86-737	€264,71 Volume Pricing	2 In Stock

50.00	594.00	10.00	≥85	200 - 1200	#86-741	€640,66 Volume Pricing	1 In Stock
12.50	600.00	10.00	≥85	200 - 1200	#65-102	€177,16 Volume Pricing	20+ In Stock
25.00	600.00	10.00	≥85	200 - 1200	#65-163	€264,71 Volume Pricing	20+ In Stock
50.00	600.00	10.00	≥85	200 - 1200	#65-224	€640,66 Volume Pricing	1 In Stock
12.50	610.00	10.00	≥85	200 - 1200	#65-103	€177,16 Volume Pricing	20+ In Stock
25.00	610.00	10.00	≥85	200 - 1200	#65-164	€264,71 Volume Pricing	4 In Stock
50.00	610.00	10.00	≥85	200 - 1200	#65-225	€640,66 Volume Pricing	4 In Stock
12.50	620.00	10.00	≥85	200 - 1200	#65-104	€177,16 Volume Pricing	20+ In Stock
25.00	620.00	10.00	≥85	200 - 1200	#65-165	€264,71 Volume Pricing	Contact Us
50.00	620.00	10.00	≥85	200 - 1200	#65-226	€640,66 Volume Pricing	15 In Stock
12.50	632.00	10.00	≥85	200 - 1200	#65-105	€177,16 Volume Pricing	9 In Stock
25.00	632.00	10.00	≥85	200 - 1200	#65-166	€264,71 Volume Pricing	8 In Stock
50.00	632.00	10.00	≥85	200 - 1200	#65-227	€640,66 Volume Pricing	Contact Us
12.50	636.00	10.00	≥85	200 - 1200	#65-106	€177,16 Volume Pricing	5 In Stock
25.00	636.00	10.00	≥85	200 - 1200	#65-167	€264,71 Volume Pricing	2 In Stock
50.00	636.00	10.00	≥85	200 - 1200	#65-228	€640,66 Volume Pricing	4 In Stock
12.50	640.00	10.00	≥85	200 - 1200	#65-107	€177,16 Volume Pricing	20+ In Stock
25.00	640.00	10.00	≥85	200 - 1200	#65-168	€264,71 Volume Pricing	20+ In Stock
50.00	640.00	10.00	≥85	200 - 1200	#65-229	€640,66 Volume Pricing	8 In Stock
12.50	647.00	10.00	≥85	200 - 1200	#65-108	€177,16 Volume Pricing	20+ In Stock

25.00	647.00	10.00	≥85	200 - 1200	#65-169	€264,71 Volume Pricing	10 In Stock
50.00	647.00	10.00	≥85	200 - 1200	#65-230	€640,66 Volume Pricing	Contact Us
12.50	650.00	10.00	≥85	200 - 1200	#65-109	€177,16 Volume Pricing	5 In Stock
25.00	650.00	10.00	≥85	200 - 1200	#65-170	€264,71 Volume Pricing	20+ In Stock
50.00	650.00	10.00	≥85	200 - 1200	#65-231	€640,66 Volume Pricing	4 In Stock
12.50	656.00	10.00	≥85	200 - 1200	#65-110	€177,16 Volume Pricing	20+ In Stock
25.00	656.00	10.00	≥85	200 - 1200	#65-171	€264,71 Volume Pricing	6 In Stock
50.00	656.00	10.00	≥85	200 - 1200	#65-232	€640,66 Volume Pricing	3 In Stock
12.50	660.00	10.00	≥85	200 - 1200	#86-086	€177,16 Volume Pricing	16 In Stock
25.00	660.00	10.00	≥85	200 - 1200	#86-089	€264,71 Volume Pricing	20+ In Stock
50.00	660.00	10.00	≥85	200 - 1200	#86-092	€640,66 Volume Pricing	7 In Stock
12.50	671.00	10.00	≥85	200 - 1200	#65-111	€177,16 Volume Pricing	10 In Stock
25.00	671.00	10.00	≥85	200 - 1200	#65-172	€264,71 Volume Pricing	7 In Stock
50.00	671.00	10.00	≥85	200 - 1200	#65-233	€640,66 Volume Pricing	3 In Stock
12.50	676.00	10.00	≥85	200 - 1200	#65-112	€177,16 Volume Pricing	11 In Stock
25.00	676.00	10.00	≥85	200 - 1200	#65-173	€264,71 Volume Pricing	5 In Stock
50.00	676.00	10.00	≥85	200 - 1200	#65-234	€640,66 Volume Pricing	Contact Us
12.50	680.00	10.00	>85	200 - 1200	#88-568	€177,16 Volume Pricing	2 In Stock
25.00	680.00	10.00	>85	200 - 1200	#88-571	€264,71 Volume Pricing	2 In Stock
50.00	680.00	10.00	>85	200 - 1200	#88-574	€640,66 Volume Pricing	1 In Stock

12.50	685.00	10.00	≥85	200 - 1200	#86-734	€177,16 Volume Pricing	10 In Stock
25.00	685.00	10.00	≥85	200 - 1200	#86-738	€264,71 Volume Pricing	17 In Stock
50.00	685.00	10.00	≥85	200 - 1200	#86-742	€640,66 Volume Pricing	5 In Stock
12.50	690.00	10.00	≥85	200 - 1200	#65-113	€177,16 Volume Pricing	2 In Stock
25.00	690.00	10.00	≥85	200 - 1200	#65-174	€264,71 Volume Pricing	20+ In Stock
50.00	690.00	10.00	≥85	200 - 1200	#65-235	€640,66 Volume Pricing	7 In Stock
12.50	694.00	10.00	≥85	200 - 1200	#65-114	€177,16 Volume Pricing	14 In Stock
25.00	694.00	10.00	≥85	200 - 1200	#65-175	€264,71 Volume Pricing	5 In Stock
50.00	694.00	10.00	≥85	200 - 1200	#65-236	€640,66 Volume Pricing	5 In Stock
12.50	700.00	10.00	>85	200 - 1200	#87-888	€194,67 Volume Pricing	20+ In Stock
25.00	700.00	10.00	>85	200 - 1200	#88-012	€282,22 Volume Pricing	20+ In Stock
50.00	700.00	10.00	>85	200 - 1200	#88-018	€669,50 Volume Pricing	7 In Stock
12.50	730.00	10.00	≥85	200 - 1200	#65-115	€194,67 Volume Pricing	20+ In Stock
25.00	730.00	10.00	≥85	200 - 1200	#65-176	€282,22 Volume Pricing	4 In Stock
50.00	730.00	10.00	≥85	200 - 1200	#65-237	€669,50 Volume Pricing	1 In Stock
12.50	750.00	10.00	>85	200 - 1200	#87-889	€194,67 Volume Pricing	20+ In Stock
25.00	750.00	10.00	>85	200 - 1200	#88-013	€282,22 Volume Pricing	Contact Us
50.00	750.00	10.00	>85	200 - 1200	#88-019	€669,50 Volume Pricing	5 In Stock
12.50	752.00	10.00	≥85	200 - 1200	#12-149	€194,67 Volume Pricing	6 In Stock
25.00	752.00	10.00	≥85	200 - 1200	#12-153	€282,22 Volume Pricing	16 In Stock

50.00	752.00	10.00	≥85	200 - 1200	#12-157	€669,50 Volume Pricing	2 In Stock
12.50	766.00	10.00	≥85	200 - 1200	#65-116	€194,67 Volume Pricing	Contact Us
25.00	766.00	10.00	≥85	200 - 1200	#65-177	€282,22 Volume Pricing	20+ In Stock
50.00	766.00	10.00	≥85	200 - 1200	#65-238	€669,50 Volume Pricing	1 In Stock
12.50	770.00	10.00	>85	200 - 1200	#87-890	€194,67 Volume Pricing	1 In Stock
25.00	770.00	10.00	>85	200 - 1200	#88-014	€282,22 Volume Pricing	1 In Stock
50.00	770.00	10.00	>85	200 - 1200	#88-020	€669,50 Volume Pricing	3 In Stock
12.50	780.00	10.00	≥85	200 - 1200	#65-117	€194,67 Volume Pricing	4 In Stock
25.00	780.00	10.00	≥85	200 - 1200	#65-178	€282,22 Volume Pricing	20+ In Stock
50.00	780.00	10.00	≥85	200 - 1200	#65-239	€669,50 Volume Pricing	11 In Stock
12.50	785.00	10.00	≥85	200 - 1200	#86-735	€194,67 Volume Pricing	20+ In Stock
25.00	785.00	10.00	≥85	200 - 1200	#86-739	€282,22 Volume Pricing	5 In Stock
50.00	785.00	10.00	≥85	200 - 1200	#86-743	€669,50 Volume Pricing	1 In Stock
12.50	800.00	10.00	≥85	200 - 1200	#65-118	€194,67 Volume Pricing	3 In Stock
25.00	800.00	10.00	≥85	200 - 1200	#65-179	€282,22 Volume Pricing	4 In Stock
50.00	800.00	10.00	≥85	200 - 1200	#65-240	€669,50 Volume Pricing	Contact Us
12.50	808.00	10.00	≥85	200 - 1200	#39-309	€194,67 Volume Pricing	20+ In Stock
25.00	808.00	10.00	≥85	200 - 1200	#39-316	€282,22 Volume Pricing	20+ In Stock
50.00	808.00	10.00	≥85	200 - 1200	#39-323	€669,50 Volume Pricing	16 In Stock
12.50	810.00	10.00	>85	200 - 1200	#87-891	€194,67 Volume Pricing	Contact Us

25.00	810.00	10.00	>85	200 - 1200	#88-015	€282,22 Volume Pricing	20+ In Stock
50.00	810.00	10.00	>85	200 - 1200	#88-021	€669,50 Volume Pricing	Contact Us
12.50	830.00	10.00	≥85	200 - 1200	#65-119	€194,67 Volume Pricing	20+ In Stock
25.00	830.00	10.00	≥85	200 - 1200	#65-180	€282,22 Volume Pricing	4 In Stock
50.00	830.00	10.00	≥85	200 - 1200	#65-241	€669,50 Volume Pricing	11 In Stock
12.50	850.00	10.00	≥85	200 - 1200	#86-087	€194,67 Volume Pricing	20+ In Stock
25.00	850.00	10.00	≥85	200 - 1200	#86-090	€282,22 Volume Pricing	20+ In Stock
50.00	850.00	10.00	≥85	200 - 1200	#86-093	€669,50 Volume Pricing	5 In Stock
12.50	852.00	10.00	≥85	200 - 1200	#65-120	€194,67 Volume Pricing	20+ In Stock
25.00	852.00	10.00	≥85	200 - 1200	#65-181	€282,22 Volume Pricing	14 In Stock
50.00	852.00	10.00	≥85	200 - 1200	#65-242	€669,50 Volume Pricing	5 In Stock
12.50	880.00	10.00	≥85	200 - 1200	#65-122	€194,67 Volume Pricing	Contact Us
25.00	880.00	10.00	≥85	200 - 1200	#65-183	€282,22 Volume Pricing	20+ In Stock
50.00	880.00	10.00	≥85	200 - 1200	#65-244	€669,50 Volume Pricing	1 In Stock
12.50	905.00	10.00	≥85	200 - 1200	#65-123	€194,67 Volume Pricing	20+ In Stock
25.00	905.00	10.00	≥85	200 - 1200	#65-184	€282,22 Volume Pricing	20+ In Stock
50.00	905.00	10.00	≥85	200 - 1200	#65-245	€669,50 Volume Pricing	4 In Stock
12.50	940.00	10.00	≥85	200 - 1200	#65-124	€194,67 Volume Pricing	20+ In Stock
25.00	940.00	10.00	≥85	200 - 1200	#65-185	€282,22 Volume Pricing	Contact Us
50.00	940.00	10.00	≥85	200 - 1200	#65-246	€669,50 Volume Pricing	11 In Stock

12.50	950.00	10.00	>85	200 - 1200	#88-569	€194,67 Volume Pricing	3 In Stock
25.00	950.00	10.00	>85	200 - 1200	#88-572	€282,22 Volume Pricing	14 In Stock
50.00	950.00	10.00	>85	200 - 1200	#88-575	€669,50 Volume Pricing	1 In Stock
12.50	980.00	10.00	≥85	200 - 1200	#65-125	€194,67 Volume Pricing	20+ In Stock
25.00	980.00	10.00	≥85	200 - 1200	#65-186	€282,22 Volume Pricing	17 In Stock
50.00	980.00	10.00	≥85	200 - 1200	#65-247	€669,50 Volume Pricing	1 In Stock
12.50	1,030.00	10.00	≥85	200 - 1200	#39-310	€194,67 Volume Pricing	5 In Stock
25.00	1,030.00	10.00	≥85	200 - 1200	#39-317	€282,22 Volume Pricing	5 In Stock
50.00	1,030.00	10.00	≥85	200 - 1200	#39-324	€669,50 Volume Pricing	20+ In Stock
12.50	1,064.00	10.00	≥85	200 - 1200	#65-126	€194,67 Volume Pricing	4 In Stock
25.00	1,064.00	10.00	≥85	200 - 1200	#65-187	€282,22 Volume Pricing	Contact Us
50.00	1,064.00	10.00	≥85	200 - 1200	#65-248	€669,50 Volume Pricing	2 In Stock
12.50	1,450.00	10.00	≥85	400 - 1800	#39-311	€229,69 Volume Pricing	1 In Stock
25.00	1,450.00	10.00	≥85	400 - 1800	#39-318	€344,02 Volume Pricing	2 In Stock
50.00	1,450.00	10.00	≥85	400 - 1800	#39-326	€819,88 Volume Pricing	Contact Us
12.50	1,550.00	10.00	≥85	200 - 1800	#86-088	€229,69 Volume Pricing	20+ In Stock
				200 - 1800	#86-091	€344,02 Volume Pricing	10 In Stock



Edmund
optics | worldwide

Copyright © 2020 Edmund Optics BV, De Meern 3522 BR, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com

50.00 1,550.00 10.00 ≥85 200 - 1800 [#86-084](#) [#86-084](#) €819,88
[Volume Pricing](#) 12 In Stock