


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [UV Lenses](#)

TECHSPEC® Laser Grade Plano-Convex (PCX) Lenses

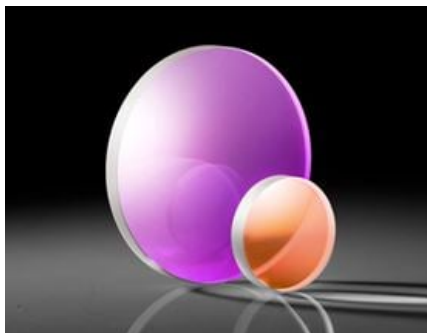

- Guaranteed Laser Damage Threshold
- 10-5 Surface Quality
- $\lambda/10$ Surface Accuracy

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Optical Properties




Substrate:

[Fused Silica](#) (Corning 7980)


Power (P-V) @ 632.8nm:

λ

Technical Information

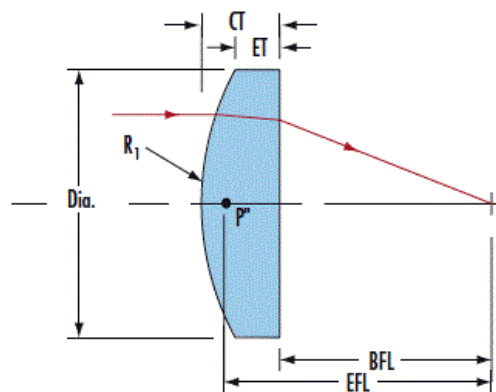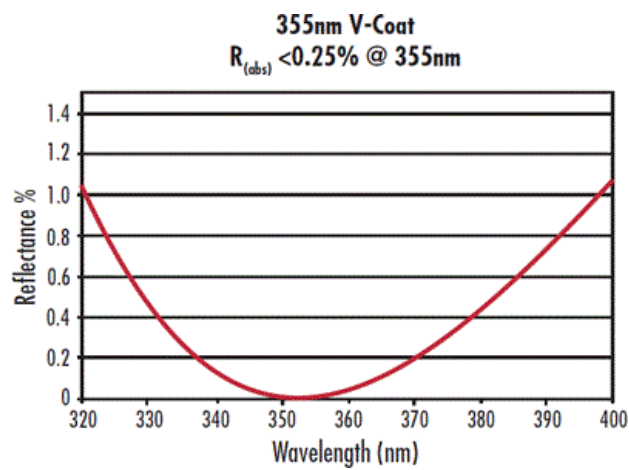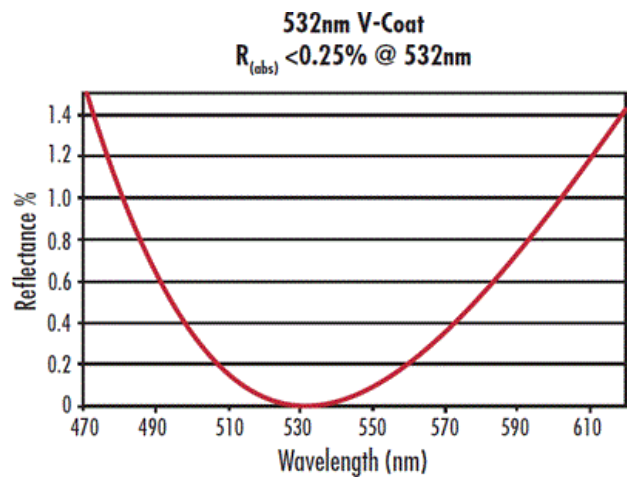

1064nm V-Coat
 $R_{(obs)} < 0.25\%$ @ 1064nm

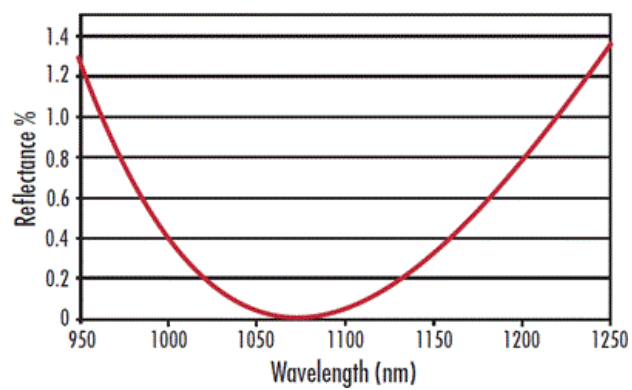

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
6.00	12.00	10.63	Uncoated	Fused Silica	#87-924	€139,00 Qty 6+ €111,00	3-4 days
6.00	12.00	10.63	Laser V-Coat (266nm)	Fused Silica	#87-928	€171,00 Qty 6+ €137,00	3-4 days
6.00	12.00	10.63	Laser V-Coat (355nm)	Fused Silica	#87-932	€171,00 Qty 6+ €137,00	3-4 days
6.00	12.00	10.63	Laser V-Coat (532nm)	Fused Silica	#87-936	€171,00 Qty 6+ €137,00	3-4 days
6.00	12.00	10.63	Laser V-Coat (1064nm)	Fused Silica	#87-940	€171,00 Qty 6+ €137,00	3-4 days
6.00	18.00	16.62	Uncoated	Fused Silica	#87-925	€139,00 Qty 6+ €111,00	3-4 days
6.00	18.00	16.62	Laser V-Coat (266nm)	Fused Silica	#87-929	€171,00 Qty 6+ €137,00	3-4 days
6.00	18.00	16.62	Laser V-Coat (355nm)	Fused Silica	#87-933	€171,00 Qty 6+ €137,00	3-4 days
6.00	18.00	16.62	Laser V-Coat (532nm)	Fused Silica	#87-937	€171,00 Qty 6+ €137,00	3-4 days
6.00	18.00	16.62	Laser V-Coat (1064nm)	Fused Silica	#87-941	€171,00 Qty 6+ €137,00	3-4 days
6.00	24.00	22.63	Uncoated	Fused Silica	#87-926	€139,00 Qty 6+ €111,00	3-4 days
6.00	24.00	22.63	Laser V-Coat (266nm)	Fused Silica	#87-930	€171,00 Qty 6+ €137,00	3-4 days
6.00	24.00	22.63	Laser V-Coat (355nm)	Fused Silica	#87-934	€171,00 Qty 6+ €137,00	3-4 days

6.00	24.00	22.63	Laser V-Coat (532nm)	Fused Silica	#87-938	€171,00 Qty 6+ €137,00	3-4 days
6.00	24.00	22.63	Laser V-Coat (1064nm)	Fused Silica	#87-942	€171,00 Qty 6+ €137,00	3-4 days
12.00	18.00	15.23	Uncoated	Fused Silica	#67-090	€149,00 Qty 6+ €119,00	3-4 days
12.00	18.00	15.23	Laser V-Coat (266nm)	Fused Silica	#67-939	€188,00 Qty 6+ €150,00	3-4 days
12.00	18.00	15.23	Laser V-Coat (355nm)	Fused Silica	#67-949	€188,00 Qty 6+ €150,00	3-4 days
12.00	18.00	15.23	Laser V-Coat (532nm)	Fused Silica	#67-959	€188,00 Qty 6+ €150,00	3-4 days
12.00	18.00	15.23	Laser V-Coat (1064nm)	Fused Silica	#67-969	€188,00 Qty 6+ €150,00	3-4 days
12.00	25.00	22.31	Uncoated	Fused Silica	#67-091	€149,00 Qty 6+ €119,00	3-4 days
12.00	25.00	22.31	Laser V-Coat (266nm)	Fused Silica	#67-940	€188,00 Qty 6+ €150,00	Contact Us
12.00	25.00	22.31	Laser V-Coat (355nm)	Fused Silica	#67-950	€188,00 Qty 6+ €150,00	3-4 days
12.00	25.00	22.31	Laser V-Coat (532nm)	Fused Silica	#67-960	€188,00 Qty 6+ €150,00	Contact Us
12.00	25.00	22.31	Laser V-Coat (1064nm)	Fused Silica	#67-970	€188,00 Qty 6+ €150,00	3-4 days
12.00	36.00	34.29	Uncoated	Fused Silica	#67-092	€149,00 Qty 6+ €119,00	3-4 days
12.00	36.00	34.29	Laser V-Coat (266nm)	Fused Silica	#67-941	€188,00 Qty 6+ €150,00	3-4 days
12.00	36.00	34.29	Laser V-Coat (355nm)	Fused Silica	#67-951	€188,00 Qty 6+ €150,00	3-4 days

12.00	36.00	34.29	Laser V-Coat (532nm)	Fused Silica	#67-961	€188,00 Qty 6+ €150,00	3-4 days
12.00	36.00	34.29	Laser V-Coat (1064nm)	Fused Silica	#67-971	€188,00 Qty 6+ €150,00	3-4 days
12.00	50.00	48.01	Uncoated	Fused Silica	#67-093	€149,00 Qty 6+ €119,00	3-4 days
12.00	50.00	48.01	Laser V-Coat (266nm)	Fused Silica	#67-942	€188,00 Qty 6+ €150,00	3-4 days
12.00	50.00	48.01	Laser V-Coat (355nm)	Fused Silica	#67-952	€188,00 Qty 6+ €150,00	3-4 days
12.00	50.00	48.01	Laser V-Coat (532nm)	Fused Silica	#67-962	€188,00 Qty 6+ €150,00	3-4 days
12.00	50.00	48.01	Laser V-Coat (1064nm)	Fused Silica	#67-972	€188,00 Qty 6+ €150,00	In Stock
12.70	25.00	21.62	Uncoated	Fused Silica	#38-634	€149,00 Qty 6+ €119,00	3-4 days
12.70	25.00	21.62	Laser V-Coat (266nm)	Fused Silica	#38-656	€188,00 Qty 6+ €150,00	Contact Us
12.70	25.00	21.62	Laser V-Coat (355nm)	Fused Silica	#38-681	€188,00 Qty 6+ €150,00	3-4 days
12.70	25.00	21.62	Laser V-Coat (532nm)	Fused Silica	#38-707	€188,00 Qty 6+ €150,00	3-4 days
12.70	25.00	21.62	Laser V-Coat (1064nm)	Fused Silica	#38-733	€188,00 Qty 6+ €150,00	3-4 days
12.70	35.00	32.30	Uncoated	Fused Silica	#38-635	€149,00 Qty 6+ €119,00	3-4 days
12.70	35.00	32.30	Laser V-Coat (266nm)	Fused Silica	#38-658	€188,00 Qty 6+ €150,00	3-4 days
12.70	35.00	32.30	Laser V-Coat (355nm)	Fused Silica	#38-684	€188,00 Qty 6+ €150,00	3-4 days

12.70	35.00	32.30	Laser V-Coat (532nm)	Fused Silica	#38-708	€188,00 Qty 6+ €150,00	3-4 days
12.70	35.00	32.30	Laser V-Coat (1064nm)	Fused Silica	#38-734	€188,00 Qty 6+ €150,00	3-4 days
12.70	50.00	47.30	Uncoated	Fused Silica	#38-636	€149,00 Qty 6+ €119,00	Contact Us
12.70	50.00	47.30	Laser V-Coat (266nm)	Fused Silica	#38-660	€188,00 Qty 6+ €150,00	3-4 days
12.70	50.00	47.30	Laser V-Coat (355nm)	Fused Silica	#38-685	€188,00 Qty 6+ €150,00	Contact Us
12.70	50.00	47.30	Laser V-Coat (532nm)	Fused Silica	#38-709	€188,00 Qty 6+ €150,00	3-4 days
12.70	50.00	47.30	Laser V-Coat (1064nm)	Fused Silica	#38-735	€188,00 Qty 6+ €150,00	In Stock
12.70	75.00	72.31	Uncoated	Fused Silica	#38-637	€149,00 Qty 6+ €119,00	3-4 days
12.70	75.00	72.31	Laser V-Coat (266nm)	Fused Silica	#38-661	€188,00 Qty 6+ €150,00	3-4 days
12.70	75.00	72.31	Laser V-Coat (355nm)	Fused Silica	#38-686	€188,00 Qty 6+ €150,00	3-4 days
12.70	75.00	72.31	Laser V-Coat (532nm)	Fused Silica	#38-711	€188,00 Qty 6+ €150,00	3-4 days
12.70	75.00	72.31	Laser V-Coat (1064nm)	Fused Silica	#38-736	€188,00 Qty 6+ €150,00	In Stock
12.70	100.00	97.32	Uncoated	Fused Silica	#38-638	€149,00 Qty 6+ €119,00	3-4 days
12.70	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-662	€188,00 Qty 6+ €150,00	3-4 days
12.70	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-687	€188,00 Qty 6+ €150,00	Contact Us

12.70	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-712	€188,00 Qty 6+ €150,00	3-4 days
12.70	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-737	€188,00 Qty 6+ €150,00	3-4 days
12.70	150.00	147.33	Uncoated	Fused Silica	#38-639	€149,00 Qty 6+ €119,00	3-4 days
12.70	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-665	€188,00 Qty 6+ €150,00	3-4 days
12.70	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-688	€188,00 Qty 6+ €150,00	3-4 days
12.70	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-715	€188,00 Qty 6+ €150,00	3-4 days
12.70	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-738	€188,00 Qty 6+ €150,00	3-4 days
12.70	200.00	197.35	Uncoated	Fused Silica	#38-640	€149,00 Qty 6+ €119,00	3-4 days
12.70	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-666	€188,00 Qty 6+ €150,00	3-4 days
12.70	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-689	€188,00 Qty 6+ €150,00	3-4 days
12.70	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-716	€188,00 Qty 6+ €150,00	3-4 days
12.70	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-739	€188,00 Qty 6+ €150,00	3-4 days
12.70	250.00	247.36	Uncoated	Fused Silica	#38-641	€149,00 Qty 6+ €119,00	3-4 days
12.70	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-667	€188,00 Qty 6+ €150,00	3-4 days
12.70	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-690	€188,00 Qty 6+ €150,00	3-4 days

12.70	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-717	€188,00 Qty 6+ €150,00	3-4 days
12.70	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-740	€188,00 Qty 6+ €150,00	3-4 days
12.70	300.00	297.38	Uncoated	Fused Silica	#38-643	€149,00 Qty 6+ €119,00	3-4 days
12.70	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-668	€188,00 Qty 6+ €150,00	3-4 days
12.70	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-691	€188,00 Qty 6+ €150,00	3-4 days
12.70	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-718	€188,00 Qty 6+ €150,00	3-4 days
12.70	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-741	€188,00 Qty 6+ €150,00	3-4 days
12.70	500.00	497.44	Uncoated	Fused Silica	#38-644	€149,00 Qty 6+ €119,00	3-4 days
12.70	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-669	€188,00 Qty 6+ €150,00	3-4 days
12.70	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-692	€188,00 Qty 6+ €150,00	3-4 days
12.70	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-719	€188,00 Qty 6+ €150,00	3-4 days
12.70	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-742	€188,00 Qty 6+ €150,00	3-4 days
12.70	1,000.00	997.59	Uncoated	Fused Silica	#38-645	€149,00 Qty 6+ €119,00	3-4 days
12.70	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-670	€188,00 Qty 6+ €150,00	3-4 days
12.70	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-693	€188,00 Qty 6+ €150,00	3-4 days

12.70	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-720	€188,00 Qty 6+ €150,00	3-4 days
12.70	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-743	€188,00 Qty 6+ €150,00	3-4 days
25.00	38.00	33.03	Uncoated	Fused Silica	#67-094	€186,00 Qty 6+ €148,00	Contact Us
25.00	38.00	33.03	Laser V-Coat (266nm)	Fused Silica	#67-943	€209,00 Qty 6+ €167,00	3-4 days
25.00	38.00	33.03	Laser V-Coat (355nm)	Fused Silica	#67-953	€209,00 Qty 6+ €167,00	3-4 days
25.00	38.00	33.03	Laser V-Coat (532nm)	Fused Silica	#67-963	€209,00 Qty 6+ €167,00	3-4 days
25.00	38.00	33.03	Laser V-Coat (1064nm)	Fused Silica	#67-973	€209,00 Qty 6+ €167,00	3-4 days
25.00	50.00	46.00	Uncoated	Fused Silica	#67-095	€186,00 Qty 6+ €148,00	3-4 days
25.00	50.00	46.00	Laser V-Coat (266nm)	Fused Silica	#67-944	€209,00 Qty 6+ €167,00	3-4 days
25.00	50.00	46.00	Laser V-Coat (355nm)	Fused Silica	#67-954	€209,00 Qty 6+ €167,00	3-4 days
25.00	50.00	46.00	Laser V-Coat (532nm)	Fused Silica	#67-964	€209,00 Qty 6+ €167,00	3-4 days
25.00	50.00	46.00	Laser V-Coat (1064nm)	Fused Silica	#67-974	€209,00 Qty 6+ €167,00	3-4 days
25.00	75.00	71.96	Uncoated	Fused Silica	#67-096	€186,00 Qty 6+ €148,00	3-4 days
25.00	75.00	71.96	Laser V-Coat (266nm)	Fused Silica	#67-945	€209,00 Qty 6+ €167,00	Contact Us
25.00	75.00	71.96	Laser V-Coat (355nm)	Fused Silica	#67-955	€209,00 Qty 6+ €167,00	In Stock

25.00	75.00	71.96	Laser V-Coat (532nm)	Fused Silica	#67-965	€209,00 Qty 6+ €167,00	3-4 days
25.00	75.00	71.96	Laser V-Coat (1064nm)	Fused Silica	#67-975	€209,00 Qty 6+ €167,00	3-4 days
25.00	100.00	97.40	Uncoated	Fused Silica	#67-097	€186,00 Qty 6+ €148,00	3-4 days
25.00	100.00	97.4	Laser V-Coat (266nm)	Fused Silica	#67-946	€209,00 Qty 6+ €167,00	3-4 days
25.00	100.00	97.40	Laser V-Coat (355nm)	Fused Silica	#67-956	€209,00 Qty 6+ €167,00	3-4 days
25.00	100.00	97.40	Laser V-Coat (532nm)	Fused Silica	#67-966	€209,00 Qty 6+ €167,00	3-4 days
25.00	100.00	97.40	Laser V-Coat (1064nm)	Fused Silica	#67-976	€209,00 Qty 6+ €167,00	3-4 days
25.00	150.00	147.82	Uncoated	Fused Silica	#67-098	€186,00 Qty 6+ €148,00	3-4 days
25.00	150.00	147.86	Laser V-Coat (266nm)	Fused Silica	#67-947	€209,00 Qty 6+ €167,00	3-4 days
25.00	150.00	147.82	Laser V-Coat (355nm)	Fused Silica	#67-957	€209,00 Qty 6+ €167,00	3-4 days
25.00	150.00	147.82	Laser V-Coat (532nm)	Fused Silica	#67-967	€209,00 Qty 6+ €167,00	3-4 days
25.00	150.00	147.82	Laser V-Coat (1064nm)	Fused Silica	#67-977	€209,00 Qty 6+ €167,00	3-4 days
25.00	250.00	248.14	Uncoated	Fused Silica	#67-099	€186,00 Qty 6+ €148,00	3-4 days
25.00	250.00	248.14	Laser V-Coat (266nm)	Fused Silica	#67-948	€209,00 Qty 6+ €167,00	3-4 days
25.00	250.00	248.14	Laser V-Coat (355nm)	Fused Silica	#67-958	€209,00 Qty 6+ €167,00	3-4 days

25.00	250.00	248.14	Laser V-Coat (532nm)	Fused Silica	#67-968	€209,00 Qty 6+ €167,00	3-4 days
25.00	250.00	248.14	Laser V-Coat (1064nm)	Fused Silica	#67-978	€209,00 Qty 6+ €167,00	In Stock
25.40	35.00	28.55	Uncoated	Fused Silica	#38-624	€186,00 Qty 6+ €148,00	3-4 days
25.40	35.00	28.55	Laser V-Coat (266nm)	Fused Silica	#38-646	€209,00 Qty 6+ €167,00	3-4 days
25.40	35.00	28.55	Laser V-Coat (355nm)	Fused Silica	#38-671	€209,00 Qty 6+ €167,00	3-4 days
25.40	35.00	28.55	Laser V-Coat (532nm)	Fused Silica	#38-694	€209,00 Qty 6+ €167,00	3-4 days
25.40	35.00	28.55	Laser V-Coat (1064nm)	Fused Silica	#38-721	€209,00 Qty 6+ €167,00	3-4 days
25.40	50.00	45.71	Uncoated	Fused Silica	#38-625	€186,00 Qty 6+ €148,00	3-4 days
25.40	50.00	45.71	Laser V-Coat (266nm)	Fused Silica	#38-647	€209,00 Qty 6+ €167,00	3-4 days
25.40	50.00	45.71	Laser V-Coat (355nm)	Fused Silica	#38-672	€209,00 Qty 6+ €167,00	3-4 days
25.40	50.00	45.71	Laser V-Coat (532nm)	Fused Silica	#38-695	€209,00 Qty 6+ €167,00	3-4 days
25.40	50.00	45.71	Laser V-Coat (1064nm)	Fused Silica	#38-722	€209,00 Qty 6+ €167,00	3-4 days
25.40	75.00	71.63	Uncoated	Fused Silica	#38-626	€186,00 Qty 6+ €148,00	3-4 days
25.40	75.00	71.63	Laser V-Coat (266nm)	Fused Silica	#38-648	€209,00 Qty 6+ €167,00	3-4 days
25.40	75.00	71.63	Laser V-Coat (355nm)	Fused Silica	#38-673	€209,00 Qty 6+ €167,00	3-4 days

25.40	75.00	71.63	Laser V-Coat (532nm)	Fused Silica	#38-699	€209,00 Qty 6+ €167,00	3-4 days
25.40	75.00	71.63	Laser V-Coat (1064nm)	Fused Silica	#38-723	€209,00 Qty 6+ €167,00	3-4 days
25.40	100.00	97.32	Uncoated	Fused Silica	#38-627	€186,00 Qty 6+ €148,00	3-4 days
25.40	100.00	97.32	Laser V-Coat (266nm)	Fused Silica	#38-649	€209,00 Qty 6+ €167,00	Contact Us
25.40	100.00	97.32	Laser V-Coat (355nm)	Fused Silica	#38-674	€209,00 Qty 6+ €167,00	3-4 days
25.40	100.00	97.32	Laser V-Coat (532nm)	Fused Silica	#38-700	€209,00 Qty 6+ €167,00	3-4 days
25.40	100.00	97.32	Laser V-Coat (1064nm)	Fused Silica	#38-724	€209,00 Qty 6+ €167,00	3-4 days
25.40	150.00	147.33	Uncoated	Fused Silica	#38-628	€186,00 Qty 6+ €148,00	3-4 days
25.40	150.00	147.33	Laser V-Coat (266nm)	Fused Silica	#38-650	€209,00 Qty 6+ €167,00	3-4 days
25.40	150.00	147.33	Laser V-Coat (355nm)	Fused Silica	#38-675	€209,00 Qty 6+ €167,00	3-4 days
25.40	150.00	147.33	Laser V-Coat (532nm)	Fused Silica	#38-701	€209,00 Qty 6+ €167,00	3-4 days
25.40	150.00	147.33	Laser V-Coat (1064nm)	Fused Silica	#38-725	€209,00 Qty 6+ €167,00	3-4 days
25.40	200.00	197.35	Uncoated	Fused Silica	#38-629	€186,00 Qty 6+ €148,00	3-4 days
25.40	200.00	197.35	Laser V-Coat (266nm)	Fused Silica	#38-651	€209,00 Qty 6+ €167,00	3-4 days
25.40	200.00	197.35	Laser V-Coat (355nm)	Fused Silica	#38-676	€209,00 Qty 6+ €167,00	3-4 days

25.40	200.00	197.35	Laser V-Coat (532nm)	Fused Silica	#38-702	€209,00 Qty 6+ €167,00	3-4 days
25.40	200.00	197.35	Laser V-Coat (1064nm)	Fused Silica	#38-726	€209,00 Qty 6+ €167,00	3-4 days
25.40	250.00	247.36	Uncoated	Fused Silica	#38-630	€186,00 Qty 6+ €148,00	3-4 days
25.40	250.00	247.36	Laser V-Coat (266nm)	Fused Silica	#38-652	€209,00 Qty 6+ €167,00	3-4 days
25.40	250.00	247.36	Laser V-Coat (355nm)	Fused Silica	#38-677	€209,00 Qty 6+ €167,00	In Stock
25.40	250.00	247.36	Laser V-Coat (532nm)	Fused Silica	#38-703	€209,00 Qty 6+ €167,00	3-4 days
25.40	250.00	247.36	Laser V-Coat (1064nm)	Fused Silica	#38-727	€209,00 Qty 6+ €167,00	3-4 days
25.40	300.00	297.38	Uncoated	Fused Silica	#38-631	€186,00 Qty 6+ €148,00	3-4 days
25.40	300.00	297.38	Laser V-Coat (266nm)	Fused Silica	#38-653	€209,00 Qty 6+ €167,00	3-4 days
25.40	300.00	297.38	Laser V-Coat (355nm)	Fused Silica	#38-678	€209,00 Qty 6+ €167,00	3-4 days
25.40	300.00	297.38	Laser V-Coat (532nm)	Fused Silica	#38-704	€209,00 Qty 6+ €167,00	3-4 days
25.40	300.00	297.38	Laser V-Coat (1064nm)	Fused Silica	#38-729	€209,00 Qty 6+ €167,00	3-4 days
25.40	500.00	497.44	Uncoated	Fused Silica	#38-632	€186,00 Qty 6+ €148,00	3-4 days
25.40	500.00	497.44	Laser V-Coat (266nm)	Fused Silica	#38-654	€209,00 Qty 6+ €167,00	3-4 days
25.40	500.00	497.44	Laser V-Coat (355nm)	Fused Silica	#38-679	€209,00 Qty 6+ €167,00	3-4 days

25.40	500.00	497.44	Laser V-Coat (532nm)	Fused Silica	#38-705	€209,00 Qty 6+ €167,00	3-4 days
25.40	500.00	497.44	Laser V-Coat (1064nm)	Fused Silica	#38-731	€209,00 Qty 6+ €167,00	3-4 days
25.40	1,000.00	997.59	Uncoated	Fused Silica	#38-633	€186,00 Qty 6+ €148,00	3-4 days
25.40	1,000.00	997.59	Laser V-Coat (266nm)	Fused Silica	#38-655	€209,00 Qty 6+ €167,00	3-4 days
25.40	1,000.00	997.59	Laser V-Coat (355nm)	Fused Silica	#38-680	€209,00 Qty 6+ €167,00	3-4 days
25.40	1,000.00	997.59	Laser V-Coat (532nm)	Fused Silica	#38-706	€209,00 Qty 6+ €167,00	3-4 days
25.40	1,000.00	997.59	Laser V-Coat (1064nm)	Fused Silica	#38-732	€209,00 Qty 6+ €167,00	3-4 days

[#70-003 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80	100.00	91.773	Uncoated	Fused Silica		€375,00	3-4 days
-------	--------	--------	----------	------------------------------	--	---------	----------

[#70-004 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144 Uncoated

[Fused Silica](#)

€375,00

3-4 days

[#70-005 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515 Uncoated

[Fused Silica](#)

€375,00

3-4 days

[#70-006 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514 Uncoated

[Fused Silica](#)

€375,00

3-4 days

[#70-007 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516 Uncoated

[Fused Silica](#)

€375,00

3-4 days

#70-013 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

50.80 100.00 91.773 Laser V-Coat (266nm)

[Fused Silica](#)

#70-014 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

50.80 150.00 143.144 Laser V-Coat (266nm)

[Fused Silica](#)

[#70-016 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (266nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-017 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat (266nm)

[Fused Silica](#)

€396,00

3-4 days

#70-023 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

50.80 100.00 91.773 Laser V-Coat (355nm)

[Fused Silica](#)

#70-024 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

50.80 150.00 143.144 Laser V-Coat (355nm)

[Fused Silica](#)

[#70-025 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat (355nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-026 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (355nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-027 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat (355nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-033 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat (532nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-034 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat (532nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-035 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 200.00 194.515

Laser V-Coat (532nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-036 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 250.00 244.514

Laser V-Coat (532nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-037 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 300.00 294.516

Laser V-Coat (532nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-043 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 100.00 91.773

Laser V-Coat
(1064nm)

[Fused Silica](#)

€396,00

3-4 days

[#70-044 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.80 150.00 143.144

Laser V-Coat
(1064nm)

[Fused Silica](#)

€396,00

3-4 days

#70-045 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

50.80 200.00 194.515 Laser V-Coat (1064nm)

[Fused Silica](#)

#70-046 New



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

€396,00

3-4 days

Laser V-

[Fused Silica](#)



Edmund
optics | worldwide

Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 : www.edmundoptics.com