

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Notch Filters](#)

TECHSPEC® OD 4.0 Notch Filters



- >OD 4.0 Rejection of Laser Wavelength from 355nm to 1064nm
- Broad Transmission Range
- [OD 6.0 Notch Filters Also Available](#)
- Low Cost Alternative to Rugate Notch Filters

Common Specifications

Thickness (mm):	5.00 ±0.1	Construction:	Mounted in Black Anodized Ring
Physical Durability:	Adhesion per MIL-PRF-13830B, Section C.4.5.12 Moderate abrasion per MIL-PRF-13830B, Section C.4.5.11 Cleaning per MIL-C-48497A Section 4.5.4.2	Substrate Thickness (mm):	3.5 ±0.5
Optical Density OD (Average):	≥4.0	Coating:	Hard Coated
Surface Quality:	60-40	Transmission (%):	90
Reflection at CWL (%):	99	Transmitted Wavefront, RMS:	<1λ


Mount Thickness (mm):

5.0


Environmental Durability:

Humidity per MIL-STD-810H, Section 507.6
Temperature per MIL-STD-810H, Section 501.7
and 502.7

Technical Information

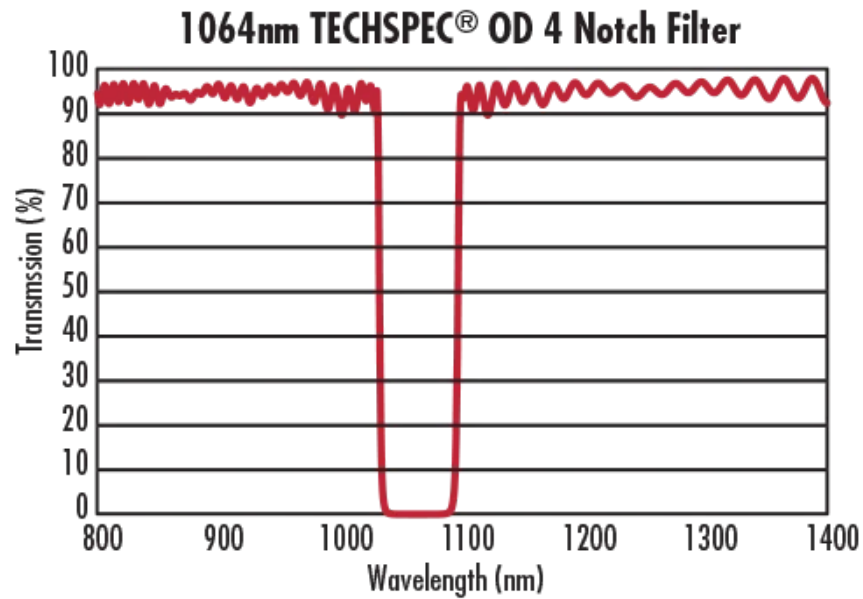

This graph is an example of a standard notch filter transmission curve. For specific wavelength data, please refer to the curve PDF attached to each respective part.

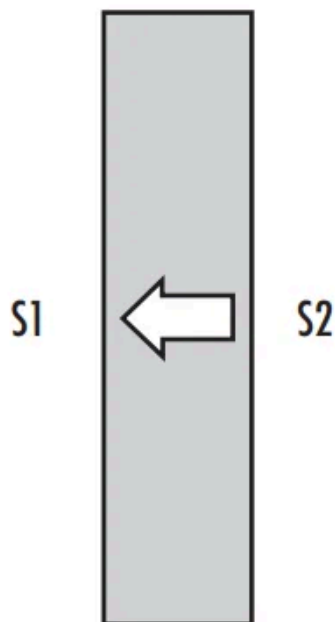

All mounted TECHSPEC® Optical Filters have an arrow on the side of the mount that points to the filter-coated surface for quick reference. Filter oriented such that arrow points to filter coated surface S1. Anti-reflective (AR) coating is

applied to S2.

Products

Dia. (mm)	CWL (nm)	FWHM (nm)	Transmission Wavelength (nm)	Stock Number	Price	Buy
12.50	355.00	17.80	325 - 475	#67-106	€320,00 Volume Pricing	3 In Stock
12.50	405.00	20.20	325 - 540	#67-107	€320,00 Volume Pricing	2 In Stock
12.50	488.00	24.40	365 - 650	#67-108	€320,00 Volume Pricing	4 In Stock
12.50	514.50	25.70	385 - 685	#67-109	€320,00 Volume Pricing	20+ In Stock
12.50	532.00	26.60	400 - 700	#67-110	€320,00 Volume Pricing	4 In Stock
12.50	632.80	31.60	475 - 845	#67-111	€320,00 Volume Pricing	5 In Stock
12.50	785.00	39.20	585 - 1045	#67-112	€320,00 Volume Pricing	20+ In Stock
12.50	808.00	40.00	600 - 1070	#86-700	€320,00 Volume Pricing	3 In Stock
12.50	830.00	42.00	625 - 1100	#86-701	€320,00 Volume Pricing	1 In Stock
12.50	980.00	49.00	735 - 1300	#67-113	€320,00 Volume Pricing	3 In Stock
12.50	1,030.00	51.50	800 - 1400	#39-383	€320,00 Volume Pricing	2 In Stock
12.50	1,064.00	53.20	800 - 1400	#67-114	€320,00 Volume Pricing	5 In Stock
25.00	355.00	17.80	325 - 475	#67-115	€465,00 Volume Pricing	2 In Stock
25.00	405.00	20.20	325 - 540	#67-116	€465,00 Volume Pricing	5 In Stock
25.00	488.00	24.40	365 - 650	#67-117	€465,00 Volume Pricing	5 In Stock
25.00	514.50	25.70	385 - 685	#67-118	€465,00 Volume Pricing	9 In Stock

25.00	532.00	26.60	400 - 700	#67-119	€465,00 Volume Pricing	12 In Stock
25.00	632.80	31.60	475 - 845	#67-120	€465,00 Volume Pricing	4 In Stock
25.00	785.00	39.20	585 - 1045	#67-121	€465,00 Volume Pricing	Contact Us
25.00	808.00	40.00	600 - 1070	#86-702	€465,00 Volume Pricing	10 In Stock
25.00	830.00	42.00	625 - 1100	#86-703	€465,00 Volume Pricing	1 In Stock
25.00	980.00	49.00	735 - 1300	#67-122	€465,00 Volume Pricing	5 In Stock
25.00	1,030.00	51.50	800 - 1400	#39-384	€465,00 Volume Pricing	1 In Stock
25.00	1,064.00	53.20	800 - 1400	#67-123	€465,00 Volume Pricing	20+ In Stock
50.00	355.00	17.80	325 - 475	#67-124	€1.010,00 Volume Pricing	1 In Stock
50.00	405.00	20.20	325 - 540	#67-125	€1.010,00 Volume Pricing	Contact Us
50.00	488.00	24.40	365 - 650	#67-126	€1.010,00 Volume Pricing	Contact Us
50.00	514.50	25.70	385 - 685	#67-127	€1.010,00 Volume Pricing	5 In Stock
50.00	532.00	26.60	400 - 700	#67-128	€1.010,00 Volume Pricing	5 In Stock
50.00	632.80	31.60	475 - 845	#67-129	€1.010,00 Volume Pricing	4 In Stock
50.00	785.00	39.20	585 - 1045	#67-130	€1.010,00 Volume Pricing	4 In Stock
50.00	808.00	40.00	600 - 1070	#86-704	€1.010,00 Volume Pricing	1 In Stock
50.00	980.00	49.00	735 - 1300	#67-131	€1.010,00 Volume Pricing	1 In Stock
50.00	1,030.00	51.50	800 - 1400	#39-385	€1.010,00 Volume Pricing	2 In Stock
50.00	1,064.00	53.20	800 - 1400	#67-132	€1.010,00 Volume Pricing	3 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands

Phone: 1-800-363-1992 :

www.edmundoptics.com