

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

TECHSPEC® NIR II Coated Plano-Convex (PCX) Lenses



- AR Coated to Provide <0.7% Reflectance per Surface for 750 - 1550nm
- Designed for 0° Angle of Incidence
- Various PCX Coating Options: [Uncoated](#), [MgF₂](#), [VIS 0°](#), [VIS-NIR](#), [NIR I](#), [VIS-EXT](#), and [YAG-BBAR](#)

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Optical Properties



Coating:

NIR II (750-1550nm)

Wavelength Range (nm):

750 - 1550

Technical Information

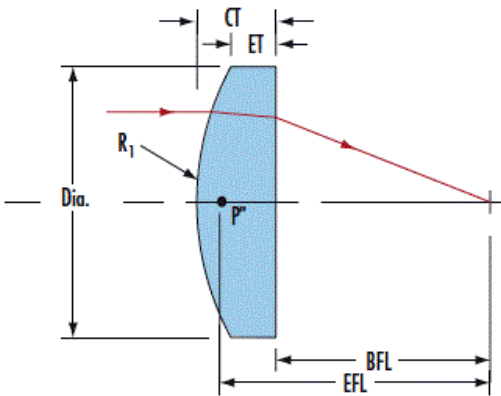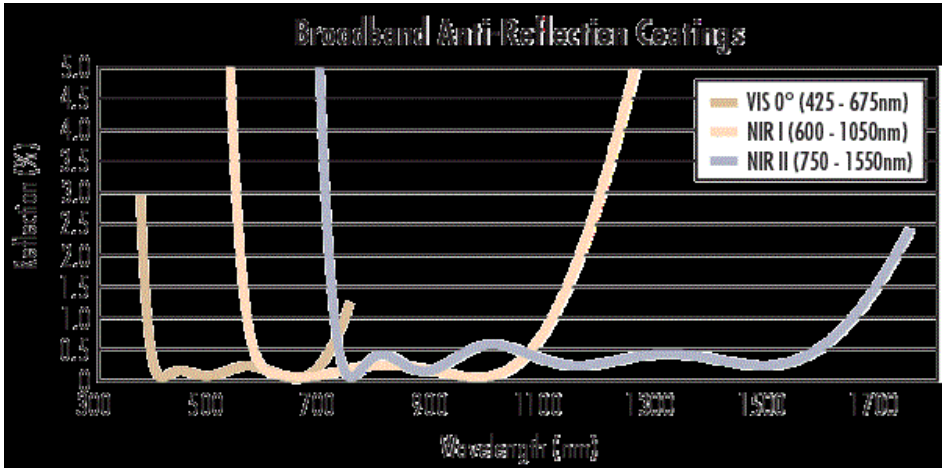

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	€80,00 Qty 10+ €72,00	3-4 days
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	€80,00 Qty 10+ €72,00	3-4 days
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	€80,00 Qty 10+ €72,00	3-4 days
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	€80,00 Qty 10+ €72,00	3-4 days
1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	€80,00 Qty 10+ €72,00	Contact Us
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	€80,00 Qty 10+ €72,00	3-4 days
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	€80,00 Qty 10+ €72,00	3-4 days
2.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-430	€79,00 Qty 10+ €71,00	3-4 days
2.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-431	€79,00 Qty 10+ €71,00	In Stock
2.00	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-432	€79,00 Qty 10+ €71,00	3-4 days
2.00	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-433	€79,00 Qty 10+ €71,00	3-4 days

[#72-256 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

2.00	4.00	3.46	NIR II (750-1550nm)	Fused Silica (Corning 7980)		€104,00	3-4 days
------	------	------	------------------------	--------------------------------	--	---------	----------

[#72-264 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

2.00	6.00	5.45	NIR II (750-1550nm)	Fused Silica (Corning 7980)		€98,50	3-4 days
------	------	------	------------------------	--------------------------------	--	--------	----------

2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	€79,00 Qty 10+ €71,00	In Stock
------	------	------	------------------------	-------------------------	-------------------------	--------------------------	----------

2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	€79,00 Qty 10+ €71,00	3-4 days
------	------	------	------------------------	-------------------------	-------------------------	--------------------------	----------

2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	€79,00 Qty 10+ €71,00	3-4 days
------	------	------	------------------------	-------------------------	-------------------------	--------------------------	----------

2.50	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-437	€79,00 Qty 10+ €71,00	3-4 days
2.50	5.00	4.57	NIR II (750-1550nm)	N-LASF9	#67-438	€79,00 Qty 10+ €71,00	3-4 days
3.00	3.00	1.88	NIR II (750-1550nm)	N-SF11	#67-439	€66,50 Qty 10+ €60,00	3-4 days
3.00	4.50	3.50	NIR II (750-1550nm)	N-LASF44	#67-440	€66,50 Qty 10+ €60,00	3-4 days
3.00	6.00	4.81	NIR II (750-1550nm)	N-BK7	#67-441	€61,50 Qty 10+ €55,50	3-4 days
#72-272 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
3.00	6.00	5.01	NIR II (750-1550nm)	Fused Silica (Corning 7980)		€104,00	3-4 days
3.00	7.50	6.51	NIR II (750-1550nm)	N-BK7	#67-442	€61,50 Qty 10+ €55,50	3-4 days
3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	€61,50 Qty 10+ €55,50	In Stock

[#72-281 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

3.00	9.00	8.11	NIR II (750- 1550nm)	Fused Silica (Corning 7980)		€98,50	3-4 days
------	------	------	----------------------------	--------------------------------------	--	--------	----------

3.00	12.00	11.29	NIR II (750- 1550nm)	N-BK7	#67-444	€61,50 Qty 10+ €55,50	3-4 days
------	-------	-------	----------------------------	-----------------------	-------------------------	--------------------------	----------

3.00	15.00	14.22	NIR II (750- 1550nm)	N-BK7	#67-445	€61,50 Qty 10+ €55,50	Contact Us
------	-------	-------	----------------------------	-----------------------	-------------------------	--------------------------	------------

4.00	4.00	3.06	NIR II (750- 1550nm)	N-LASF44	#67-446	€64,00 Qty 10+ €57,50	3-4 days
------	------	------	----------------------------	--------------------------	-------------------------	--------------------------	----------

4.00	6.00	4.51	NIR II (750- 1550nm)	N-BK7	#67-447	€64,00 Qty 10+ €57,50	3-4 days
------	------	------	----------------------------	-----------------------	-------------------------	--------------------------	----------

4.00	8.00	7.17	NIR II (750- 1550nm)	N-BAF10	#67-448	€60,00 Qty 10+ €54,00	3-4 days
------	------	------	----------------------------	-------------------------	-------------------------	--------------------------	----------

[#72-289 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

4.00	8.00	6.91	NIR II (750-1550nm)	Fused Silica (Corning 7980)		€124,00	3-4 days
------	------	------	------------------------	--------------------------------	--	---------	----------

4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	€60,00 Qty 10+ €54,00	3-4 days
------	-------	------	------------------------	-----------------------	-------------------------	--------------------------	----------

4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	€60,00 Qty 10+ €54,00	Contact Us
------	-------	----	------------------------	-----------------------	-------------------------	--------------------------	------------

[#72-297 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

4.00	12.00	11.04	NIR II (750-1550nm)	Fused Silica (Corning 7980)		€119,00	3-4 days
------	-------	-------	------------------------	--------------------------------	--	---------	----------

4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	€64,00 Qty 10+ €57,50	3-4 days
------	------	------	------------------------	--------------------------	-------------------------	--------------------------	----------

4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	€60,00 Qty 10+ €54,00	3-4 days
5.00	5.00	3.96	NIR II (750-1550nm)	N-LASF44	#67-453	€48,25 Qty 10+ €43,25	In Stock
5.00	7.50	6.43	NIR II (750-1550nm)	N-SF11	#67-454	€47,75 Qty 10+ €43,00	3-4 days
5.00	10.00	8.91	NIR II (750-1550nm)	N-BK7	#67-455	€47,75 Qty 10+ €43,00	3-4 days
5.00	12.00	10.83	NIR II (750-1550nm)	N-BK7	#67-456	€47,75 Qty 10+ €43,00	3-4 days
5.00	15.00	13.94	NIR II (750-1550nm)	N-BK7	#67-457	€47,75 Qty 10+ €43,00	3-4 days
5.00	20.00	19.02	NIR II (750-1550nm)	N-BK7	#67-458	€47,75 Qty 10+ €43,00	3-4 days
5.00	25.00	23.95	NIR II (750-1550nm)	N-BK7	#87-921	€47,75 Qty 10+ €43,00	3-4 days
5.00	30.00	28.95	NIR II (750-1550nm)	N-BK7	#87-922	€47,75 Qty 10+ €43,00	3-4 days
6.00	6.00	4.60	NIR II (750-1550nm)	N-SF11	#67-459	€40,00 Qty 10+ €36,00	3-4 days
6.00	7.50	6.10	NIR II (750-1550nm)	N-SF11	#67-460	€39,50 Qty 10+ €35,50	3-4 days
6.00	9.00	7.95	NIR II (750-1550nm)	N-SF5	#67-461	€39,50 Qty 10+ €35,50	In Stock
6.00	10.00	8.82	NIR II (750-1550nm)	N-BK7	#38-386	€39,50 Qty 10+ €35,50	Contact Us
6.00	12.00	10.94	NIR II (750-1550nm)	N-BK7	#67-462	€38,50 Qty 10+ €34,50	3-4 days

6.00	15.00	13.68	NIR II (750-1550nm)	N-BK7	#67-463	€38,50 Qty 10+ €34,50	3-4 days
6.00	18.00	17.07	NIR II (750-1550nm)	N-BK7	#67-464	€38,50 Qty 10+ €34,50	3-4 days
6.00	20.00	19.04	NIR II (750-1550nm)	N-BK7	#38-387	€38,50 Qty 10+ €34,50	3-4 days
6.00	21.00	20.06	NIR II (750-1550nm)	N-BK7	#67-465	€38,50 Qty 10+ €34,50	3-4 days
6.00	24.00	23.01	NIR II (750-1550nm)	N-BK7	#67-466	€38,50 Qty 10+ €34,50	3-4 days
6.00	25.00	24.04	NIR II (750-1550nm)	N-BK7	#38-388	€38,50 Qty 10+ €34,50	3-4 days
6.00	30.00	29.14	NIR II (750-1550nm)	N-BK7	#67-467	€38,50 Qty 10+ €34,50	Contact Us
6.00	36.00	34.95	NIR II (750-1550nm)	N-BK7	#67-468	€38,50 Qty 10+ €34,50	3-4 days
6.00	48.00	46.95	NIR II (750-1550nm)	N-BK7	#67-469	€38,50 Qty 10+ €34,50	3-4 days
6.00	60.00	58.95	NIR II (750-1550nm)	N-BK7	#67-470	€38,50 Qty 10+ €34,50	3-4 days
6.00	72.00	70.97	NIR II (750-1550nm)	N-BK7	#67-471	€38,50 Qty 10+ €34,50	3-4 days

[#71-296 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 7.00 5.50

NIR II
(750-1550nm)

[N-LASF9](#)

€40,00
Qty 11+ €36,00

3-4 days

[#71-303 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 10.00 8.10

NIR II
(750-1550nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-310 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

7.00 12.00 10.30

NIR II
(750-1550nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-317 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 8.00 6.40

NIR II
(750-1550nm)

[N-LASF9](#)

€40,00
Qty 11+ €36,00

3-4 days

[#71-324 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 10.00 7.60

NIR II
(750-1550nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

[#71-331 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

8.00 12.00 10.00

NIR II
(750-1550nm)

[N-LASF9](#)

€39,50
Qty 11+ €35,50

3-4 days

9.00 9.00 7.32

NIR II
(750-1550nm)

[N-SF11](#)

[#67-472](#)

€40,50
Qty 10+ €36,25

3-4 days

9.00 10.00 8.49

NIR II
(750-1550nm)

[N-SF11](#)

[#38-389](#)

€40,50
Qty 10+ €36,25

3-4 days

9.00 12.00 10.60

NIR II
(750-1550nm)

[N-SF11](#)

[#67-473](#)

€40,50
Qty 10+ €36,25

Contact Us

9.00	13.50	11.94	NIR II (750-1550nm)	N-SF5	#67-474	€40,50 Qty 10+ €36,25	Contact Us
9.00	15.00	13.02	NIR II (750-1550nm)	N-BK7	#67-475	€40,50 Qty 10+ €36,25	In Stock
9.00	18.00	16.41	NIR II (750-1550nm)	N-BK7	#67-476	€39,50 Qty 10+ €35,50	3-4 days
9.00	20.00	18.55	NIR II (750-1550nm)	N-BK7	#38-390	€39,50 Qty 10+ €35,50	3-4 days
9.00	22.00	20.73	NIR II (750-1550nm)	N-BK7	#67-477	€39,50 Qty 10+ €35,50	3-4 days
9.00	25.00	23.68	NIR II (750-1550nm)	N-BK7	#38-391	€39,50 Qty 10+ €35,50	3-4 days
9.00	27.00	25.34	NIR II (750-1550nm)	N-BK7	#67-478	€39,50 Qty 10+ €35,50	In Stock
9.00	36.00	34.48	NIR II (750-1550nm)	N-BK7	#67-479	€39,50 Qty 10+ €35,50	3-4 days
9.00	45.00	43.98	NIR II (750-1550nm)	N-BK7	#67-480	€39,50 Qty 10+ €35,50	3-4 days
9.00	54.00	52.69	NIR II (750-1550nm)	N-BK7	#67-481	€39,50 Qty 10+ €35,50	3-4 days
9.00	72.00	70.68	NIR II (750-1550nm)	N-BK7	#67-482	€39,50 Qty 10+ €35,50	3-4 days
9.00	90.00	88.68	NIR II (750-1550nm)	N-BK7	#67-483	€39,50 Qty 10+ €35,50	3-4 days
10.00	10.00	8.18	NIR II (750-1550nm)	N-SF11	#67-484	€40,50 Qty 10+ €36,25	In Stock
10.00	12.50	10.99	NIR II (750-1550nm)	N-SF11	#38-392	€40,50 Qty 10+ €36,25	3-4 days

10.00	15.00	13.32	NIR II (750-1550nm)	N-SF11	#67-485	€40,50 Qty 10+ €36,25	In Stock
10.00	17.50	15.66	NIR II (750-1550nm)	N-BK7	#38-393	€39,50 Qty 10+ €35,50	3-4 days
10.00	20.00	18.03	NIR II (750-1550nm)	N-BK7	#67-486	€39,50 Qty 10+ €35,50	3-4 days
10.00	25.00	23.02	NIR II (750-1550nm)	N-BK7	#67-487	€39,50 Qty 10+ €35,50	3-4 days
10.00	30.00	28.01	NIR II (750-1550nm)	N-BK7	#67-488	€39,50 Qty 10+ €35,50	3-4 days
10.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-489	€39,50 Qty 10+ €35,50	3-4 days
10.00	50.00	48.02	NIR II (750-1550nm)	N-BK7	#67-490	€39,50 Qty 10+ €35,50	Contact Us
10.00	75.00	73.02	NIR II (750-1550nm)	N-BK7	#67-491	€39,50 Qty 10+ €35,50	Contact Us
10.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-492	€39,50 Qty 10+ €35,50	In Stock
12.00	12.00	9.76	NIR II (750-1550nm)	N-SF11	#67-493	€44,00 Qty 10+ €39,50	3-4 days
12.00	15.00	12.03	NIR II (750-1550nm)	N-BK7	#67-494	€44,00 Qty 10+ €39,50	3-4 days
12.00	18.00	16.22	NIR II (750-1550nm)	N-SF5	#67-495	€44,00 Qty 10+ €39,50	In Stock
12.00	20.00	17.69	NIR II (750-1550nm)	N-BK7	#67-496	€44,00 Qty 10+ €39,50	3-4 days
12.00	24.00	22.15	NIR II (750-1550nm)	N-BK7	#67-497	€43,00 Qty 10+ €38,50	3-4 days

12.00	25.00	23.22	NIR II (750-1550nm)	N-BK7	#38-394	€43,00 Qty 10+ €38,50	3-4 days
12.00	30.00	28.02	NIR II (750-1550nm)	N-BK7	#67-498	€43,00 Qty 10+ €38,50	In Stock
12.00	36.00	34.02	NIR II (750-1550nm)	N-BK7	#33-357	€43,00 Qty 10+ €38,50	3-4 days
12.00	42.00	40.22	NIR II (750-1550nm)	N-BK7	#67-500	€43,00 Qty 10+ €38,50	Contact Us
12.00	48.00	46.36	NIR II (750-1550nm)	N-BK7	#67-501	€43,00 Qty 10+ €38,50	3-4 days
12.00	50.00	48.75	NIR II (750-1550nm)	N-BK7	#38-395	€43,00 Qty 10+ €38,50	3-4 days
12.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-502	€43,00 Qty 10+ €38,50	In Stock
12.00	60.00	58.37	NIR II (750-1550nm)	N-BK7	#67-503	€43,00 Qty 10+ €38,50	3-4 days
12.00	72.00	70.42	NIR II (750-1550nm)	N-BK7	#67-504	€43,00 Qty 10+ €38,50	3-4 days
12.00	84.00	82.39	NIR II (750-1550nm)	N-BK7	#67-505	€43,00 Qty 10+ €38,50	In Stock
12.00	100.00	98.35	NIR II (750-1550nm)	N-BK7	#67-506	€43,00 Qty 10+ €38,50	In Stock
12.50	12.50	10.40	NIR II (750-1550nm)	N-SF11	#38-397	€43,00 Qty 10+ €38,50	3-4 days
12.50	15.00	13.26	NIR II (750-1550nm)	N-SF11	#38-398	€43,00 Qty 10+ €38,50	3-4 days
12.50	17.50	15.00	NIR II (750-1550nm)	N-BK7	#38-399	€43,00 Qty 10+ €38,50	3-4 days

12.50	20.00	17.69	NIR II (750-1550nm)	N-BK7	#38-400	€43,00 Qty 10+ €38,50	3-4 days
12.50	25.00	22.96	NIR II (750-1550nm)	N-BK7	#38-401	€42,00 Qty 10+ €37,75	3-4 days
12.50	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-402	€42,00 Qty 10+ €37,75	Contact Us
12.50	35.00	33.42	NIR II (750-1550nm)	N-BK7	#38-403	€42,00 Qty 10+ €37,75	3-4 days
12.50	40.00	38.55	NIR II (750-1550nm)	N-BK7	#38-404	€42,00 Qty 10+ €37,75	3-4 days
12.50	45.00	43.68	NIR II (750-1550nm)	N-BK7	#38-405	€42,00 Qty 10+ €37,75	3-4 days
12.50	50.00	48.68	NIR II (750-1550nm)	N-BK7	#38-406	€42,00 Qty 10+ €37,75	In Stock
12.50	75.00	73.88	NIR II (750-1550nm)	N-BK7	#38-407	€42,00 Qty 10+ €37,75	In Stock
12.50	100.00	98.95	NIR II (750-1550nm)	N-BK7	#38-408	€42,00 Qty 10+ €37,75	3-4 days
12.70	12.70	10.46	NIR II (750-1550nm)	N-SF11	#67-507	€43,00 Qty 10+ €38,50	3-4 days
12.70	15.00	11.53	NIR II (750-1550nm)	N-BK7	#67-508	€43,00 Qty 10+ €38,50	3-4 days
12.70	19.10	16.46	NIR II (750-1550nm)	N-BK7	#67-509	€43,00 Qty 10+ €38,50	3-4 days
12.70	20.00	17.49	NIR II (750-1550nm)	N-BK7	#38-409	€43,00 Qty 10+ €38,50	3-4 days
12.70	25.40	23.43	NIR II (750-1550nm)	N-BK7	#67-510	€42,00 Qty 10+ €37,75	3-4 days

12.70	30.00	28.22	NIR II (750-1550nm)	N-BK7	#38-410	€42,00 Qty 10+ €37,75	3-4 days
12.70	31.80	29.81	NIR II (750-1550nm)	N-BK7	#67-511	€42,00 Qty 10+ €37,75	Contact Us
12.70	38.10	36.12	NIR II (750-1550nm)	N-BK7	#67-512	€42,00 Qty 10+ €37,75	3-4 days
12.70	40.00	38.48	NIR II (750-1550nm)	N-BK7	#38-411	€42,00 Qty 10+ €37,75	3-4 days
12.70	44.50	42.69	NIR II (750-1550nm)	N-BK7	#67-513	€42,00 Qty 10+ €37,75	3-4 days
12.70	50.80	49.15	NIR II (750-1550nm)	N-BK7	#67-514	€42,00 Qty 10+ €37,75	3-4 days
12.70	100.00	98.88	NIR II (750-1550nm)	N-BK7	#38-412	€42,00 Qty 10+ €37,75	Contact Us
15.00	15.00	11.71	NIR II (750-1550nm)	N-SF5	#67-515	€44,00 Qty 10+ €39,50	In Stock
15.00	18.00	15.61	NIR II (750-1550nm)	N-SF5	#67-516	€44,00 Qty 10+ €39,50	Contact Us
15.00	20.00	17.74	NIR II (750-1550nm)	N-SF5	#67-517	€44,00 Qty 10+ €39,50	In Stock
15.00	22.50	20.50	NIR II (750-1550nm)	N-SF5	#67-518	€44,00 Qty 10+ €39,50	In Stock
15.00	25.00	22.50	NIR II (750-1550nm)	N-BK7	#38-413	€43,00 Qty 10+ €38,50	3-4 days
15.00	30.00	27.90	NIR II (750-1550nm)	N-BK7	#67-519	€43,00 Qty 10+ €38,50	Contact Us
15.00	40.00	38.02	NIR II (750-1550nm)	N-BK7	#67-520	€43,00 Qty 10+ €38,50	3-4 days

15.00	45.00	43.35	NIR II (750-1550nm)	N-BK7	#67-521	€43,00 Qty 10+ €38,50	3-4 days
15.00	50.00	48.35	NIR II (750-1550nm)	N-BK7	#38-414	€43,00 Qty 10+ €38,50	Contact Us
15.00	60.00	58.65	NIR II (750-1550nm)	N-BK7	#67-522	€43,00 Qty 10+ €38,50	3-4 days
15.00	75.00	73.79	NIR II (750-1550nm)	N-BK7	#67-523	€43,00 Qty 10+ €38,50	3-4 days
15.00	100.00	98.02	NIR II (750-1550nm)	N-BK7	#67-524	€43,00 Qty 10+ €38,50	3-4 days
15.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#14-378	€43,00 Qty 10+ €38,50	Contact Us
15.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#14-386	€43,00 Qty 10+ €38,50	Contact Us
18.00	18.00	15.20	NIR II (750-1550nm)	N-SF11	#67-525	€44,50 Qty 10+ €40,00	3-4 days
18.00	20.00	17.59	NIR II (750-1550nm)	N-SF11	#38-415	€44,00 Qty 10+ €39,50	3-4 days
18.00	22.50	20.26	NIR II (750-1550nm)	N-SF11	#67-526	€44,00 Qty 10+ €39,50	3-4 days
18.00	25.00	21.51	NIR II (750-1550nm)	N-BK7	#38-416	€44,00 Qty 10+ €39,50	Contact Us
18.00	27.00	24.73	NIR II (750-1550nm)	N-SF5	#67-527	€44,00 Qty 10+ €39,50	3-4 days
18.00	30.00	27.10	NIR II (750-1550nm)	N-BK7	#38-419	€42,50 Qty 10+ €38,25	3-4 days
18.00	36.00	33.65	NIR II (750-1550nm)	N-BK7	#67-528	€42,50 Qty 10+ €38,25	In Stock

18.00	50.00	48.09	NIR II (750-1550nm)	N-BK7	#38-420	€42,50 Qty 10+ €38,25	3-4 days
18.00	54.00	52.02	NIR II (750-1550nm)	N-BK7	#67-529	€42,50 Qty 10+ €38,25	In Stock
18.00	72.00	70.05	NIR II (750-1550nm)	N-BK7	#67-530	€42,50 Qty 10+ €38,25	In Stock
20.00	20.00	17.42	NIR II (750-1550nm)	N-SF11	#67-531	€45,00 Qty 10+ €40,50	In Stock
20.00	25.00	22.76	NIR II (750-1550nm)	N-SF11	#67-532	€44,50 Qty 10+ €40,00	3-4 days
20.00	30.00	27.30	NIR II (750-1550nm)	N-BAF10	#67-533	€44,50 Qty 10+ €40,00	3-4 days
20.00	35.00	32.04	NIR II (750-1550nm)	N-BK7	#67-534	€44,50 Qty 10+ €40,00	Contact Us
20.00	40.00	36.77	NIR II (750-1550nm)	N-BK7	#67-535	€43,00 Qty 10+ €38,50	In Stock
20.00	50.00	47.87	NIR II (750-1550nm)	N-BK7	#67-536	€43,00 Qty 10+ €38,50	3-4 days
20.00	60.00	57.03	NIR II (750-1550nm)	N-BK7	#67-537	€43,00 Qty 10+ €38,50	3-4 days
20.00	70.00	68.03	NIR II (750-1550nm)	N-BK7	#67-538	€43,00 Qty 10+ €38,50	Contact Us
20.00	80.00	78.45	NIR II (750-1550nm)	N-BK7	#67-539	€43,00 Qty 10+ €38,50	Contact Us
20.00	100.00	97.13	NIR II (750-1550nm)	N-BK7	#67-540	€43,00 Qty 10+ €38,50	In Stock
20.00	150.00	148.02	NIR II (750-1550nm)	N-BK7	#67-541	€43,00 Qty 10+ €38,50	Contact Us

25.00	25.00	20.22	NIR II (750-1550nm)	N-SF5	#67-542	€45,00 Qty 10+ €40,50	3-4 days
25.00	30.00	24.69	NIR II (750-1550nm)	N-BK7	#67-543	€45,00 Qty 10+ €40,50	In Stock
25.00	35.00	30.42	NIR II (750-1550nm)	N-BK7	#67-544	€45,00 Qty 10+ €40,50	In Stock
25.00	40.00	36.31	NIR II (750-1550nm)	N-BK7	#67-545	€45,00 Qty 10+ €40,50	3-4 days
25.00	50.00	46.75	NIR II (750-1550nm)	N-BK7	#67-546	€43,00 Qty 10+ €38,50	In Stock
25.00	60.00	56.90	NIR II (750-1550nm)	N-BK7	#67-547	€43,00 Qty 10+ €38,50	3-4 days
25.00	75.00	72.00	NIR II (750-1550nm)	N-BK7	#67-548	€43,00 Qty 10+ €38,50	3-4 days
25.00	85.00	82.17	NIR II (750-1550nm)	N-BK7	#67-549	€43,00 Qty 10+ €38,50	3-4 days
25.00	100.00	97.17	NIR II (750-1550nm)	N-BK7	#67-550	€43,00 Qty 10+ €38,50	In Stock
25.00	125.00	122.70	NIR II (750-1550nm)	N-BK7	#67-551	€43,00 Qty 10+ €38,50	3-4 days
25.00	150.00	147.81	NIR II (750-1550nm)	N-BK7	#67-552	€43,00 Qty 10+ €38,50	3-4 days
25.00	175.00	172.85	NIR II (750-1550nm)	N-BK7	#67-553	€43,00 Qty 10+ €38,50	3-4 days
25.00	200.00	197.89	NIR II (750-1550nm)	N-BK7	#33-363	€43,00 Qty 10+ €38,50	3-4 days
25.00	250.00	248.02	NIR II (750-1550nm)	N-BK7	#67-555	€43,00 Qty 10+ €38,50	3-4 days

25.00	300.00	298.02	NIR II (750-1550nm)	N-BK7	#67-556	€43,00 Qty 10+ €38,50	3-4 days
25.00	400.00	397.89	NIR II (750-1550nm)	N-BK7	#33-369	€43,00 Qty 10+ €38,50	3-4 days
25.00	500.00	497.89	NIR II (750-1550nm)	N-BK7	#67-558	€43,00 Qty 10+ €38,50	3-4 days
25.00	750.00	747.89	NIR II (750-1550nm)	N-BK7	#67-559	€43,00 Qty 10+ €38,50	In Stock
25.40	25.40	21.48	NIR II (750-1550nm)	N-SF11	#67-560	€45,00 Qty 10+ €40,50	Contact Us
25.40	35.00	30.46	NIR II (750-1550nm)	N-BK7	#38-421	€45,00 Qty 10+ €40,50	3-4 days
25.40	38.10	33.48	NIR II (750-1550nm)	N-BK7	#67-561	€45,00 Qty 10+ €40,50	Contact Us
25.40	40.00	36.11	NIR II (750-1550nm)	N-BK7	#38-422	€45,00 Qty 10+ €40,50	3-4 days
25.40	50.80	47.5	NIR II (750-1550nm)	N-BK7	#67-562	€43,00 Qty 10+ €38,50	3-4 days
25.40	63.50	60.37	NIR II (750-1550nm)	N-BK7	#67-563	€43,00 Qty 10+ €38,50	3-4 days
25.40	75.00	72.69	NIR II (750-1550nm)	N-BK7	#38-424	€43,00 Qty 10+ €38,50	In Stock
25.40	76.20	73.56	NIR II (750-1550nm)	N-BK7	#67-564	€43,00 Qty 10+ €38,50	3-4 days
25.40	88.90	86.26	NIR II (750-1550nm)	N-BK7	#67-565	€43,00 Qty 10+ €38,50	3-4 days
25.40	100.00	98.02	NIR II (750-1550nm)	N-BK7	#38-425	€43,00 Qty 10+ €38,50	3-4 days

25.40	101.60	98.97	NIR II (750-1550nm)	N-BK7	#67-566	€43,00 Qty 10+ €38,50	3-4 days
25.40	125.00	123.02	NIR II (750-1550nm)	N-BK7	#38-431	€43,00 Qty 10+ €38,50	3-4 days
25.40	150.00	148.02	NIR II (750-1550nm)	N-BK7	#38-432	€43,00 Qty 10+ €38,50	3-4 days
30.00	30.00	26.13	NIR II (750-1550nm)	N-SF11	#67-567	€55,50 Qty 10+ €50,00	3-4 days
30.00	40.00	37.20	NIR II (750-1550nm)	N-SF11	#67-568	€53,50 Qty 10+ €48,00	3-4 days
30.00	50.00	46.17	NIR II (750-1550nm)	N-SF5	#67-569	€53,50 Qty 10+ €48,00	Contact Us
30.00	60.00	56.03	NIR II (750-1550nm)	N-BK7	#67-570	€52,00 Qty 10+ €46,75	3-4 days
30.00	75.00	70.95	NIR II (750-1550nm)	N-BK7	#67-571	€52,00 Qty 10+ €46,75	3-4 days
30.00	100.00	96.01	NIR II (750-1550nm)	N-BK7	#67-572	€52,00 Qty 10+ €46,75	In Stock
30.00	120.00	116.04	NIR II (750-1550nm)	N-BK7	#67-573	€52,00 Qty 10+ €46,75	3-4 days
35.00	35.00	30.52	NIR II (750-1550nm)	N-SF11	#38-433	€57,00 Qty 10+ €51,50	3-4 days
35.00	50.00	44.40	NIR II (750-1550nm)	N-BK7	#38-434	€55,50 Qty 10+ €50,00	Contact Us
35.00	70.00	66.04	NIR II (750-1550nm)	N-BK7	#38-435	€55,50 Qty 10+ €50,00	3-4 days
35.00	100.00	97.03	NIR II (750-1550nm)	N-BK7	#38-436	€55,50 Qty 10+ €50,00	3-4 days

40.00	40.00	35.13	NIR II (750-1550nm)	N-SF11	#67-574	€62,00 Qty 10+ €56,00	3-4 days
40.00	60.00	53.9	NIR II (750-1550nm)	N-BK7	#67-575	€62,00 Qty 10+ €56,00	3-4 days
40.00	80.00	74.73	NIR II (750-1550nm)	N-BK7	#33-387	€61,00 Qty 10+ €55,00	3-4 days
40.00	100.00	95.39	NIR II (750-1550nm)	N-BK7	#33-375	€61,00 Qty 10+ €55,00	3-4 days
40.00	200.00	196.7	NIR II (750-1550nm)	N-BK7	#33-381	€61,00 Qty 10+ €55,00	3-4 days
40.00	300.00	296.7	NIR II (750-1550nm)	N-BK7	#67-579	€61,00 Qty 10+ €55,00	3-4 days
40.00	400.00	396.7	NIR II (750-1550nm)	N-BK7	#67-580	€61,00 Qty 10+ €55,00	3-4 days
50.00	50.00	43.28	NIR II (750-1550nm)	N-SF11	#67-581	€67,00 Qty 10+ €60,50	Contact Us
50.00	75.00	67.75	NIR II (750-1550nm)	N-BK7	#67-582	€65,00 Qty 10+ €58,50	In Stock
50.00	100.00	93.41	NIR II (750-1550nm)	N-BK7	#67-583	€62,50 Qty 10+ €56,50	Contact Us
50.00	125.00	117.479	NIR II (750-1550nm)	N-BK7	#67-584	€62,50 Qty 10+ €56,50	In Stock
50.00	150.00	144.07	NIR II (750-1550nm)	N-BK7	#67-585	€62,50 Qty 10+ €56,50	3-4 days
50.00	175.00	169.05	NIR II (750-1550nm)	N-BK7	#67-586	€62,50 Qty 10+ €56,50	3-4 days
50.00	200.00	196.66	NIR II (750-1550nm)	N-BK7	#67-587	€62,50 Qty 10+ €56,50	Contact Us

50.00	250.00	246.74	NIR II (750-1550nm)	N-BK7	#67-588	€62,50 Qty 10+ €56,50	In Stock
50.00	500.00	496.70	NIR II (750-1550nm)	N-BK7	#67-589	€62,50 Qty 10+ €56,50	3-4 days
#71-338 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
50.80	50.81	44.08	NIR II (750-1550nm)	N-LASF9		€67,00 Qty 11+ €60,50	3-4 days
#71-345 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
50.80	76.20	68.95	NIR II (750-1550nm)	N-LASF9		€65,00 Qty 11+ €58,50	3-4 days
75.00	75.00	53.49	NIR II (750-1550nm)	N-BK7	#86-921	€130,00 Qty 10+ €117,00	3-4 days

[#71-858 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 100.00 87.57

NIR II
(750-1550nm)

[N-BK7](#)

€128,00

3-4 days

[#72-305 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 100.00 85.61

NIR II
(750-1550nm)

Fused
Silica
(Corning
7980)

€655,00

Contact Us

[#72-313 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 125.00 112.66

NIR II
(750-1550nm)

Fused Silica
(Corning 7980)

€635,00

3-4 days

[#71-859 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 125.00 115.99

NIR II
(750-1550nm)

[N-BK7](#)

€128,00

3-4 days

75.00 150.00 142.45

NIR II
(750-1550nm)

[N-BK7](#)

[#86-922](#)

€128,00
Qty 10+ €115,00

3-4 days

[#72-321 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 150.00 136.31

NIR II
(750-1550nm)

Fused Silica
(Corning 7980)

€615,00

3-4 days

[#71-860 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 175.00 168.68

NIR II
(750-1550nm)

[N-BK7](#)

€128,00

3-4 days

75.00 200.00 194.24

NIR II
(750-1550nm)

[N-BK7](#)

[#86-923](#)

€128,00
Qty 10+ €115,00

3-4 days

[#72-329 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 200.00 187.18

NIR II
(750-
1550nm)

Fused
Silica
(Corning
7980)

€595,00

3-4 days

75.00 250.00 244.73

NIR II
(750-
1550nm)

[N-BK7](#)

[#86-924](#)

€128,00
Qty 10+ €115,00

3-4 days

[#71-861 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00 300.00 294.4

NIR II
(750-
1550nm)

[N-BK7](#)

€128,00

3-4 days

[#71-862 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 400.00 394.4

NIR II
(750-1550nm)

[N-BK7](#)

€128,00

3-4 days

75.00 500.00 494.73

NIR II
(750-1550nm)

[N-BK7](#)

[#86-925](#)

€128,00
Qty 10+ €115,00

3-4 days

[#71-863 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00 750.00 745.35

NIR II
(750-1550nm)

[N-BK7](#)

€128,00

Contact Us



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com