

[All Products](#) / [Optics](#) / [Optical Filters](#) / [Longpass Filters](#)

Infrared (IR) Longpass Filters



- Coated on Silicon or Germanium Substrates
- Ideal for Isolating Broad Spectral Regions
- Durable, First-Surface Coatings
- **Due to material supply chain disruptions with germanium, there may be increased lead times and price changes on our germanium products. For more information, please contact our customer service team.**

Common Specifications

General

Note: Transmission at cut-on wavelength is 5% of peak transmission.

Physical & Mechanical Properties

Thickness (mm): 1.00 ±0.2

Parallelism (arcmin): <10

Clear Aperture (%): 90

Optical Properties

Optical Density OD (Average): ≥3.0

Coating: Traditional Coated

Surface Quality: 80-50


Transmission (%): >85

Surface Flatness (P-V): 3 - 5λ

Environmental & Durability Factors

Operating Temperature (°C): -62 to +71

Technical Information

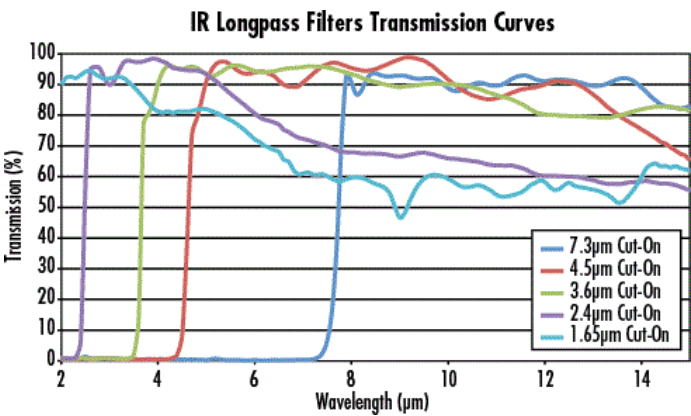

Products

Dia. (mm)	Cut-On Wavelength (nm)	Blocking Wavelength Range (nm)	Thickness (mm)	Transmission Wavelength (nm)	Stock Number	Price	Buy
12.50	1,050.00	200 - 1050	1.00	1100 - 2100	#33-967	€151,41 Volume Pricing	4 In Stock
25.00	1,050.00	200 - 1050	1.00	1100 - 2100	#68-651	€320,33 Volume Pricing	4 In Stock
50.00	1,050.00	200 - 1050	1.00	1100 - 2100	#68-657	€465,56 Volume Pricing	3 In Stock
12.50	1,650.00	200 - 1650	1.00	1730 - 3300	#33-968	€169,95 Volume Pricing	6 In Stock
25.00	1,650.00	200 - 1650	1.00	1730 - 3300	#68-652	€345,05 Volume Pricing	6 In Stock
50.00	1,650.00	200 - 1650	1.00	1730 - 3300	#68-658	€502,64 Volume Pricing	3 In Stock
12.50	2,400.00	200 - 2400	1.00	2520 - 4800	#33-969	€182,31 Volume Pricing	1 In Stock
25.00	2,400.00	200 - 2400	1.00	2520 - 4800	#68-653	€357,41 Volume Pricing	10 In Stock
50.00	2,400.00	200 - 2400	1.00	2520 - 4800	#68-659	€540,75 Volume Pricing	2 In Stock
12.50	3,600.00	200 - 3600	1.00	3780 - 7200	#33-970	€432,60	2 In Stock
50.00	3,600.00	200 - 3600	1.00	3780 - 7200	#68-660	€1.333,85	Contact Us
12.50	4,500.00	200 - 4500	1.00	4730 - 9000	#33-971	€432,60	5 In Stock
50.00	4,500.00	200 - 4500	1.00	4730 - 9000	#68-661	€1.333,85	1 In Stock
12.50	6,000.00	200 - 6000	1.00	6300 - 12000	#36-150	€432,60	4 In Stock

[#36-151 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.00	6,000.00	200 - 6000	1.00	6300 - 12000		€757,05	Contact Us
-------	----------	------------	------	--------------	--	---------	------------

50.00	6,000.00	200 - 6000	1.00	6300 - 12000	#36-152	€1.333,85	2 In Stock
-------	----------	------------	------	--------------	-------------------------	-----------	------------

12.50	7,300.00	200 - 7300	1.00	7670 - 14600	#33-972	€432,60	2 In Stock
-------	----------	------------	------	--------------	-------------------------	---------	------------

[#68-656 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.00	7,300.00	200 - 7300	1.00	7670 - 14600		€757,05	1 In Stock
-------	----------	------------	------	--------------	--	---------	------------



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands

50.00	7,300.00	200 - 7300	1.00	7670 - 14600	#68-662	€1.333,85	1 In Stock
-------	----------	------------	------	--------------	-------------------------	-----------	------------

[www.edmundoptics.com](#)