


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [Visible Windows](#)

TECHSPEC® Gorilla® Glass Windows

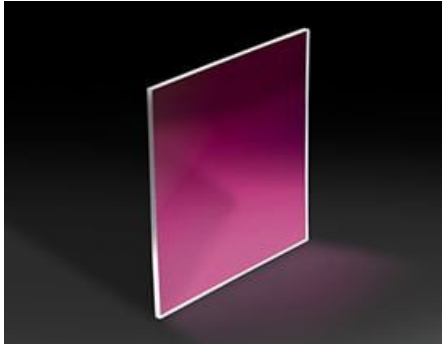


- Chemically Strengthened Drawn Glass
- Highly Resistance to Surface Scratches
- Ideal for Electronic Displays

Common Specifications

Chemical Strengthening Cycle (hours):	8	Type of Window:	Glass
Bevel:	Protective as needed	Clear Aperture (%):	90.00
Poisson's Ratio:	0.22	Young's Modulus (GPa):	70
Substrate:	Gorilla® Glass	Index of Refraction (n_d):	1.5
Surface Quality:	80-50		
Density (g/cm³):			2.39
Coefficient of Thermal Expansion CTE (10⁻⁶/°C):			7.58 (0 to +300°C)

Technical Information

Gorilla® Glass 3 Typical Transmission

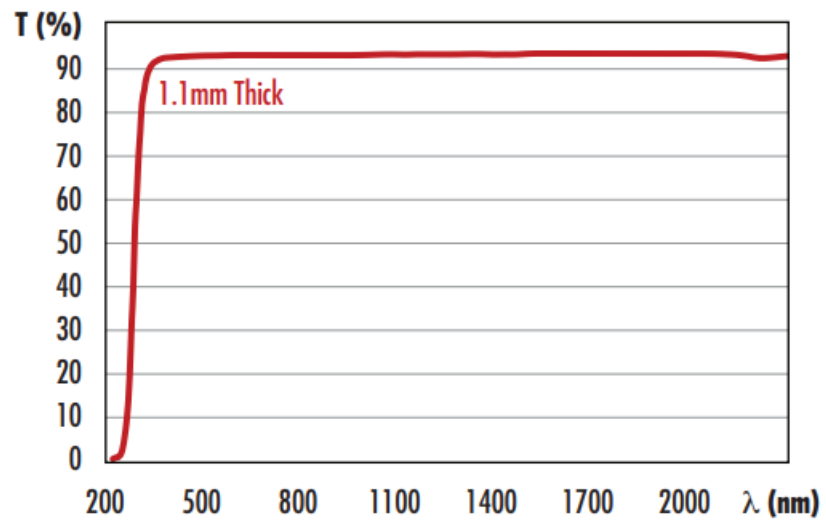

Products

Dia. (mm)	Dimensions (mm)	Thickness (mm)	Coating	Stock Number	Price	Buy
5.00	-	1.10	Uncoated	#83-359	€33,50 Volume Pricing	20+ In Stock
5.00	-	1.10	MgF ₂ (400-700nm)	#22-848	€54,00 Volume Pricing	6 In Stock
10.00	-	1.10	Uncoated	#83-360	€33,50 Volume Pricing	20+ In Stock
10.00	-	1.10	MgF ₂ (400-700nm)	#22-849	€54,00 Volume Pricing	8 In Stock
12.50	-	1.10	Uncoated	#83-361	€33,50 Volume Pricing	20+ In Stock
12.50	-	1.10	MgF ₂ (400-700nm)	#22-850	€54,00 Volume Pricing	8 In Stock
20.00	-	1.10	Uncoated	#83-362	€34,50 Volume Pricing	20+ In Stock
20.00	-	0.40	Uncoated	#29-719	€34,50 Volume Pricing	Contact Us
20.00	-	0.55	Uncoated	#29-720	€34,50 Volume Pricing	4 In Stock
20.00	-	1.50	Uncoated	#29-721	€34,50 Volume Pricing	20+ In Stock
20.00	-	2.00	Uncoated	#29-722	€34,50 Volume Pricing	Contact Us
20.00	-	1.10	MgF ₂ (400-700nm)	#22-851	€55,00 Volume Pricing	5 In Stock
25.00	-	1.10	Uncoated	#83-363	€34,50 Volume Pricing	9 In Stock
25.00	-	0.40	Uncoated	#21-232	€34,50 Volume Pricing	20+ In Stock
25.00	-	0.55	Uncoated	#21-233	€34,50 Volume Pricing	2 In Stock
25.00	-	0.80	Uncoated	#21-234	€34,50 Volume Pricing	17 In Stock

25.00	-	1.50	Uncoated	#21-235	€34,50 Volume Pricing	14 In Stock
25.00	-	2.00	Uncoated	#21-236	€34,50 Volume Pricing	20+ In Stock
25.00	-	1.10	MgF ₂ (400-700nm)	#22-852	€55,00 Volume Pricing	7 In Stock
30.00	-	1.10	Uncoated	#83-364	€43,00 Volume Pricing	20+ In Stock
30.00	-	0.40	Uncoated	#29-723	€43,00 Volume Pricing	6 In Stock
30.00	-	0.55	Uncoated	#29-724	€43,00 Volume Pricing	1 In Stock
30.00	-	1.50	Uncoated	#29-725	€43,00 Volume Pricing	1 In Stock
30.00	-	2.00	Uncoated	#29-726	€43,00 Volume Pricing	6 In Stock
30.00	-	1.10	MgF ₂ (400-700nm)	#22-853	€69,00 Volume Pricing	5 In Stock
40.00	-	1.10	Uncoated	#83-365	€48,00 Volume Pricing	20+ In Stock
40.00	-	1.10	MgF ₂ (400-700nm)	#22-854	€73,00 Volume Pricing	20+ In Stock
50.00	-	1.10	Uncoated	#83-366	€50,50 Volume Pricing	20+ In Stock
50.00	-	0.40	Uncoated	#29-727	€50,50 Volume Pricing	20+ In Stock
50.00	-	0.55	Uncoated	#29-728	€50,50 Volume Pricing	9 In Stock
50.00	-	1.50	Uncoated	#29-729	€50,50 Volume Pricing	12 In Stock
50.00	-	2.00	Uncoated	#29-730	€50,50 Volume Pricing	2 In Stock
50.00	-	1.10	MgF ₂ (400-700nm)	#22-855	€76,50 Volume Pricing	17 In Stock
75.00	-	1.10	Uncoated	#11-854	€53,00 Volume Pricing	20+ In Stock
75.00	-	1.10	MgF ₂ (400-700nm)	#22-856	€102,00 Volume Pricing	3 In Stock

100.00	-	1.10	Uncoated	#21-239	€66,00 Volume Pricing	11 In Stock
100.00	-	0.40	Uncoated	#29-731	€66,00 Volume Pricing	1 In Stock
100.00	-	0.55	Uncoated	#29-732	€66,00 Volume Pricing	1 In Stock
100.00	-	1.50	Uncoated	#29-733	€66,00 Volume Pricing	5 In Stock
100.00	-	2.00	Uncoated	#29-734	€66,00 Volume Pricing	6 In Stock
200.00	-	1.10	Uncoated	#21-240	€109,00 Volume Pricing	2 In Stock
-	203.2 x 254	1.10	Uncoated	#21-237	€109,00 Volume Pricing	3 In Stock
-	254 x 304.8	1.10	Uncoated	#21-238	€123,00 Volume Pricing	7 In Stock
-	25.00 x 25.00	1.10	Uncoated	#12-228	€33,50 Volume Pricing	5 In Stock
-	50.00 x 50.00	1.10	Uncoated	#11-853	€51,00 Volume Pricing	11 In Stock
-	75.00 x 75.00	1.10	Uncoated	#11-855	€53,00 Volume Pricing	Contact Us
-	100.00 x 100.00	1.10	Uncoated	#83-367	€60,00 Volume Pricing	20+ In Stock
-	100.00 x 100.00	0.40	Uncoated	#29-970	€60,00 Volume Pricing	11 In Stock
-	100.00 x 100.00	0.55	Uncoated	#29-971	€60,00 Volume Pricing	7 In Stock
-	100.00 x 100.00	1.50	Uncoated	#29-972	€60,00 Volume Pricing	6 In Stock
-	100.00 x 100.00	2.00	Uncoated	#29-973	€60,00 Volume Pricing	12 In Stock
150.00	-	1.10	Uncoated	#29-736	€83,00 Volume Pricing	6 In Stock
-	150.00 x 150.00	1.10	Uncoated	#29-735	€83,00 Volume Pricing	10 In Stock
-	200.00 x 200.00	1.10	Uncoated	#83-368	€109,00 Volume Pricing	Contact Us

-	250.00 x 250.00	1.10	Uncoated	#17-161	€123,00 Volume Pricing	6 In Stock
-	500.00 x 500.00	1.10	Uncoated	#17-162	€335,00 Volume Pricing	2 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com