

[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Molded](#)

LightPath® Geltech™ Molded Aspheric Lenses See More by [Lightpath®](#)



- Eliminate Spherical Aberration
- Multiple Coating Options Available
- Range of Numerical Apertures

Common Specifications

Physical & Mechanical Properties

Bevel:


Protective bevel as needed

Optical Properties

Focal Length Tolerance (%):

±1

Technical Information

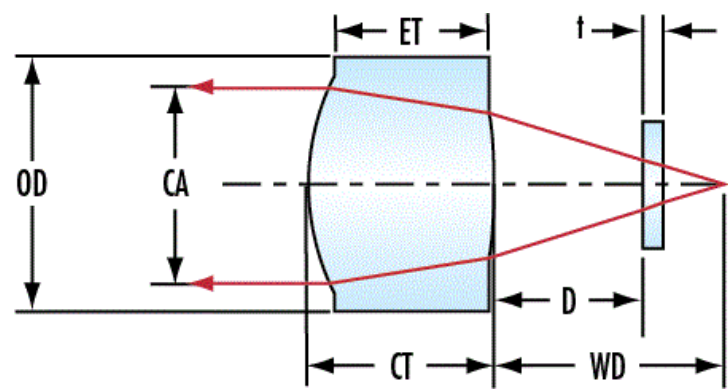

Products

Dia. (mm)	Dimensions (mm)	EFL (mm)	NA	Coating	Stock Number	Price	Buy
#71-004 New							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
4.00	-	6.20	0.30	BBAR (350-700nm)		€109,00 Qty 11+ €96,00	3-4 days
#71-003 New							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
4.00	-	2.50	0.70	BBAR (350-700nm)		€99,00 Qty 11+ €87,00	3-4 days
6.33	-	22.00	0.13	BBAR (350-700nm)	#83-543	€91,50 Qty 11+ €80,50	3-4 days

6.33	-	22.00	0.13	BBAR (600-1050nm)	#83-544	€91,50 Qty 11+ €80,50	3-4 days
#83-546 Clearance							
×							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
2.00	-	5.00	0.15	BBAR (350-700nm)		€43,75	3-4 days
2.00	-	5.00	0.15	BBAR (600-1050nm)	#48-145	€91,50 Qty 11+ €80,50	In Stock
4.99	-	15.04	0.15	BBAR (350-700nm)	#16-689	€93,50 Qty 11+ €82,00	3-4 days
6.50	-	18.40	0.15	BBAR (350-700nm)	#87-113	€99,00 Qty 11+ €87,50	3-4 days
6.50	-	18.40	0.15	BBAR (600-1050nm)	#87-114	€88,50 Qty 11+ €78,00	3-4 days
6.50	-	15.29	0.16	BBAR (350-700nm)	#37-098	€81,00 Qty 11+ €71,00	3-4 days
6.50	-	15.29	0.16	BBAR (600-1050nm)	#37-099	€78,00 Qty 11+ €68,50	In Stock
6.50	-	15.29	0.16	BBAR (1050-1600nm)	#37-100	€78,00 Qty 11+ €68,50	3-4 days

6.33	-	13.86	0.18	BBAR (600-1050nm)	#46-372	€83,00 Qty 11+ €73,50	3-4 days
#48-160 Clearance							
							
Clearance							
Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
6.33	-	13.86	0.18	BBAR (1050-1600nm)		€41,50	Contact Us
6.33	-	13.90	0.18	BBAR (350-700nm)	#83-556	€91,50 Qty 11+ €80,50	3-4 days
6.00	-	11.00	0.24	BBAR (1050-1600nm)	#37-111	€78,00 Qty 11+ €68,50	3-4 days

[#16-693 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

2.05	-	2.51	0.20	BBAR (350-700nm)	€41,50	Contact Us
------	---	------	------	------------------	--------	------------

[#16-694 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

2.05	-	2.51	0.20	BBAR (600-1050nm)	€41,50	Contact Us
------	---	------	------	-------------------	--------	------------

7.20	-	11.00	0.25	BBAR (350-700nm)	#87-117 €91,50 Qty 11+ €80,50	In Stock
------	---	-------	------	------------------	---	----------

[#87-118 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

7.20	-	11.00	0.25	BBAR (600-1050nm)	€14,95	3-4 days
------	---	-------	------	-------------------	--------	----------

7.20	-	11.00	0.25	BBAR (1050-1600nm)	€83,00 Qty 11+ €73,50	3-4 days
------	---	-------	------	--------------------	--------------------------	----------

6.51	-	7.50	0.3	BBAR (350-700nm)	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	-----	------------------	--------------------------	----------

6.51	-	7.50	0.3	BBAR (600-1050nm)	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	-----	-------------------	--------------------------	----------

6.51	-	7.50	0.3	BBAR (1050-1600nm)	€67,50 Qty 11+ €60,00	Contact Us
------	---	------	-----	--------------------	--------------------------	------------

7.20	-	11.00	0.3	BBAR (350-700nm)	€67,50 Qty 11+ €60,00	In Stock
------	---	-------	-----	------------------	--------------------------	----------

7.20	-	11.00	0.3	BBAR (600-1050nm)	€67,50 Qty 11+ €60,00	3-4 days
------	---	-------	-----	-------------------	--------------------------	----------

3.00	-	3.52	0.4	BBAR (350-700nm)	€93,50 Qty 11+ €82,00	3-4 days
------	---	------	-----	------------------	--------------------------	----------

7.20	-	6.24	0.4	BBAR (350-700nm)	€99,00 Qty 11+ €87,50	3-4 days
------	---	------	-----	------------------	--------------------------	----------

7.20	-	6.24	0.4	BBAR (600-1050nm)	#87-126	€93,50 Qty 11+ €82,00	3-4 days
7.20	-	6.24	0.4	BBAR (1050-1600nm)	#87-127	€93,50 Qty 11+ €82,00	3-4 days
4.70	-	4.50	0.43	BBAR (350-700nm)	#83-578	€67,50 Qty 11+ €60,00	In Stock
4.70	-	4.50	0.43	BBAR (600-1050nm)	#83-579	€67,50 Qty 11+ €60,00	In Stock
4.70	-	4.50	0.43	BBAR (1050-1600nm)	#83-580	€67,50 Qty 11+ €60,00	Contact Us
6.65	-	6.70	0.44	BBAR (350-700nm)	#19-701	€81,00 Qty 11+ €69,50	3-4 days
6.65	-	6.70	0.44	BBAR (600-1050nm)	#19-702	€81,00 Qty 11+ €69,50	In Stock

[#16-687 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.42	-	4.47	0.47	BBAR (350-700nm)		€41,50	3-4 days
6.00	-	4.60	0.55	BBAR (1050-1600nm)	#87-159	€67,50 Qty 11+ €60,00	3-4 days

[#37-112 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

-	1.0 x 1.0	0.55	0.5	BBAR (350-700nm)	€47,75	3-4 days
---	-----------	------	-----	------------------	--------	----------

[#37-113 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

-	1.0 x 1.0	0.55	0.5	BBAR (600-1050nm)	€47,75	3-4 days
---	-----------	------	-----	-------------------	--------	----------

-	1.0 x 1.0	0.55	0.5	BBAR (1050-1600nm)	#37-114	€91,50 Qty 11+ €80,50	3-4 days
---	-----------	------	-----	--------------------	-------------------------	--------------------------	----------

1.40	-	1.05	0.5	BBAR (1050-1600nm)	#16-704	€93,50 Qty 11+ €82,00	3-4 days
------	---	------	-----	--------------------	-------------------------	--------------------------	----------

9.94	-	8.00	0.5	BBAR (350-700nm)	#37-102	€99,00 Qty 11+ €87,00	3-4 days
9.94	-	8.00	0.5	BBAR (600-1050nm)	#37-103	€93,50 Qty 11+ €82,00	In Stock
9.94	-	8.00	0.5	BBAR (1050-1600nm)	#37-104	€93,50 Qty 11+ €82,00	3-4 days
11.00	-	10.00	0.5	BBAR (350-700nm)	#33-425	€147,00 Qty 11+ €129,00	Contact Us
11.00	-	10.00	0.5	BBAR (600-1050nm)	#33-426	€147,00 Qty 11+ €129,00	3-4 days

[#33-427 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

11.00	-	10.00	0.5	BBAR (1050-1600nm)		€83,00	In Stock
-------	---	-------	-----	-----------------------	--	--------	----------

9.20	-	6.75	0.54	BBAR (350-700nm)	#16-691	€93,50 Qty 11+ €82,00	3-4 days
6.00	-	4.60	0.55	BBAR (350-700nm)	#87-157	€67,50 Qty 11+ €60,00	3-4 days
6.00	-	4.60	0.55	BBAR (600-1050nm)	#87-158	€67,50 Qty 11+ €60,00	3-4 days

[#47-144 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

9.94	-	8.00	0.50	BBAR (350-700nm)	€38,50	3-4 days
------	---	------	------	------------------	--------	----------

3.00	-	2.00	0.50	BBAR (350-700nm)	#83-582	€67,50 Qty 11+ €60,00	In Stock
------	---	------	------	------------------	-------------------------	--------------------------	----------

3.00	-	2.00	0.50	BBAR (600-1050nm)	#83-583	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	-------------------	-------------------------	--------------------------	----------

4.70	-	2.76	0.5	BBAR (350-700nm)	#87-133	€83,00 Qty 11+ €73,50	3-4 days
------	---	------	-----	------------------	-------------------------	--------------------------	----------

[#87-134 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

4.70	-	2.76	0.5	BBAR (600-1050nm)	€43,75	3-4 days
------	---	------	-----	-------------------	--------	----------

4.00	-	2.73	0.55	BBAR (350-700nm)	#83-605	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	------------------	-------------------------	--------------------------	----------

4.00	-	2.73	0.55	BBAR (600-1050nm)	#83-606	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	-------------------	-------------------------	--------------------------	----------

[#83-607 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

4.00	-	2.73	0.55	BBAR (1050-1600nm)		€26,00	In Stock
------	---	------	------	--------------------	--	--------	----------

4.50	-	2.75	0.55	BBAR (350-700nm)	#83-616	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	------------------	-------------------------	--------------------------	----------

4.50	-	2.75	0.55	BBAR (600-1050nm)	#66-926	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	-------------------	-------------------------	--------------------------	----------

4.50	-	2.75	0.55	BBAR (1050-1600nm)	#66-927	€67,50 Qty 11+ €60,00	3-4 days
------	---	------	------	--------------------	-------------------------	--------------------------	----------

[#16-699 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

5.59	-	4.13	0.55	BBAR (350-700nm)		€45,75	3-4 days
------	---	------	------	------------------	--	--------	----------

5.59	-	4.13	0.55	BBAR (1050-1600nm)	#16-701	€93,50 Qty 11+ €82,00	3-4 days
6.33	-	4.51	0.55	BBAR (350-700nm)	#87-153	€91,50 Qty 11+ €80,50	3-4 days
6.33	-	4.51	0.55	BBAR (600-1050nm)	#87-154	€88,50 Qty 11+ €78,00	In Stock
6.33	-	4.51	0.55	BBAR (1050-1600nm)	#87-155	€88,50 Qty 11+ €78,00	In Stock
2.40	-	1.45	0.58	BBAR (350-700nm)	#83-613	€67,50 Qty 11+ €60,00	3-4 days
2.40	-	1.45	0.58	BBAR (600-1050nm)	#83-614	€67,50 Qty 11+ €60,00	3-4 days
2.40	-	1.45	0.58	BBAR (1050-1600nm)	#83-615	€67,50 Qty 11+ €60,00	3-4 days
7.20	-	5.50	0.56	BBAR (350-700nm)	#87-145	€99,00 Qty 11+ €87,00	In Stock

7.20	-	5.50	0.60	BBAR (600-1050nm)	#87-146	€99,00 Qty 11+ €87,00	3-4 days
7.20	-	5.50	0.56	BBAR (1050-1600nm)	#87-147	€93,50 Qty 11+ €82,00	3-4 days
15.00	-	10.00	0.6	BBAR (350-700nm)	#37-105	€81,00 Qty 11+ €71,00	In Stock
15.00	-	10.00	0.6	BBAR (600-1050nm)	#37-106	€81,00 Qty 11+ €71,00	In Stock
15.00	-	10.00	0.6	BBAR (1050-1600nm)	#37-107	€81,00 Qty 11+ €71,00	3-4 days
4.00	-	2.75	0.60	BBAR (350-700nm)	#83-626	€67,50 Qty 11+ €60,00	3-4 days
4.00	-	2.75	0.60	BBAR (600-1050nm)	#83-627	€67,50 Qty 11+ €60,00	3-4 days
6.33	-	4.03	0.64	BBAR (350-700nm)	#87-161	€88,50 Qty 11+ €78,00	In Stock
6.33	-	4.03	0.64	BBAR (600-1050nm)	#87-162	€91,50 Qty 11+ €80,50	In Stock
6.33	-	4.03	0.64	BBAR (1050-1600nm)	#87-163	€93,50 Qty 11+ €82,50	3-4 days
6.33	-	3.10	0.68	BBAR (350-700nm)	#87-165	€91,50 Qty 11+ €80,50	Contact Us
6.33	-	3.10	0.68	BBAR (600-1050nm)	#87-166	€88,50 Qty 11+ €78,00	3-4 days
				BBAR (600-1050nm)	#83-674	€147,00 Qty 11+ €129,00	In Stock