

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)

TECHSPEC® Cx Series Fixed Focal Length Lenses



- Up to 2/3", C-Mount Lens
- Up to 7.5 MegaPixels, 2.8µm Pixel Size Sensors
- Flexible (Cx) Version of our C Series Lenses with Interchangeable Apertures, Filters and Liquid Lens
- 12mm to 50mm Focal Length

Common Specifications

Physical & Mechanical Properties

Iris Option: Fixed	Maximum Rear Protrusion (mm): 0
---------------------------	--

Optical Properties

Maximum Image Circle (mm): 11.00	Aperture (f/#): Accessory Dependent
Coating: 425 - 675nm BBAR	Coating Specification: 425 - 675nm BBAR

Sensor

Maximum Sensor Format: 2/3"


Threading & Mounting

Filter Thread: M25.5 x 0.50 (Male)	Mount: C-Mount
Filter Thread Adapter: #89-941 (Required)	

Environmental & Durability Factors

Storage Temperature (°C): -20 to +60 For questions regarding operating temperature please contact our support team

Technical Information

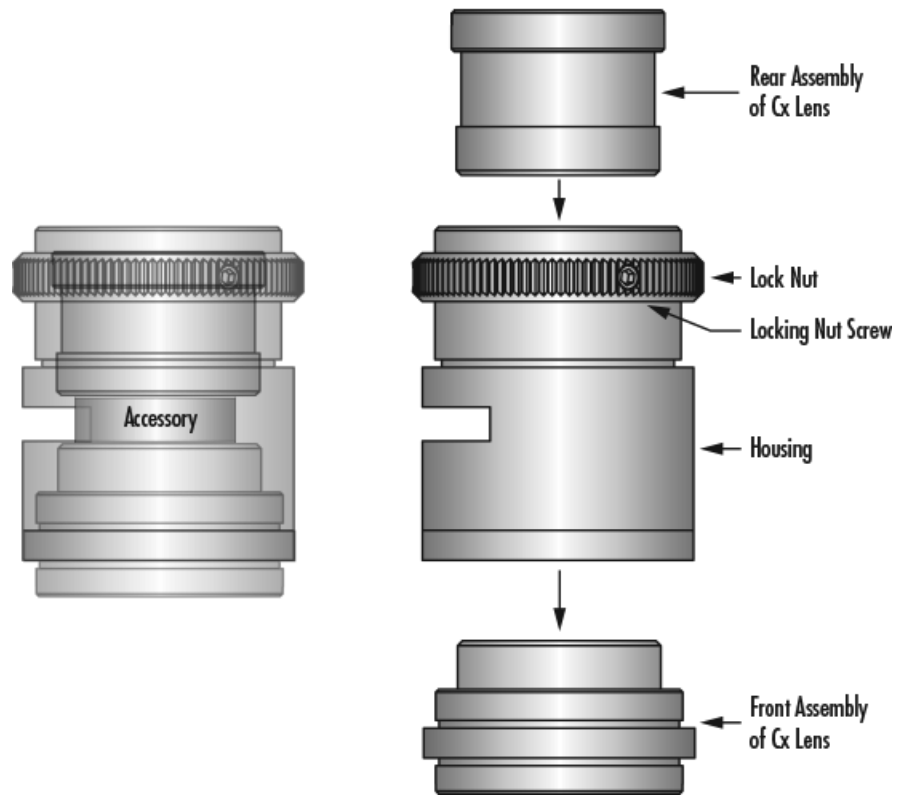

Cx Lens Assembly Diagram

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Mount	Stock Number	Price	Buy
12.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-562	€245,00	In Stock
16.00	2/3"	Accessory Dependent	100 - ∞	C- Mount	#33-563	€245,00	3-4 days
25.00	2/3"	Accessory Dependent	150 - ∞	C- Mount	#33-564	€245,00	In Stock
35.00	2/3"	Accessory Dependent	225 - ∞	C- Mount	#33-565	€245,00	3-4 days
50.00	2/3"	Accessory Dependent	300 - 1,675	C- Mount	#33-566	€330,00	In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com