


[All Products](#) / [Lights and Illumination](#) / [Machine Vision Lighting](#) / [Bar Lights](#)

Effilux Adjustable LED Bar Lights

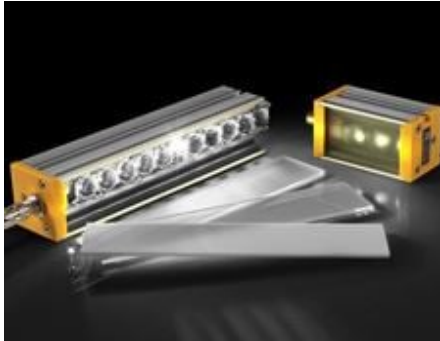

- Direct Access to Optics for Quick, Manual Adjustment of Illumination Cone Angles
- Included Interchangeable Windows Allows for Easy Adjustment of Light Diffusion
- Easy to Integrate Linescan Accessory for Linear or Darkfield Lighting

Common Specifications

General

Type of Illumination:	LED Illuminator	Manufacturer:	Effilux
Geometry:	Bar Light	Illumination Mode:	Strobed or Constant

Hardware & Interface Connectivity

Connector:	M12, 5 pins	Input Voltage (V):	24V DC
Power Supply:	Power Supply Required and Sold Separately: USA: #15-874 Europe: #15-875 Japan: #73-409 Korea: #73-409 China: #15-874		

Threading & Mounting

Mount:	2 Rails (1 for M6 T-Nuts)
---------------	---------------------------

Environmental & Durability Factors

Operating Temperature (°C):	-10 to 50	Environmental Rating:	IP40
------------------------------------	-----------	------------------------------	------

Technical Information

Products

Dimensions (mm)	Color	Wavelength (nm)	Stock Number	Price	Buy
55.0 x 51.0 x 49.0	White	-	#34-873	€330,00	3-4 days
55.0 x 51.0 x 49.0	Red	625.00	#34-874	€315,00	3-4 days
95.0 x 51.0 x 49.0	White	-	#28-110	€425,00	3-4 days
135.0 x 51.0 x 49.0	White	-	#34-875	€600,00	3-4 days
135.0 x 51.0 x 49.0	Red	625.00	#34-876	€600,00	3-4 days
235.0 x 51.0 x 49.0	White	-	#34-877	€770,00	3-4 days
235.0 x 51.0 x 49.0	Red	625.00	#34-878	€735,00	3-4 days
335.0 x 51.0 x 49.0	White	-	#34-879	€960,00	3-4 days
335.0 x 51.0 x 49.0	Red	625.00	#34-880	€980,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com