


[All Products](#) / [Lasers](#) / [Laser Sources](#) / [Industrial and Pointing Lasers](#)

Violet and Blue Alignment Laser Diodes

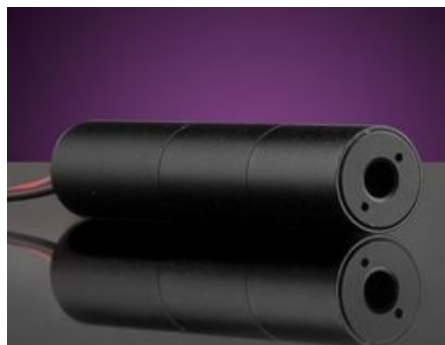

- TTL Modulation up to 10kHz
- Circular and Elliptical Beam Profiles
- Focus Adjustable



Common Specifications

Physical & Mechanical Properties

Length (mm):	36.00
--------------	-------

Optical Properties

Wavelength Tolerance (nm):	±5
----------------------------	----

Electrical

Modulation Frequency (kHz):	0 - 10
-----------------------------	--------

Technical Information

Products

Wavelength (nm)	Output Power (mW)	Beam Diameter (mm)	Beam Divergence (mrad)	Stock Number	Price	Buy
405.00	1	3.5 Typical	<0.5	#37-023	€371,00 Qty 10+ €334,00	3-4 days
405.00	5	3.2 x 1.5	<0.5	#37-024	€383,00 Qty 10+ €345,00	3-4 days
405.00	10	3.5 Typical	<0.5	#37-025	€399,00 Qty 10+ €360,00	3-4 days
405.00	25	3.5 typical	<0.5	#19-461	€487,00 Qty 10+ €438,00	3-4 days
405.00	100	3.5 typical	<1.0	#19-462	€645,00 Qty 10+ €580,00	In Stock
450.00	1	3.5 typical	<1.0	#19-463	€355,00 Qty 10+ €319,00	3-4 days
450.00	5	3.5 typical	<1.0	#19-464	€355,00 Qty 10+ €319,00	3-4 days
450.00	10	3.5 typical	<1.0	#19-465	€381,00 Qty 10+ €343,00	3-4 days
450.00	25	3.5 typical	<1.0	#19-466	€487,00 Qty 10+ €438,00	3-4 days
450.00	100	3.5 typical	<1.0	#19-467	€645,00 Qty 10+ €580,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com