

[All Products](#) / [Imaging Lenses](#) / [Fixed Focal Length Lenses](#)

TECHSPEC® UCi Series Fixed Focal Length Lenses



- Up to 1/1.8", C-Mount, S-Mount Lens
- Up to 12 MegaPixels, 1.85µm Pixel Size Sensors
- Instrumentation (UCi) versions of our UC Series Lenses with Streamlined Mechanical Designs and Fixed Apertures
- 4mm to 35mm Focal Length

Common Specifications

Physical & Mechanical Properties

Iris Option: Fixed

Optical Properties

Coating: $\lambda/4$ MgF₂

Coating Specification: $\lambda/4$ MgF₂

Sensor


Optimized Sensor Format: 1/2.5"

Environmental & Durability Factors


Storage Temperature (°C): -20 to +60 For questions regarding operating temperature please contact our support team

Technical Information


4mm Focal Length

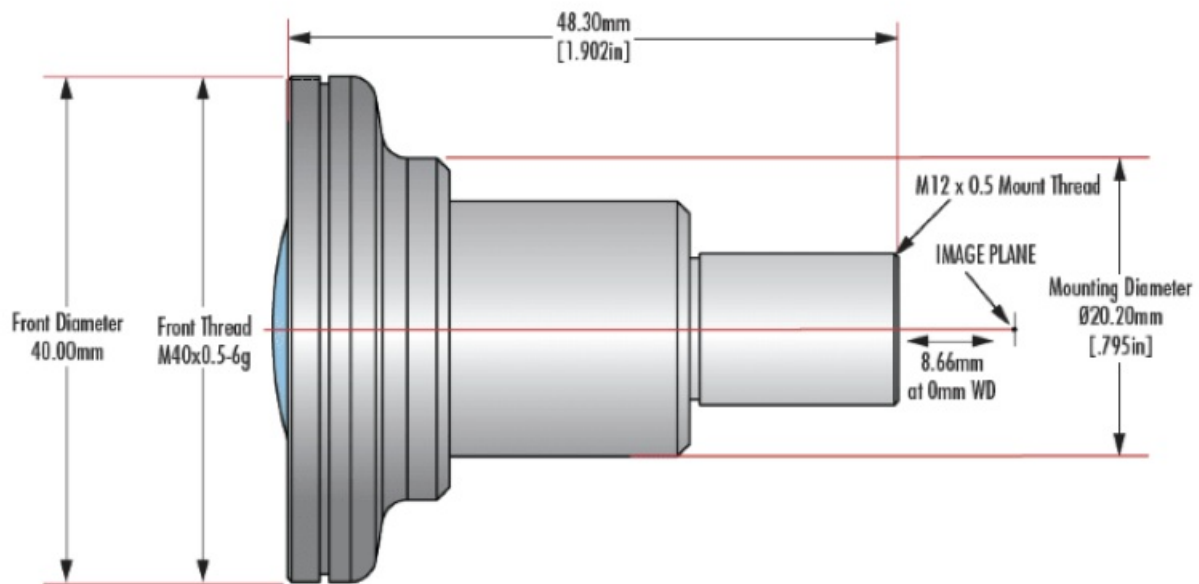


6mm Focal Length

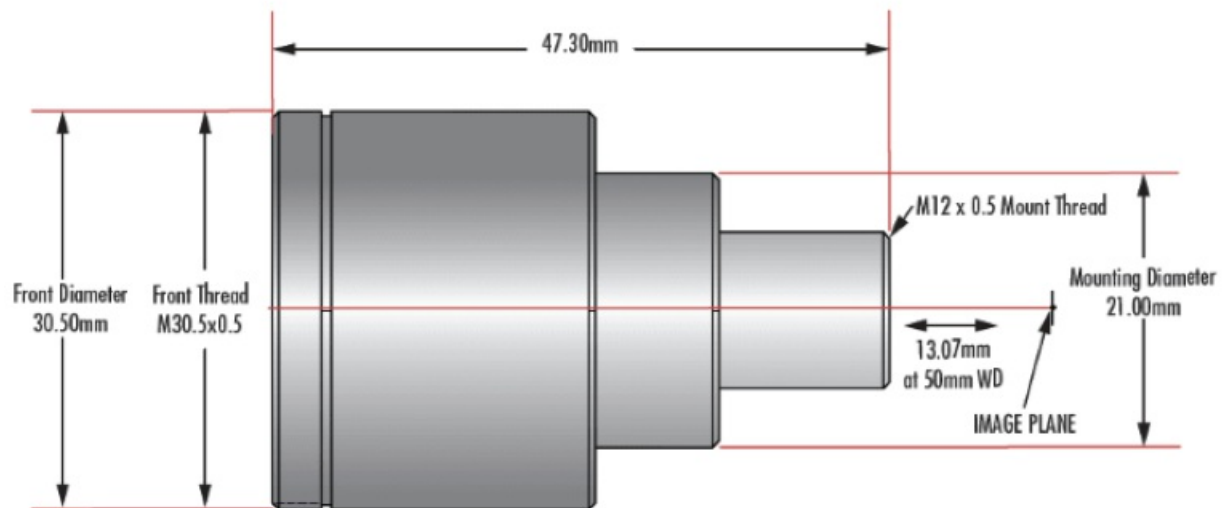


12mm Focal Length

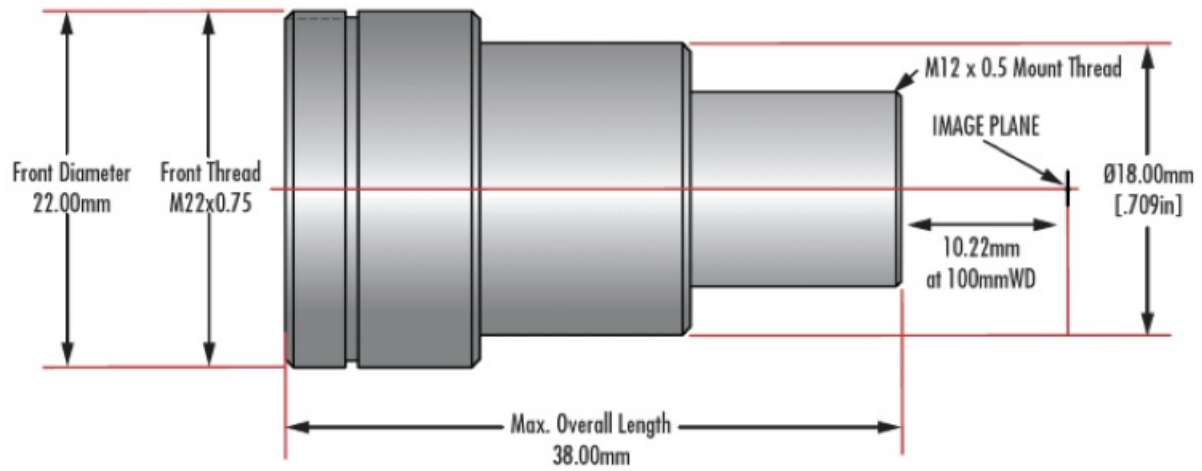


16mm Focal Length

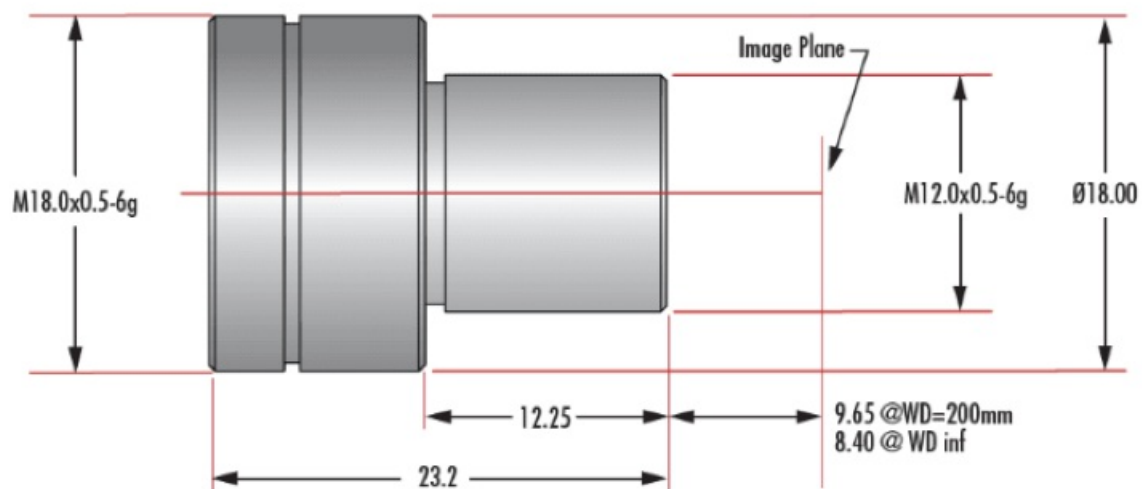

25mm Focal Length

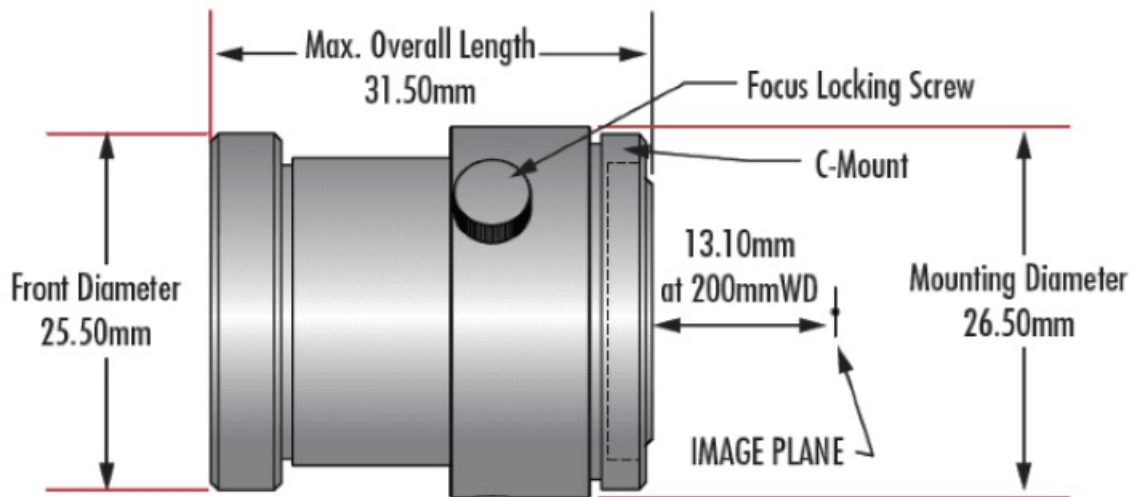

35mm Focal Length

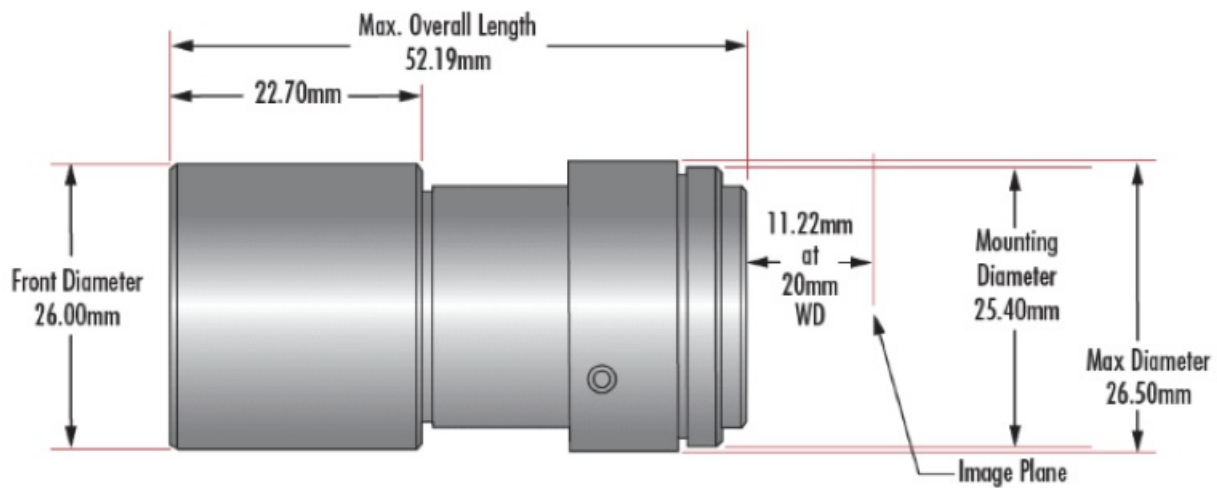

Products

FL (mm)	Max. Sensor Format	Aperture (f/#)	WD (mm)	Mount	Stock Number	Price	Buy
4.00	1/2"	f/1.8	0 - ∞	M12 x 0.5 (S-Mount)	#33-855	€235,00	3-4 days
4.00	1/2"	f/2.8	0 - ∞	M12 x 0.5 (S-Mount)	#33-856	€235,00	3-4 days
4.00	1/2"	f/4.0	0 - ∞	M12 x 0.5 (S-Mount)	#33-857	€235,00	3-4 days
4.00	1/2"	f/5.6	0 - ∞	M12 x 0.5 (S-Mount)	#33-858	€235,00	3-4 days
4.00	1/2"	f/8.0	0 - ∞	M12 x 0.5 (S-Mount)	#33-859	€235,00	Contact Us
4.00	1/2"	f/11.0	0 - ∞	M12 x 0.5 (S-Mount)	#33-860	€235,00	3-4 days
4.00	1/2"	f/16.0	0 - ∞	M12 x 0.5 (S-Mount)	#33-861	€235,00	3-4 days
6.00	1/2"	f/1.85	50 - ∞	M12 x 0.5 (S-Mount)	#33-862	€235,00	3-4 days
6.00	1/2"	f/2.8	50 - ∞	M12 x 0.5 (S-Mount)	#33-863	€235,00	3-4 days
6.00	1/2"	f/4.0	50 - ∞	M12 x 0.5 (S-Mount)	#33-864	€235,00	3-4 days
6.00	1/2"	f/5.6	50 - ∞	M12 x 0.5 (S-Mount)	#33-865	€235,00	3-4 days
6.00	1/2"	f/8.0	50 - ∞	M12 x 0.5 (S-Mount)	#33-866	€235,00	3-4 days
6.00	1/2"	f/11.0	50 - ∞	M12 x 0.5 (S-Mount)	#33-867	€235,00	3-4 days
6.00	1/2"	f/16.0	50 - ∞	M12 x 0.5 (S-Mount)	#33-868	€235,00	3-4 days
12.00	1/1.8"	f/1.8	100 - ∞	M12 x 0.5 (S-Mount)	#33-876	€235,00	3-4 days
12.00	1/1.8"	f/2.8	100 - ∞	M12 x 0.5 (S-Mount)	#33-877	€235,00	3-4 days

12.00	1/1.8"	f/4.0	100 - ∞	M12 x 0.5 (S-Mount)	#33-878	€235,00	3-4 days
12.00	1/1.8"	f/5.6	100 - ∞	M12 x 0.5 (S-Mount)	#33-879	€235,00	3-4 days
12.00	1/1.8"	f/8.0	100 - ∞	M12 x 0.5 (S-Mount)	#33-880	€235,00	Contact Us
12.00	1/1.8"	f/11.0	100 - ∞	M12 x 0.5 (S-Mount)	#33-881	€235,00	3-4 days
12.00	1/1.8"	f/16.0	100 - ∞	M12 x 0.5 (S-Mount)	#33-882	€235,00	3-4 days
16.00	1/1.8"	f/1.8	200 - ∞	M12 x 0.5 (S-Mount)	#33-883	€235,00	3-4 days
16.00	1/1.8"	f/2.8	200 - ∞	M12 x 0.5 (S-Mount)	#33-884	€235,00	3-4 days
16.00	1/1.8"	f/4.0	200 - ∞	M12 x 0.5 (S-Mount)	#33-885	€235,00	3-4 days
16.00	1/1.8"	f/5.6	200 - ∞	M12 x 0.5 (S-Mount)	#33-886	€235,00	In Stock
16.00	1/1.8"	f/8.0	200 - ∞	M12 x 0.5 (S-Mount)	#33-887	€235,00	3-4 days
16.00	1/1.8"	f/11	200 - ∞	M12 x 0.5 (S-Mount)	#33-888	€235,00	3-4 days
16.00	1/1.8"	f/16	200 - ∞	M12 x 0.5 (S-Mount)	#33-889	€235,00	3-4 days
25.00	1/1.8"	f/1.85	200 - ∞	C-Mount	#33-890	€235,00	3-4 days
25.00	1/1.8"	f/2.8	200 - ∞	C-Mount	#33-891	€235,00	3-4 days
25.00	1/1.8"	f/4.0	200 - ∞	C-Mount	#33-892	€235,00	3-4 days
25.00	1/1.8"	f/5.6	200 - ∞	C-Mount	#33-893	€235,00	3-4 days
25.00	1/1.8"	f/8.0	200 - ∞	C-Mount	#33-894	€235,00	3-4 days
25.00	1/1.8"	f/11.0	200 - ∞	C-Mount	#33-895	€235,00	3-4 days
25.00	1/1.8"	f/16.0	200 - ∞	C-Mount	#33-896	€235,00	3-4 days

35.00	1/1.8"	f/1.85	200 - ∞	C-Mount	#33-897	€250,00	3-4 days
35.00	1/1.8"	f/2.8	200 - ∞	C-Mount	#33-898	€250,00	Contact Us
35.00	1/1.8"	f/4.0	200 - ∞	C-Mount	#33-899	€250,00	3-4 days
35.00	1/1.8"	f/5.6	200 - ∞	C-Mount	#33-900	€250,00	3-4 days
35.00	1/1.8"	f/8.0	200 - ∞	C-Mount	#33-901	€250,00	3-4 days
35.00	1/1.8"	f/11.0	200 - ∞	C-Mount	#33-902	€250,00	3-4 days
35.00	1/1.8"	f/16	200 - ∞	C-Mount	#33-854	€250,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
 Phone: 1-800-363-1992 :
www.edmundoptics.com