

[All Products](#) /
 [Laser Optics](#) /
 [Laser Windows](#) /
 [Laser Line Windows](#)

TECHSPEC® $\lambda/10$ Laser Line Coated Windows



- 10-5 Surface Quality
- Damage Thresholds at Design Wavelengths
- Diameters from 12.5 to 50.8mm Available
- [Uncoated Substrates Available](#)

Common Specifications



Physical & Mechanical Properties

Bevel:	Protective as needed	Clear Aperture (%):	90
Edges:	Fine Ground		


Optical Properties

Angle of Incidence (°):	0
Surface Quality:	10-5

Technical Information

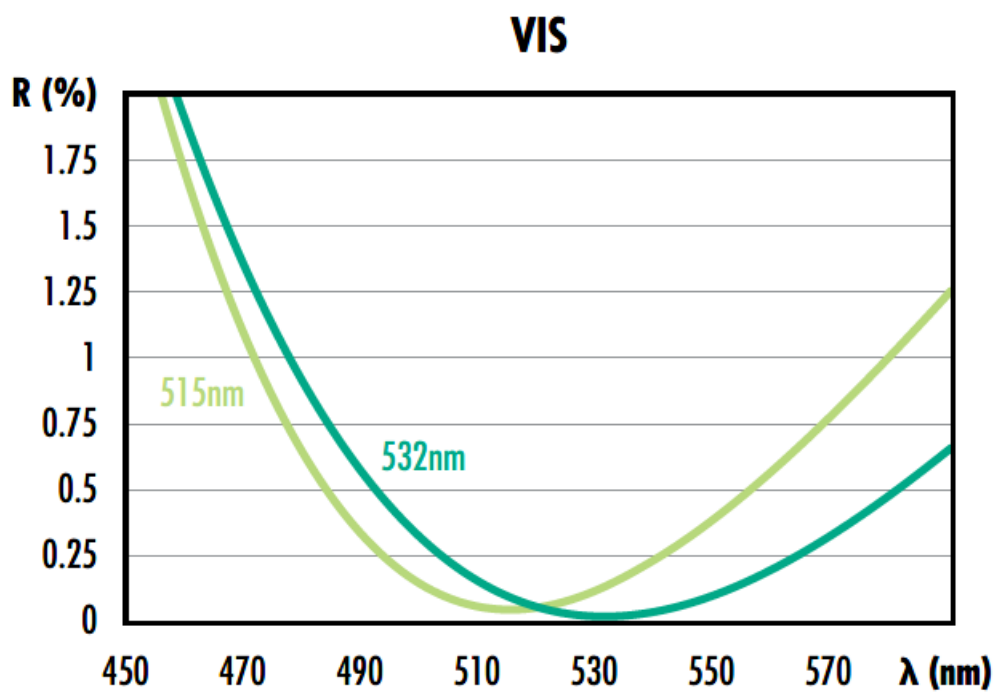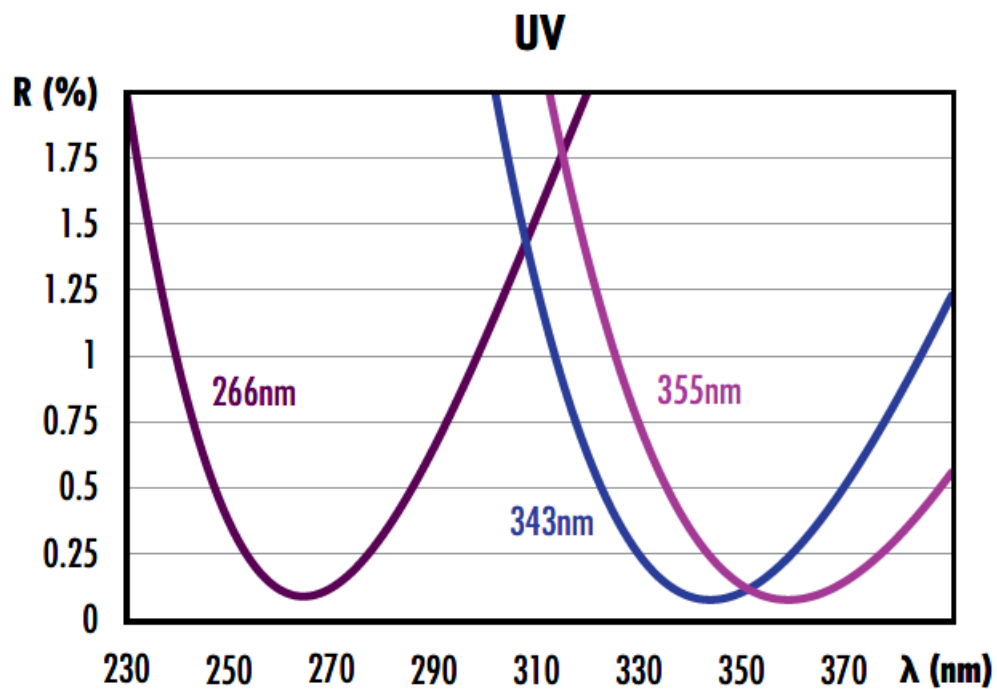

NIR

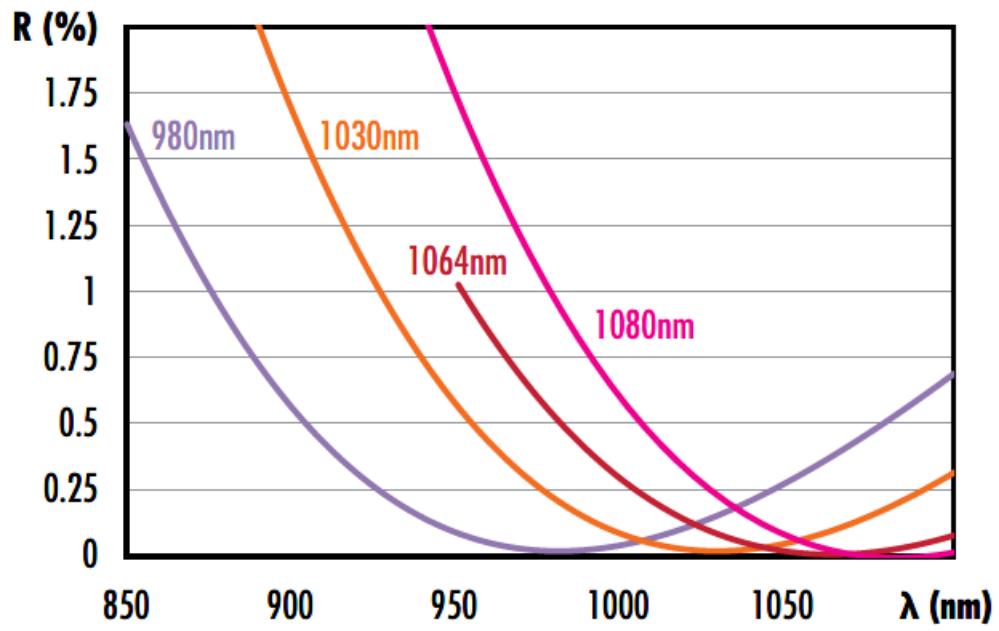

Products

Coating	Substrate	Dia. (mm)	Thickness (mm)	Stock Number	Price	Buy
Laser V-Coat (266nm)	Fused Silica	12.50	3.00	#48-204	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	12.70	6.35	#38-918	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	19.10	6.35	#38-921	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	25.00	3.00	#48-205	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	25.40	6.35	#38-923	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	38.10	6.35	#38-925	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (266nm)	Fused Silica	50.80	9.53	#38-928	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (343nm)	Fused Silica	12.70	6.35	#39-668	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (343nm)	Fused Silica	19.10	6.35	#39-670	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (343nm)	Fused Silica	25.40	6.35	#39-671	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (343nm)	Fused Silica	38.10	6.35	#39-673	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (343nm)	Fused Silica	50.80	9.53	#39-675	€270,00 Qty 6+ €216,00	3-4 days

Laser V-Coat (343nm)	Fused Silica	76.20	12.70	#27-040	€800,00 Qty 6+ €640,00	Contact Us
Laser V-Coat (355nm)	Fused Silica	12.50	3.00	#48-206	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	12.70	6.35	#38-936	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	19.10	6.35	#38-938	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	25.00	3.00	#48-207	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	25.40	6.35	#38-942	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	38.10	6.35	#38-949	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (355nm)	Fused Silica	50.80	9.53	#38-951	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (515nm)	Fused Silica	12.70	6.35	#39-681	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (515nm)	Fused Silica	19.10	6.35	#39-683	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (515nm)	Fused Silica	25.40	6.35	#39-684	€158,00 Qty 6+ €126,00	In Stock
Laser V-Coat (515nm)	Fused Silica	38.10	6.35	#39-688	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (515nm)	Fused Silica	50.80	9.53	#39-690	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (515nm)	Fused Silica	76.20	12.70	#27-041	€800,00 Qty 6+ €640,00	3-4 days

Laser V-Coat (532nm)	Fused Silica	12.50	3.00	#48-208	€135,00 Qty 6+ €108,00	In Stock
Laser V-Coat (532nm)	Fused Silica	12.70	6.35	#38-966	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	19.10	6.35	#38-968	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	25.00	3.00	#48-209	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	25.40	6.35	#38-969	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	38.10	6.35	#38-973	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	50.80	9.53	#38-975	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (980nm)	Fused Silica	12.70	6.35	#39-702	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (980nm)	Fused Silica	19.10	6.35	#39-704	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (980nm)	Fused Silica	25.40	6.35	#39-705	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (980nm)	Fused Silica	38.10	6.35	#39-707	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (980nm)	Fused Silica	50.80	9.53	#39-710	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (1030nm)	Fused Silica	12.70	6.35	#39-717	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (1030nm)	Fused Silica	19.10	6.35	#39-719	€145,00 Qty 6+ €116,00	3-4 days

Laser V-Coat (1030nm)	Fused Silica	25.40	6.35	#39-720	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (1030nm)	Fused Silica	38.10	6.35	#39-722	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (1030nm)	Fused Silica	50.80	9.53	#39-724	€270,00 Qty 6+ €216,00	3-4 days
Laser V-Coat (1030nm)	Fused Silica	76.20	12.70	#27-042	€800,00 Qty 6+ €640,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	12.50	3.00	#48-210	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	12.70	6.35	#38-982	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	19.10	6.35	#38-984	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	25.00	3.00	#48-211	€158,00 Qty 6+ €126,00	In Stock
Laser V-Coat (1064nm)	Fused Silica	25.40	6.35	#38-985	€158,00 Qty 6+ €126,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	38.10	6.35	#38-988	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	50.80	9.53	#38-990	€270,00 Qty 6+ €216,00	In Stock
Laser V-Coat (1080nm)	Fused Silica	12.70	6.35	#11-397	€135,00 Qty 6+ €108,00	3-4 days
Laser V-Coat (1080nm)	Fused Silica	19.10	6.35	#11-399	€145,00 Qty 6+ €116,00	3-4 days
Laser V-Coat (1080nm)	Fused Silica	25.40	6.35	#11-400	€158,00 Qty 6+ €126,00	3-4 days

Laser V-Coat (1080nm)	Fused Silica	38.10	6.35	#11-402	€222,00 Qty 6+ €177,00	3-4 days
Laser V-Coat (1080nm)	Fused Silica	50.80	9.53	#11-404	€270,00 Qty 6+ €216,00	3-4 days

[#38-933 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (355nm)	N-BK7	25.40	6.35		€112,00	3-4 days
-------------------------	-----------------------	-------	------	--	---------	----------

[#38-963 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (532nm)

[N-BK7](#)

25.40

6.35

€102,00

3-4 days

[#39-699 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (980nm)

[N-BK7](#)

25.40

6.35

€71,00

3-4 days

[#38-977 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (1064nm)

[N-BK7](#)

12.70

6.35

€102,00

3-4 days

[#11-453 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

Laser V-Coat (1064nm)

[N-BK7](#)

38.10

6.35

€102,00

3-4 days

Laser V-Coat (266nm)

[Fused Silica](#)

76.20

12.70

[#20-437](#)

€800,00
Qty 6+ €640,00

3-4 days

Laser V-Coat (355nm)	Fused Silica	76.20	12.70	#20-444	€800,00 Qty 6+ €640,00	3-4 days
Laser V-Coat (532nm)	Fused Silica	76.20	12.70	#20-449	€800,00 Qty 6+ €640,00	3-4 days
Laser V-Coat (1064nm)	Fused Silica	76.20	12.70	#20-450	€800,00 Qty 6+ €640,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com