

[All Products](#) / [Optics](#) / [Optical Mirrors](#) / [Off-Axis Mirrors](#)

TECHSPEC® Aluminum Off-Axis Parabolic Mirrors




- Aluminum Coatings for UV, Visible, and NIR Applications
- Range of Surface Roughness, Including 50Å and 100Å
- 15°, 30°, 45°, 60°, or 90° Offset Angle Options
- Gold and Silver Coated Off-Axis Parabolic Mirrors Also Available

Common Specifications

Optical Properties

Focal Length Tolerance (%) : ±1	Coating Type: Metal
Surface Quality: 80-50	Substrate: Aluminum 6061-T6

Technical Information

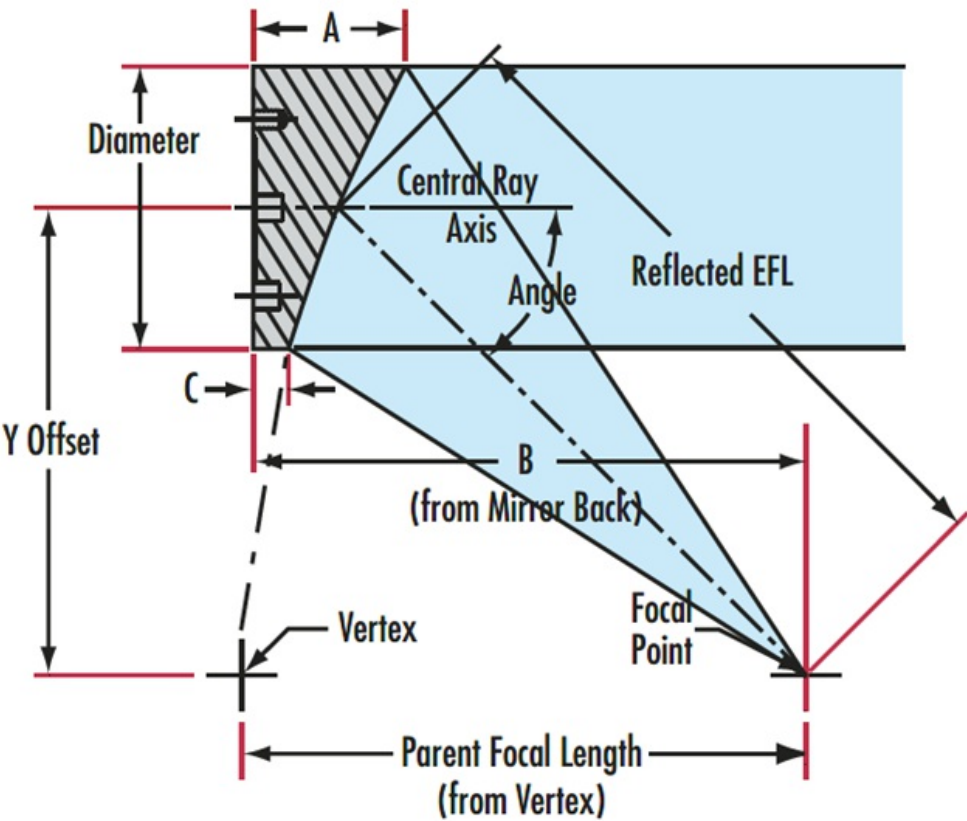

Products

Dia. (mm)	EFL (mm)	Coating	Off- Set Angle (°)	Surface Roughness (Å)	Stock Number	Price	Buy
6.35	6.35	Protected Aluminum (400- 2000nm)	90	<50 RMS	#37-282	€180,00 Qty 6+ €161,50	Contact Us
6.35	6.35	Enhanced Aluminum (250- 700nm)	90	<50 RMS	#37-288	€198,00 Qty 6+ €178,00	Contact Us
6.35	12.70	Protected Aluminum (400- 2000nm)	90	<50 RMS	#37-283	€180,00 Qty 6+ €161,50	3-4 days
6.35	12.70	Enhanced Aluminum (250- 700nm)	90	<50 RMS	#37-289	€198,00 Qty 6+ €178,00	Contact Us
6.35	25.40	Protected Aluminum (400- 2000nm)	90	<50 RMS	#37-284	€180,00 Qty 6+ €161,50	In Stock
6.35	25.40	Enhanced Aluminum (250- 700nm)	90	<50 RMS	#37-290	€198,00 Qty 6+ €178,00	3-4 days
6.35	50.80	Protected Aluminum (400- 2000nm)	90	<50 RMS	#37-285	€180,00 Qty 6+ €161,50	3-4 days
6.35	50.80	Enhanced Aluminum (250- 700nm)	90	<50 RMS	#37-291	€198,00 Qty 6+ €178,00	3-4 days

[#37-292 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

6.35	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS		€139,00	3-4 days
6.35	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-287	€180,00 Qty 6+ €161,50	3-4 days
6.35	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-293	€198,00 Qty 6+ €178,00	3-4 days
12.70	12.70	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-258	€192,00 Qty 6+ €173,00	3-4 days
12.70	12.70	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-264	€208,00 Qty 6+ €187,00	3-4 days
12.70	12.70	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-481	€187,00 Qty 6+ €168,50	3-4 days
12.70	25.40	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-259	€192,00 Qty 6+ €173,00	3-4 days
12.70	25.40	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-265	€208,00 Qty 6+ €187,00	In Stock

12.70	25.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-482	€187,00 Qty 6+ €168,50	3-4 days
12.70	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-260	€192,00 Qty 6+ €173,00	3-4 days
12.70	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-266	€208,00 Qty 6+ €187,00	3-4 days
12.70	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-483	€187,00 Qty 6+ €168,50	3-4 days
12.70	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-261	€192,00 Qty 6+ €173,00	3-4 days
12.70	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-267	€208,00 Qty 6+ €187,00	3-4 days
12.70	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-262	€192,00 Qty 6+ €173,00	3-4 days
12.70	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-268	€208,00 Qty 6+ €187,00	3-4 days
12.70	203.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-263	€192,00 Qty 6+ €173,00	3-4 days
12.70	203.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-269	€208,00 Qty 6+ €187,00	3-4 days
25.40	25.40	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-406	€239,00 Qty 6+ €215,50	3-4 days
25.40	25.40	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-232	€250,00 Qty 6+ €224,50	3-4 days

25.40	25.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-500	€192,00 Qty 6+ €173,00	In Stock
25.40	27.22	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-514	€317,00 Qty 6+ €285,50	3-4 days
25.40	33.85	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-496	€229,00 Qty 6+ €206,00	3-4 days
25.40	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-407	€239,00 Qty 6+ €215,50	3-4 days
25.40	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-233	€250,00 Qty 6+ €224,50	3-4 days
25.40	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-502	€192,00 Qty 6+ €173,00	In Stock
25.40	50.80	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-498	€192,00 Qty 6+ €173,00	3-4 days
25.40	54.45	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-490	€250,00 Qty 6+ €224,50	3-4 days
25.40	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-226	€239,00 Qty 6+ €215,50	In Stock
25.40	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-234	€250,00 Qty 6+ €224,50	In Stock
25.40	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-517	€192,00 Qty 6+ €173,00	Contact Us
25.40	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-408	€239,00 Qty 6+ €215,50	3-4 days

25.40	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-235	€250,00 Qty 6+ €224,50	Contact Us
25.40	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-504	€192,00 Qty 6+ €173,00	In Stock
#37-227 Clearance							
× Clearance Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.							
25.40	127.00	Protected Aluminum (400-2000nm)	90	<50 RMS		€307,00 Qty 6+ €276,00	3-4 days
25.40	127.00	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-563	€317,00 Qty 6+ €285,50	3-4 days
25.40	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-518	€192,00 Qty 6+ €173,00	Contact Us

[#37-229 Clearance](#)



Clearance

Availability is limited, so buy before these products disappear. Sorry, we cannot accept returns. Receive up to 80% off select products.

25.40	177.80	Protected Aluminum (400-2000nm)	90	<50 RMS		€292,00	3-4 days
-------	--------	---------------------------------	----	---------	--	---------	----------

25.40	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#34-520	€421,00 Qty 6+ €379,00	3-4 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	----------

25.40	203.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-230	€239,00 Qty 6+ €215,50	Contact Us
-------	--------	---------------------------------	----	---------	-------------------------	---------------------------	------------

25.40	203.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-239	€250,00 Qty 6+ €224,50	Contact Us
-------	--------	-------------------------------	----	---------	-------------------------	---------------------------	------------

25.40	203.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-590	€192,00 Qty 6+ €173,00	In Stock
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	----------

25.40	272.24	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-606	€590,00 Qty 6+ €529,00	3-4 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	----------

25.40	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-538	€255,00 Qty 6+ €229,50	3-4 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	----------

25.40	646.00	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-540	€255,00 Qty 6+ €229,50	3-4 days
-------	--------	---------------------------------	----	----------	-------------------------	---------------------------	----------

50.80	50.80	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-306	€468,00 Qty 6+ €421,00	3-4 days
50.80	50.80	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-409	€437,00 Qty 6+ €393,00	3-4 days
50.80	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-506	€421,00 Qty 6+ €379,00	In Stock
50.80	54.45	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-492	€452,00 Qty 6+ €407,00	Contact Us
50.80	59.51	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-550	€442,00 Qty 6+ €398,00	Contact Us
50.80	76.20	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-984	€437,00 Qty 6+ €393,00	In Stock
50.80	76.20	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-993	€468,00 Qty 6+ €421,00	3-4 days
50.80	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-508	€421,00 Qty 6+ €379,00	3-4 days
50.80	81.79	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-607	€452,00 Qty 6+ €407,00	In Stock
50.80	89.28	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-552	€442,00 Qty 6+ €398,00	3-4 days
50.80	101.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#87-410	€437,00 Qty 6+ €393,00	3-4 days
50.80	101.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-307	€468,00 Qty 6+ €421,00	Contact Us

50.80	101.60	Protected Aluminum (400-2000nm)	60	<100 RMS	#35-516	€473,00 Qty 6+ €426,00	3-4 days
50.80	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-510	€421,00 Qty 6+ €379,00	3-4 days
50.80	108.89	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-494	€452,00 Qty 6+ €407,00	In Stock
50.80	136.12	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-609	€499,00 Qty 6+ €449,50	3-4 days
50.80	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-512	€421,00 Qty 6+ €379,00	3-4 days
50.80	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-519	€421,00 Qty 6+ €379,00	3-4 days
50.80	190.50	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-520	€421,00 Qty 6+ €379,00	3-4 days
50.80	190.60	Protected Aluminum (400-2000nm)	90	<50 RMS	#37-988	€437,00 Qty 6+ €393,00	3-4 days
50.80	190.60	Enhanced Aluminum (250-700nm)	90	<50 RMS	#37-996	€468,00 Qty 6+ €421,00	In Stock
50.80	272.24	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-610	€452,00 Qty 6+ €407,00	In Stock
50.80	310.08	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-542	€359,00 Qty 6+ €323,00	3-4 days
50.80	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-594	€359,00 Qty 6+ €323,00	3-4 days

50.80	516.81	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-544	€359,00 Qty 6+ €323,00	3-4 days
76.20	50.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-521	€905,00 Qty 6+ €814,50	3-4 days
76.20	76.20	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-522	€735,00 Qty 6+ €660,00	3-4 days
76.20	89.28	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-586	€850,00 Qty 6+ €763,00	In Stock
76.20	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-565	€735,00 Qty 6+ €660,00	3-4 days
76.20	127.00	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-523	€705,00 Qty 6+ €636,50	3-4 days
76.20	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-524	€705,00 Qty 6+ €636,50	3-4 days
76.20	177.80	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-564	€705,00 Qty 6+ €636,50	3-4 days
76.20	178.53	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-588	€735,00 Qty 6+ €660,00	3-4 days
76.20	272.23	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-580	€765,00 Qty 6+ €688,00	Contact Us
76.20	646.00	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-597	€765,00 Qty 6+ €688,00	3-4 days
101.60	101.60	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-566	€960,00 Qty 6+ €866,00	3-4 days

101.60	119.03	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-628	€905,00 Qty 6+ €814,50	Contact Us
101.60	152.40	Protected Aluminum (400-2000nm)	90	<100 RMS	#35-592	€960,00 Qty 6+ €866,00	Contact Us
101.60	178.55	Protected Aluminum (400-2000nm)	45	<100 RMS	#35-629	€905,00 Qty 6+ €814,50	3-4 days
101.60	326.69	Protected Aluminum (400-2000nm)	30	<100 RMS	#35-584	€960,00 Qty 6+ €866,00	3-4 days
101.60	387.60	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-574	€905,00 Qty 6+ €814,50	3-4 days
101.60	516.81	Protected Aluminum (400-2000nm)	15	<100 RMS	#35-576	€905,00 Qty 6+ €814,50	In Stock



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com