


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Standard Plano-Convex \(PCX\) Lenses](#)

Micro Plano-Convex (PCX) Lenses

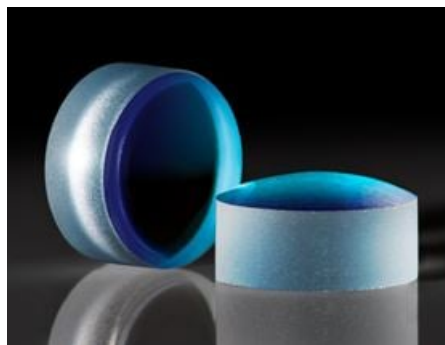

- Diameters as Small as 1mm
- Short Focal Lengths for Integration into Compact Devices
- Broadband Antireflection Coating Options Available

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective as needed

Optical Properties

Focal Length Tolerance (%):

± 1

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
1.00	0.60	0.17	NIR I (600-1050nm)	N-LASF9	#45-951	€82,40 Volume Pricing	Contact Us
1.00	0.60	0.17	Uncoated	N-LASF9	#45-588	€68,50 Volume Pricing	11 In Stock
1.00	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-952	€82,40 Volume Pricing	5 In Stock
1.00	1.00	0.57	Uncoated	N-LASF9	#45-589	€68,50 Volume Pricing	20+ In Stock
1.00	0.60	0.17	MgF ₂ (400-700nm)	N-LASF9	#65-257	€74,68 Volume Pricing	6 In Stock
1.00	0.60	0.17	NIR II (750-1550nm)	N-LASF9	#67-423	€82,40 Volume Pricing	Contact Us
1.00	0.60	0.17	VIS 0° (425-675nm)	N-LASF9	#65-273	€82,40 Volume Pricing	5 In Stock
1.00	0.60	0.17	VIS-EXT (350-700nm)	N-LASF9	#35-694	€83,95 Volume Pricing	5 In Stock
1.00	0.60	0.17	VIS-NIR (400-1000nm)	N-LASF9	#65-289	€83,95 Volume Pricing	5 In Stock
1.00	0.60	0.17	YAG-BBAR (500-1100nm)	N-LASF9	#35-710	€83,95 Volume Pricing	3 In Stock
1.00	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-258	€74,68 Volume Pricing	16 In Stock
1.00	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-424	€82,40 Volume Pricing	2 In Stock
1.00	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-274	€82,40 Volume Pricing	Contact Us
1.00	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-695	€83,95 Volume Pricing	14 In Stock
1.00	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-290	€83,95 Volume Pricing	5 In Stock
1.00	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-711	€83,95 Volume Pricing	Contact Us

1.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-259	€74,68 Volume Pricing	Contact Us
1.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#65-305	€82,40 Volume Pricing	Contact Us
1.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-425	€82,40 Volume Pricing	7 In Stock
1.00	1.50	1.07	Uncoated	N-LASF9	#65-252	€68,50 Volume Pricing	20+ In Stock
1.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-275	€82,40 Volume Pricing	3 In Stock
1.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-696	€83,95 Volume Pricing	7 In Stock
1.00	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-291	€83,95 Volume Pricing	Contact Us
1.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-712	€83,95 Volume Pricing	11 In Stock
1.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-260	€74,68 Volume Pricing	1 In Stock
1.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-306	€82,40 Volume Pricing	7 In Stock
1.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-426	€82,40 Volume Pricing	20+ In Stock
1.00	2.00	1.57	Uncoated	N-LASF9	#65-253	€68,50 Volume Pricing	5 In Stock
1.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-276	€82,40 Volume Pricing	Contact Us
1.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-697	€83,95 Volume Pricing	11 In Stock
1.00	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-292	€83,95 Volume Pricing	6 In Stock
1.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-713	€83,95 Volume Pricing	5 In Stock
1.50	1.00	0.57	NIR I (600-1050nm)	N-LASF9	#45-953	€82,40 Volume Pricing	8 In Stock
1.50	1.00	0.57	Uncoated	N-LASF9	#43-394	€68,50 Volume Pricing	20+ In Stock
1.50	1.00	0.57	MgF ₂ (400-700nm)	N-LASF9	#65-261	€74,68 Volume Pricing	2 In Stock

1.50	1.00	0.57	NIR II (750-1550nm)	N-LASF9	#67-427	€82,40 Volume Pricing	20+ In Stock
1.50	1.00	0.57	VIS 0° (425-675nm)	N-LASF9	#65-277	€82,40 Volume Pricing	14 In Stock
1.50	1.00	0.57	VIS-EXT (350-700nm)	N-LASF9	#35-698	€83,95 Volume Pricing	Contact Us
1.50	1.00	0.57	VIS-NIR (400-1000nm)	N-LASF9	#65-293	€83,95 Volume Pricing	5 In Stock
1.50	1.00	0.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-714	€83,95 Volume Pricing	9 In Stock
1.50	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-262	€74,68 Volume Pricing	1 In Stock
1.50	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-428	€82,40 Volume Pricing	9 In Stock
1.50	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-954	€82,40 Volume Pricing	20+ In Stock
1.50	1.50	1.07	Uncoated	N-LASF9	#43-395	€68,50 Volume Pricing	4 In Stock
1.50	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-278	€82,40 Volume Pricing	6 In Stock
1.50	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-699	€83,95 Volume Pricing	Contact Us
1.50	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-294	€83,95 Volume Pricing	12 In Stock
1.50	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-715	€83,95 Volume Pricing	4 In Stock
1.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-263	€74,68 Volume Pricing	14 In Stock
1.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#65-307	€82,40 Volume Pricing	5 In Stock
1.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-429	€82,40 Volume Pricing	9 In Stock
1.50	2.00	1.57	Uncoated	N-LASF9	#65-254	€68,50 Volume Pricing	20+ In Stock
1.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-279	€82,40 Volume Pricing	14 In Stock
1.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-700	€83,95 Volume Pricing	10 In Stock

1.50	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-295	€83,95 Volume Pricing	17 In Stock
1.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-716	€83,95 Volume Pricing	5 In Stock
2.00	1.50	1.07	NIR I (600-1050nm)	N-LASF9	#45-955	€81,37 Volume Pricing	10 In Stock
2.00	1.50	1.07	Uncoated	N-LASF9	#43-396	€67,47 Volume Pricing	20+ In Stock
2.00	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-956	€81,37 Volume Pricing	9 In Stock
2.00	2.00	1.57	Uncoated	N-LASF9	#43-397	€67,47 Volume Pricing	20+ In Stock
2.00	1.50	1.07	MgF ₂ (400-700nm)	N-LASF9	#65-264	€73,65 Volume Pricing	6 In Stock
2.00	1.50	1.07	NIR II (750-1550nm)	N-LASF9	#67-430	€81,37 Volume Pricing	20+ In Stock
2.00	1.50	1.07	VIS 0° (425-675nm)	N-LASF9	#65-280	€81,37 Volume Pricing	5 In Stock
2.00	1.50	1.07	VIS-EXT (350-700nm)	N-LASF9	#35-701	€82,92 Volume Pricing	20+ In Stock
2.00	1.50	1.07	VIS-NIR (400-1000nm)	N-LASF9	#65-296	€82,92 Volume Pricing	20+ In Stock
2.00	1.50	1.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-717	€82,92 Volume Pricing	4 In Stock
2.00	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-265	€73,65 Volume Pricing	9 In Stock
2.00	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-431	€81,37 Volume Pricing	10 In Stock
2.00	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-281	€81,37 Volume Pricing	Contact Us
2.00	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-702	€82,92 Volume Pricing	20+ In Stock
2.00	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-297	€82,92 Volume Pricing	20+ In Stock
2.00	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-718	€82,92 Volume Pricing	3 In Stock
2.00	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-266	€73,65 Volume Pricing	2 In Stock

2.00	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#65-308	€81,37 Volume Pricing	20+ In Stock
2.00	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-432	€81,37 Volume Pricing	14 In Stock
2.00	3.00	2.57	Uncoated	N-LASF9	#65-255	€67,47 Volume Pricing	20+ In Stock
2.00	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-282	€81,37 Volume Pricing	14 In Stock
2.00	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-703	€82,92 Volume Pricing	20+ In Stock
2.00	3.00	2.57	VIS-NIR (400-1000nm)	N-LASF9	#65-298	€82,92 Volume Pricing	5 In Stock
2.00	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-719	€82,92 Volume Pricing	3 In Stock
2.00	4.00	3.57	MgF ₂ (400-700nm)	N-LASF9	#65-267	€73,65 Volume Pricing	8 In Stock
2.00	4.00	3.57	NIR I (600-1050nm)	N-LASF9	#65-309	€81,37 Volume Pricing	7 In Stock
2.00	4.00	3.57	NIR II (750-1550nm)	N-LASF9	#67-433	€81,37 Volume Pricing	12 In Stock
2.00	4.00	3.57	Uncoated	N-LASF9	#65-256	€67,47 Volume Pricing	20+ In Stock
2.00	4.00	3.57	VIS 0° (425-675nm)	N-LASF9	#65-283	€81,37 Volume Pricing	8 In Stock
2.00	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-704	€82,92 Volume Pricing	10 In Stock
2.00	4.00	3.57	VIS-NIR (400-1000nm)	N-LASF9	#65-299	€82,92 Volume Pricing	4 In Stock
2.00	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-720	€82,92 Volume Pricing	10 In Stock
2.50	2.00	1.57	NIR I (600-1050nm)	N-LASF9	#45-957	€81,37 Volume Pricing	20+ In Stock
2.50	2.00	1.57	Uncoated	N-LASF9	#43-398	€67,47 Volume Pricing	20+ In Stock
2.50	2.00	1.57	MgF ₂ (400-700nm)	N-LASF9	#65-268	€73,65 Volume Pricing	6 In Stock
2.50	2.00	1.57	NIR II (750-1550nm)	N-LASF9	#67-434	€81,37 Volume Pricing	20+ In Stock

2.50	2.00	1.57	VIS 0° (425-675nm)	N-LASF9	#65-284	€81,37 Volume Pricing	17 In Stock
2.50	2.00	1.57	VIS-EXT (350-700nm)	N-LASF9	#35-705	€82,92 Volume Pricing	4 In Stock
2.50	2.00	1.57	VIS-NIR (400-1000nm)	N-LASF9	#65-300	€82,92 Volume Pricing	2 In Stock
2.50	2.00	1.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-721	€82,92 Volume Pricing	5 In Stock
2.50	2.50	2.05	MgF ₂ (400-700nm)	N-LASF9	#65-269	€73,65 Volume Pricing	7 In Stock
2.50	2.50	2.07	NIR II (750-1550nm)	N-LASF9	#67-435	€81,37 Volume Pricing	7 In Stock
2.50	2.50	2.07	NIR I (600-1050nm)	N-LASF9	#45-958	€81,37 Volume Pricing	9 In Stock
2.50	2.50	2.07	Uncoated	N-LASF9	#43-399	€67,47 Volume Pricing	20+ In Stock
2.50	2.50	2.05	VIS 0° (425-675nm)	N-LASF9	#65-285	€81,37 Volume Pricing	3 In Stock
2.50	2.50	2.07	VIS-EXT (350-700nm)	N-LASF9	#35-706	€82,92 Volume Pricing	Contact Us
2.50	2.50	2.05	VIS-NIR (400-1000nm)	N-LASF9	#65-301	€82,92 Volume Pricing	10 In Stock
2.50	2.50	2.07	YAG-BBAR (500-1100nm)	N-LASF9	#35-722	€82,92 Volume Pricing	Contact Us
2.50	3.00	2.57	Uncoated	N-LASF9	#45-590	€67,47 Volume Pricing	20+ In Stock
2.50	3.00	2.57	MgF ₂ (400-700nm)	N-LASF9	#65-270	€73,65 Volume Pricing	7 In Stock
2.50	3.00	2.57	NIR I (600-1050nm)	N-LASF9	#45-959	€81,37 Volume Pricing	9 In Stock
2.50	3.00	2.57	NIR II (750-1550nm)	N-LASF9	#67-436	€81,37 Volume Pricing	4 In Stock
2.50	3.00	2.57	VIS 0° (425-675nm)	N-LASF9	#65-286	€81,37 Volume Pricing	20+ In Stock
2.50	3.00	2.57	VIS-EXT (350-700nm)	N-LASF9	#35-707	€82,92 Volume Pricing	13 In Stock
2.50	3.00	2.57	VIS-NIR (400-1000nm)	N-LASF9	#65-302	€82,92 Volume Pricing	20+ In Stock

2.50	3.00	2.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-723	€82,92 Volume Pricing	20+ In Stock
2.50	4.00	3.57	MgF ₂ (400- 700nm)	N-LASF9	#65-271	€73,65 Volume Pricing	5 In Stock
2.50	4.00	3.57	NIR I (600- 1050nm)	N-LASF9	#48-646	€81,37 Volume Pricing	4 In Stock
2.50	4.00	3.57	NIR II (750- 1550nm)	N-LASF9	#67-437	€81,37 Volume Pricing	Contact Us
2.50	4.00	3.57	Uncoated	N-LASF9	#48-643	€67,47 Volume Pricing	20+ In Stock
2.50	4.00	3.57	VIS 0° (425- 675nm)	N-LASF9	#65-287	€81,37 Volume Pricing	5 In Stock
2.50	4.00	3.57	VIS-EXT (350-700nm)	N-LASF9	#35-708	€82,92 Volume Pricing	14 In Stock
2.50	4.00	3.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-303	€82,92 Volume Pricing	10 In Stock
2.50	4.00	3.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-724	€82,92 Volume Pricing	10 In Stock
2.50	5.00	4.57	MgF ₂ (400- 700nm)	N-LASF9	#65-272	€73,65 Volume Pricing	5 In Stock
2.50	5.00	4.57	NIR I (600- 1050nm)	N-LASF9	#48-647	€81,37 Volume Pricing	20+ In Stock
2.50	5.00	4.57	NIR II (750- 1550nm)	N-LASF9	#67-438	€81,37 Volume Pricing	5 In Stock
2.50	5.00	4.57	Uncoated	N-LASF9	#48-644	€67,47 Volume Pricing	11 In Stock
2.50	5.00	4.57	VIS 0° (425- 675nm)	N-LASF9	#65-288	€81,37 Volume Pricing	20+ In Stock
2.50	5.00	4.57	VIS-EXT (350-700nm)	N-LASF9	#35-709	€82,92 Volume Pricing	3 In Stock
2.50	5.00	4.57	VIS-NIR (400- 1000nm)	N-LASF9	#65-304	€82,92 Volume Pricing	13 In Stock
2.50	5.00	4.57	YAG-BBAR (500-1100nm)	N-LASF9	#35-725	€82,92 Volume Pricing	3 In Stock
3.00	3.00	1.88	VIS-EXT (350-700nm)	N-SF11	#88-615	€71,07 Volume Pricing	Contact Us
3.00	3.00	1.88	YAG-BBAR (500-1100nm)	N-SF11	#88-774	€71,07 Volume Pricing	16 In Stock

3.00	12.00	11.29	MgF ₂ (400-700nm)	N-BK7	#45-273	€55,62 Volume Pricing	14 In Stock
3.00	12.00	11.29	NIR I (600-1050nm)	N-BK7	#45-964	€63,35 Volume Pricing	4 In Stock
3.00	12.00	11.29	Uncoated	N-BK7	#45-272	€49,44 Volume Pricing	20+ In Stock
3.00	12.00	11.29	VIS 0° (425-675nm)	N-BK7	#49-172	€63,35 Volume Pricing	11 In Stock
3.00	12.00	11.29	VIS-EXT (350-700nm)	N-BK7	#88-620	€65,92 Volume Pricing	12 In Stock
3.00	12.00	11.29	VIS-NIR (400-1000nm)	N-BK7	#49-179	€65,92 Volume Pricing	10 In Stock
3.00	12.00	11.29	YAG-BBAR (500-1100nm)	N-BK7	#88-779	€65,92 Volume Pricing	8 In Stock
3.00	15.00	14.17	MgF ₂ (400-700nm)	N-BK7	#45-426	€55,62 Volume Pricing	12 In Stock
3.00	15.00	14.22	NIR I (600-1050nm)	N-BK7	#45-965	€63,35 Volume Pricing	20+ In Stock
3.00	15.00	14.22	Uncoated	N-BK7	#45-425	€49,44 Volume Pricing	20+ In Stock
3.00	15.00	14.17	VIS 0° (425-675nm)	N-BK7	#49-173	€63,35 Volume Pricing	10 In Stock
3.00	15.00	14.22	VIS-EXT (350-700nm)	N-BK7	#88-621	€65,92 Volume Pricing	Contact Us
3.00	15.00	14.17	VIS-NIR (400-1000nm)	N-BK7	#49-180	€65,92 Volume Pricing	5 In Stock
3.00	15.00	14.22	YAG-BBAR (500-1100nm)	N-BK7	#88-780	€65,92 Volume Pricing	17 In Stock
3.00	3.00	1.88	MgF ₂ (400-700nm)	N-SF11	#45-118	€60,77 Volume Pricing	20+ In Stock
3.00	3.00	1.88	NIR I (600-1050nm)	N-SF11	#45-960	€68,50 Volume Pricing	11 In Stock
3.00	3.00	1.88	Uncoated	N-SF11	#45-117	€54,59 Volume Pricing	20+ In Stock
3.00	3.00	1.88	VIS 0° (425-675nm)	N-SF11	#49-167	€68,50 Volume Pricing	20+ In Stock
3.00	3.00	1.88	VIS-NIR (400-1000nm)	N-SF11	#49-174	€71,07 Volume Pricing	7 In Stock

3.00	4.50	3.50	MgF ₂ (400-700nm)	N-LASF44	#45-142	€60,77 Volume Pricing	Contact Us
3.00	4.50	3.50	NIR I (600-1050nm)	N-LASF44	#45-961	€68,50 Volume Pricing	14 In Stock
3.00	4.50	3.50	Uncoated	N-LASF44	#45-141	€54,59 Volume Pricing	20+ In Stock
3.00	4.50	3.50	VIS 0° (425-675nm)	N-LASF44	#49-168	€68,50 Volume Pricing	4 In Stock
3.00	4.50	3.50	VIS-NIR (400-1000nm)	N-LASF44	#49-175	€71,07 Volume Pricing	20+ In Stock
3.00	6.00	4.81	MgF ₂ (400-700nm)	N-BK7	#32-953	€55,62 Volume Pricing	20+ In Stock
3.00	6.00	4.81	NIR I (600-1050nm)	N-BK7	#45-962	€63,35 Volume Pricing	20+ In Stock
3.00	6.00	4.81	Uncoated	N-BK7	#32-952	€49,44 Volume Pricing	20+ In Stock
3.00	6.00	4.81	VIS 0° (425-675nm)	N-BK7	#49-169	€63,35 Volume Pricing	20+ In Stock
3.00	6.00	4.81	VIS-EXT (350-700nm)	N-BK7	#88-617	€65,92 Volume Pricing	10 In Stock
3.00	6.00	4.81	VIS-NIR (400-1000nm)	N-BK7	#49-176	€65,92 Volume Pricing	5 In Stock
3.00	6.00	4.81	YAG-BBAR (500-1100nm)	N-BK7	#88-776	€65,92 Volume Pricing	20+ In Stock
3.00	7.50	6.51	Uncoated	N-BK7	#48-645	€49,44 Volume Pricing	20+ In Stock
3.00	7.50	6.51	VIS 0° (425-675nm)	N-BK7	#49-170	€63,35 Volume Pricing	5 In Stock
3.00	7.50	6.51	VIS-EXT (350-700nm)	N-BK7	#88-618	€65,92 Volume Pricing	Contact Us
3.00	7.50	6.51	VIS-NIR (400-1000nm)	N-BK7	#49-177	€65,92 Volume Pricing	20+ In Stock
3.00	7.50	6.51	YAG-BBAR (500-1100nm)	N-BK7	#88-777	€65,92 Volume Pricing	20+ In Stock
3.00	9.00	8.01	MgF ₂ (400-700nm)	N-BK7	#32-955	€55,62 Volume Pricing	10 In Stock
3.00	9.00	8.01	NIR I (600-1050nm)	N-BK7	#45-963	€63,35 Volume Pricing	14 In Stock

3.00	9.00	8.01	Uncoated	N-BK7	#32-954	€49,44 Volume Pricing	20+ In Stock
3.00	9.00	8.01	VIS 0° (425-675nm)	N-BK7	#49-171	€63,35 Volume Pricing	14 In Stock
3.00	9.00	8.01	VIS-EXT (350-700nm)	N-BK7	#88-619	€65,92 Volume Pricing	2 In Stock
3.00	9.00	8.01	VIS-NIR (400-1000nm)	N-BK7	#49-178	€65,92 Volume Pricing	20+ In Stock
3.00	9.00	8.01	YAG-BBAR (500-1100nm)	N-BK7	#88-778	€65,92 Volume Pricing	6 In Stock
3.00	12.00	11.29	NIR II (750-1550nm)	N-BK7	#67-444	€63,35 Volume Pricing	10 In Stock
3.00	15.00	14.22	NIR II (750-1550nm)	N-BK7	#67-445	€63,35 Volume Pricing	1 In Stock
3.00	3.00	1.88	NIR II (750-1550nm)	N-SF11	#67-439	€68,50 Volume Pricing	13 In Stock
3.00	4.50	3.50	NIR II (750-1550nm)	N-LASF44	#67-440	€68,50 Volume Pricing	20+ In Stock
3.00	4.50	3.50	VIS-EXT (350-700nm)	N-LASF44	#88-616	€71,07 Volume Pricing	20+ In Stock
3.00	4.50	3.5	YAG-BBAR (500-1100nm)	N-LASF44	#88-775	€71,07 Volume Pricing	15 In Stock
3.00	6.00	4.81	NIR II (750-1550nm)	N-BK7	#67-441	€63,35 Volume Pricing	20+ In Stock
3.00	7.50	6.51	MgF ₂ (400-700nm)	N-BK7	#48-910	€55,62 Volume Pricing	5 In Stock
3.00	7.50	6.51	NIR I (600-1050nm)	N-BK7	#48-648	€63,35 Volume Pricing	20+ In Stock
3.00	7.50	6.51	NIR II (750-1550nm)	N-BK7	#67-442	€63,35 Volume Pricing	15 In Stock
3.00	9.00	8.01	NIR II (750-1550nm)	N-BK7	#67-443	€63,35 Volume Pricing	4 In Stock
4.00	10.00	8.92	MgF ₂ (400-700nm)	N-BK7	#45-430	€51,24 Volume Pricing	Contact Us
4.00	10.00	8.92	NIR I (600-1050nm)	N-BK7	#48-705	€61,80 Volume Pricing	20+ In Stock
4.00	10.00	8.92	Uncoated	N-BK7	#45-429	€45,06 Volume Pricing	20+ In Stock

4.00	10.00	8.92	VIS 0° (425-675nm)	N-BK7	#47-864	€61,80 Volume Pricing	5 In Stock
4.00	10.00	8.92	VIS-EXT (350-700nm)	N-BK7	#88-625	€66,95 Volume Pricing	17 In Stock
4.00	10.00	8.92	VIS-NIR (400-1000nm)	N-BK7	#47-853	€66,95 Volume Pricing	20+ In Stock
4.00	10.00	8.92	YAG-BBAR (500-1100nm)	N-BK7	#88-784	€66,95 Volume Pricing	7 In Stock
4.00	12.00	11.00	MgF ₂ (400-700nm)	N-BK7	#45-432	€51,24 Volume Pricing	20+ In Stock
4.00	12.00	11.00	NIR I (600-1050nm)	N-BK7	#48-706	€61,80 Volume Pricing	3 In Stock
4.00	12.00	11.00	Uncoated	N-BK7	#45-431	€45,06 Volume Pricing	14 In Stock
4.00	12.00	11.00	VIS 0° (425-675nm)	N-BK7	#47-865	€61,80 Volume Pricing	11 In Stock
4.00	12.00	11.00	VIS-EXT (350-700nm)	N-BK7	#88-626	€66,95 Volume Pricing	3 In Stock
4.00	12.00	11.00	VIS-NIR (400-1000nm)	N-BK7	#47-854	€66,95 Volume Pricing	Contact Us
4.00	12.00	11.00	YAG-BBAR (500-1100nm)	N-BK7	#88-785	€66,95 Volume Pricing	10 In Stock
4.00	4.00	3.06	MgF ₂ (400-700nm)	N-LASF44	#45-224	€55,62 Volume Pricing	20+ In Stock
4.00	4.00	3.06	NIR I (600-1050nm)	N-LASF44	#48-702	€65,92 Volume Pricing	20+ In Stock
4.00	4.00	3.06	Uncoated	N-LASF44	#45-223	€49,44 Volume Pricing	20+ In Stock
4.00	4.00	3.06	VIS 0° (425-675nm)	N-LASF44	#47-861	€65,92 Volume Pricing	20+ In Stock
4.00	4.00	3.06	VIS-NIR (400-1000nm)	N-LASF44	#47-850	€71,07 Volume Pricing	8 In Stock
4.00	6.00	4.51	MgF ₂ (400-700nm)	N-BK7	#45-428	€55,62 Volume Pricing	20+ In Stock
4.00	6.00	4.51	NIR I (600-1050nm)	N-BK7	#48-703	€65,92 Volume Pricing	14 In Stock
4.00	6.00	4.51	Uncoated	N-BK7	#45-427	€49,44 Volume Pricing	20+ In Stock

4.00	6.00	4.51	VIS 0° (425-675nm)	N-BK7	#47-862	€65,92 Volume Pricing	6 In Stock
4.00	6.00	4.51	VIS-EXT (350-700nm)	N-BK7	#88-623	€71,07 Volume Pricing	14 In Stock
4.00	6.00	4.51	VIS-NIR (400-1000nm)	N-BK7	#47-851	€71,07 Volume Pricing	20+ In Stock
4.00	6.00	4.51	YAG-BBAR (500-1100nm)	N-BK7	#88-782	€71,07 Volume Pricing	1 In Stock
4.00	8.00	7.17	MgF ₂ (400-700nm)	N-BAF10	#45-226	€51,24 Volume Pricing	14 In Stock
4.00	8.00	7.17	NIR I (600-1050nm)	N-BAF10	#48-704	€61,80 Volume Pricing	10 In Stock
4.00	8.00	7.17	Uncoated	N-BAF10	#45-225	€45,06 Volume Pricing	20+ In Stock
4.00	8.00	7.17	VIS 0° (425-675nm)	N-BAF10	#47-863	€61,80 Volume Pricing	11 In Stock
4.00	8.00	7.17	VIS-NIR (400-1000nm)	N-BAF10	#47-852	€66,95 Volume Pricing	Contact Us
4.00	10.00	8.96	NIR II (750-1550nm)	N-BK7	#67-449	€61,80 Volume Pricing	16 In Stock
4.00	12.00	11	NIR II (750-1550nm)	N-BK7	#67-450	€61,80 Volume Pricing	1 In Stock
4.00	4.00	3.06	NIR II (750-1550nm)	N-LASF44	#67-446	€65,92 Volume Pricing	12 In Stock
4.00	4.00	3.06	VIS-EXT (350-700nm)	N-LASF44	#88-622	€71,07 Volume Pricing	20+ In Stock
4.00	4.00	3.06	YAG-BBAR (500-1100nm)	N-LASF44	#88-781	€71,07 Volume Pricing	20+ In Stock
4.00	6.00	4.51	NIR II (750-1550nm)	N-BK7	#67-447	€65,92 Volume Pricing	20+ In Stock
4.00	8.00	7.17	NIR II (750-1550nm)	N-BAF10	#67-448	€61,80 Volume Pricing	13 In Stock
4.50	4.50	3.05	MgF ₂ (400-700nm)	N-LASF44	#45-144	€55,62 Volume Pricing	9 In Stock
4.50	4.50	3.05	NIR I (600-1050nm)	N-LASF44	#48-707	€65,92 Volume Pricing	20+ In Stock
4.50	4.50	3.05	NIR II (750-1550nm)	N-LASF44	#67-451	€65,92 Volume Pricing	17 In Stock

4.50	4.50	3.05	Uncoated	N-LASF44	#45-143	€49,44 Volume Pricing	20+ In Stock
4.50	4.50	3.05	VIS 0° (425-675nm)	N-LASF44	#47-866	€65,92 Volume Pricing	20+ In Stock
4.50	4.50	3.05	VIS-EXT (350-700nm)	N-LASF44	#88-627	€71,07 Volume Pricing	17 In Stock
4.50	4.50	3.05	VIS-NIR (400-1000nm)	N-LASF44	#47-855	€71,07 Volume Pricing	20+ In Stock
4.50	4.50	3.05	YAG-BBAR (500-1100nm)	N-LASF44	#88-786	€71,07 Volume Pricing	7 In Stock
4.50	9.00	7.41	MgF ₂ (400-700nm)	N-BK7	#45-148	€51,24 Volume Pricing	20+ In Stock
4.50	9.00	7.41	NIR I (600-1050nm)	N-BK7	#48-708	€61,80 Volume Pricing	8 In Stock
4.50	9.00	7.41	Uncoated	N-BK7	#45-147	€45,06 Volume Pricing	20+ In Stock
4.50	9.00	7.41	VIS 0° (425-675nm)	N-BK7	#47-867	€61,80 Volume Pricing	20+ In Stock
4.50	9.00	7.41	VIS-EXT (350-700nm)	N-BK7	#88-628	€66,95 Volume Pricing	3 In Stock
4.50	9.00	7.41	VIS-NIR (400-1000nm)	N-BK7	#47-856	€66,95 Volume Pricing	7 In Stock
4.50	9.00	7.41	YAG-BBAR (500-1100nm)	N-BK7	#88-787	€66,95 Volume Pricing	3 In Stock
4.50	9.00	7.41	NIR II (750-1550nm)	N-BK7	#67-452	€61,80 Volume Pricing	2 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands

Phone: 1-800-363-1992 :

www.edmundoptics.com