


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Aspheric Lenses](#) / [Glass Polished](#)

TECHSPEC® Near-Infrared (NIR) Aspheric Lenses

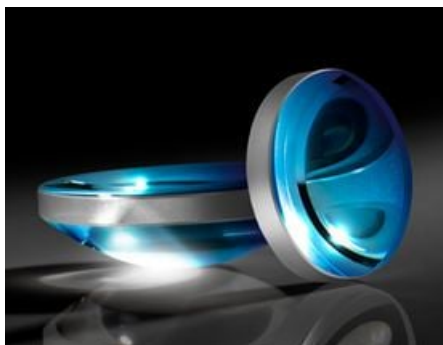

- Optimized for Applications in the NIR
- Uncoated or AR coated versions available
- Multiple Design Wavelengths Available

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Technical Information

Products

Dia. (mm)	EFL (mm)	Aspheric DWL (nm)	NA	Coating	Stock Number	Price	Buy
10.00	8.00	780	0.63	Uncoated	#13-496	€172,00 Qty 6+ €137,00	3-4 days
10.00	8.00	780	0.63	VIS+ (350-700nm)	#16-266	€192,00 Qty 6+ €154,00	3-4 days
10.00	8.00	780	0.63	NIR+ (600-1050nm)	#16-278	€192,00 Qty 6+ €154,00	3-4 days
10.00	8.00	780	0.63	SWIR+ (900-1700nm)	#16-290	€192,00 Qty 6+ €154,00	3-4 days
12.50	25.00	780	0.25	Uncoated	#13-498	€198,00 Qty 6+ €158,00	3-4 days
12.50	25.00	780	0.25	VIS+ (350-700nm)	#16-268	€218,00 Qty 6+ €175,00	3-4 days
12.50	25.00	780	0.25	NIR+ (600-1050nm)	#16-280	€218,00 Qty 6+ €175,00	3-4 days
12.50	25.00	780	0.25	SWIR+ (900-1700nm)	#16-292	€218,00 Qty 6+ €175,00	In Stock
12.50	10.00	780	0.63	Uncoated	#13-497	€198,00 Qty 6+ €158,00	3-4 days
12.50	10.00	780	0.63	VIS+ (350-700nm)	#16-267	€218,00 Qty 6+ €175,00	3-4 days
12.50	10.00	780	0.63	NIR+ (600-1050nm)	#16-279	€218,00 Qty 6+ €175,00	3-4 days
12.50	10.00	780	0.63	SWIR+ (900-1700nm)	#16-291	€218,00 Qty 6+ €175,00	3-4 days
15.00	30.00	1550	0.25	Uncoated	#17-417	€312,00 Qty 6+ €250,00	3-4 days

[#29-987 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

15.00	30.00	1550	0.25	SWIR+		€333,00 Qty 6+ €266,00	3-4 days
-------	-------	------	------	-------	--	---------------------------	----------

15.00	30.00	1550	0.25	1550nm V-Coat	#22-937	€333,00 Qty 6+ €266,00	3-4 days
-------	-------	------	------	------------------	-------------------------	---------------------------	----------

15.00	15.00	2000	0.5	Uncoated	#18-749	€600,00 Qty 6+ €478,00	3-4 days
-------	-------	------	-----	----------	-------------------------	---------------------------	----------

15.00	15.00	1550	0.5	Uncoated	#17-416	€312,00 Qty 6+ €250,00	3-4 days
-------	-------	------	-----	----------	-------------------------	---------------------------	----------

[#29-986 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

15.00	15.00	1550	0.5	SWIR+		€333,00 Qty 6+ €266,00	3-4 days
-------	-------	------	-----	-------	--	---------------------------	----------

15.00	15.00	1550	0.5	1550nm V-Coat	#22-936	€333,00 Qty 6+ €266,00	3-4 days
15.00	12.00	780	0.63	Uncoated	#13-499	€213,00 Qty 6+ €171,00	3-4 days
15.00	12.00	780	0.63	VIS+ (350- 700nm)	#16-269	€234,00 Qty 6+ €187,00	3-4 days
15.00	12.00	780	0.63	NIR+ (600- 1050nm)	#16-281	€234,00 Qty 6+ €187,00	3-4 days
15.00	12.00	780	0.63	SWIR+ (900- 1700nm)	#16-293	€234,00 Qty 6+ €187,00	3-4 days
15.00	11.25	1550	0.67	Uncoated	#17-415	€333,00 Qty 6+ €266,00	3-4 days
#29-985 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
15.00	11.25	1550	0.67	SWIR+		€354,00 Qty 6+ €283,00	3-4 days
15.00	11.25	1550	0.67	1550nm V-Coat	#22-935	€354,00 Qty 6+ €283,00	3-4 days
18.00	15.00	780	0.60	Uncoated	#13-500	€234,00 Qty 6+ €187,00	3-4 days
18.00	15.00	780	0.60	VIS+ (350- 700nm)	#16-270	€255,00 Qty 6+ €204,00	3-4 days

18.00	15.00	780	0.60	NIR+ (600-1050nm)	#16-282	€255,00 Qty 6+ €204,00	In Stock
18.00	15.00	780	0.60	SWIR+ (900-1700nm)	#16-294	€255,00 Qty 6+ €204,00	3-4 days
20.00	17.99	780	0.56	Uncoated	#13-501	€244,00 Qty 6+ €196,00	3-4 days
20.00	17.99	780	0.56	VIS+ (350-700nm)	#16-271	€265,00 Qty 6+ €212,00	3-4 days
20.00	17.99	780	0.56	NIR+ (600-1050nm)	#16-283	€265,00 Qty 6+ €212,00	3-4 days
20.00	17.99	780	0.56	SWIR+ (900-1700nm)	#16-295	€265,00 Qty 6+ €212,00	3-4 days
25.00	50.00	780	0.25	Uncoated	#13-503	€250,00 Qty 6+ €200,00	3-4 days
25.00	50.00	1550	0.25	Uncoated	#17-421	€364,00 Qty 6+ €291,00	3-4 days
25.00	50.00	780	0.25	VIS+ (350-700nm)	#16-273	€281,00 Qty 6+ €225,00	3-4 days
25.00	50.00	780	0.25	NIR+ (600-1050nm)	#16-285	€281,00 Qty 6+ €225,00	In Stock
25.00	50.00	780	0.25	SWIR+ (900-1700nm)	#16-297	€281,00 Qty 6+ €225,00	3-4 days

[#29-990 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

25.00 50.00 1550 0.25 SWIR+

€395,00
Qty 6+ €316,00

Contact Us

25.00 50.00 1550 0.25 1550nm
V-Coat

[#22-940](#)

€395,00
Qty 6+ €316,00

3-4 days

25.00 25.00 1550 0.5 Uncoated

[#17-419](#)

€364,00
Qty 6+ €291,00

3-4 days

[#29-989 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

25.00 25.00 1550 0.5 SWIR+

€395,00
Qty 6+ €316,00

3-4 days

25.00 25.00 1550 0.5 1550nm
V-Coat

[#22-939](#)

€395,00
Qty 6+ €316,00

3-4 days

25.00	20.00	780	0.63	Uncoated	#13-502	€250,00 Qty 6+ €200,00	3-4 days
25.00	20.00	780	0.63	VIS+ (350-700nm)	#16-272	€281,00 Qty 6+ €225,00	3-4 days
25.00	20.00	780	0.63	NIR+ (600-1050nm)	#16-284	€281,00 Qty 6+ €225,00	Contact Us
25.00	20.00	780	0.63	SWIR+ (900-1700nm)	#16-296	€281,00 Qty 6+ €225,00	3-4 days
25.00	15.00	1550	0.83	Uncoated	#17-418	€390,00 Qty 6+ €312,00	3-4 days
#29-988 New							
× New Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
25.00	15.00	1550	0.83	SWIR+		€421,00 Qty 6+ €337,00	Contact Us
25.00	15.00	1550	0.83	1550nm V-Coat	#22-938	€421,00 Qty 6+ €337,00	3-4 days
30.00	26.00	780	0.58	Uncoated	#13-504	€328,00 Qty 6+ €262,00	3-4 days
30.00	26.00	780	0.58	VIS+ (350-700nm)	#16-274	€359,00 Qty 6+ €287,00	3-4 days
30.00	26.00	780	0.58	NIR+ (600-1050nm)	#16-286	€359,00 Qty 6+ €287,00	3-4 days

30.00	26.00	780	0.58	SWIR+ (900-1700nm)	#16-298	€359,00 Qty 6+ €287,00	3-4 days
45.00	32.00	780	0.70	Uncoated	#13-505	€458,00 Qty 6+ €366,00	3-4 days
45.00	32.00	780	0.70	VIS+ (350-700nm)	#16-275	€494,00 Qty 6+ €395,00	3-4 days
45.00	32.00	780	0.70	NIR+ (600-1050nm)	#16-287	€494,00 Qty 6+ €395,00	3-4 days
45.00	32.00	780	0.70	SWIR+ (900-1700nm)	#16-299	€494,00 Qty 6+ €395,00	3-4 days
50.00	100.00	780	0.25	Uncoated	#13-507	€530,00 Qty 6+ €424,00	3-4 days
50.00	100.00	780	0.25	VIS+ (350-700nm)	#16-277	€580,00 Qty 6+ €466,00	3-4 days
50.00	100.00	780	0.25	NIR+ (600-1050nm)	#16-289	€580,00 Qty 6+ €466,00	3-4 days
50.00	100.00	780	0.25	SWIR+ (900-1700nm)	#16-301	€580,00 Qty 6+ €466,00	3-4 days
50.00	40.00	780	0.63	Uncoated	#13-506	€530,00 Qty 6+ €424,00	3-4 days
50.00	40.00	780	0.63	VIS+ (350-700nm)	#16-276	€580,00 Qty 6+ €466,00	3-4 days
50.00	40.00	780	0.63	NIR+ (600-1050nm)	#16-288	€580,00 Qty 6+ €466,00	3-4 days
50.00	40.00	780	0.63	SWIR+ (900-1700nm)	#16-300	€580,00 Qty 6+ €466,00	3-4 days
75.00	150.00	780	0.25	Uncoated	#13-509	€830,00 Qty 6+ €665,00	3-4 days
75.00	150.00	780	0.25	NIR+ (600-1050nm)	#28-916	€935,00 Qty 6+ €750,00	3-4 days

100.00	100.00	780	0.50	NIR+ (600-1050nm)	#28-917	€1.220,00 Qty 6+ €980,00	3-4 days
75.00	60.00	780	0.63	Uncoated	#13-508	€830,00 Qty 6+ €665,00	3-4 days
75.00	60.00	780	0.63	NIR+ (600-1050nm)	#28-915	€935,00 Qty 6+ €750,00	3-4 days
100.00	200.00	780	0.25	Uncoated	#13-511	€1.120,00 Qty 6+ €895,00	3-4 days
100.00	200.00	780	0.25	NIR+ (600-1050nm)	#28-918	€1.220,00 Qty 6+ €980,00	3-4 days
100.00	100.00	780	0.50	Uncoated	#13-510	€1.120,00 Qty 6+ €895,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK

Phone: 1-800-363-1992 :

www.edmundoptics.com