


[All Products](#) / [Optics](#) / [Optical Filters](#) / [Shortpass Filters](#)

TECHSPEC® Low GDD Dichroic Shortpass Ultrafast Filters

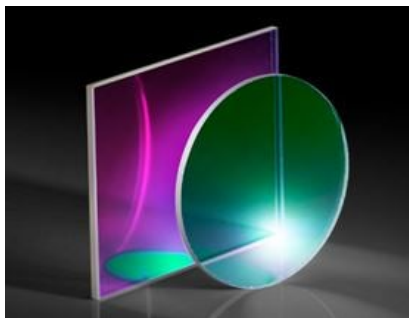

- Reduced Thickness for Limited GDD
- Broad Transmission and Reflection Ranges
- Ideal for Ultrafast Laser Applications
- Controlled GDD Specification Using [In-House Metrology](#)

Common Specifications

Physical & Mechanical Properties

Thickness (mm):	1.05 ±0.1	Dimensional Tolerance (mm):	+0.0/-0.2
Optical Properties			
Angle of Incidence (°):	45	Substrate:	Fused Silica (Corning 7980)
Coating:	Hard Coated	P-Polarization Transmission (%):	>80
Reflection (%):	>97 Average Polarization	S-Polarization Transmission (%):	>80
Surface Quality:	60-40	Transmission (%):	>85 Average Polarization
Transmitted Wavefront, RMS:	$\lambda/4$	Slope Factor (%):	3.00
Cut-Off Tolerance (%):	±2	S-Polarization Reflection (%):	>95
P-Polarization Reflection (%):	>95	Coating Specification:	Surface 1: Hard Dielectric Sputtered Surface 2: AR Coated

Technical Information

Products

Dimensions (mm)	Dia. (mm)	Cut-Off Wavelength (nm)	Transmission Wavelength (nm)	Wavelength Range (nm)	Stock Number	Price	Buy
-	25.00	450.00	325 - 430	325 - 545	#13-996	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	450.00	325 - 430	325 - 545	#14-008	€214,24 Volume Pricing	2 In Stock
-	25.00	500.00	325 - 480	325 - 610	#13-997	€193,64 Volume Pricing	Contact Us
25.2 x 35.6	-	500.00	325 - 480	325 - 610	#14-009	€214,24 Volume Pricing	1 In Stock
-	25.00	600.00	400 - 580	400 - 795	#13-999	€193,64 Volume Pricing	8 In Stock
25.2 x 35.6	-	600.00	400 - 580	400 - 795	#14-011	€214,24 Volume Pricing	1 In Stock
-	25.00	650.00	400 - 630	400 - 850	#14-001	€193,64 Volume Pricing	3 In Stock
25.2 x 35.6	-	650.00	400 - 630	400 - 850	#14-012	€214,24 Volume Pricing	Contact Us
-	25.00	700.00	400 - 680	400 - 900	#14-002	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	700.00	400 - 680	400 - 900	#14-013	€214,24 Volume Pricing	2 In Stock
-	25.00	750.00	400 - 725	400 - 990	#14-003	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	750.00	400 - 725	400 - 990	#14-014	€214,24 Volume Pricing	Contact Us
-	25.00	800.00	400 - 775	400 - 1050	#14-004	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	800.00	400 - 775	400 - 1050	#14-015	€214,24 Volume Pricing	1 In Stock
-	25.00	850.00	400 - 820	400 - 1110	#14-005	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	850.00	400 - 820	400 - 1110	#14-016	€214,24 Volume Pricing	1 In Stock
-	25.00	900.00	465 - 865	465 - 1170	#14-006	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	900.00	465 - 865	465 - 1170	#14-017	€214,24 Volume Pricing	1 In Stock
-	25.00	950.00	495 - 912	495 - 1325	#14-030	€193,64 Volume Pricing	3 In Stock

25.2 x 35.6	-	950.00	495 - 912	495 - 1235	#14-036	€214,24 Volume Pricing	1 In Stock
-	25.00	1,050.00	546 - 1008	546 - 1365	#14-032	€193,64 Volume Pricing	2 In Stock
25.2 x 35.6	-	1,050.00	546 - 1008	546 - 1365	#14-038	€214,24 Volume Pricing	2 In Stock
-	25.00	1,100.00	572 - 1056	572 - 1430	#14-033	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	1,100.00	572 - 1056	572 - 1430	#14-039	€214,24 Volume Pricing	1 In Stock
-	25.00	1,200.00	624 - 1152	624 - 1560	#14-035	€193,64 Volume Pricing	1 In Stock
25.2 x 35.6	-	1,200.00	624 - 1152	624 - 1560	#14-041	€214,24 Volume Pricing	1 In Stock



Copyright 2025 | Edmund Optics BV, De Maas 22B, 5684 PL Best, The Netherlands
Phone: 1-800-363-1992 :
www.edmundoptics.com