


[All Products](#) / [Laser Optics](#) / [Laser Mirrors](#) / [Laser Line Mirrors](#)

TECHSPEC® Nd:YAG Laser Output Couplers

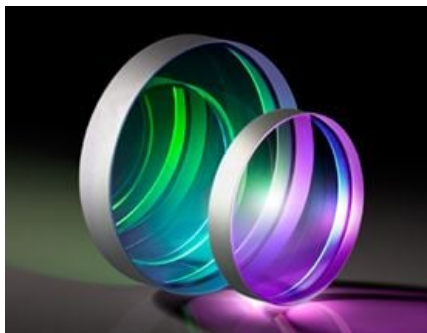

- Designs for 532nm and 1064nm Nd:YAG Lasers
- 80% Reflectivity at Nd:YAG DWL
- UV Fused Silica Substrates

Common Specifications

General

Note:

Arrow on edge points towards S1

Optical Properties

Coating Type:

Dielectric


Angle of Incidence (°):

0

Substrate:

[Fused Silica](#) (Corning 7980)

Technical Information

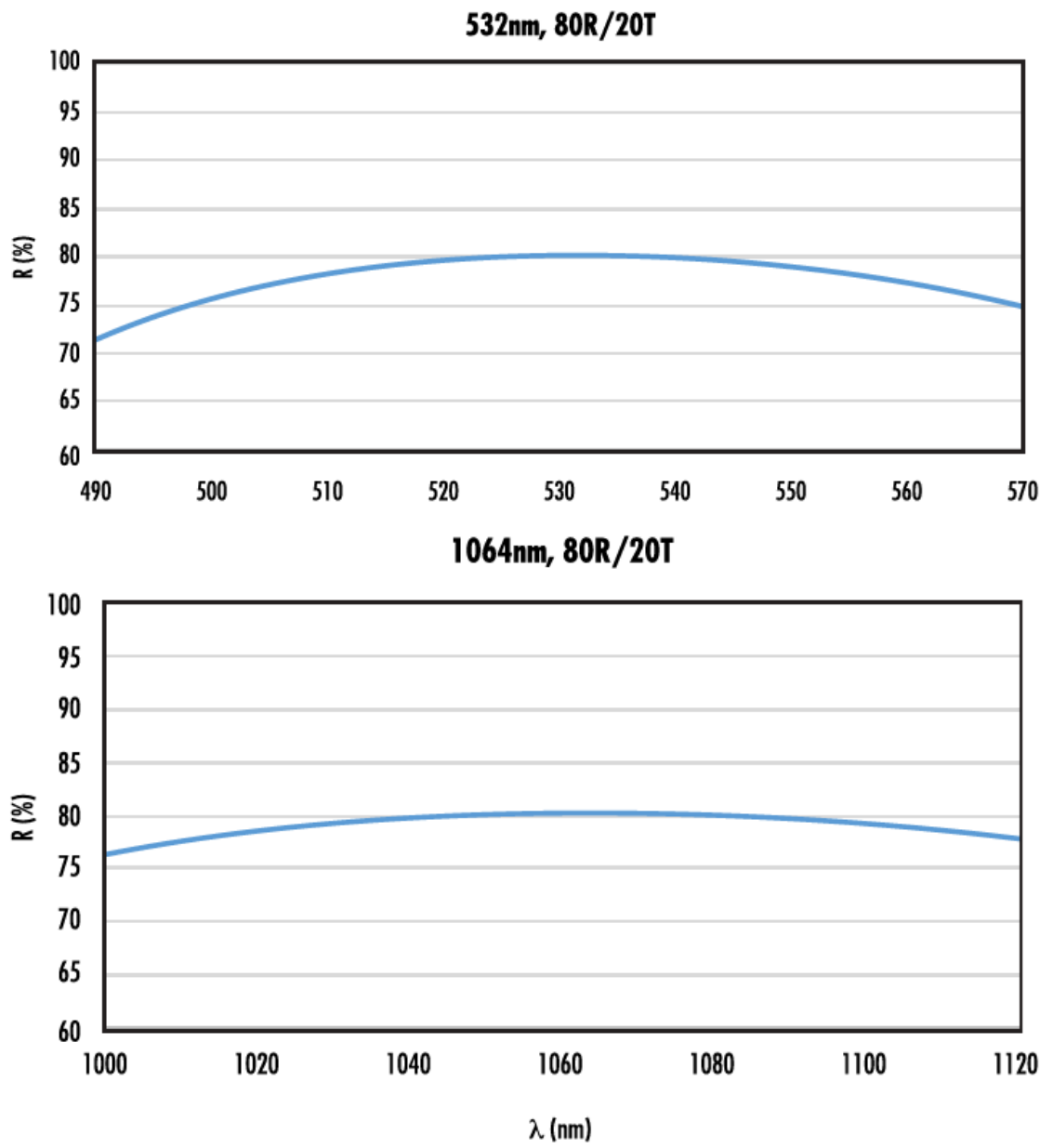

Products

Reflection/Transmission Ratio (R/T)	DWL (nm)	Dia. (mm)	Thickness (mm)	AOI (°)	Stock Number	Price	Buy
90/10	1064	19.05	9.53	0	#17-622	€156,00 Qty 10+ €141,00	3-4 days
80/20	1064	12.70	6.35	0	#14-740	€131,00 Qty 10+ €116,00	3-4 days
80/20	1064	19.05	9.53	0	#17-623	€156,00 Qty 10+ €141,00	3-4 days
80/20	1064	25.40	6.35	0	#14-739	€166,00 Qty 10+ €146,00	3-4 days
80/20	532	12.70	6.35	0	#14-742	€131,00 Qty 10+ €116,00	3-4 days
80/20	532	25.40	6.35	0	#14-741	€166,00 Qty 10+ €146,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com