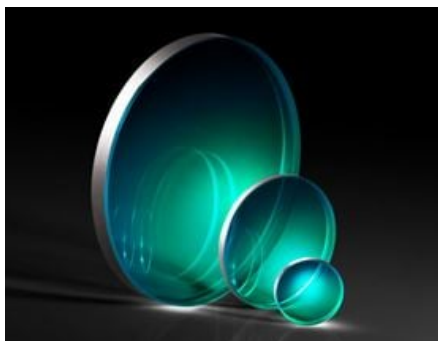


[All Products](#) / [Optics](#) / [Windows and Diffusers](#) / [UV and IR Windows](#)
**TECHSPEC®  $\lambda/4$  UV Fused Silica Windows**


- Available Uncoated or BBAR Coated for UV, Visible, and NIR
- Ideal for Imaging Applications
- Circular and Rectangular Sizes from 5 to 200mm
- [\$\lambda\$](#)  or  [\$\lambda/10\$](#)  UV Fused Silica Windows Also Available

## Common Specifications

### Physical & Mechanical Properties

|                         |                      |                                            |     |
|-------------------------|----------------------|--------------------------------------------|-----|
| <b>Bevel:</b>           | Protective as needed | <b>Clear Aperture (%):</b>                 | 90  |
| <b>Edges:</b>           | Fine Ground          | <b>Knoop Hardness (kg/mm<sup>2</sup>):</b> | 522 |
| <b>Poisson's Ratio:</b> | 0.16                 | <b>Young's Modulus (GPa):</b>              | 73  |


### Optical Properties

|                                        |       |                                                |       |
|----------------------------------------|-------|------------------------------------------------|-------|
| <b>Abbe Number (<math>v_d</math>):</b> | 67.8  | <b>Index of Refraction (<math>n_d</math>):</b> | 1.458 |
| <b>Surface Quality:</b>                | 40-20 |                                                |       |


### Material Properties

|                                    |      |
|------------------------------------|------|
| <b>Density (g/cm<sup>3</sup>):</b> | 2.20 |
|------------------------------------|------|


Technical Information

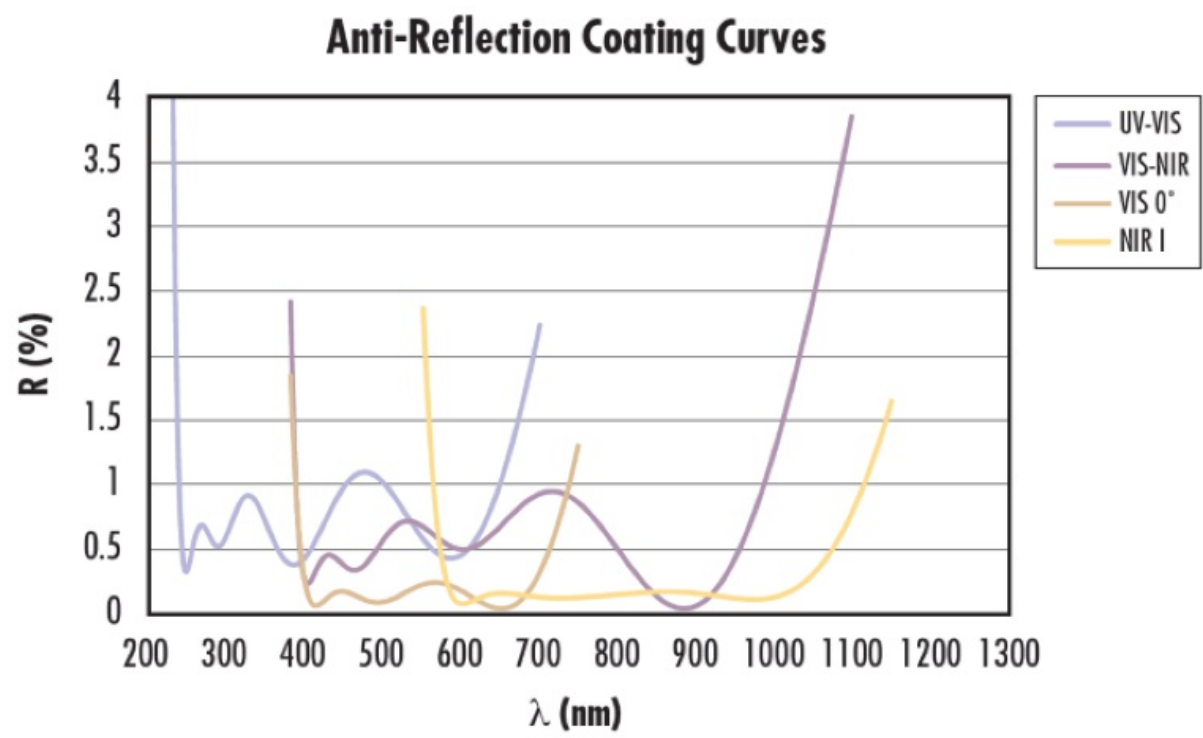

### Standard Visible Anti-Reflection Coatings

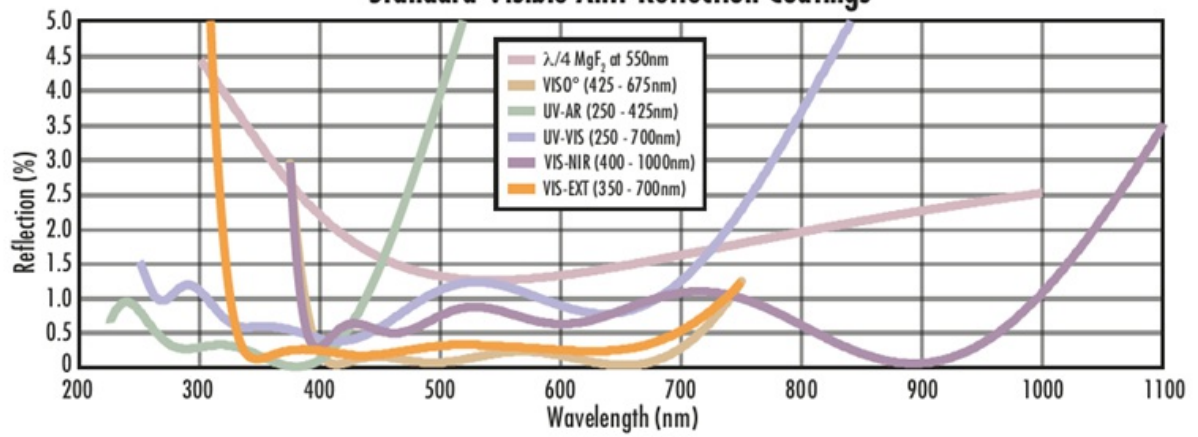

### Standard Near Infrared Anti-Reflection Coatings

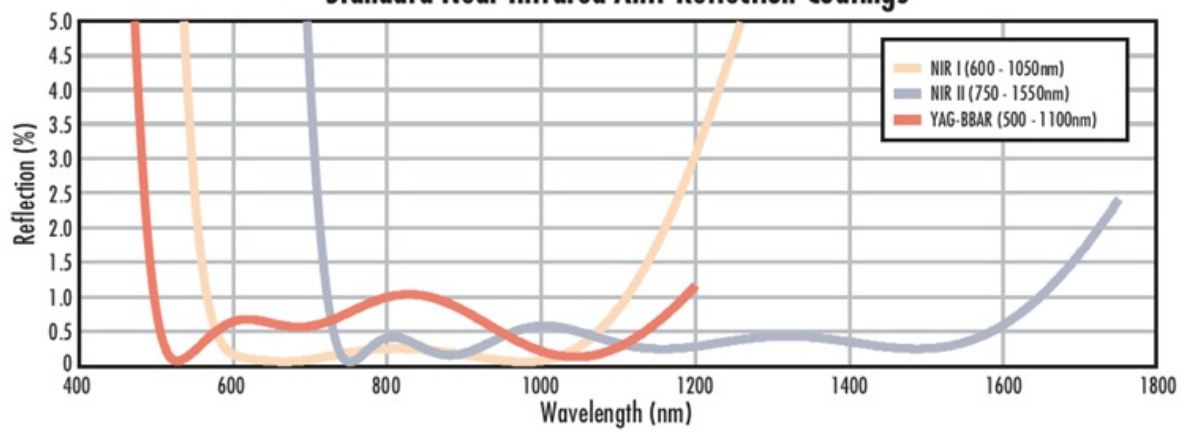

## Products

| Dia.<br>(mm) | Dimensions<br>(mm) | Thickness<br>(mm) | Coating                 | Stock Number            | Price                    | Buy      |
|--------------|--------------------|-------------------|-------------------------|-------------------------|--------------------------|----------|
| 5.00         | -                  | 1.00              | Uncoated                | <a href="#">#14-955</a> | €92,50<br>Qty 6+ €73,50  | In Stock |
| 5.00         | -                  | 1.00              | UV-AR<br>(250-425nm)    | <a href="#">#25-633</a> | €116,00<br>Qty 6+ €92,50 | 3-4 days |
| 5.00         | -                  | 1.00              | UV-VIS<br>(250-700nm)   | <a href="#">#14-968</a> | €116,00<br>Qty 6+ €92,50 | 3-4 days |
| 5.00         | -                  | 1.00              | VIS-NIR<br>(400-1000nm) | <a href="#">#14-981</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days |
| 5.00         | -                  | 1.00              | VIS 0°<br>(425-675nm)   | <a href="#">#18-320</a> | €113,00<br>Qty 6+ €90,50 | 3-4 days |
| 5.00         | -                  | 1.00              | NIR I<br>(600-1050nm)   | <a href="#">#18-333</a> | €113,00<br>Qty 6+ €90,50 | 3-4 days |
| 5.00         | -                  | 1.00              | NIR II<br>(750-1550nm)  | <a href="#">#25-650</a> | €113,00<br>Qty 6+ €90,50 | 3-4 days |
| -            | 6.00 x 6.00        | 2.00              | Uncoated                | <a href="#">#29-297</a> | €92,50<br>Qty 6+ €73,50  | 3-4 days |
| 10.00        | -                  | 1.00              | Uncoated                | <a href="#">#14-956</a> | €95,00<br>Qty 6+ €75,50  | 3-4 days |
| 10.00        | -                  | 1.00              | UV-AR<br>(250-425nm)    | <a href="#">#25-634</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days |
| 10.00        | -                  | 1.00              | UV-VIS<br>(250-700nm)   | <a href="#">#14-969</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days |
| 10.00        | -                  | 1.00              | VIS-NIR<br>(400-1000nm) | <a href="#">#14-982</a> | €124,00<br>Qty 6+ €98,50 | In Stock |
| 10.00        | -                  | 1.00              | VIS 0°<br>(425-675nm)   | <a href="#">#18-321</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days |

|       |   |      |                         |                         |                          |            |
|-------|---|------|-------------------------|-------------------------|--------------------------|------------|
| 10.00 | - | 1.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-334</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 10.00 | - | 1.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-651</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 10.00 | - | 2.00 | Uncoated                | <a href="#">#14-957</a> | €95,00<br>Qty 6+ €75,50  | Contact Us |
| 10.00 | - | 2.00 | UV-AR<br>(250-425nm)    | <a href="#">#25-635</a> | €121,00<br>Qty 6+ €96,50 | Contact Us |
| 10.00 | - | 2.00 | UV-VIS<br>(250-700nm)   | <a href="#">#14-970</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days   |
| 10.00 | - | 2.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-983</a> | €124,00<br>Qty 6+ €98,50 | Contact Us |
| 10.00 | - | 2.00 | VIS 0°<br>(425-675nm)   | <a href="#">#18-322</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 10.00 | - | 2.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-335</a> | €119,00<br>Qty 6+ €94,50 | Contact Us |
| 10.00 | - | 2.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-652</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |

[#70-520 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |          |  |                         |          |
|-------|---|------|----------|--|-------------------------|----------|
| 10.00 | - | 3.00 | Uncoated |  | €95,00<br>Qty 6+ €75,50 | 3-4 days |
|-------|---|------|----------|--|-------------------------|----------|

[#72-335 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

10.00

-

3.00

UV-AR  
(250-  
425nm)

€121,00  
Qty 6+ €96,50

3-4 days

---

[#72-336 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

10.00

-

3.00

UV-VIS  
(250-  
700nm)

€121,00  
Qty 6+ €96,50

3-4 days

---

[#72-337 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

10.00

-

3.00

VIS 0°  
(425-  
675nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-338 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

10.00

-

3.00

NIR I  
(600-  
1050nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-339 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

10.00

-

3.00

NIR II  
(750-1550nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-340 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

10.00

-

3.00

VIS-NIR  
(400-1000nm)

€124,00  
Qty 6+ €98,50

3-4 days

---

[#70-521 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

Uncoated

€95,00  
Qty 6+ €75,50

3-4 days

---

[#72-341 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

UV-AR  
(250-425nm)

€121,00  
Qty 6+ €96,50

3-4 days

---

[#72-342 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

UV-VIS  
(250-700nm)

€121,00  
Qty 6+ €96,50

3-4 days

---

[#72-343 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

VIS 0°  
(425-675nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-344 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

NIR I  
(600-1050nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-345 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

12.50

-

1.00

NIR II  
(750-1550nm)

€119,00  
Qty 6+ €94,50

3-4 days

---

[#72-346 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |                         |                          |            |
|-------|---|------|-----------------------------|-------------------------|--------------------------|------------|
| 12.50 | - | 1.00 | VIS-NIR<br>(400-<br>1000nm) |                         | €124,00<br>Qty 6+ €98,50 | 3-4 days   |
| 12.50 | - | 2.00 | Uncoated                    | <a href="#">#14-958</a> | €95,00<br>Qty 6+ €75,50  | 3-4 days   |
| 12.50 | - | 2.00 | UV-AR<br>(250-<br>425nm)    | <a href="#">#25-636</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days   |
| 12.50 | - | 2.00 | UV-VIS<br>(250-<br>700nm)   | <a href="#">#14-971</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days   |
| 12.50 | - | 2.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#14-984</a> | €124,00<br>Qty 6+ €98,50 | Contact Us |
| 12.50 | - | 2.00 | VIS 0°<br>(425-<br>675nm)   | <a href="#">#18-323</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 12.50 | - | 2.00 | NIR I<br>(600-<br>1050nm)   | <a href="#">#18-336</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 12.50 | - | 2.00 | NIR II<br>(750-<br>1550nm)  | <a href="#">#25-653</a> | €119,00<br>Qty 6+ €94,50 | 3-4 days   |
| 12.50 | - | 3.00 | Uncoated                    | <a href="#">#14-959</a> | €95,00<br>Qty 6+ €75,50  | In Stock   |
| 12.50 | - | 3.00 | UV-AR<br>(250-<br>425nm)    | <a href="#">#25-638</a> | €121,00<br>Qty 6+ €96,50 | 3-4 days   |

|       |   |      |                         |                         |                           |            |
|-------|---|------|-------------------------|-------------------------|---------------------------|------------|
| 12.50 | - | 3.00 | UV-VIS<br>(250-700nm)   | <a href="#">#14-972</a> | €121,00<br>Qty 6+ €96,50  | 3-4 days   |
| 12.50 | - | 3.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-985</a> | €124,00<br>Qty 6+ €98,50  | Contact Us |
| 12.50 | - | 3.00 | VIS 0°<br>(425-675nm)   | <a href="#">#18-324</a> | €119,00<br>Qty 6+ €94,50  | 3-4 days   |
| 12.50 | - | 3.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-337</a> | €119,00<br>Qty 6+ €94,50  | 3-4 days   |
| 12.50 | - | 3.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-654</a> | €119,00<br>Qty 6+ €94,50  | 3-4 days   |
| 15.00 | - | 2.00 | Uncoated                | <a href="#">#14-960</a> | €100,00<br>Qty 6+ €80,00  | 3-4 days   |
| 15.00 | - | 2.00 | UV-AR<br>(250-425nm)    | <a href="#">#25-639</a> | €127,00<br>Qty 6+ €101,00 | 3-4 days   |
| 15.00 | - | 2.00 | UV-VIS<br>(250-700nm)   | <a href="#">#14-973</a> | €127,00<br>Qty 6+ €101,00 | 3-4 days   |
| 15.00 | - | 2.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-986</a> | €129,00<br>Qty 6+ €103,00 | 3-4 days   |
| 15.00 | - | 2.00 | VIS 0°<br>(425-675nm)   | <a href="#">#18-325</a> | €124,00<br>Qty 6+ €98,50  | 3-4 days   |
| 15.00 | - | 2.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-338</a> | €124,00<br>Qty 6+ €98,50  | 3-4 days   |
| 15.00 | - | 2.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-655</a> | €124,00<br>Qty 6+ €98,50  | Contact Us |

[#70-522 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

Uncoated

€106,00  
Qty 6+ €84,00

3-4 days

---

[#72-347 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

UV-AR  
(250-425nm)

€132,00  
Qty 6+ €105,00

3-4 days

---

[#72-348 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

UV-VIS  
(250-700nm)

€132,00  
Qty 6+ €105,00

3-4 days

---

[#72-349 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

VIS 0°  
(425-675nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-350 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

NIR I  
(600-1050nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-351 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

1.00

NIR II  
(750-1550nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-352 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |  |                           |          |
|-------|---|------|-----------------------------|--|---------------------------|----------|
| 20.00 | - | 1.00 | VIS-NIR<br>(400-<br>1000nm) |  | €135,00<br>Qty 6+ €107,00 | 3-4 days |
|-------|---|------|-----------------------------|--|---------------------------|----------|

---

|       |   |      |          |                         |                          |          |
|-------|---|------|----------|-------------------------|--------------------------|----------|
| 20.00 | - | 2.00 | Uncoated | <a href="#">#14-961</a> | €106,00<br>Qty 6+ €84,00 | 3-4 days |
|-------|---|------|----------|-------------------------|--------------------------|----------|

---

|       |   |      |                          |                         |                           |          |
|-------|---|------|--------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | UV-AR<br>(250-<br>425nm) | <a href="#">#25-640</a> | €132,00<br>Qty 6+ €105,00 | 3-4 days |
|-------|---|------|--------------------------|-------------------------|---------------------------|----------|

---

|       |   |      |                           |                         |                           |          |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | UV-VIS<br>(250-<br>700nm) | <a href="#">#14-974</a> | €132,00<br>Qty 6+ €105,00 | 3-4 days |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|

---

|       |   |      |                             |                         |                           |          |
|-------|---|------|-----------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#14-987</a> | €135,00<br>Qty 6+ €107,00 | In Stock |
|-------|---|------|-----------------------------|-------------------------|---------------------------|----------|

---

|       |   |      |                           |                         |                           |          |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | VIS 0°<br>(425-<br>675nm) | <a href="#">#18-326</a> | €129,00<br>Qty 6+ €103,00 | 3-4 days |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|

---

|       |   |      |                           |                         |                           |          |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | NIR I<br>(600-<br>1050nm) | <a href="#">#18-339</a> | €129,00<br>Qty 6+ €103,00 | 3-4 days |
|-------|---|------|---------------------------|-------------------------|---------------------------|----------|

---

|       |   |      |                            |                         |                           |          |
|-------|---|------|----------------------------|-------------------------|---------------------------|----------|
| 20.00 | - | 2.00 | NIR II<br>(750-<br>1550nm) | <a href="#">#25-656</a> | €129,00<br>Qty 6+ €103,00 | 3-4 days |
|-------|---|------|----------------------------|-------------------------|---------------------------|----------|

---

[#70-523 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

3.00

Uncoated

€106,00  
Qty 6+ €84,00

3-4 days

---

[#72-353 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

3.00

UV-AR  
(250-425nm)

€132,00  
Qty 6+ €105,00

3-4 days

---

[#72-354 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

20.00

-

3.00

UV-VIS  
(250-  
700nm)

€132,00  
Qty 6+ €105,00

3-4 days

---

[#72-355 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

20.00

-

3.00

VIS 0°  
(425-  
675nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-356 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

3.00

NIR I  
(600-1050nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-357 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

20.00

-

3.00

NIR II  
(750-1550nm)

€129,00  
Qty 6+ €103,00

3-4 days

---

[#72-358 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

20.00

-

3.00

VIS-NIR  
(400-  
1000nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#70-524 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

25.00

-

1.00

Uncoated

€111,00  
Qty 6+ €88,00

3-4 days

---

[#72-359 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

1.00

UV-AR  
(250-425nm)

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-360 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

1.00

UV-VIS  
(250-700nm)

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-361 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

1.00

VIS 0°  
(425-675nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-362 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

1.00

NIR I  
(600-1050nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-363 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

25.00

-

1.00

NIR II  
(750-  
1550nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-364 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

25.00

-

1.00

VIS-NIR  
(400-  
1000nm)

€140,00  
Qty 6+ €111,50

In Stock

---

25.00

-

2.00

Uncoated

[#14-962](#)

€111,00  
Qty 6+ €88,00

3-4 days

---

25.00

-

2.00

UV-AR  
(250-  
425nm)

[#25-641](#)

€137,00  
Qty 6+ €109,00

3-4 days

---

25.00

-

2.00

UV-VIS  
(250-  
700nm)

[#14-975](#)

€137,00  
Qty 6+ €109,00

3-4 days

---

|       |   |      |                         |                         |                           |            |
|-------|---|------|-------------------------|-------------------------|---------------------------|------------|
| 25.00 | - | 2.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-988</a> | €140,00<br>Qty 6+ €111,50 | 3-4 days   |
| 25.00 | - | 2.00 | VIS 0°<br>(425-675nm)   | <a href="#">#18-327</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days   |
| 25.00 | - | 2.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-340</a> | €135,00<br>Qty 6+ €107,00 | In Stock   |
| 25.00 | - | 2.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-657</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days   |
| 25.00 | - | 3.00 | Uncoated                | <a href="#">#14-963</a> | €111,00<br>Qty 6+ €88,00  | Contact Us |
| 25.00 | - | 3.00 | UV-AR<br>(250-425nm)    | <a href="#">#25-642</a> | €137,00<br>Qty 6+ €109,00 | 3-4 days   |
| 25.00 | - | 3.00 | UV-VIS<br>(250-700nm)   | <a href="#">#14-976</a> | €137,00<br>Qty 6+ €109,00 | 3-4 days   |
| 25.00 | - | 3.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-989</a> | €140,00<br>Qty 6+ €111,50 | 3-4 days   |
| 25.00 | - | 3.00 | VIS 0°<br>(425-675nm)   | <a href="#">#18-328</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days   |
| 25.00 | - | 3.00 | NIR I<br>(600-1050nm)   | <a href="#">#18-341</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days   |
| 25.00 | - | 3.00 | NIR II<br>(750-1550nm)  | <a href="#">#25-658</a> | €135,00<br>Qty 6+ €107,00 | Contact Us |
| 25.00 | - | 4.00 | Uncoated                | <a href="#">#14-964</a> | €111,00<br>Qty 6+ €88,00  | In Stock   |
| 25.00 | - | 4.00 | UV-AR<br>(250-425nm)    | <a href="#">#25-643</a> | €137,00<br>Qty 6+ €109,00 | 3-4 days   |
| 25.00 | - | 4.00 | UV-VIS<br>(250-700nm)   | <a href="#">#14-977</a> | €137,00<br>Qty 6+ €109,00 | 3-4 days   |
| 25.00 | - | 4.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#14-990</a> | €140,00<br>Qty 6+ €111,50 | 3-4 days   |

|       |   |      |                        |                         |                           |          |
|-------|---|------|------------------------|-------------------------|---------------------------|----------|
| 25.00 | - | 4.00 | VIS 0°<br>(425-675nm)  | <a href="#">#18-329</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days |
| 25.00 | - | 4.00 | NIR I<br>(600-1050nm)  | <a href="#">#18-342</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days |
| 25.00 | - | 4.00 | NIR II<br>(750-1550nm) | <a href="#">#25-659</a> | €135,00<br>Qty 6+ €107,00 | 3-4 days |

#### [#70-525 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

|       |   |      |          |  |                          |          |
|-------|---|------|----------|--|--------------------------|----------|
| 25.00 | - | 5.00 | Uncoated |  | €111,00<br>Qty 6+ €88,00 | 3-4 days |
|-------|---|------|----------|--|--------------------------|----------|

#### [#72-365 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

|       |   |      |                      |  |                           |          |
|-------|---|------|----------------------|--|---------------------------|----------|
| 25.00 | - | 5.00 | UV-AR<br>(250-425nm) |  | €137,00<br>Qty 6+ €109,00 | 3-4 days |
|-------|---|------|----------------------|--|---------------------------|----------|

[#72-366 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

5.00

UV-VIS  
(250-700nm)

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-367 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

5.00

VIS 0°  
(425-675nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-368 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

5.00

NIR I  
(600-1050nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-369 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.00

-

5.00

NIR II  
(750-1550nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-376 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |  |                           |          |
|-------|---|------|-----------------------------|--|---------------------------|----------|
| 25.00 | - | 5.00 | VIS-NIR<br>(400-<br>1000nm) |  | €140,00<br>Qty 6+ €111,50 | 3-4 days |
|-------|---|------|-----------------------------|--|---------------------------|----------|

---

|   |               |      |          |                         |                           |          |
|---|---------------|------|----------|-------------------------|---------------------------|----------|
| - | 25.00 x 35.00 | 3.00 | Uncoated | <a href="#">#29-298</a> | €142,00<br>Qty 6+ €113,50 | 3-4 days |
| - | 25.20 x 35.60 | 1.00 | Uncoated | <a href="#">#29-299</a> | €142,00<br>Qty 6+ €113,50 | 3-4 days |

---

[#70-526 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |          |  |                          |          |
|-------|---|------|----------|--|--------------------------|----------|
| 25.40 | - | 3.00 | Uncoated |  | €111,00<br>Qty 6+ €88,00 | 3-4 days |
|-------|---|------|----------|--|--------------------------|----------|

---

[#72-377 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

UV-AR  
(250-425nm)

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-378 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

UV-VIS  
(250-700nm)

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-379 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

VIS 0°  
(425-675nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-380 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

NIR I  
(600-1050nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-381 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

NIR II  
(750-1550nm)

€135,00  
Qty 6+ €107,00

3-4 days

---

[#72-382 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

25.40

-

3.00

VIS-NIR  
(400-1000nm)

€140,00  
Qty 6+ €111,50

3-4 days

---

[#70-527 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

Uncoated

€121,00  
Qty 6+ €96,50

3-4 days

---

[#72-383 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

UV-AR  
(250-425nm)

€150,00  
Qty 6+ €119,50

3-4 days

---

[#72-384 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

30.00

-

3.00

UV-VIS  
(250-  
700nm)

€148,00  
Qty 6+ €117,50

3-4 days

---

[#72-385 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

30.00

-

3.00

VIS 0°  
(425-  
675nm)

€148,00  
Qty 6+ €117,50

3-4 days

---

[#72-386 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

NIR I  
(600-1050nm)

€145,00  
Qty 6+ €115,50

3-4 days

---

[#72-387 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

NIR II  
(750-1550nm)

€145,00  
Qty 6+ €115,50

3-4 days

---

[#72-388 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

30.00

-

3.00

VIS-NIR  
(400-1000nm)

€145,00  
Qty 6+ €115,50

3-4 days

---

[#70-528 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

Uncoated

€137,00  
Qty 6+ €109,00

3-4 days

---

[#72-389 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

UV-AR  
(250-425nm)

€156,00  
Qty 6+ €124,00

3-4 days

---

[#72-390 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

UV-VIS  
(250-700nm)

€153,00  
Qty 6+ €122,00

3-4 days

---

[#72-391 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

VIS 0°  
(425-675nm)

€153,00  
Qty 6+ €122,00

3-4 days

---

[#72-392 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

NIR I  
(600-1050nm)

€150,00  
Qty 6+ €119,50

3-4 days

---

[#72-393 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

NIR II  
(750-1550nm)

€150,00  
Qty 6+ €119,50

3-4 days

---

[#72-394 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

35.00

-

3.00

VIS-NIR  
(400-1000nm)

€150,00  
Qty 6+ €119,50

3-4 days

---

[#70-529 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

Uncoated

€156,00  
Qty 6+ €124,00

3-4 days

---

[#72-395 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

UV-AR  
(250-425nm)

€187,00  
Qty 6+ €149,00

3-4 days

---

[#72-396 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

UV-VIS  
(250-700nm)

€187,00  
Qty 6+ €149,00

In Stock

---

[#72-397 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

VIS 0°  
(425-675nm)

€185,00  
Qty 6+ €147,00

3-4 days

---

[#72-398 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

NIR I  
(600-1050nm)

€185,00  
Qty 6+ €147,00

Contact Us

---

[#72-399 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

40.00

-

2.00

NIR II  
(750-1550nm)

€185,00  
Qty 6+ €147,00

3-4 days

---

## [#72-400 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |                         |                           |          |
|-------|---|------|-----------------------------|-------------------------|---------------------------|----------|
| 40.00 | - | 2.00 | VIS-NIR<br>(400-<br>1000nm) |                         | €190,00<br>Qty 6+ €151,00 | 3-4 days |
| 40.00 | - | 4.00 | Uncoated                    | <a href="#">#14-965</a> | €156,00<br>Qty 6+ €124,00 | 3-4 days |
| 40.00 | - | 4.00 | UV-AR<br>(250-<br>425nm)    | <a href="#">#25-644</a> | €187,00<br>Qty 6+ €149,00 | 3-4 days |
| 40.00 | - | 4.00 | UV-VIS<br>(250-<br>700nm)   | <a href="#">#14-978</a> | €187,00<br>Qty 6+ €149,00 | 3-4 days |
| 40.00 | - | 4.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#14-991</a> | €190,00<br>Qty 6+ €151,00 | 3-4 days |
| 40.00 | - | 4.00 | VIS 0°<br>(425-<br>675nm)   | <a href="#">#18-330</a> | €185,00<br>Qty 6+ €147,00 | 3-4 days |
| 40.00 | - | 4.00 | NIR I<br>(600-<br>1050nm)   | <a href="#">#18-343</a> | €185,00<br>Qty 6+ €147,00 | 3-4 days |
| 40.00 | - | 4.00 | NIR II<br>(750-<br>1550nm)  | <a href="#">#25-660</a> | €185,00<br>Qty 6+ €147,00 | 3-4 days |

[#70-530 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

Uncoated

€177,00  
Qty 6+ €140,50

3-4 days

---

[#72-401 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

UV-AR  
(250-425nm)

€208,00  
Qty 6+ €166,00

3-4 days

---

[#72-402 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

UV-VIS  
(250-700nm)

€208,00  
Qty 6+ €166,00

3-4 days

---

[#72-403 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

VIS 0°  
(425-675nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-404 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

NIR I  
(600-1050nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-405 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

NIR II  
(750-1550nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-406 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

1.00

VIS-NIR  
(400-1000nm)

€211,00  
Qty 6+ €168,00

3-4 days

---

[#70-531 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

2.00

Uncoated

€177,00  
Qty 6+ €140,50

Contact Us

---

[#72-407 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

2.00

UV-AR  
(250-425nm)

€208,00  
Qty 6+ €166,00

3-4 days

---

[#72-408 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

2.00

UV-VIS  
(250-700nm)

€208,00  
Qty 6+ €166,00

Contact Us

---

[#72-409 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

50.00

-

2.00

VIS 0°  
(425-  
675nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-410 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

50.00

-

2.00

NIR I  
(600-  
1050nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-412 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

50.00

-

2.00

NIR II  
(750-  
1550nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-413 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

50.00

-

2.00

VIS-NIR  
(400-  
1000nm)

€211,00  
Qty 6+ €168,00

3-4 days

---

[#70-532 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

Uncoated

€177,00  
Qty 6+ €140,50

3-4 days

---

[#72-414 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

UV-AR  
(250-425nm)

€208,00  
Qty 6+ €166,00

3-4 days

---

[#72-415 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

UV-VIS  
(250-700nm)

€208,00  
Qty 6+ €166,00

3-4 days

---

[#72-416 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

VIS 0°  
(425-675nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-417 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

NIR I  
(600-1050nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-418 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

50.00

-

3.00

NIR II  
(750-1550nm)

€206,00  
Qty 6+ €164,00

3-4 days

---

[#72-419 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |                         |                           |            |
|-------|---|------|-----------------------------|-------------------------|---------------------------|------------|
| 50.00 | - | 3.00 | VIS-NIR<br>(400-<br>1000nm) |                         | €211,00<br>Qty 6+ €168,00 | 3-4 days   |
| 50.00 | - | 4.00 | Uncoated                    | <a href="#">#14-966</a> | €177,00<br>Qty 6+ €140,50 | In Stock   |
| 50.00 | - | 4.00 | UV-AR<br>(250-<br>425nm)    | <a href="#">#25-645</a> | €208,00<br>Qty 6+ €166,00 | 3-4 days   |
| 50.00 | - | 4.00 | UV-VIS<br>(250-<br>700nm)   | <a href="#">#14-979</a> | €208,00<br>Qty 6+ €166,00 | Contact Us |
| 50.00 | - | 4.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#14-992</a> | €211,00<br>Qty 6+ €168,00 | Contact Us |
| 50.00 | - | 4.00 | VIS 0°<br>(425-<br>675nm)   | <a href="#">#18-331</a> | €206,00<br>Qty 6+ €164,00 | 3-4 days   |
| 50.00 | - | 4.00 | NIR I<br>(600-<br>1050nm)   | <a href="#">#18-344</a> | €206,00<br>Qty 6+ €164,00 | 3-4 days   |
| 50.00 | - | 4.00 | NIR II<br>(750-<br>1550nm)  | <a href="#">#25-661</a> | €206,00<br>Qty 6+ €164,00 | 3-4 days   |

[#70-533 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

Uncoated

€280,00  
Qty 6+ €222,50

Contact Us

---

[#72-420 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

UV-AR  
(250-425nm)

€348,00  
Qty 6+ €277,00

3-4 days

---

[#72-421 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

UV-VIS  
(250-700nm)

€348,00  
Qty 6+ €277,00

Contact Us

---

[#72-422 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

VIS 0°  
(425-675nm)

€343,00  
Qty 6+ €273,00

3-4 days

---

[#72-423 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

NIR I  
(600-1050nm)

€343,00  
Qty 6+ €273,00

3-4 days

---

[#72-424 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00

-

2.00

NIR II  
(750-1550nm)

€343,00  
Qty 6+ €273,00

3-4 days

[#72-425 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|       |   |      |                             |  |                           |          |
|-------|---|------|-----------------------------|--|---------------------------|----------|
| 75.00 | - | 2.00 | VIS-NIR<br>(400-<br>1000nm) |  | €353,00<br>Qty 6+ €281,50 | 3-4 days |
|-------|---|------|-----------------------------|--|---------------------------|----------|

|        |   |      |                             |                         |                           |          |
|--------|---|------|-----------------------------|-------------------------|---------------------------|----------|
| 75.00  | - | 4.00 | Uncoated                    | <a href="#">#14-967</a> | €280,00<br>Qty 6+ €222,50 | In Stock |
| 75.00  | - | 4.00 | UV-AR<br>(250-<br>425nm)    | <a href="#">#25-646</a> | €348,00<br>Qty 6+ €277,00 | 3-4 days |
| 75.00  | - | 4.00 | UV-VIS<br>(250-<br>700nm)   | <a href="#">#14-980</a> | €348,00<br>Qty 6+ €277,00 | 3-4 days |
| 75.00  | - | 4.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#14-993</a> | €353,00<br>Qty 6+ €281,50 | In Stock |
| 75.00  | - | 4.00 | VIS 0°<br>(425-<br>675nm)   | <a href="#">#18-332</a> | €343,00<br>Qty 6+ €273,00 | In Stock |
| 75.00  | - | 4.00 | NIR I<br>(600-<br>1050nm)   | <a href="#">#18-345</a> | €343,00<br>Qty 6+ €273,00 | 3-4 days |
| 75.00  | - | 4.00 | NIR II<br>(750-<br>1550nm)  | <a href="#">#25-663</a> | €343,00<br>Qty 6+ €273,00 | 3-4 days |
| 100.00 | - | 2.00 | Uncoated                    | <a href="#">#20-159</a> | €398,00<br>Qty 6+ €317,00 | 3-4 days |

[#29-619 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                      |  |                           |          |
|--------|---|------|----------------------|--|---------------------------|----------|
| 100.00 | - | 2.00 | UV-AR<br>(250-425nm) |  | €660,00<br>Qty 6+ €527,00 | 3-4 days |
|--------|---|------|----------------------|--|---------------------------|----------|

---

|        |   |      |                       |                         |                           |            |
|--------|---|------|-----------------------|-------------------------|---------------------------|------------|
| 100.00 | - | 2.00 | UV-VIS<br>(250-700nm) | <a href="#">#22-055</a> | €660,00<br>Qty 6+ €527,00 | Contact Us |
|--------|---|------|-----------------------|-------------------------|---------------------------|------------|

---

|        |   |      |                         |                         |                           |          |
|--------|---|------|-------------------------|-------------------------|---------------------------|----------|
| 100.00 | - | 2.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#22-061</a> | €660,00<br>Qty 6+ €527,00 | 3-4 days |
|--------|---|------|-------------------------|-------------------------|---------------------------|----------|

---

|        |   |      |                       |                         |                           |          |
|--------|---|------|-----------------------|-------------------------|---------------------------|----------|
| 100.00 | - | 2.00 | VIS 0°<br>(425-675nm) | <a href="#">#22-058</a> | €660,00<br>Qty 6+ €527,00 | 3-4 days |
|--------|---|------|-----------------------|-------------------------|---------------------------|----------|

---

[#29-620 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                       |  |                           |          |
|--------|---|------|-----------------------|--|---------------------------|----------|
| 100.00 | - | 2.00 | NIR I<br>(600-1050nm) |  | €660,00<br>Qty 6+ €527,00 | 3-4 days |
|--------|---|------|-----------------------|--|---------------------------|----------|

---

[#29-621 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                            |  |                           |            |
|--------|---|------|----------------------------|--|---------------------------|------------|
| 100.00 | - | 2.00 | NIR II<br>(750-<br>1550nm) |  | €660,00<br>Qty 6+ €527,00 | Contact Us |
|--------|---|------|----------------------------|--|---------------------------|------------|

---

|        |   |      |          |                         |                           |          |
|--------|---|------|----------|-------------------------|---------------------------|----------|
| 125.00 | - | 3.00 | Uncoated | <a href="#">#20-161</a> | €545,00<br>Qty 6+ €432,50 | In Stock |
|--------|---|------|----------|-------------------------|---------------------------|----------|

---

[#29-622 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                          |  |                           |          |
|--------|---|------|--------------------------|--|---------------------------|----------|
| 125.00 | - | 3.00 | UV-AR<br>(250-<br>425nm) |  | €885,00<br>Qty 6+ €705,50 | 3-4 days |
|--------|---|------|--------------------------|--|---------------------------|----------|

---

|        |   |      |                           |                         |                           |          |
|--------|---|------|---------------------------|-------------------------|---------------------------|----------|
| 125.00 | - | 3.00 | UV-VIS<br>(250-<br>700nm) | <a href="#">#22-056</a> | €885,00<br>Qty 6+ €705,50 | 3-4 days |
|--------|---|------|---------------------------|-------------------------|---------------------------|----------|

---

|        |   |      |                             |                         |                           |          |
|--------|---|------|-----------------------------|-------------------------|---------------------------|----------|
| 125.00 | - | 3.00 | VIS-NIR<br>(400-<br>1000nm) | <a href="#">#22-062</a> | €885,00<br>Qty 6+ €705,50 | 3-4 days |
|--------|---|------|-----------------------------|-------------------------|---------------------------|----------|

---

|                                                                                                                |   |      |                        |                         |                           |            |
|----------------------------------------------------------------------------------------------------------------|---|------|------------------------|-------------------------|---------------------------|------------|
| 125.00                                                                                                         | - | 3.00 | VIS 0°<br>(425-675nm)  | <a href="#">#22-059</a> | €885,00<br>Qty 6+ €705,50 | 3-4 days   |
| <hr/>                                                                                                          |   |      |                        |                         |                           |            |
| <a href="#">#29-623 New</a>                                                                                    |   |      |                        |                         |                           |            |
| <div><div><div>×</div></div></div>                                                                             |   |      |                        |                         |                           |            |
| New                                                                                                            |   |      |                        |                         |                           |            |
| Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else! |   |      |                        |                         |                           |            |
| 125.00                                                                                                         | - | 3.00 | NIR I<br>(600-1050nm)  |                         | €885,00<br>Qty 6+ €705,50 | 3-4 days   |
| <hr/>                                                                                                          |   |      |                        |                         |                           |            |
| <a href="#">#29-624 New</a>                                                                                    |   |      |                        |                         |                           |            |
| <div><div><div>×</div></div></div>                                                                             |   |      |                        |                         |                           |            |
| New                                                                                                            |   |      |                        |                         |                           |            |
| Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else! |   |      |                        |                         |                           |            |
| 125.00                                                                                                         | - | 3.00 | NIR II<br>(750-1550nm) |                         | €885,00<br>Qty 6+ €705,50 | Contact Us |
| <hr/>                                                                                                          |   |      |                        |                         |                           |            |
| 150.00                                                                                                         | - | 3.00 | Uncoated               | <a href="#">#20-162</a> | €680,00<br>Qty 6+ €542,00 | 3-4 days   |

[#29-625 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                      |  |                             |          |
|--------|---|------|----------------------|--|-----------------------------|----------|
| 150.00 | - | 3.00 | UV-AR<br>(250-425nm) |  | €1.100,00<br>Qty 6+ €878,00 | 3-4 days |
|--------|---|------|----------------------|--|-----------------------------|----------|

---

|        |   |      |                       |                         |                             |          |
|--------|---|------|-----------------------|-------------------------|-----------------------------|----------|
| 150.00 | - | 3.00 | UV-VIS<br>(250-700nm) | <a href="#">#22-057</a> | €1.100,00<br>Qty 6+ €878,00 | 3-4 days |
|--------|---|------|-----------------------|-------------------------|-----------------------------|----------|

---

|        |   |      |                         |                         |                             |            |
|--------|---|------|-------------------------|-------------------------|-----------------------------|------------|
| 150.00 | - | 3.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#22-063</a> | €1.100,00<br>Qty 6+ €878,00 | Contact Us |
|--------|---|------|-------------------------|-------------------------|-----------------------------|------------|

---

|        |   |      |                       |                         |                             |          |
|--------|---|------|-----------------------|-------------------------|-----------------------------|----------|
| 150.00 | - | 3.00 | VIS 0°<br>(425-675nm) | <a href="#">#22-060</a> | €1.100,00<br>Qty 6+ €878,00 | 3-4 days |
|--------|---|------|-----------------------|-------------------------|-----------------------------|----------|

---

[#29-626 New](#)



New

Launched  
on our  
website  
before  
appearing  
in our  
latest print  
catalogs.  
Be the  
first to buy  
before  
anyone  
else!

|        |   |      |                       |  |                             |          |
|--------|---|------|-----------------------|--|-----------------------------|----------|
| 150.00 | - | 3.00 | NIR I<br>(600-1050nm) |  | €1.100,00<br>Qty 6+ €878,00 | 3-4 days |
|--------|---|------|-----------------------|--|-----------------------------|----------|

[#29-627 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

|        |   |      |                        |  |                             |            |
|--------|---|------|------------------------|--|-----------------------------|------------|
| 150.00 | - | 3.00 | NIR II<br>(750-1550nm) |  | €1.100,00<br>Qty 6+ €878,00 | Contact Us |
|--------|---|------|------------------------|--|-----------------------------|------------|

---

|        |   |      |          |                         |                             |          |
|--------|---|------|----------|-------------------------|-----------------------------|----------|
| 200.00 | - | 5.00 | Uncoated | <a href="#">#26-476</a> | €1.000,00<br>Qty 6+ €798,00 | In Stock |
|--------|---|------|----------|-------------------------|-----------------------------|----------|

---

|        |   |      |                         |                         |                               |            |
|--------|---|------|-------------------------|-------------------------|-------------------------------|------------|
| 200.00 | - | 5.00 | VIS-NIR<br>(400-1000nm) | <a href="#">#26-685</a> | €1.425,00<br>Qty 6+ €1.134,00 | Contact Us |
|--------|---|------|-------------------------|-------------------------|-------------------------------|------------|

---

[#29-938 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

|        |   |      |          |  |                               |          |
|--------|---|------|----------|--|-------------------------------|----------|
| 250.00 | - | 8.00 | Uncoated |  | €3.110,00<br>Qty 6+ €2.478,00 | 3-4 days |
|--------|---|------|----------|--|-------------------------------|----------|

---





Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)