

[All Products](#) / [Lights and Illumination](#) / [Microscopy Lighting](#) / [Microscopy Illumination Sources](#)

## SCHOTT VisiLED UV Ringlights See More by [SCHOTT Optical Components](#)




- Switch Between Bright-Field and UV Illumination
- Maximum UV Illuminance up to 160 W/m<sup>2</sup>
- Actively Controlled LED Temperature
- Five Segment Modes (Full, Semi, Quarter-Circle, Dual-Segment, Four-Segment)


## Technical Information



SCHOTT VisiLED UV Ringlights feature 5 different segment modes to achieve optimal illumination for your application.

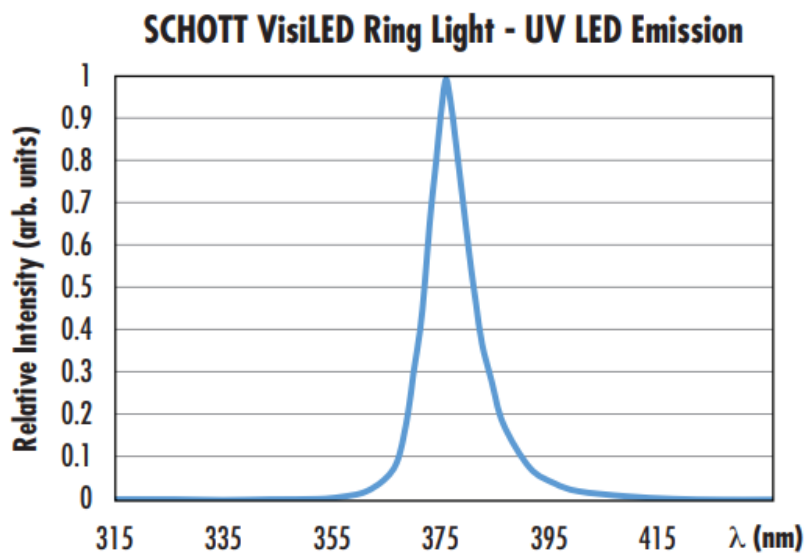

**SCHOTT VisiLED Ring Light - White LED Emission**

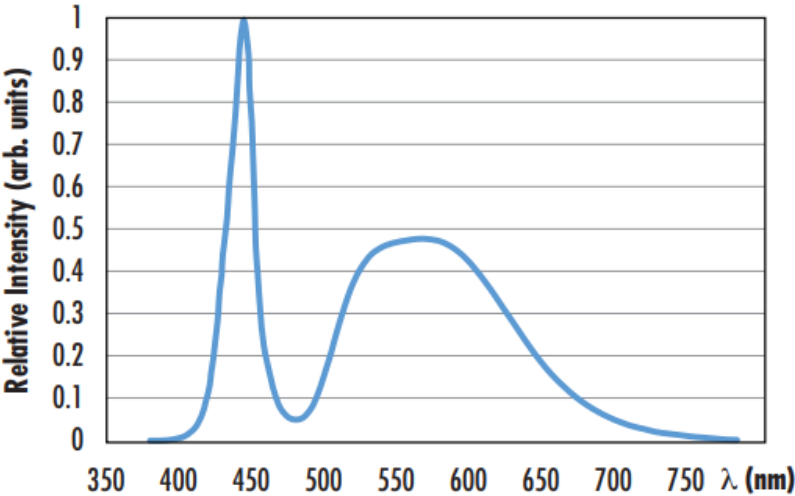

## Products

Color	Illumination Mode	Inner Diameter (mm)	Outer Diameter (mm)	Irradiance	Stock Number	Price	Buy
UV	Variable	66	114	UV: 160 W/m <sup>2</sup> White: 100 klx at 75mm	<a href="#">#16-789</a>	€1.590,00	3-4 days



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK  
Phone: 1-800-363-1992 :  
[www.edmundoptics.com](http://www.edmundoptics.com)