


[All Products](#) / [Optics](#) / [Optical Lenses](#) / [Plano-Convex \(PCX\) Lenses](#) / [Fused Silica Plano-Convex \(PCX\) Lenses](#)

TECHSPEC®

UV Fused Silica Plano-Convex (PCX) Lenses - VIS 0° Coated

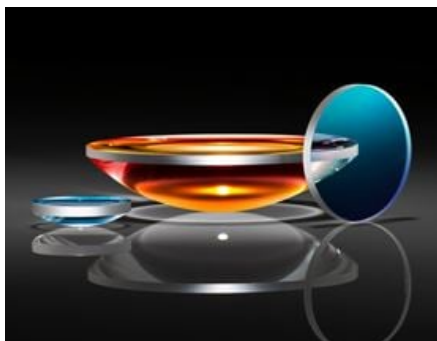

- AR Coated to Provide <0.4% Reflection per Surface for 425 - 675nm
- Precision Fused Silica Substrate
- Various Coating Options: [Uncoated](#), [MgF₂](#), [UV-AR](#), [UV-VIS](#), [VIS-EXT](#), [VIS-NIR](#), [YAG-BBAR](#), [NIR I](#), and [NIR II](#)

Common Specifications

Physical & Mechanical Properties

Bevel:

Protective bevel as needed

Optical Properties

Wavelength Range (nm):

425 - 675

Technical Information

Products

Dia. (mm)	EFL (mm)	BFL (mm)	Coating	Substrate	Stock Number	Price	Buy
#72-254 New							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
2.00	4.00	3.46	VIS 0° (425-675nm)	Fused Silica (Corning 7980)		€104,00 Qty 6+ €83,50	3-4 days
#72-262 New							
							
New							
Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!							
2.00	6.00	5.45	VIS 0° (425-675nm)	Fused Silica (Corning 7980)		€98,50 Qty 6+ €79,00	3-4 days

[#72-270 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

3.00	6.00	5.01	VIS 0° (425-675nm)	Fused Silica (Corning 7980)	€104,00 Qty 6+ €83,50	3-4 days
------	------	------	-----------------------	--------------------------------	--------------------------	----------

[#72-279 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

3.00	9.00	8.11	VIS 0° (425-675nm)	Fused Silica (Corning 7980)	€98,50 Qty 6+ €79,00	3-4 days
------	------	------	-----------------------	--------------------------------	-------------------------	----------

[#72-287 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

4.00	8.00	6.91	VIS 0° (425- 675nm)	Fused Silica (Corning 7980)		€124,00 Qty 6+ €99,50	3-4 days
------	------	------	---------------------------	--------------------------------------	--	--------------------------	----------

[#72-295 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

4.00	12.00	11.04	VIS 0° (425- 675nm)	Fused Silica (Corning 7980)		€118,50 Qty 6+ €95,00	3-4 days
------	-------	-------	---------------------------	--------------------------------------	--	--------------------------	----------

5.00	10.00	8.63	VIS 0° (425- 675nm)	Fused Silica	#89-423	€136,00 Qty 6+ €109,00	3-4 days
------	-------	------	---------------------------	----------------------------------	-------------------------	---------------------------	----------

5.00	15.00	13.83	VIS 0° (425- 675nm)	Fused Silica	#89-424	€128,00 Qty 6+ €102,00	3-4 days
------	-------	-------	---------------------------	----------------------------------	-------------------------	---------------------------	----------

5.00	20.00	18.97	VIS 0° (425- 675nm)	Fused Silica	#89-425	€128,00 Qty 6+ €102,00	3-4 days
------	-------	-------	---------------------------	----------------------------------	-------------------------	---------------------------	----------

5.00	25.00	23.97	VIS 0° (425-675nm)	Fused Silica	#89-426	€128,00 Qty 6+ €102,00	3-4 days
6.00	9.00	7.29	VIS 0° (425-675nm)	Fused Silica	#48-944	€138,00 Qty 6+ €110,00	3-4 days
6.00	12.00	10.63	VIS 0° (425-675nm)	Fused Silica	#48-945	€138,00 Qty 6+ €110,00	3-4 days
6.00	15.00	13.63	VIS 0° (425-675nm)	Fused Silica	#48-946	€133,00 Qty 6+ €106,00	3-4 days
6.00	18.00	16.62	VIS 0° (425-675nm)	Fused Silica	#48-947	€133,00 Qty 6+ €106,00	3-4 days
6.00	21.00	19.63	VIS 0° (425-675nm)	Fused Silica	#36-715	€133,00 Qty 6+ €106,00	3-4 days
6.00	24.00	22.63	VIS 0° (425-675nm)	Fused Silica	#48-948	€133,00 Qty 6+ €106,00	3-4 days
6.00	36.00	34.63	VIS 0° (425-675nm)	Fused Silica	#36-716	€133,00 Qty 6+ €106,00	3-4 days
9.00	12.00	9.26	VIS 0° (425-675nm)	Fused Silica	#48-949	€141,00 Qty 6+ €113,00	3-4 days
9.00	13.50	11.44	VIS 0° (425-675nm)	Fused Silica	#48-950	€141,00 Qty 6+ €113,00	3-4 days
9.00	18.00	15.94	VIS 0° (425-675nm)	Fused Silica	#48-951	€141,00 Qty 6+ €113,00	In Stock
9.00	22.00	19.94	VIS 0° (425-675nm)	Fused Silica	#36-717	€136,00 Qty 6+ €109,00	3-4 days
9.00	27.00	25.63	VIS 0° (425-675nm)	Fused Silica	#48-952	€136,00 Qty 6+ €109,00	In Stock
9.00	36.00	34.63	VIS 0° (425-675nm)	Fused Silica	#48-953	€136,00 Qty 6+ €109,00	3-4 days

10.00	20.00	17.94	VIS 0° (425-675nm)	Fused Silica	#36-718	€143,00 Qty 6+ €114,00	3-4 days
10.00	25.00	22.94	VIS 0° (425-675nm)	Fused Silica	#36-719	€143,00 Qty 6+ €114,00	3-4 days
12.00	18.00	15.26	VIS 0° (425-675nm)	Fused Silica	#48-954	€146,00 Qty 6+ €117,00	3-4 days
12.00	25.00	22.31	VIS 0° (425-675nm)	Fused Silica	#48-955	€146,00 Qty 6+ €117,00	3-4 days
12.00	30.00	27.56	VIS 0° (425-675nm)	Fused Silica	#48-956	€141,00 Qty 6+ €113,00	3-4 days
12.00	36.00	34.29	VIS 0° (425-675nm)	Fused Silica	#48-957	€141,00 Qty 6+ €113,00	3-4 days
12.00	40.00	37.85	VIS 0° (425-675nm)	Fused Silica	#48-958	€141,00 Qty 6+ €113,00	3-4 days
12.00	50.00	48.01	VIS 0° (425-675nm)	Fused Silica	#48-959	€133,00 Qty 6+ €106,00	3-4 days
12.00	72.00	70.29	VIS 0° (425-675nm)	Fused Silica	#36-720	€133,00 Qty 6+ €106,00	3-4 days
12.00	84.00	82.28	VIS 0° (425-675nm)	Fused Silica	#36-721	€133,00 Qty 6+ €106,00	3-4 days
12.00	100.00	98.33	VIS 0° (425-675nm)	Fused Silica	#48-960	€133,00 Qty 6+ €106,00	3-4 days
15.00	25.00	22.09	VIS 0° (425-675nm)	Fused Silica	#84-307	€153,00 Qty 6+ €122,00	3-4 days
15.00	30.00	27.53	VIS 0° (425-675nm)	Fused Silica	#84-308	€153,00 Qty 6+ €122,00	3-4 days
15.00	45.00	42.94	VIS 0° (425-675nm)	Fused Silica	#84-309	€148,00 Qty 6+ €118,00	3-4 days

15.00	60.00	57.94	VIS 0° (425-675nm)	Fused Silica	#84-310	€148,00 Qty 6+ €118,00	3-4 days
15.00	75.00	72.94	VIS 0° (425-675nm)	Fused Silica	#84-311	€148,00 Qty 6+ €118,00	3-4 days
18.00	27.00	23.23	VIS 0° (425-675nm)	Fused Silica	#36-722	€153,00 Qty 6+ €122,00	3-4 days
18.00	36.00	32.92	VIS 0° (425-675nm)	Fused Silica	#36-723	€153,00 Qty 6+ €122,00	3-4 days
18.00	54.00	51.6	VIS 0° (425-675nm)	Fused Silica	#36-724	€148,00 Qty 6+ €118,00	3-4 days
20.00	30.00	25.88	VIS 0° (425-675nm)	Fused Silica	#49-977	€158,00 Qty 6+ €126,00	3-4 days
20.00	35.00	31.58	VIS 0° (425-675nm)	Fused Silica	#49-978	€158,00 Qty 6+ €126,00	3-4 days
20.00	40.00	36.92	VIS 0° (425-675nm)	Fused Silica	#49-979	€158,00 Qty 6+ €126,00	3-4 days
20.00	50.00	47.25	VIS 0° (425-675nm)	Fused Silica	#49-980	€153,00 Qty 6+ €122,00	3-4 days
20.00	60.00	57.60	VIS 0° (425-675nm)	Fused Silica	#49-981	€153,00 Qty 6+ €122,00	3-4 days
20.00	80.00	77.95	VIS 0° (425-675nm)	Fused Silica	#49-982	€153,00 Qty 6+ €122,00	3-4 days
25.00	35.00	29.17	VIS 0° (425-675nm)	Fused Silica	#36-725	€161,00 Qty 6+ €129,00	3-4 days
25.00	38.00	33.03	VIS 0° (425-675nm)	Fused Silica	#48-961	€161,00 Qty 6+ €129,00	3-4 days
25.00	40.00	34.86	VIS 0° (425-675nm)	Fused Silica	#36-726	€161,00 Qty 6+ €129,00	3-4 days

25.00	50.00	46.00	VIS 0° (425-675nm)	Fused Silica	#48-962	€161,00 Qty 6+ €129,00	3-4 days
25.00	60.00	56.92	VIS 0° (425-675nm)	Fused Silica	#48-963	€156,00 Qty 6+ €125,00	3-4 days
25.00	75.00	71.96	VIS 0° (425-675nm)	Fused Silica	#48-964	€156,00 Qty 6+ €125,00	3-4 days
25.00	100.00	97.40	VIS 0° (425-675nm)	Fused Silica	#48-965	€156,00 Qty 6+ €125,00	3-4 days
25.00	125.00	122.65	VIS 0° (425-675nm)	Fused Silica	#48-966	€148,00 Qty 6+ €118,00	3-4 days
25.00	150.00	147.82	VIS 0° (425-675nm)	Fused Silica	#48-967	€148,00 Qty 6+ €118,00	3-4 days
25.00	175.00	172.94	VIS 0° (425-675nm)	Fused Silica	#48-968	€148,00 Qty 6+ €118,00	3-4 days
25.00	200.00	198.02	VIS 0° (425-675nm)	Fused Silica	#48-969	€148,00 Qty 6+ €118,00	3-4 days
25.00	250.00	248.14	VIS 0° (425-675nm)	Fused Silica	#48-970	€148,00 Qty 6+ €118,00	Contact Us
25.00	400.00	398.33	VIS 0° (425-675nm)	Fused Silica	#48-971	€148,00 Qty 6+ €118,00	3-4 days
30.00	50.00	45.2	VIS 0° (425-675nm)	Fused Silica	#84-312	€194,00 Qty 6+ €155,00	3-4 days
30.00	60.00	55.89	VIS 0° (425-675nm)	Fused Silica	#84-313	€194,00 Qty 6+ €155,00	3-4 days
30.00	90.00	86.57	VIS 0° (425-675nm)	Fused Silica	#84-314	€189,00 Qty 6+ €151,00	3-4 days
30.00	120.00	116.57	VIS 0° (425-675nm)	Fused Silica	#84-315	€189,00 Qty 6+ €151,00	Contact Us

30.00	150.00	146.57	VIS 0° (425-675nm)	Fused Silica	#84-316	€184,00 Qty 6+ €147,00	3-4 days
50.00	75.00	66.43	VIS 0° (425-675nm)	Fused Silica	#67-233	€304,00 Qty 6+ €243,00	3-4 days
50.00	100.00	93.84	VIS 0° (425-675nm)	Fused Silica	#67-234	€304,00 Qty 6+ €243,00	3-4 days
50.00	150.00	145.20	VIS 0° (425-675nm)	Fused Silica	#67-235	€299,00 Qty 6+ €239,00	In Stock
50.00	200.00	195.19	VIS 0° (425-675nm)	Fused Silica	#67-236	€299,00 Qty 6+ €239,00	3-4 days
50.00	250.00	245.21	VIS 0° (425-675nm)	Fused Silica	#67-237	€299,00 Qty 6+ €239,00	3-4 days

[#72-303 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	100.00	85.61	VIS 0° (425-675nm)	Fused Silica (Corning 7980)		€655,00 Qty 6+ €238,00	3-4 days
-------	--------	-------	-----------------------	--------------------------------	--	---------------------------	----------

[#72-311 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	125.00	112.66	VIS 0° (425-675nm)	Fused Silica (Corning 7980)	€635,00 Qty 6+ €238,00	3-4 days
-------	--------	--------	-----------------------	--------------------------------	---------------------------	----------

[#72-319 New](#)



New

Launched on our website before appearing in our latest print catalogs. Be the first to buy before anyone else!

75.00	150.00	136.31	VIS 0° (425-675nm)	Fused Silica (Corning 7980)	€615,00 Qty 6+ €238,00	3-4 days
-------	--------	--------	-----------------------	--------------------------------	---------------------------	----------

[#72-327 New](#)



New

Launched
on our
website
before
appearing
in our
latest print
catalogs.
Be the
first to buy
before
anyone
else!

75.00	200.00	187.18	VIS 0° (425- 675nm)	Fused Silica (Corning 7980)	€595,00 Qty 6+ €238,00	3-4 days
-------	--------	--------	---------------------------	--------------------------------------	---------------------------	----------



Copyright 2023 | Edmund Optics, Ltd Unit 1, Opus Avenue, Nether Poppleton, York, YO26 6BL, UK
Phone: 1-800-363-1992 :
www.edmundoptics.com
