

 

In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union



SUBMIT

10 LED, Red Adjustable LED Bar Light

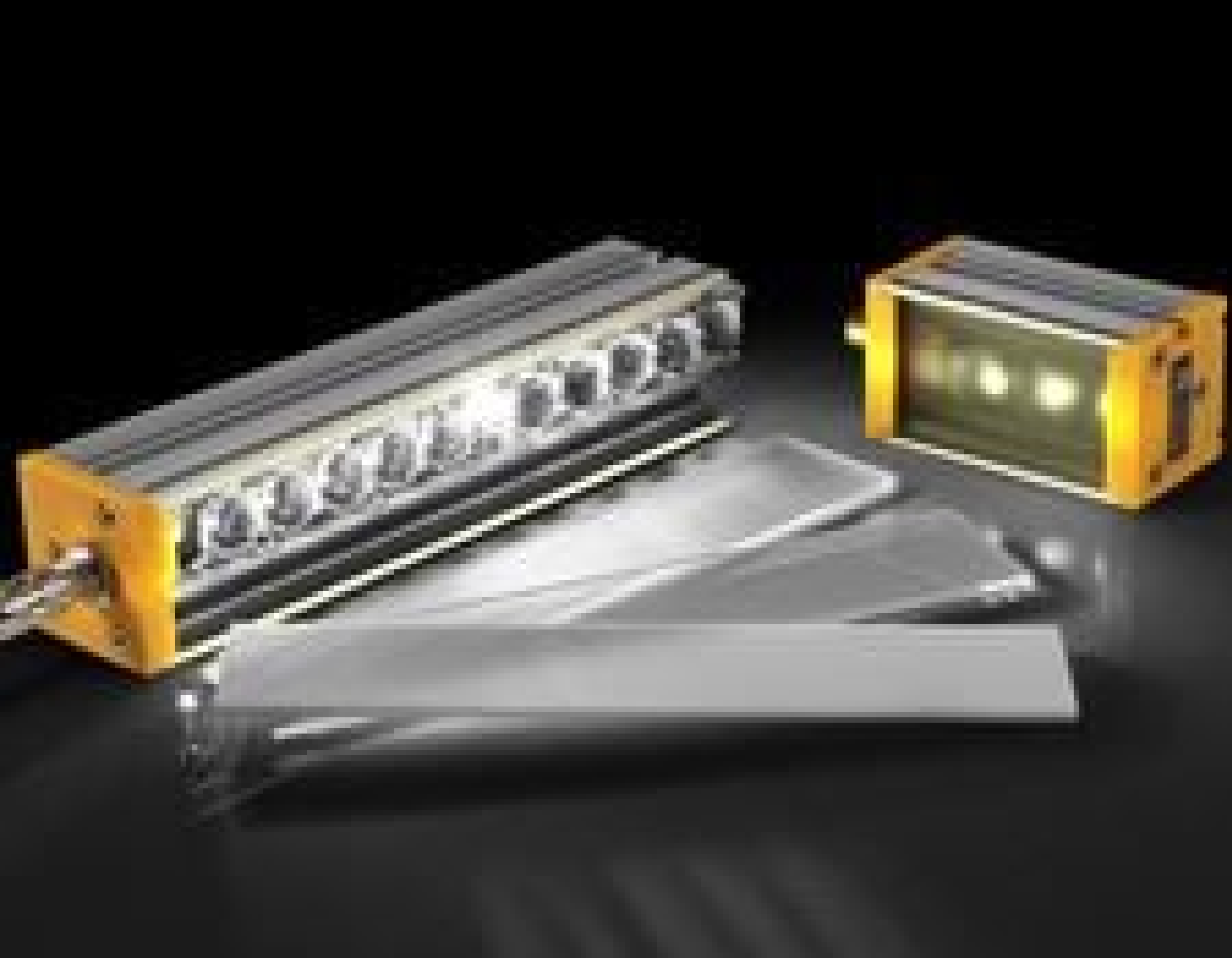

Stock #34-878 3-4 DAYS



1



€700,00

ADD TO CART

Qty 1+

€700,00

Volume Pricing

[Request Quote](#)

⚠ Prices shown are exclusive of VAT/local taxes

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Color:
Red

Connector:
M12, 5 pins

Input Voltage (V):
24VDC

Model Number: EFFI-FLEX-10-625
Mount: 2 Rails (1 for M6 T-Nuts)
Operating Temperature (°C): -10 to 50
Dimensions (mm): 235.0 x 51.0 x 49.0
Wavelength (nm): 625.00
Power Supply: Power Supply Required and Sold Separately. USA: #15-874 Europe: #15-875 Japan: #15-874 Korea: #15-874 China: #15-874
Number of LEDs: 10.00
Type of Illumination: LED Illuminator
Geometry: Line Light
Illumination Mode: Strobed or Constant
Environmental Rating: IP40

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View