


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

1.0 OD 25mm Dia, Absorptive ND Filter

See More by [Hoya](#)

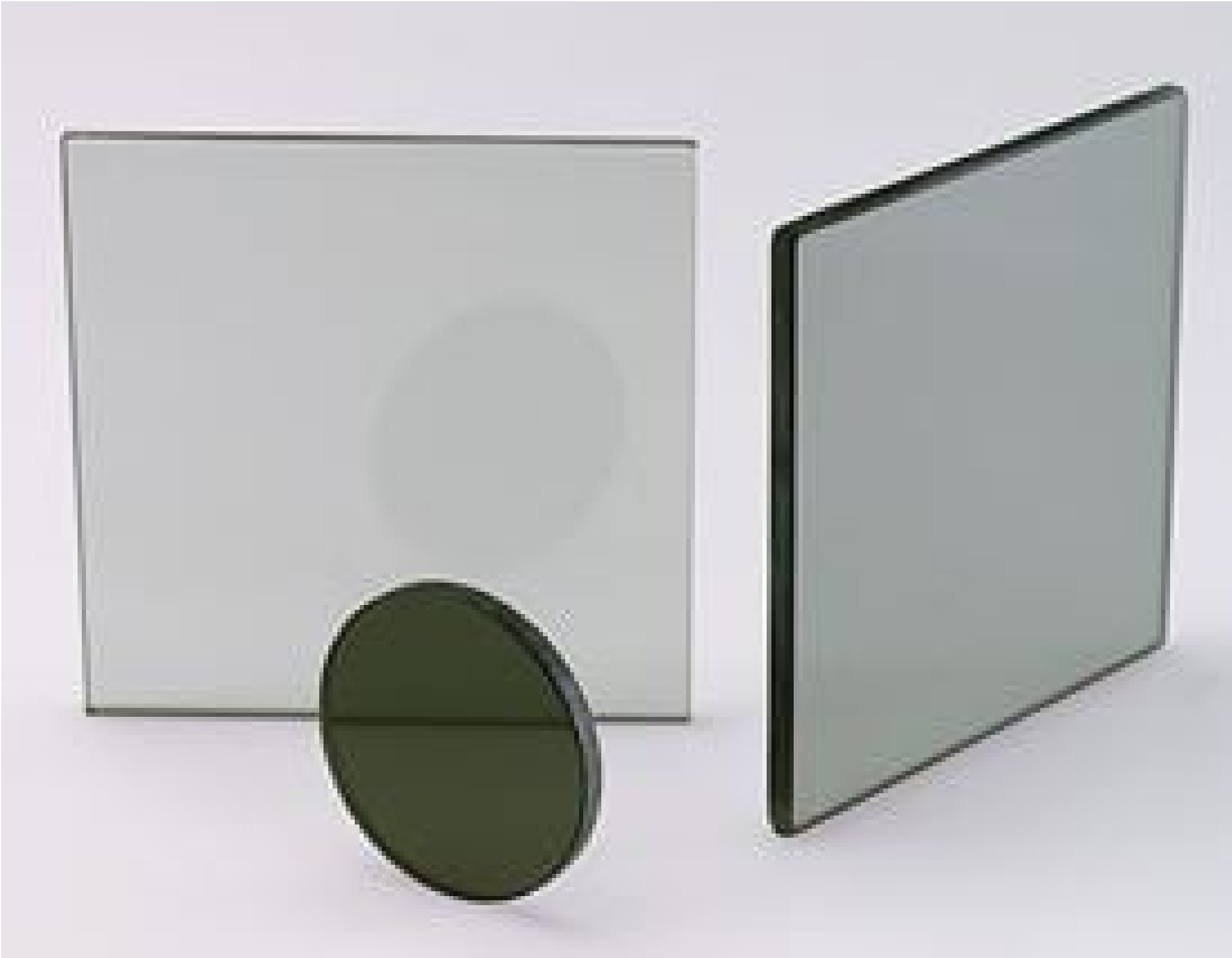

Stock #48-090 3-4 DAYS



1



€44,00

ADD TO CART

Qty 1-10

€44,00

Qty 11+

€39,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm):
25.00

Optical Density OD (Average):

1.0 ±0.05
Glass/Filter Number: Hoya ND-0.3
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 490
Thickness (mm): 1.00
Thickness Tolerance (mm): ±0.5
Transmission (%): 10.0 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View