


TECHSPEC® 10 x 10mm Protected Silver, λ/20 Mirror

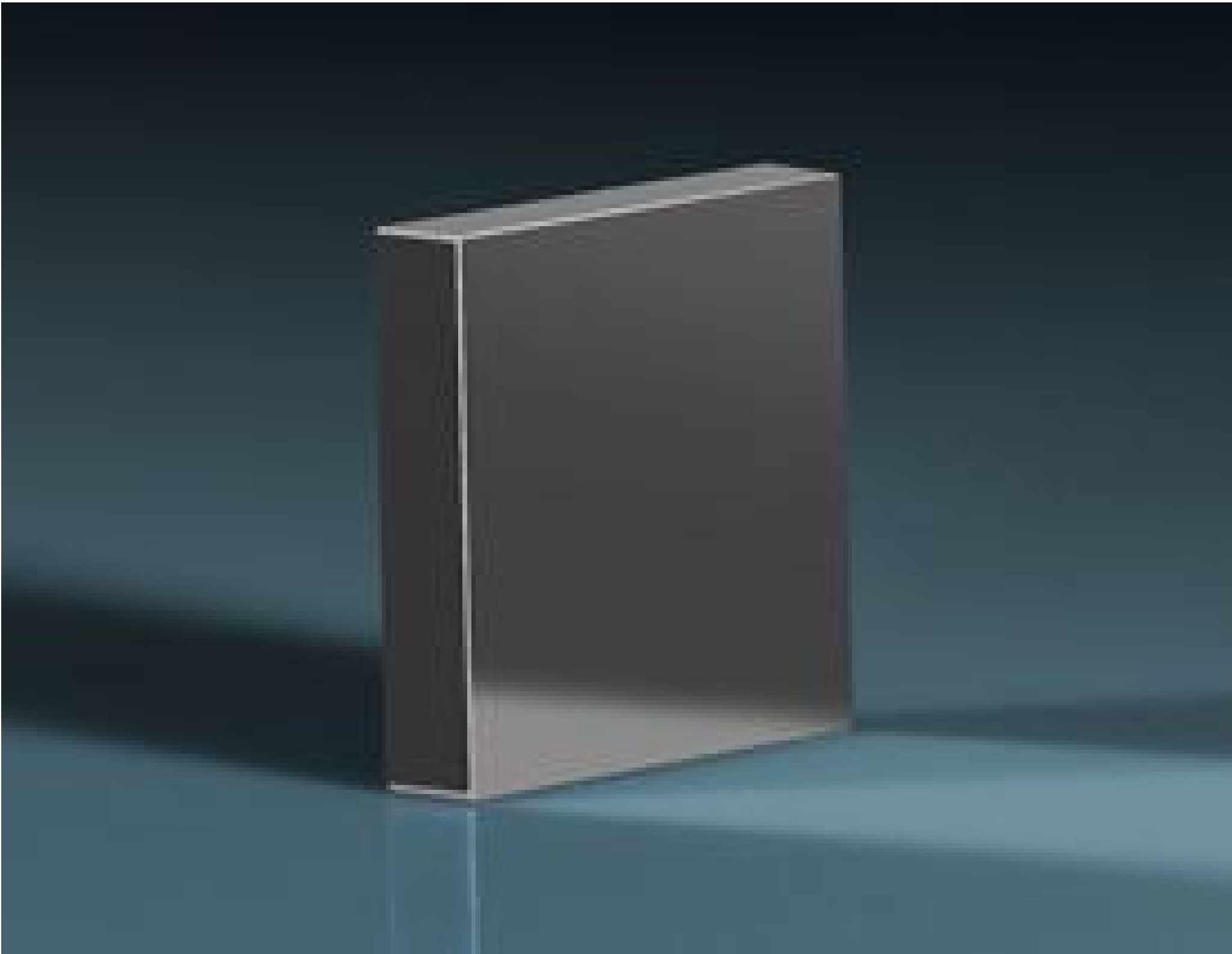

10 x 10mm Protected Silver, λ/20 Mirror, #34-387

Stock **#34-387** [CONTACT US](#)

- 1 + **€142,00**

ADD TO CART

Qty 1-5

€142,00

Qty 6+

€113,50

Volume Pricing

[Request Quote](#)

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Surface Flatness (P-V):
λ/20 (flatness pre-coating)

Substrate: ☐
[Fused Silica](#) (Corning 7980)

Back Surface:
Commercial Polish

Surface Quality: 20-10
Dimensions (mm): 10.0 x 10.0 +0.00/-0.20
Coating Specification: R _{avg} >98% @ 450 - 2000nm R _{avg} >98% @ 2000 - 10,000nm
Coating: Protected Silver (450-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 2.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 10000
Length (mm): 10.00
Width (mm): 10.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant