


100µm Emitter, 500µm Pitch Slow Axis Collimator

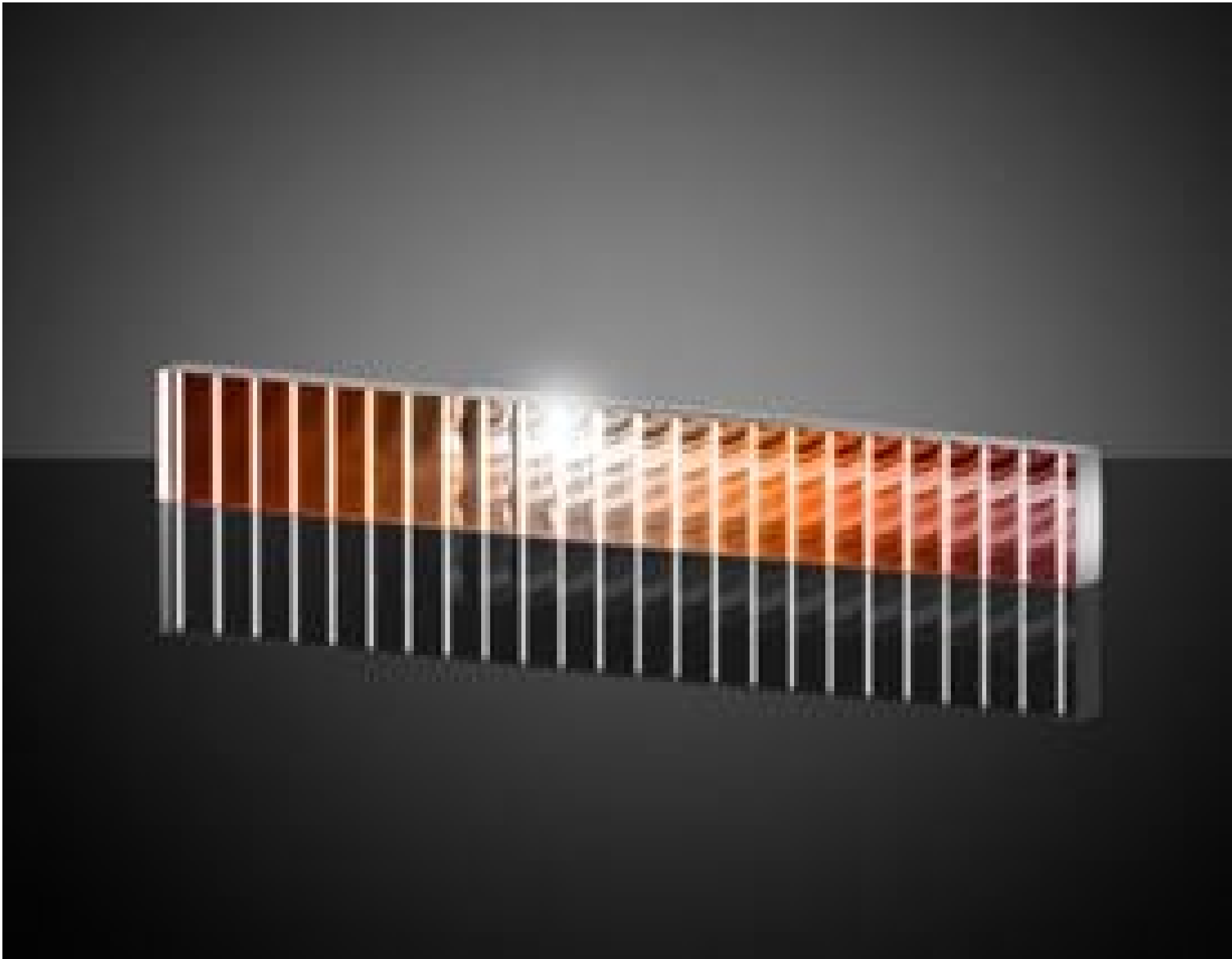

Slow Axis Collimators

Stock **#88-404** ☒ In Stock

-

1

+

€184,00

ADD TO CART

Qty 1-10
€184,00

Qty 11+
€162,00

Volume Pricing
Request Quote

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Effective Focal Length EFL (mm):
2.88

Substrate: ☐
[S-TIH53](#)

f/#:
7.69

Numerical Aperture NA: 0.07
Coating: BBAR (790-990nm)
Type: Beam Shaper
Wavelength Range (nm): 790 - 990
Back Focal Length BFL (mm): 2.58
Clear Aperture CA (mm): 11.0 x 1.4
Coating Specification: R _{avg} <1.0% @ 790 - 990nm
Emitter Size (µm): 100.00
Height (mm): 1.50
Height Tolerance (mm): 0.05
Length (mm): 12.00
Length Tolerance (mm): ±0.05
Pitch (µm): 500.00
Surface Accuracy: λ/4
Transmission (%): >99
Width (mm): 0.55
Width Tolerance (mm): 0.01
Divergence 1/e² (mrad): 40.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View