


100mm, White, MicroBrite Brightfield Ring Light

See More by [Advanced Illumination](#)

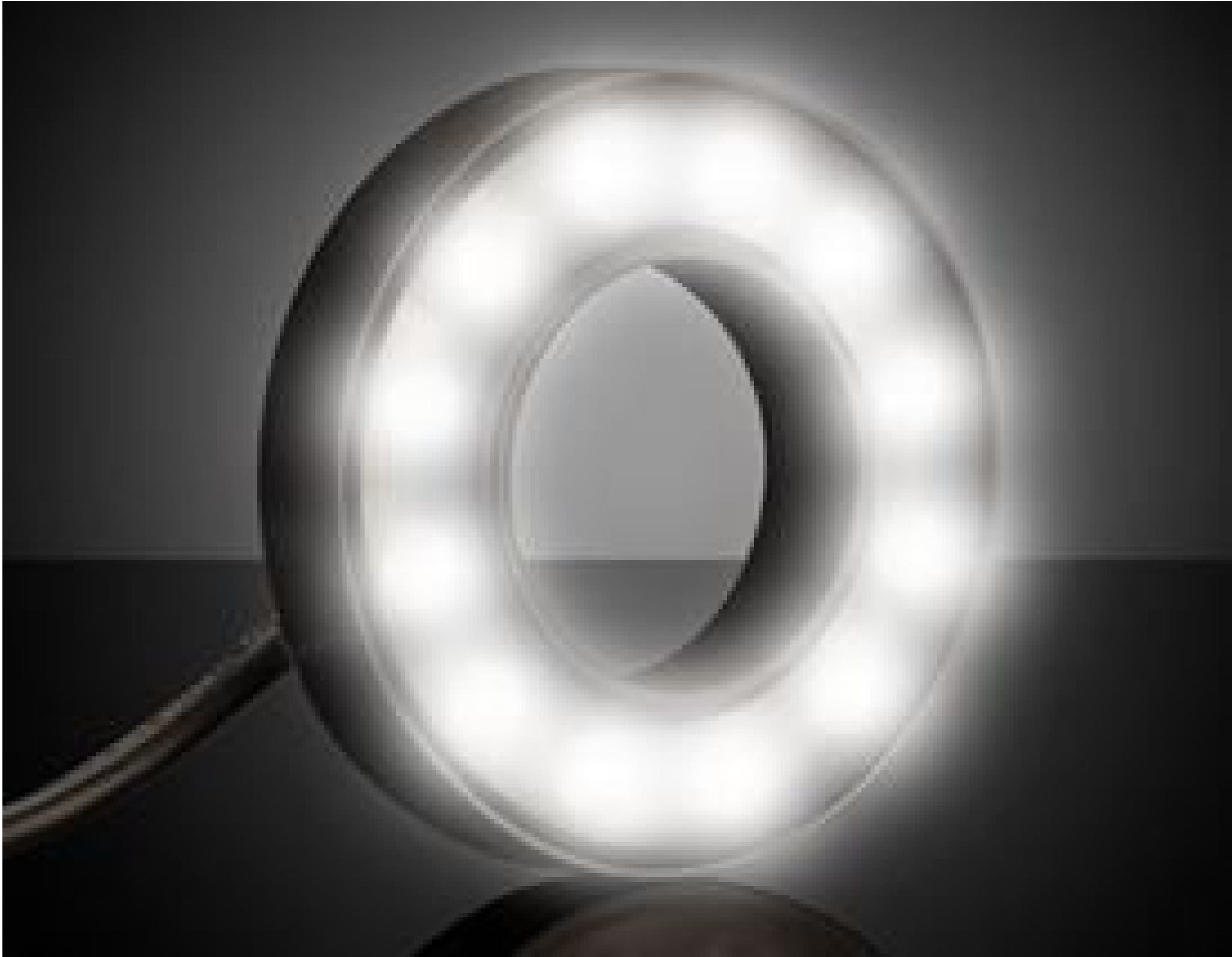

Stock #18-574 3-4 DAYS

- 1 + **€1.177,00**

ADD TO CART

Qty 1+
€1.177,00

Volume Pricing
Request Quote

⚠ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Color: White
Height (mm): 19.09
Inner Diameter (mm): 100
Input Voltage (V): 24V
Model Number:

RL208M-100WHIIC
Operating Temperature (°C): 0 - 60
Outer Diameter (mm): 145.34
Dimensions (mm): 100.00 x 145.34 x 19.09
Mounting Threads: M4 x4
Weight (g): 400
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: Not Available China: #66-855
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Maximum Input Current: 0.27A
Illumination Mode: Constant
Environmental Rating: IP50

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)