


In order to provide more accurate inventory information, please select your shipping country:

Select Your Country/Region: European Union

SUBMIT

TECHSPEC® 10mm Aluminized, Schmidt Prism

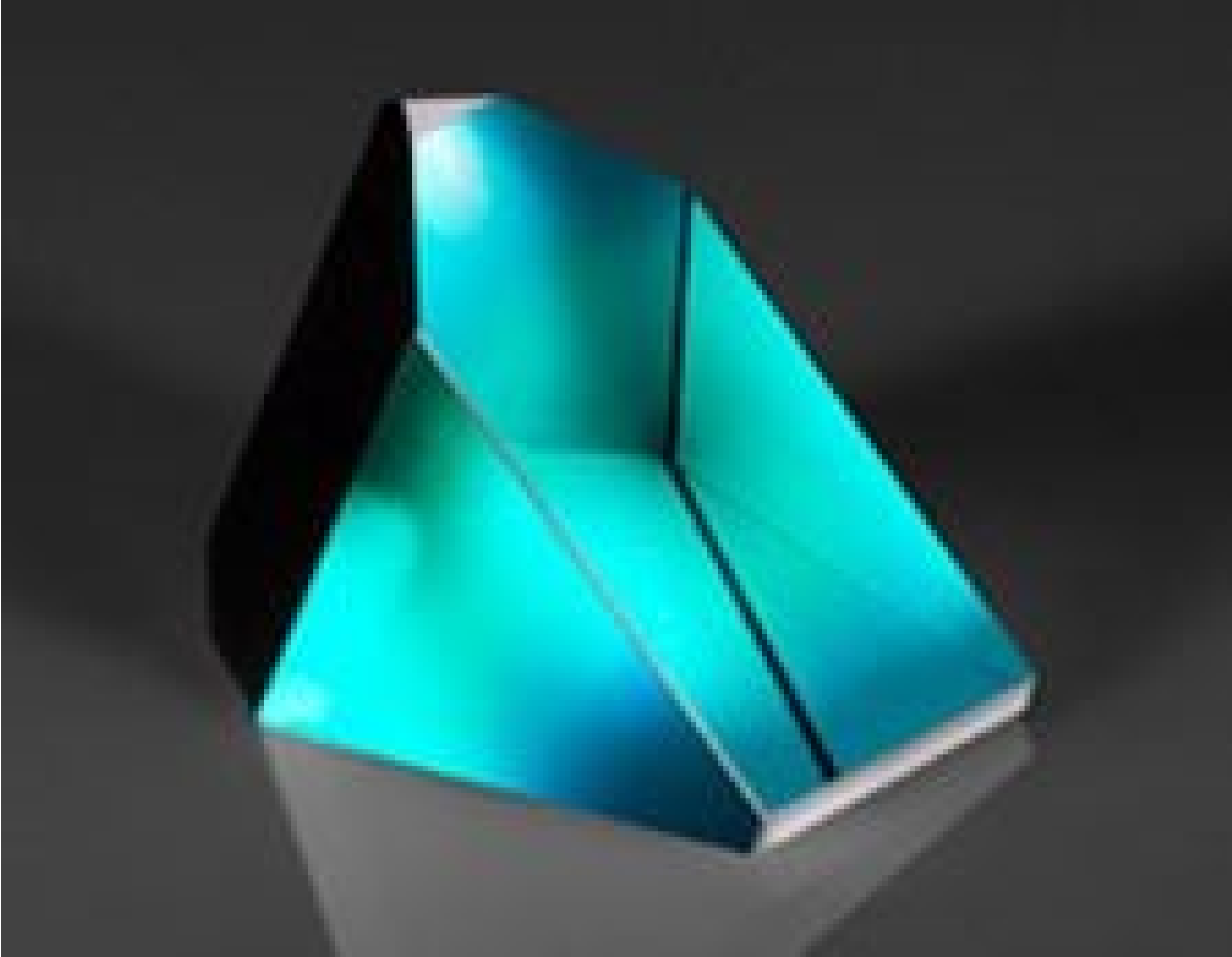

Stock #47-259 3-4 DAYS



1



€180,00

ADD TO CART

Qty 1-5

€180,00

Qty 6+

€144,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Angle Tolerance (arcsec):
5.00

Coating:
VIS 0° & Aluminized

Substrate: ☐
[N-BK7](#)

Height (mm): 16.5
Length (mm): 14.70
Surface Quality: 40-20
Type: Schmidt Prism
Dimensional Tolerance (mm): ±0.1
Bevel: Protective bevel as needed
Image Orientation: Right-Handed
Coating Specification: Entrance/Exit Faces: R _{avg} ≤0.4% @ 425 - 675nm Roof: R _{avg} >85% @ 400 - 700nm w/Black Overpaint
Ray Deviation (°): 45
Wavelength Range (nm): 400 - 700
Surface Flatness (P-V): λ/8
Width (mm): 10.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant