


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

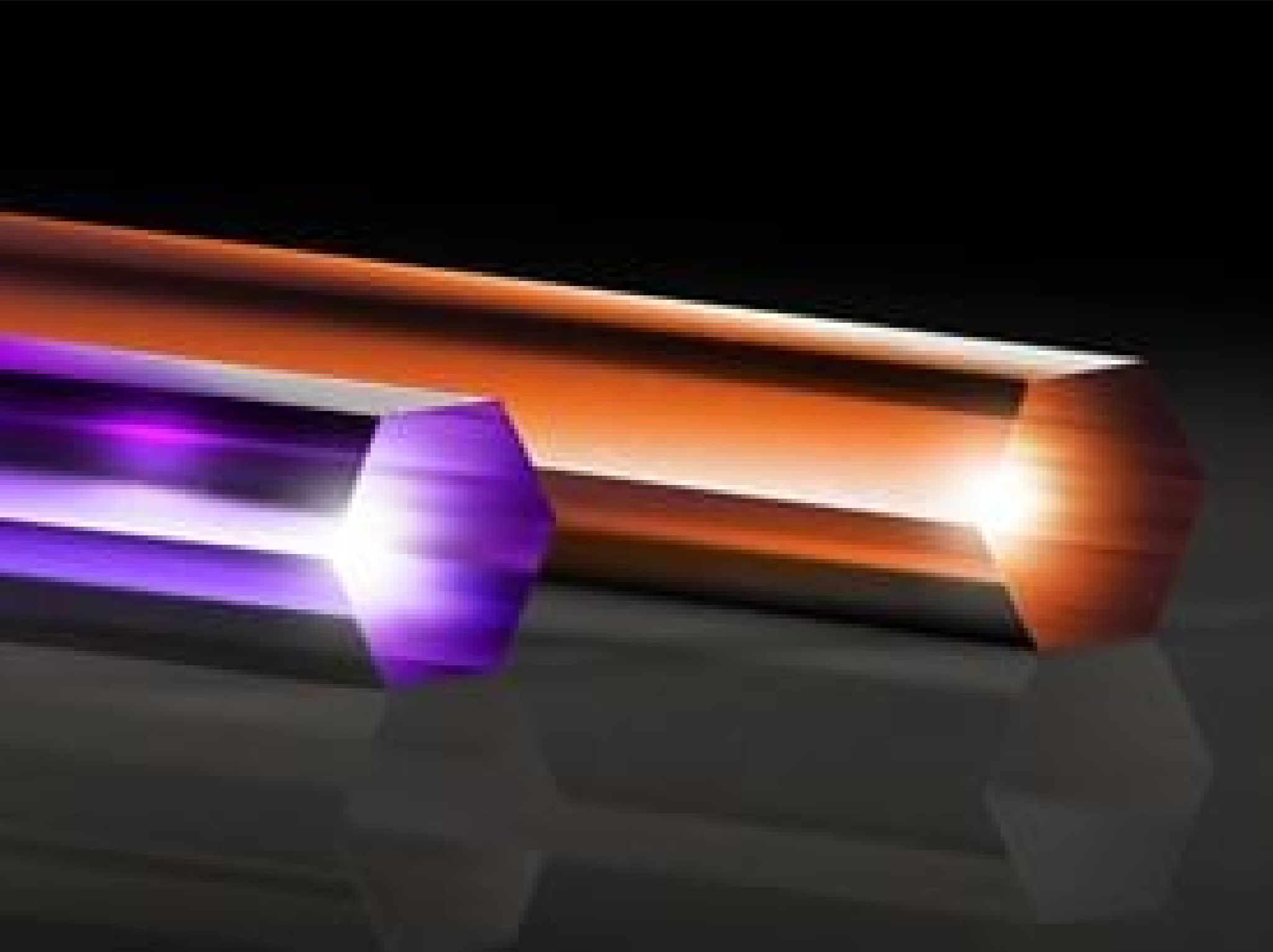

Fused Silica Light Pipe Homogenizing Rods



Stock #23-505 3-4 DAYS



1



€285,00

ADD TO CART

Qty 1-5

€285,00

Qty 6+

€228,00

Volume Pricing

[Request Quote](#)

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Coating:
VIS-NIR (400-1000nm)

Substrate:

[Fused Silica](#) (Corning 7980)

Length (mm):
75.00

Surface Quality:
60-40

Type:
Light Pipe

Entrance and Exit Aperture (mm):
10.00

Parallelism (arcmin):
5.00

Length Tolerance (mm):
±0.3

Aperture Tolerance (mm):
±0.10

Image Orientation:
Light Homogenization

Coating Specification:
R_{abs} ≤0.25% @ 880nm
R_{avg} ≤1.25% @ 400 - 870nm
R_{avg} ≤1.25% @ 890 - 1000nm

Light Source NA:
High

Wavelength Range (nm):
400 - 1000

Surface Flatness (P-V):
3λ

Damage Threshold, Reference: 
5 J/cm² @ 532nm, 10ns

#Sorting:
57.00

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)

Reach 235:
[Compliant](#)