


TECHSPEC® 10mm Dia Protected Gold, λ/20 Mirror

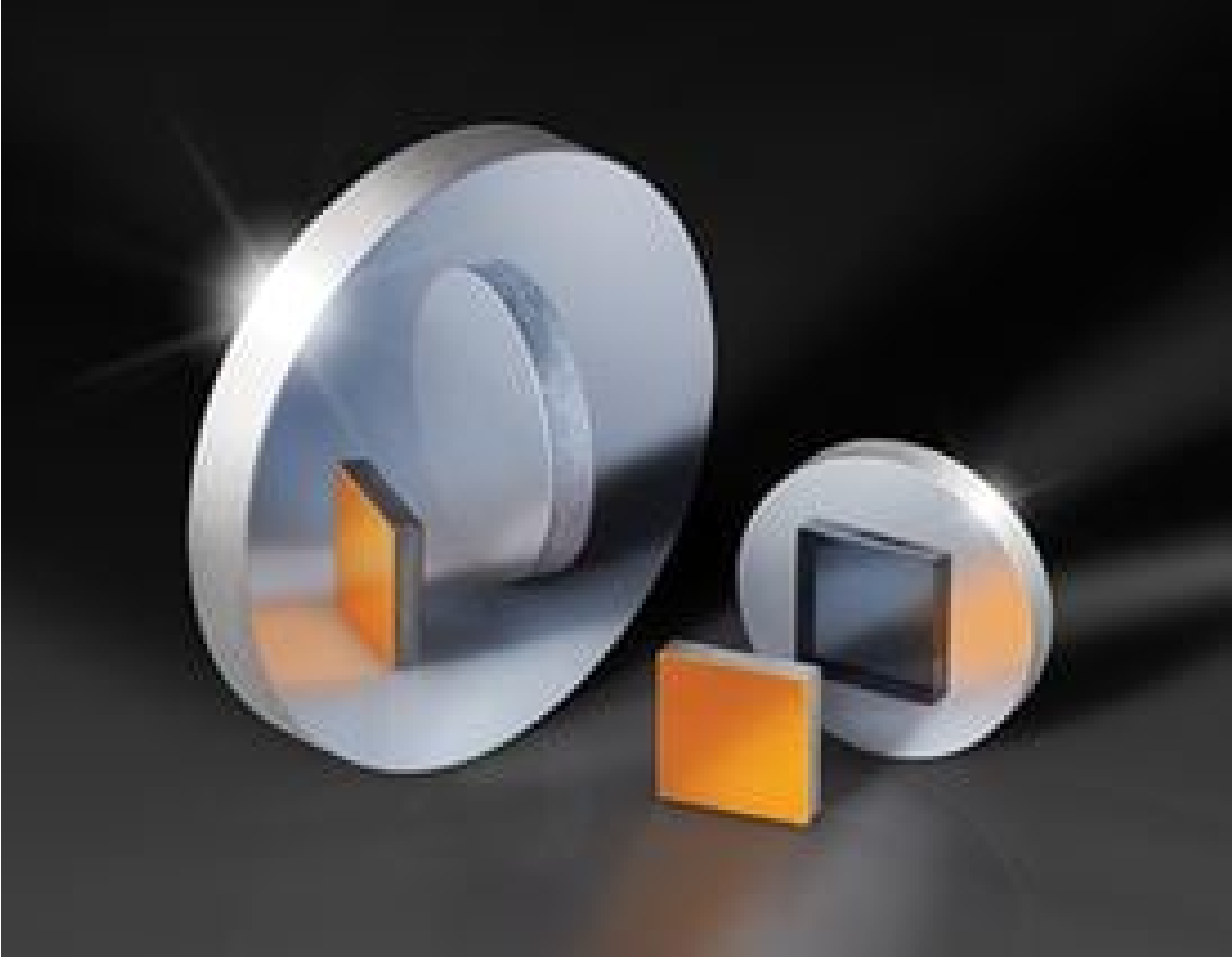

Stock **#34-370** [CONTACT US](#)

⊖ 1 ⊕ **€147,00**

ADD TO CART

Qty 1-5
€147,00

Qty 6+
€118,00

Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Diameter (mm): 10.00 +0.0/-0.20
Surface Flatness (P-V): λ/20 (flatness pre-coating)
Substrate: ☐ Fused Silica (Corning 7980)

Back Surface: Commercial Polish
Surface Quality: 20-10
Coating Specification: R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm
Coating: Protected Gold (700-10000nm)
Coating Type: Metal
Clear Aperture (%): 90.00
Edges: Ground, protective bevel as needed
Parallelism (arcsec): 30.00
Thickness (mm): 2.00 ±0.20
Type: Flat Mirror
Wavelength Range (nm): 700 - 10000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant