


10mm Dia x 20mm Focal Length, Spherical Mirror

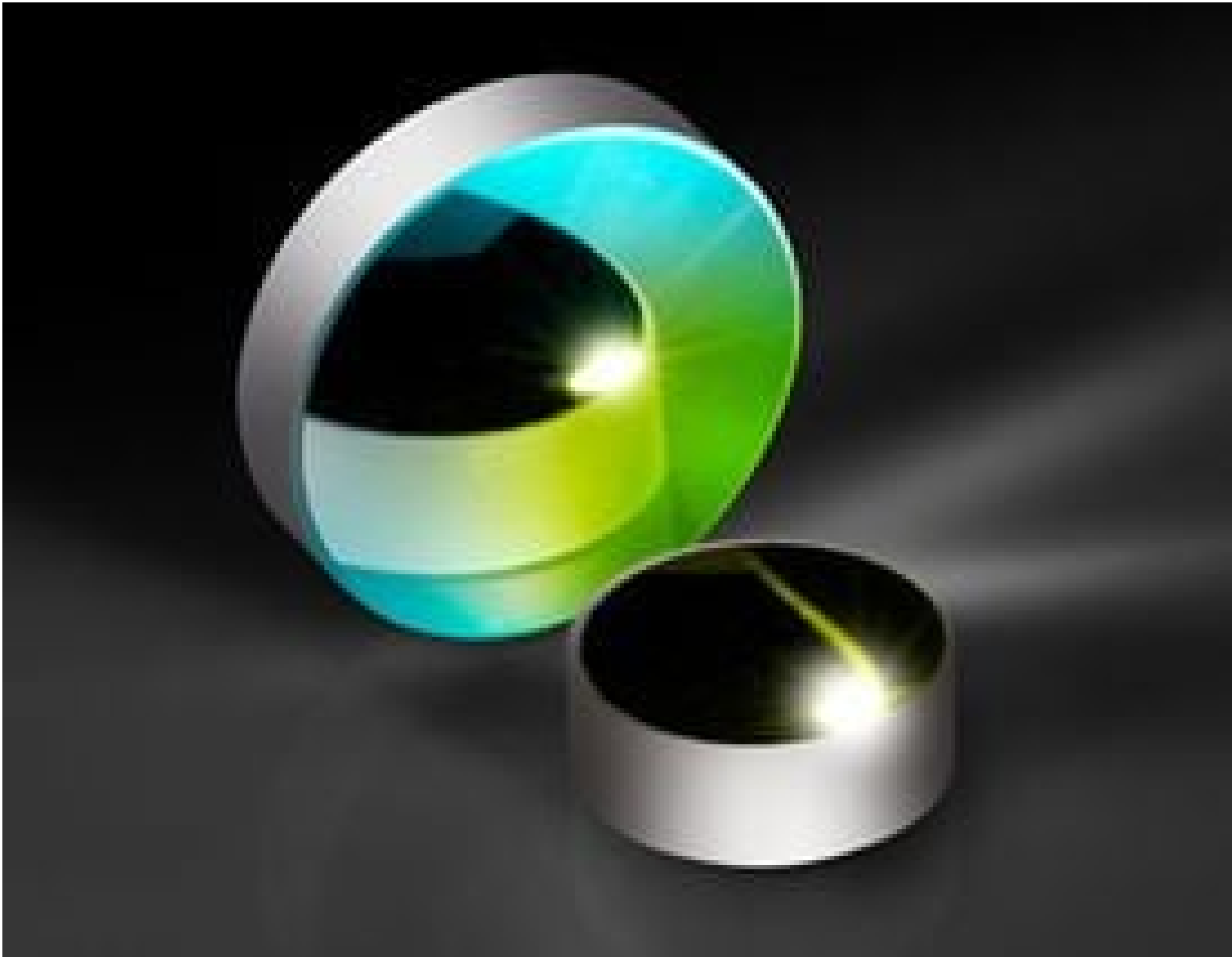

Stock **#46-232** 3-4 DAYS

- 1 + **€37,50**

ADD TO CART

Qty 1-49
€37,50
Qty 50+
€33,50
Volume Pricing
Request Quote

ⓘ Prices shown are exclusive of VAT/local taxes

Get Product Downloads

Substrate: ☐
[N-BK7](#)

Focal Length Tolerance (%):
±2

Surface Quality:
60-40

Surface Accuracy:

N4
Diameter (mm): 10.00 +0.00/-0.30
Effective Focal Length EFL (mm): 20.00
Radius of Curvature (mm): 40.00
Aperture (f/#): f/2
Coating: Protected Aluminum (400-2000nm)
Coating Specification: R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm
Coating Type: Metal
Back Surface: Ground
Center Thickness CT (mm): 3.00
Center Thickness Tolerance (mm): ±0.30
Edge Thickness ET (mm): 3.31
Edges: Ground
Radius R (mm): 40.0
Type: Spherical Mirror
Wavelength Range (nm): 400 - 2000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant