


In order to provide more accurate inventory information, please select your shipping country.

Select Your Country/Region: European Union



SUBMIT

110 Grooves/mm, 25mm Sq, Transmission Grating Beamsplitter

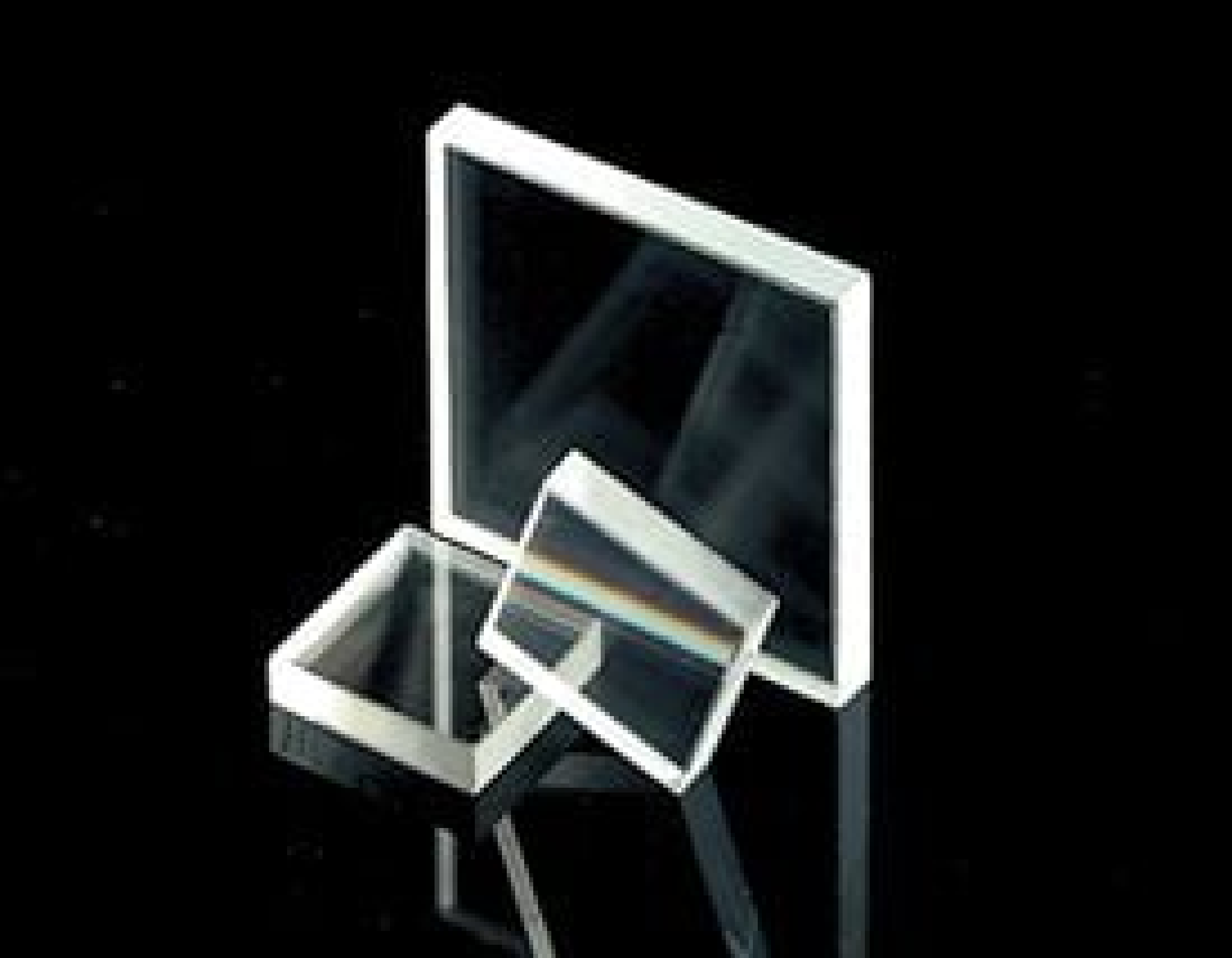

Stock #46-074 3-4 DAYS



1



€262,00

ADD TO CART

Qty 1-10
€262,00

Qty 11+
€236,00

Volume Pricing
Request Quote

Prices shown are exclusive of VAT/local taxes

Get Product Downloads



Groove Density (grooves/mm):
110

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
25.0 x 25.0 ±0.5

Construction: Blazed Grating
Length (mm): 25.00
Substrate: ☐ E270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 25.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
